



Southwire™

SIM Push™ **FITTINGS** CATALOG

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SOUTHWIRE.COM

SIMPush™ FEATURES & BENEFITS

PUSH INSTALL RIGID



NEVER THREAD CONDUIT AGAIN

- " Works with RMC, IMC, GRC, ARC and rigid stainless-steel conduit
- " Works with threaded and non-threaded conduit
- " Watertight
- " Removable & reusable with SIMPush™ removal tool
- " Maintains ground
- " IP66, NEMA 4X, direct burial

PUSH INSTALL EMT



FAST, NO TOOL INSTALLATION

- " Replaces compression and set screw fittings
- " No screws or moving parts to lose
- " Watertight couplings and connectors available
- " Removable & reusable with SIMPush™ removal tool
- " Maintains ground

PUSH INSTALL LIQUID TIGHT



FAST PUSH ON INSTALLATION

- " Watertight, concrete tight
- " Works with FLNM-B conduit
- " Removable & reusable with SIMPush™ removal tool
- " IP66, NEMA 4X, direct burial

PUSH INSTALL PVC



NO ADHESIVE NEEDED

- " Concrete tight and rated for burial
- " UV resistant resin
- " Removable & reusable with SIMPush™ removal tool
- " IP66, NEMA 4X, direct burial

SIMPush™ EMT COUPLINGS

ALUMINUM



E-CP-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Use to quickly joint two pieces of EMT conduit.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65070301	E-CP-050	1/2"	1	1.749"	1.105"	1.105"	E-RT-1P	---
65070305	E-CP-050-Q5	1/2"	5	1.749"	1.105"	1.105"	E-RT-1P	---
65070303	E-CP-050-Q20	1/2"	20	1.749"	1.105"	1.105"	E-RT-1P	---
65070401	E-CP-075	3/4"	1	1.939"	1.282"	1.282"	E-RT-1P	---
65070405	E-CP-075-Q5	3/4"	5	1.939"	1.282"	1.282"	E-RT-1P	---
65070403	E-CP-075-Q20	3/4"	20	1.939"	1.282"	1.282"	E-RT-1P	---
65070601	E-CP-100	1"	1	2.011"	1.60"	1.60"	E-RT-2P	---
65070701	E-CP-125	1-1/4"	1	2.273"	2.09"	2.09"	E-RT-2P	---
65070801	E-CP-150	1-1/2"	1	3.18"	2.35"	2.35"	E-RT-3P	---
65070901	E-CP-200	2"	1	3.772"	2.9"	2.9"	E-RT-3P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65070302	E-CP-050WT	1/2"	40	1.749"	1.105"	1.105"	E-RT-1P	YES
65070402	E-CP-075WT	3/4"	30	1.939"	1.282"	1.282"	E-RT-1P	YES
65070602	E-CP-100WT	1"	20	2.011"	1.60"	1.60"	E-RT-2P	YES
65070702	E-CP-125WT	1-1/4"	20	2.273"	2.09"	2.09"	E-RT-2P	YES
65070802	E-CP-150WT	1-1/2"	12	3.18"	2.35"	2.35"	E-RT-3P	YES
65070902	E-CP-200WT	2"	6	3.772"	2.90"	2.90"	E-RT-3P	YES

SIMPush™ FITTINGS

SIMPush™ EMT BOX CONNECTOR

ALUMINUM



E-BC-050



FEATURES

- Locknut included
- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects EMT conduit to box or enclosure.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65071001	E-BC-050	1/2"	1	1.559"	1.105"	1.105"	E-RT-1P	---
65071003	E-BC-050-Q5	1/2"	5	1.559"	1.105"	1.105"	E-RT-1P	---
65071101	E-BC-075	3/4"	1	1.673"	1.31"	1.31"	E-RT-1P	---
65071103	E-BC-075-Q5	3/4"	5	1.673"	1.31"	1.31"	E-RT-1P	---
65071201	E-BC-100	1"	1	1.84"	1.80"	1.80"	E-RT-2P	---
65071401	E-BC-125	1-1/4"	1	2.129"	2.09"	2.09"	E-RT-2P	---
65071501	E-BC-150	1-1/2"	1	2.59"	2.35"	2.35"	E-RT-3P	---
65071601	E-BC-200	2"	1	2.915"	2.90"	2.90"	E-RT-3P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65071002	E-BC-050WT	1/2"	40	1.559"	1.105"	1.105"	E-RT-1P	YES
65071102	E-BC-075WT	3/4"	30	1.673"	1.31"	1.31"	E-RT-1P	YES
65071202	E-BC-100WT	1"	20	1.84"	1.80"	1.80"	E-RT-2P	YES
65071402	E-BC-125WT	1-1/4"	20	2.129"	2.09"	2.09"	E-RT-2P	YES
65071502	E-BC-150WT	1-1/2"	15	2.59"	2.35"	2.35"	E-RT-3P	YES
65071602	E-BC-200WT	2"	8	2.915"	2.90"	2.90"	E-RT-3P	YES

SIMPush™ FITTINGS

SIMPush™ EMT ELBOW

90° - ALUMINUM



E-PE-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects 2 lengths of EMT conduit for a 90° bend.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65071701	E-PE-050	1/2"	1	2.534"	2.535"	1.105"	E-RT-1P	---
65071801	E-PE-075	3/4"	1	2.981"	2.981"	1.282"	E-RT-1P	---
65071901	E-PE-100	1"	1	3.633"	3.633"	1.60"	E-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65071702	E-PE-050WT	1/2"	25	2.534"	2.535"	1.105"	E-RT-1P	YES
65071802	E-PE-075WT	3/4"	15	2.981"	2.981"	1.282"	E-RT-1P	YES
65071902	E-PE-100WT	1"	7	3.633"	3.633"	1.60"	E-RT-2P	YES
65072002	E-PE-125WT	1-1/4"	6	4.323"	4.323"	2.09"	E-RT-2P	YES

SIMPush™ FITTINGS

SIMPush™ EMT OFFSET CONNECTOR

90° - ALUMINUM



E-PB-050



FEATURES

- Locknut included
- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects EMT conduit to box or enclosure.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65072201	E-PB-050	1/2"	1	2.51"	2.522"	1.105"	E-RT-1P	---
65072301	E-PB-075	3/4"	1	2.981"	2.882"	1.282"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65072202	E-PB-050WT	1/2"	25	2.51"	2.522"	1.105"	E-RT-1P	YES
65072302	E-PB-075WT	3/4"	15	2.981"	2.882"	1.282"	E-RT-1P	YES
65072402	E-PB-100WT	1"	7	3.677"	3.622"	1.60"	E-RT-2P	YES
65072502	E-PB-125WT	1-1/4"	6	4.515"	4.378"	2.09"	E-RT-2P	YES

SIMPush™ FITTINGS

SIMPush™ OFFSET CONNECTOR

ALUMINUM



E-OC-050



FEATURES

- Locknut included
- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects EMT conduit to box or enclosure.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65072601	E-OC-050	1/2"	1	2.292"	1.33"	1.105"	E-RT-1P	---
65072701	E-OC-075	3/4"	1	3.118"	2.036"	1.282"	E-RT-1P	---
65072801	E-OC-100	1"	1	3.32"	2.268"	1.60"	E-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65072602	E-OC-050WT	1/2"	30	2.292"	1.33"	1.105"	E-RT-1P	YES
65072702	E-OC-075WT	3/4"	18	3.118"	2.036"	1.282"	E-RT-1P	YES
65072802	E-OC-100WT	1"	12	3.32"	2.268"	1.60"	E-RT-2P	YES

SIMPush™ FITTINGS

SIMPush™ COUPLING

EMT TO FLEXIBLE METAL CONDUIT - ALUMINUM



E-FC-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly joins EMT conduit and flexible metal conduit (FMC).

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65072901	E-FC-050	1/2"	1	1.891"	1.209"	1.209"	E-RT-1P, LT-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65072902	E-FC-050W	1/2"	20	1.891"	1.209"	1.209"	E-RT-1P, LT-RT-1P	---
65073002	E-FC-075W	3/4"	15	2.056"	1.411"	1.411"	E-RT-1P, LT-RT-1P	---

SIMPush™ FITTINGS

SIMPush™ EMT ELBOW

90° INSIDE ELBOW - ALUMINUM



E-IE-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly joins EMT conduit and flexible metal conduit (FMC).

STANDARD MATERIAL

- Copper free aluminum


CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65073101	E-IE-050	1/2"	1	2.315"	1.893"	1.105"	E-RT-1P	---
65073201	E-IE-075	3/4"	1	2.684"	2.121"	1.282"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65073102	E-IE-050WT	1/2"	15	2.315"	1.893"	1.105"	E-RT-1P	YES
65073202	E-IE-075WT	3/4"	12	2.684"	2.121"	1.282"	E-RT-1P	YES

SIMPush™ EMT CONDUIT BODIES

LB TYPE - ALUMINUM

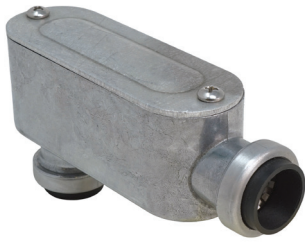

E-LB-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65074001	E-LB-050	1/2"	1	4.67"	2.521"	1.31"	E-RT-1P	---
65074101	E-LB-075	3/4"	1	5.505"	2.855"	1.53"	E-RT-1P	---
65074201	E-LB-100	1"	1	6.216"	3.151"	1.74"	E-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65074002	E-LB-050W	1/2"	8	4.67"	2.521"	1.31"	E-RT-1P	---
65074102	E-LB-075W	3/4"	6	5.505"	2.855"	1.53"	E-RT-1P	---
65074202	E-LB-100W	1"	4	6.216"	3.151"	1.74"	E-RT-2P	---
65074302	E-LB-125W	1-1/4"	3	8.064"	4.212"	2.49"	E-RT-2P	---
65074402	E-LB-150W	1-1/2"	3	8.335"	4.633"	2.49"	E-RT-3P	---
65074502	E-LB-200W	2"	1	10.756"	5.478"	3.10"	E-RT-3P	---

SIMPush™ FITTINGS

SIMPush™ EMT CONDUIT BODIES

C TYPE - ALUMINUM



E-CB-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum


CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65076001	E-CB-050	1/2"	1	5.47"	1.659"	1.31"	E-RT-1P	---
65076101	E-CB-075	3/4"	1	6.339"	1.899"	1.53"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65076002	E-CB-050W	1/2"	8	5.47"	1.659"	1.31"	E-RT-1P	---
65076102	E-CB-075W	3/4"	6	6.339"	1.899"	1.53"	E-RT-1P	---
65076302	E-CB-100W	1"	6	6.862"	2.159"	1.74"	E-RT-2P	---
65076402	E-CB-125W	1-1/4"	4	8.898"	3.109"	2.49"	E-RT-2P	---
65076502	E-CB-150W	1-1/2"	4	9.44"	3.109"	2.49"	E-RT-3P	---

SIMPUSH™ EMT CONDUIT BODIES

LR TYPE - ALUMINUM

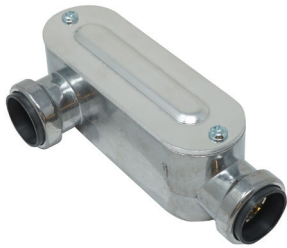

E-LR-050W



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
CONTRACTOR PACK								
65074602	E-LR-050W	1/2"	8	4.67"	1.659"	2.165"	E-RT-1P	---
65074802	E-LR-075W	3/4"	6	5.505"	1.899"	2.487"	E-RT-1P	---
65074902	E-LR-100W	1"	4	6.116"	2.159"	2.748"	E-RT-2P	---
65075002	E-LR-125W	1-1/4"	4	8.064"	3.109"	3.589"	E-RT-2P	---
65075102	E-LR-150W	1-1/2"	3	8.335"	3.109"	4.01"	E-RT-3P	---
65075202	E-LR-200W	2"	1	10.756"	3.669"	4.964"	E-RT-3P	---

SIMPush™ EMT CONDUIT BODIES

LL TYPE - ALUMINUM



E-LL-050W



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
CONTRACTOR PACK								
65075302	E-LL-050W	1/2"	8	4.67"	1.659"	2.165"	E-RT-1P	---
65075502	E-LL-075W	3/4"	6	5.505"	1.899"	2.487"	E-RT-1P	---
65075602	E-LL-100W	1"	4	6.116"	2.159"	2.748"	E-RT-2P	---
65075702	E-LL-125W	1-1/4"	4	8.064"	3.109"	3.589"	E-RT-2P	---
65075802	E-LL-150W	1-1/2"	3	8.335"	3.109"	4.016"	E-RT-3P	---
65075902	E-LL-200W	2"	1	10.756"	3.669"	4.925"	E-RT-3P	---

SIMPush™ EMT CONDUIT BODIES

T TYPE - ALUMINUM



E-TB-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BOX	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65073301	E-TB-050	1/2"	1	5.47"	2.165"	1.634"	E-RT-1P	---
65073401	E-TB-075	3/4"	1	6.34"	2.48"	1.874"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65073302	E-TB-050W	1/2"	4	5.47"	2.165"	1.634"	E-RT-1P	---
65073402	E-TB-075W	3/4"	4	6.34"	2.48"	1.874"	E-RT-1P	---
65073502	E-TB-100W	1"	4	6.862"	2.726"	2.134"	E-RT-2P	---
65073602	E-TB-125W	1-1/4"	4	8.898"	3.589"	3.104"	E-RT-2P	---
65073702	E-TB-150W	1-1/2"	1	9.44"	4.01"	3.104"	E-RT-3P	---
65073802	E-TB-200W	2"	1	12.052"	4.906"	3.664"	E-RT-3P	---

SIMPush™ EMT WATERTIGHT COUPLING

ALUMINUM



EW-CP-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects 2 lengths of EMT in water tight applications.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65076601	EW-CP-050	1/2"	1	1.956"	1.209"	1.209"	E-RT-1P	---
65076701	EW-CP-075	3/4"	1	2.075"	1.411"	1.411"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65076602	EW-CP-050WT	1/2"	30	1.956"	1.209"	1.209"	EW-RT-1P	YES
65076702	EW-CP-075WT	3/4"	20	2.075"	1.411"	1.411"	EW-RT-1P	YES
65076802	EW-CP-100WT	1"	16	2.201"	1.779"	1.779"	EW-RT-100	YES

SIMPush™ EMT WATERTIGHT CONNECTOR

ALUMINUM



EW-CP-050



FEATURES

- No tool installation
- Reusable, test to 100 removal cycles
- Replaces traditional set screw and compression fittings
- Maintains grounding path

APPLICATIONS

- Quickly connects EMT conduit to box or enclosure in watertight applications.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- cULus Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65076901	EW-BC-050	1/2"	1	1.663"	1.209"	1.209"	E-RT-1P	---
65077101	EW-BC-075	3/4"	1	1.663"	1.411"	1.411"	E-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65076902	EW-BC-050WT	1/2"	30	1.663"	1.209"	1.209"	EW-RT-1P	YES
65077102	EW-BC-075WT	3/4"	20	1.663"	1.411"	1.411"	EW-RT-1P	YES
65077202	EW-BC-100WT	1"	12	2.009"	1.779"	1.779"	EW-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ RIGID COUPLINGS

ALUMINUM



R-CP-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Used to quickly join two pieces of threadless Rigid conduit or IMC.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65077301	R-CP-050	1/2"	1	3.14"	1.299"	1.299"	R-RT-1P	---
65077303	R-CP-050-Q5	1/2"	5	3.14"	1.299"	1.299"	R-RT-1P	---
65077401	R-CP-075	3/4"	1	3.19"	1.499"	1.499"	R-RT-1P	---
65077403	R-CP-075-Q5	3/4"	5	3.19"	1.499"	1.499"	R-RT-1P	---
65077501	R-CP-100	1"	1	3.57"	1.795"	1.795"	R-RT-2P	---
65077601	R-CP-125	1-1/4"	1	4.078"	2.286"	2.286"	R-RT-2P	---
65077701	R-CP-150	1-1/2"	1	4.158"	2.56"	2.56"	R-RT-3P	---
65077801	R-CP-200	2"	1	4.408"	3.06"	3.06"	R-RT-3P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65077302	R-CP-050WT	1/2"	30	3.14"	1.299"	1.299"	R-RT-1P	YES
65077402	R-CP-075WT	3/4"	20	3.19"	1.499"	1.499"	R-RT-1P	YES
65077502	R-CP-100WT	1"	18	3.57"	1.795"	1.795"	R-RT-2P	YES
65077602	R-CP-125WT	1-1/4"	12	4.078"	2.286"	2.286"	R-RT-2P	YES
65077702	R-CP-150WT	1-1/2"	9	4.158"	2.56"	2.56"	R-RT-3P	YES
65077802	R-CP-200WT	2"	4	4.408"	3.06"	3.06"	R-RT-3P	YES

SIMPush™ FITTINGS

SIMPush™ RIGID CONNECTORS

ALUMINUM



R-BC-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Used to quickly connect threadless Rigid/IMC to a box or enclosure.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65077901	R-BC-050	1/2"	1	2.235"	1.298"	1.298"	R-RT-1P	---
65078001	R-BC-075	3/4"	1	2.264"	1.498"	1.498"	R-RT-1P	---
65078101	R-BC-100	1"	1	2.64"	1.795"	1.795"	R-RT-2P	---
65078201	R-BC-125	1-1/4"	1	3.0"	2.29"	2.29"	R-RT-2P	---
65078301	R-BC-150	1-1/2"	1	3.436"	2.566"	2.566"	R-RT-3P	---
65078401	R-BC-200	2"	1	3.60"	3.06"	3.06"	R-RT-3P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65077902	R-BC-050WT	1/2"	35	2.235"	1.298"	1.298"	R-RT-1P	YES
65078002	R-BC-075WT	3/4"	25	2.264"	1.498"	1.498"	R-RT-1P	YES
65078102	R-BC-100WT	1"	15	2.64"	1.795"	1.795"	R-RT-2P	YES
65078202	R-BC-125WT	1-1/4"	10	3.0"	2.29"	2.29"	R-RT-2P	YES
65078302	R-BC-150WT	1-1/2"	6	3.436"	2.566"	2.566"	R-RT-3P	YES
65078402	R-BC-200WT	2"	5	3.6"	3.06"	3.06"	R-RT-3P	YES

SIMPush™ FITTINGS

SIMPush™ RIGID PULL ELBOW ALUMINUM



R-PE-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Quickly connects threaded Rigid/IMC conduit to a box or enclosure for a 90° bend.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65078501	R-PE-050	1/2"	1	3.16"	3.16"	1.298"	R-RT-1P	---
65078601	R-PE-075	3/4"	1	3.549"	3.549"	1.653"	R-RT-1P	---
65078701	R-PE-100	1"	1	4.433"	4.433"	1.93"	R-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65078502	R-PE-050WT	1/2"	18	3.16"	3.16"	1.298"	R-RT-1P	YES
65078602	R-PE-075WT	3/4"	8	3.549"	3.549"	1.653"	R-RT-1P	YES
65078702	R-PE-100WT	1"	6	4.433"	4.433"	1.93"	R-RT-2P	YES
65078902	R-PE-125WT	1-1/4"	4	5.354"	5.354"	2.42"	R-RT-2P	YES

SIMPush™ RIGID TO BOX - ALUMINUM PULL ELBOW CONNECTORS



R-PB-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Quickly connects threaded Rigid/IMC conduit to a box or enclosure for a 90° bend.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65079001	R-PB-050	1/2"	1	3.159"	3.159"	1.298"	R-RT-1P	---
65079101	R-PB-075	3/4"	1	3.54"	3.54"	1.653"	R-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65079002	R-PB-050WT	1/2"	12	3.159"	3.159"	1.298"	R-RT-1P	YES
65079102	R-PB-075WT	3/4"	8	3.54"	3.54"	1.653"	R-RT-1P	YES
65079202	R-PB-100WT	1"	6	4.419"	4.419"	1.929"	R-RT-2P	YES
65079302	R-PB-125WT	1-1/4"	4	5.35"	5.35"	2.42"	R-RT-2P	YES

SIMPush™ FITTINGS

SIMPush™ RIGID REDUCER COUPLING

ALUMINUM



R-RD-075-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Used to quickly transition one size of Rigid or IMC pipe size to another enclosure for a 90° bend.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65079501	R-RD-075-050	3/4"-1/2"	1	3.28"	1.653"	1.653"	R-RT-1P	---
65079701	R-RD-100-050	1"-1/2"	1	3.51"	1.411"	1.411"	R-RT-1P, R-RT-2P	---
65079801	R-RD-100-075	1"-3/4"	1	3.55"	1.929"	1.929"	R-RT-1P, R-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65079502	R-RD-075-050W	3/4"-1/2"	20	3.28"	1.653"	1.653"	R-RT-1P	---
65079702	R-RD-100-050W	1"-1/2"	20	3.51"	1.411"	1.411"	R-RT-1P, R-RT-2P	---
65079802	R-RD-100-075W	1"-3/4"	10	3.55"	1.929"	1.929"	R-RT-1P, R-RT-2P	-
65079902	R-RD-125-100W	1-1/4"-1"	12	4.03"	2.249"	2.249"	R-RT-2P	---
65080002	R-RD-150-100W	1-1/2"-1"	12	4.056"	2.522"	2.522"	R-RT-2P, R-RT-3P	---

SIMPush™ FITTINGS

SIMPush™ RIGID CONDUIT BODIES

T TYPE - ALUMINUM



R-TB-050



FEATURES

- Gasket NBR Nitrile
- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65080101	R-TB-050	1/2"	1	6.801"	2.208"	2.83"	R-RT-1P	---
65080201	R-TB-075	3/4"	1	7.56"	2.463"	3.09"	R-RT-1P	---
65080301	R-TB-100	1"	1	8.60"	2.969"	3.328"	R-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65080102	R-TB-050W	1/2"	4	6.801"	2.208"	2.83"	R-RT-1P	---
65080202	R-TB-075W	3/4"	4	7.56"	2.463"	3.09"	R-RT-1P	---
65080302	R-TB-100W	1"	4	8.60"	2.969"	3.328"	R-RT-2P	---
65080502	R-TB-125W	1-1/4"	3	10.82"	3.976"	4.53"	R-RT-2P	---
65080602	R-TB-150W	1-1/2"	3	10.88"	4.192"	4.56"	R-RT-3P	---
65080702	R-TB-200W	2"	1	12.99"	5.041"	5.31"	R-RT-3P	---

SIMPush™ FITTINGS

SIMPush™ RIGID CONDUIT BODIES

LB TYPE - ALUMINUM



R-LB-050



FEATURES

- Gasket NBR Nitrile
- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65080801	R-LB-050	1/2"	1	5.336"	1.31"	3.06"	R-RT-1P	---
65080901	R-LB-075	3/4"	1	6.0"	1.53"	3.34"	R-RT-1P	---
65081001	R-LB-100	1"	1	6.81"	1.74"	3.83"	R-RT-2P	---
65081101	R-LB-125	1-1/4"	1	8.89"	2.49"	5.03"	R-RT-2P	---
65081301	R-LB-150	1-1/2"	1	8.84"	2.49"	5.06"	R-RT-3P	---
65081401	R-LB-200	2"	1	11.05"	3.1"	5.76"	R-RT-3P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65080802	R-LB-050W	1/2"	4	5.336"	1.31"	3.06"	R-RT-1P	---
65080902	R-LB-075W	3/4"	4	6.0"	1.53"	3.34"	R-RT-1P	---
65081002	R-LB-100W	1"	4	6.81"	1.74"	3.83"	R-RT-2P	---
65081102	R-LB-125W	1-1/4"	4	8.89"	2.49"	5.03"	R-RT-2P	---
65081302	R-LB-150W	1-1/2"	4	8.84"	2.49"	5.06"	R-RT-3P	---
65081402	R-LB-200W	2"	1	11.05"	3.1"	5.76"	R-RT-3P	---

SIMPush™ FITTINGS

SIMPush™ RIGID CONDUIT BODIES

LR TYPE - ALUMINUM



R-LR-050



FEATURES

- Gasket NBR Nitrile
- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65081501	R-LR-050	1/2"	1	5.34"	2.83"	1.40"	R-RT-1P	---
65081601	R-LR-075	3/4"	1	6.11"	3.09"	1.64"	R-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65081502	R-LR-050W	1/2"	4	5.34"	2.83"	1.40"	R-RT-1P	---
65081602	R-LR-075W	3/4"	4	6.11"	3.09"	1.64"	R-RT-1P	---
65081702	R-LR-100W	1"	4	6.99"	3.33"	1.90"	R-RT-2P	---
65081802	R-LR-125W	1-1/4"	3	9.02"	4.53"	2.85"	R-RT-2P	---
65081902	R-LR-150W	1-1/2"	3	9.05"	4.56"	2.85"	R-RT-3P	---

SIMPush™ FITTINGS

SIMPUSH™ RIGID CONDUIT BODIES

LL TYPE - ALUMINUM



R-LL-050



FEATURES

- Gasket NBR Nitrile
- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65082101	R-LL-050	1/2"	1	5.34"	2.83"	1.40"	R-RT-1P	---
65082201	R-LL-075	3/4"	1	6.11"	3.09"	1.64"	R-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65082102	R-LL-050W	1/2"	4	5.34"	2.83"	1.40"	R-RT-1P	---
65082202	R-LL-075W	3/4"	4	6.11"	3.09"	1.64"	R-RT-1P	---
65082302	R-LL-100W	1"	4	6.99"	3.33"	1.90"	R-RT-2P	---
65082402	R-LL-125W	1-1/4"	3	9.02"	4.53"	2.85"	R-RT-2P	---
65082502	R-LL-150W	1-1/2"	3	9.05"	4.56"	2.85"	R-RT-3P	---

SIMPUSH™ FITTINGS

SIMPush™ RIGID CONDUIT BODIES

C TYPE - ALUMINUM



R-CB-050

FEATURES

- Gasket NBR Nitrile
- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Allows access for inspection, pulling and maintenance.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65082601	R-CB-050	1/2"	1	6.80"	1.31"	1.30"	R-RT-1P	---
65082701	R-CB-075	3/4"	1	7.56"	1.53"	1.499"	R-RT-1P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65082602	R-CB-050W	1/2"	8	6.80"	1.31"	1.3"	R-RT-1P	---
65082702	R-CB-075W	3/4"	6	7.56"	1.53"	1.499"	R-RT-1P	---
65082802	R-CB-100W	1"	6	8.605"	1.74"	1.70"	R-RT-2P	---
65082902	R-CB-125W	1-1/4"	4	10.818"	2.49"	2.29"	R-RT-2P	---

SIMPush™ FITTINGS

SIMPush™ RIGID OFFSET NIPPLE CONNECTOR

ALUMINUM



R-ON-050



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Used to offset Rigid/IMC conduit when entering a box or enclosure.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65083001	R-ON-050	1/2"	1	3.018"	1.298"	2.221"	R-RT-1P	---
65083101	R-ON-075	3/4"	1	3.775"	1.653"	2.436"	R-RT-1P	---
65083201	R-ON-100	1"	1	4.132"	1.929"	2.94"	R-RT-2P	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65083002	R-ON-050WT	1/2"	12	3.018"	1.298"	2.221"	R-RT-1P	YES
65083102	R-ON-075WT	3/4"	10	3.775"	1.653"	2.436"	R-RT-1P	YES
65083202	R-ON-100WT	1"	7	4.132"	1.929"	2.94"	R-RT-2P	YES
65083302	R-ON-125WT	1-1/4"	4	4.374"	2.42"	3.104"	R-RT-2P	YES

SIMPush™ COMBINATION COUPLINGS

EMT TO RIGID - ALUMINUM



R-E-075W



FEATURES

- No need to thread conduit
- Works with threaded or non-threaded RMC, IMC, GRC, ARC and rigid stainless steel
- Copper free aluminum, powder coat
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Connects EMT conduit to threaded Rigid/IMC conduit.

STANDARD MATERIAL

- Copper free aluminum

CERTIFICATIONS

- UL Listed, 514B, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
CONTRACTOR PACK								
65079402	R-E-075W	3/4"	15	2.707"	1.653"	1.653"	R-RT-1P, E-RT-1P	---

SIMPush™ FITTINGS

SIMPush™ NON-METALLIC LIQUID TIGHT COUPLINGS

PVC



LTNM-CP-050



FEATURES

- Simple fast push on installation
- Works with Type B nonmetallic flexible liquid tight conduit
- UV resistant PVC
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Used to quickly join two pieces of non-metallic liquidtight conduit.

STANDARD MATERIAL

- PVC

CERTIFICATIONS

- cULus Listed, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
67599601	LTNM-CP-050	1/2"	1	2.325"	1.419"	1.419"	PLT-RT-1P	---
67599701	LTNM-CP-075	3/4"	1	2.437"	1.653"	1.653"	PLT-RT-1P	---
67599801	LTNM-CP-100	1"	1	2.543"	1.929"	1.929"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
67599602	LTNM-CP-050WT	1/2"	30	2.325"	1.419"	1.419"	PLT-RT-1P	YES
67599702	LTNM-CP-075WT	3/4"	24	2.437"	1.653"	1.653"	PLT-RT-1P	YES
67599802	LTNM-CP-100WT	1"	20	2.543"	1.929"	1.929"	PLT-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ NON-METALLIC LIQUID-TIGHT CONNECTOR

PVC



LTNM-BC-050



FEATURES

- Simple fast push on installation
- Works with Type B nonmetallic flexible liquid tight conduit
- UV resistant PVC
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Quickly connects nonmetallic liquidtight to box or enclosure.

STANDARD MATERIAL

- PVC

CERTIFICATIONS

- cULus Listed, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
67599901	LTNM-BC-050	1/2"	1	1.797"	1.425"	1.425"	PLT-RT-1P	---
67599903	LTNM-BC-050-Q5	1/2"	5	1.797"	1.425"	1.425"	PLT-RT-1P	---
67600001	LTNM-BC-075	3/4"	1	1.836"	1.653"	1.653"	PLT-RT-1P	---
67600003	LTNM-BC-075-Q5	3/4"	5	1.836"	1.653"	1.653"	PLT-RT-1P	---
67600101	LTNM-BC-100	1"	1	1.941"	1.929"	1.929"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
67599902	LTNM-BC-050WT	1/2"	35	1.797"	1.425"	1.425"	PLT-RT-1P	YES
67600002	LTNM-BC-075WT	3/4"	30	1.836"	1.653"	1.653"	PLT-RT-1P	YES
67600102	LTNM-BC-100WT	1"	20	2.20"	1.929"	1.929"	PLT-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ NON-METALLIC LIQUID-TIGHT 90° CONNECTOR

PVC



LTNM-90-050



FEATURES

- Simple fast push on installation
- Works with Type B nonmetallic flexible liquid tight conduit
- UV resistant PVC
- Reusable, tested for up to 100 removal cycles
- Watertight, concrete tight, direct burial rated

APPLICATIONS

- Quickly connects nonmetallic liquidtight to box or enclosure at 90° angle.

STANDARD MATERIAL

- PVC

CERTIFICATIONS

- cULus Listed, IP66, NEMA 4X

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
67600201	LTNM-90-050	1/2"	1	2.735"	1.419"	2.735"	PLT-RT-1P	---
67600203	LTNM-90-050-Q5	1/2"	5	2.735"	1.419"	2.735"	PLT-RT-1P	---
67600301	LTNM-90-075	3/4"	1	2.985"	1.653"	2.985"	PLT-RT-1P	---
67600401	LTNM-90-100	1"	1	3.254"	1.929"	3.254"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
67600202	LTNM-90-050WT	1/2"	24	2.735"	1.419"	2.735"	PLT-RT-1P	YES
67600302	LTNM-90-075WT	3/4"	15	2.985"	1.653"	2.985"	PLT-RT-1P	YES
67600402	LTNM-90-100WT	1"	9	3.254"	1.929"	3.254"	PLT-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ PVC COUPLING

SCHEDULE 40 & 80



P-CP-050



FEATURES

- No adhesive needed
- Works with schedule 40 and schedule 80 UL Listed PVC conduit and well as HDPE cable in conduit
- Reusable, tested for up to 100 removal cycles
- UV resistant PVC
- IP66, NEMA 4X, watertight, concrete tight, rated for direct burial

APPLICATIONS

- Quickly connects two pieces of PVC conduit.

STANDARD MATERIAL

- Schedule 40 & 80

CERTIFICATIONS

- UL Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65083401	P-CP-050	1/2"	1	2.325"	1.419"	1.419"	PLT-RT-1P	---
65083403	P-CP-050-Q5	1/2"	5	2.325"	1.419"	1.419"	PLT-RT-1P	---
65083501	P-CP-075	3/4"	1	2.437"	1.653"	1.653"	PLT-RT-1P	---
65083503	P-CP-075-Q5	3/4"	5	2.437"	1.653"	1.653"	PLT-RT-1P	---
65083601	P-CP-100	1"	1	2.543"	1.929"	1.929"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65083402	P-CP-050WT	1/2"	30	2.325"	1.419"	1.419"	PLT-RT-1P	YES
65083502	P-CP-075WT	3/4"	24	2.437"	1.653"	1.653"	PLT-RT-1P	YES
65083602	P-CP-100WT	1"	20	2.543"	1.929"	1.929"	PLT-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ PVC CONNECTOR/MALE ADAPTER

SCHEDULE 40 & 80



P-MA-050



FEATURES

- No adhesive needed
- Works with schedule 40 and schedule 80 UL Listed PVC conduit and well as HDPE cable in conduit
- Reusable, tested for up to 100 removal cycles
- UV resistant PVC
- IP66, NEMA 4X, watertight, concrete tight, rated for direct burial

APPLICATIONS

- Quickly connects PVC conduit to box or enclosure.

STANDARD MATERIAL

- Schedule 40 & 80

CERTIFICATIONS

- UL Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
65083701	P-MA-050	1/2"	1	1.797"	1.425"	1.425"	PLT-RT-1P	---
65083703	P-MA-050-Q5	1/2"	1	1.797"	1.425"	1.425"	PLT-RT-1P	---
65083901	P-MA-075	3/4"	1	1.836"	1.653"	1.653"	PLT-RT-1P	---
65083903	P-MA-075-Q5	3/4"	1	1.836"	1.653"	1.653"	PLT-RT-1P	---
65084001	P-MA-100	1"	1	1.941"	1.929"	1.929"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
65083702	P-MA-050WT	1/2"	40	1.797"	1.425"	1.425"	PLT-RT-1P	YES
65083902	P-MA-075WT	3/4"	30	1.836"	1.653"	1.653"	PLT-RT-1P	YES
65084002	P-MA-100WT	1"	20	1.941"	1.929"	1.929"	PLT-RT-100	YES

SIMPush™ FITTINGS

SIMPush™ PVC 90° CONNECTOR

SCHEDULE 40 & 80



P-90-050



FEATURES

- No adhesive needed
- Works with schedule 40 and schedule 80 UL Listed PVC conduit and well as HDPE cable in conduit
- Reusable, tested for up to 100 removal cycles
- UV resistant PVC
- IP66, NEMA 4X, watertight, concrete tight, rated for direct burial

APPLICATIONS

- Quickly connects PVC conduit to box or enclosure.

STANDARD MATERIAL

- Schedule 40 & 80

CERTIFICATIONS

- UL Listed

STOCK #	MODEL #	SIZE	QUANTITY PER BAG	OVERALL PRODUCT DIMENSIONS			ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
				HEIGHT	WEIGHT	LENGTH		
RETAIL POLY-BAG PACKAGING								
67599301	P-90-050	1/2"	1	2.735"	1.419"	2.735"	PLT-RT-1P	---
67599401	P-90-075	3/4"	1	2.985"	1.653"	2.985"	PLT-RT-1P	---
67599501	P-90-100	1"	1	3.254"	1.929"	3.254"	PLT-RT-100	---
STOCK #	MODEL #	SIZE	QUANTITY PER BOX	HEIGHT	WEIGHT	LENGTH	ASSOCIATED REMOVAL TOOL MODEL #	REMOVAL TOOL INCLUDED
CONTRACTOR PACK								
67599302	P-90-050WT	1/2"	15	2.735"	1.419"	2.735"	PLT-RT-1P	YES
67599402	P-90-075WT	3/4"	10	2.985"	1.653"	2.985"	PLT-RT-1P	YES
67599502	P-90-100WT	1"	8	3.254"	1.929"	3.254"	PLT-RT-100	YES

SIMPush™ REMOVAL TOOL



E-RT-1P

FEATURES

- All removal tools are sold individually or in pairs

APPLICATIONS

- Quickly removes SIMPush™ fitting (reference below chart).

STOCK #	MODEL #	DESCRIPTION	OVERALL PRODUCT DIMENSIONS		
			HEIGHT	WEIGHT	LENGTH
67602502	E-RT-1P	1/2" & 3/4" EMT, PUSH CONNECT REMOVAL TOOL	1.714"	2.226"	1.697"
67602503	E-RT-2P	1" & 1-1/4" EMT, PUSH CONNECT REMOVAL TOOL	2.467"	3.312"	2.498"
67602504	E-RT-3P	1-1/2" & 2" EMT, PUSH CONNECT REMOVAL TOOL	3.552"	4.625"	3.581"
67603202	EW-RT-1P	1/2" & 3/4" EMT WATERTIGHT, PUSH CONNECT REMOVAL TOOL	1.714"	2.226"	1.697"
67603201	EW-RT-100	1" EMT WATERTIGHT, PUSH CONNECT REMOVAL TOOL	2.056"	2.715"	1.141"
67601802	R-RT-1P	1/2" & 3/4" RIGID & IMC, PUSH CONNECT REMOVAL TOOL	1.714"	2.226"	1.697"
67601803	R-RT-2P	1" & 1-1/4" RIGID & IMC, PUSH CONNECT REMOVAL TOOL	2.467"	3.312"	2.498"
67601804	R-RT-3P	1-1/2" & 2" RIGID & IMC, PUSH CONNECT REMOVAL TOOL	3.552"	4.625"	3.581"
67601204	PLT-RT-1P	1/2" & 3/4" LIQUID-TIGHT NON METALLIC + PVC, PUSH CONNECT REMOVAL TOOL	1.871"	2.441"	1.854"
67601205	PLT-RT-100	1" LIQUID-TIGHT NON METALLIC + PVC, PUSH CONNECT REMOVAL TOOL	2.1896"	2.844"	1.199"

*All removal tools are sold individually or in pairs.

SIMPush™ FITTINGS



Southwire™

SIM Push™ FITTINGS CATALOG

GET SOCIAL WITH US:



**/SOUTHWIRETOOLS
/SOUTHWIRETOOLSLATINO**



@SOUTHWIRETOOLS



@SOUTHWIRETOOLS



SOUTHWIRETOOLS

SOUTHWIRE.COM | 1-855-SWTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/® - Trademark or Registered Trademark of Southwire Company.