

1. Bare Transmission & Distribution Conductors (AAC, AAAC, ACAR, ACSR, AACSR, ZTACSR, ACSS, ACSS/HS285®)



 
2. Bare Transmission & Distribution TW Conductors (AAC/TW, ACSR/TW, ACSS/TW, ACSS/TW HS285®)



3. C7® Overhead Conductor with Tokyo Rope Aluminum Conductor, Composite Supported (ACCS/TW/C7-TS) Thermal-Resistant Aluminum Conductor, Composite Reinforced (ZTACCR/TW/C7-TS)



4. Max Storm™ Overhead Conductor (ZTACSR/TW/HS285)



5. VR2® – Vibration Resistant Conductors (AAC/VR2®, ACSR/VR2®, ZTACSR, TACSR/VR2®)



6. Bare Copper Conductors



7. Proof Positive® Conductors (Copper, Copperclad)



8. Transformer Riser Wire



9. Protected Ground Wire



10. Tie Wire



11. Covered Aerial MV™ /Tree Wire/Covered Conductor



12. Covered Line Wire



 
13. 600V Multiplex Service Drop



14. 600V SquirrelShield® Service Drop




15. 600V Reverse Twist Secondary (RTS)(MRC)



16. 600V Parallel Aerial Cable (PAC)



 17. 69kV – 500kV High Voltage Underground Conductors\*



18. 15kV – 46kV Primary Underground\* (TRXLP or EPR)



19. 15kV-46kV PILC Replacement (Parallel or Triplex)




20. 600V Secondary Underground (Standard, Hi-Score, SureSeal® Cable)



21. 600V PowerGlide® Secondary Underground



22. SIMpull® Cable-In-Conduit (Cable Options: MV, 600V, Fiber)Conductor

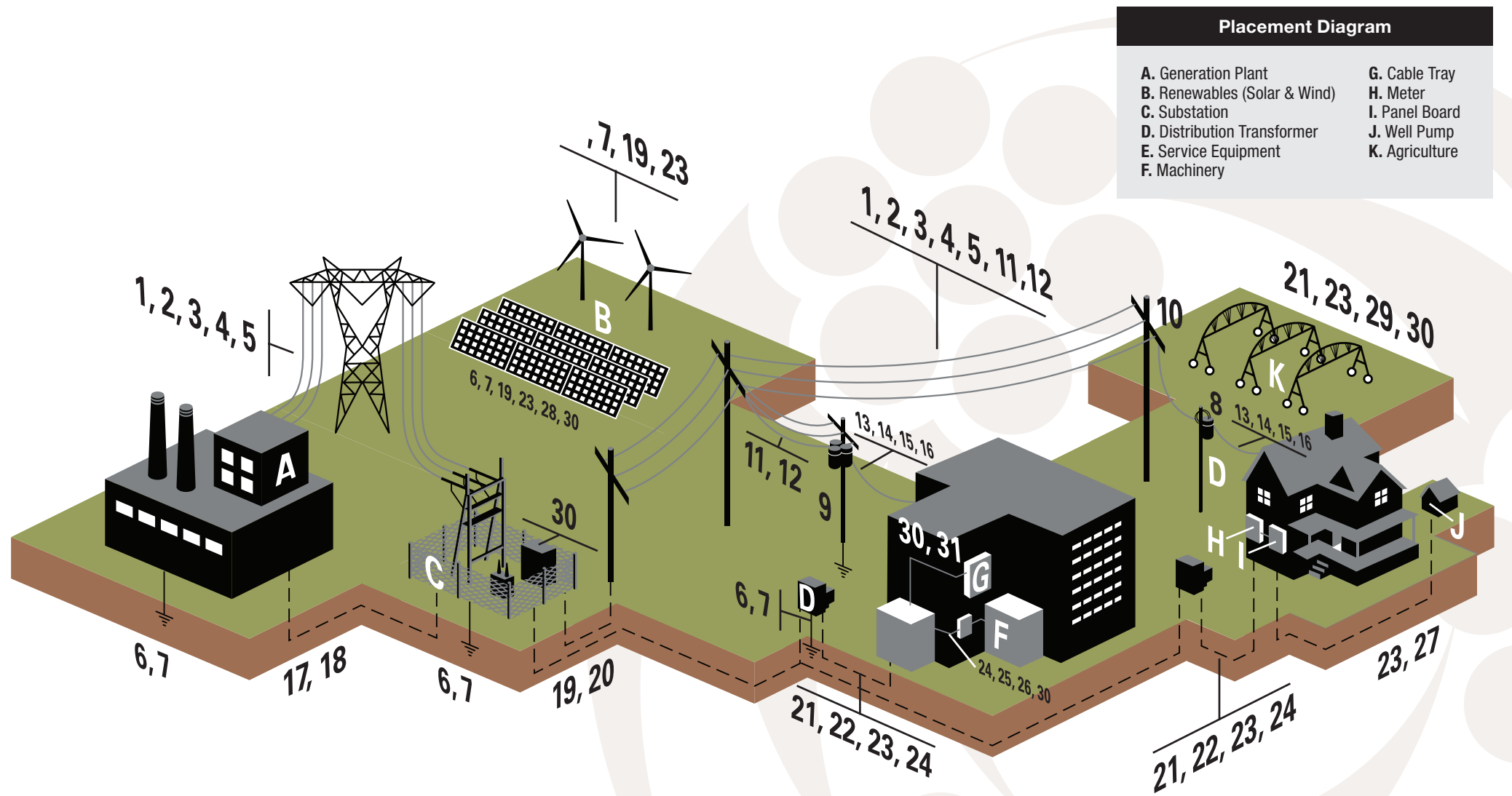

23. RHH/RHW-2/USE-2 (Triple Rated) (MRC)



24. XHHW-2



25. THWN-2



26. UF-B



27. 2kV Photovoltaic (PV) Wire



28. Proof Positive® Span Cable



29. Unshielded Control Cable



30. Shielded Control Cable

\* Various constructions options available