



Southwire™

BENDING MADE EASY



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SOUTHWIRE.COM



Southwire®

MAXIS® MULTI-SHOE BENDER

The Maxis® Multi-Shoe Bender incorporates multiple-shoe groups for a lightweight highly transportable bender.

- **MUSCLE THROUGH THE MOST DEMANDING JOBS** – Ultra-rigid drivetrain optimizes power and efficiency aiding with the most difficult of bends
- **CONSISTENT BENDING PERFORMANCE** – Precision engineered chassis helps to provide a smooth bending experience
- **RESISTS WRINKLING** – Advanced pressure pedal and roller system for wrinkle-free bends on EMT & IMC conduit
- **PRECISION STRAIGHT-TRACK SHOE MOUNTING** – Proprietary shoe mounting design self-aligns & auto-centers the shoe for uniform, clean bends
- **ACCURATE BENDING** – Large, easy-to-read degree protractor with adjustable pointer arrow for precise bends
- **CONVENIENT STORAGE** – Operator's Manual Storage Canister helps keep you organized
- **WELL DESIGNED FOR LONG LIFE** – 2 year industry-leading warranty has you covered



AUTOSTOP accessory (BMAS-01)* automatically stops bending shoe for consistent, repetitive bends. Great for pre-fab shops!

*BMAS-01 sold separately



 **WE'VE GOT IT
MADE IN AMERICA™**

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire®

SPECIFICATIONS

MODEL #	STOCK #	UPC #	DESCRIPTION	HEIGHT	WIDTH	LENGTH	WEIGHT
MSB2000	66975540	032886310362	Maxis® Multi-Shoe Bender	41"	28"	30"	241lbs

ACCESSORIES

MODEL	STOCK #	UPC	DESCRIPTION
MSB2000I*	66975840	032886310379	MSB2000I INCLUDES MSB2000 BENDER, IMC SHOE & IMC ROLLER
MSB2000E*	66976140	032886310386	MSB2000E INCLUDES MSB2000 BENDER, EMT SHOE & EMT ROLLER
MSB2000R*	66976440	032886310393	MSB2000R INCLUDES MSB2000 BENDER, RIGID SHOE & RIGID ROLLER
MSB-SGRP-IMC	66976740	032886310409	IMC SHOE GROUP FOR MSB2000 INCLUDES IMC SHOE & ROLLER
MSB-SGRP-EMT	66977040	032886310416	EMT SHOE GROUP FOR MSB2000 INCLUDES EMT SHOE & ROLLER
MSB-SGRP-RIG	66977340	032886310423	RIGID SHOE GROUP FOR MSB2000 INCLUDES RIGID SHOE & ROLLER
MSB-SHOE-EMT	66977640	032886310430	EMT SHOE FOR MSB2000
MSB-SHOE-RIGIMC	66977940	032886310447	RIGID/IMC SHOE FOR MSB2000
MSB-ROLL-IMC	66978540	032886310461	ROLLER, IMC, MSB2000
MSB-ROLL-EMT	66978240	032886310454	ROLLER, EMT, MSB2000
MSB-ROLL-RIG	66978840	032886310478	ROLLER, RIGID, MSB2000

**This is a Made-To-Order kit. To see available inventory, look-up the bender and shoe group separately*



1-855-798-6657 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire®

BENDmax™ COMPACT POWER BENDER

COMPACT POWER BENDER FOR 3/4" - 2" EMT, IMC, & RIGID CONDUIT

- Bends 3/4" - 2" EMT, IMC, and RIGID conduit
- Double sided shoe for EMT, IMC, & RIGID conduit
- Large analog protractor for accurate bends
- Push cart mounted platform
- Industrial-grade DC drive and electrical components
- Adjustable squeeze setting for wrinkle-free bends on EMT and IMC conduit
- Durable locking casters
- Fits through finished 30" door frames
- Durable two-position hand pendant
- No assembly required



*BMAS-01 sold separately

BENDmax AutoStop accessory (BMAS-01)* automatically stops bending shoe for consistent, repetitive bends. Great for prefab shops.

SPECIFICATIONS

 **WE'VE GOT IT
MADE IN AMERICA™**

MODEL #	STOCK #	CAPACITY	DESCRIPTION	HEIGHT	WIDTH	DEPTH	WEIGHT
BML2000	64601201	3/4" - 2" EMT, IMC, RIGID CONDUIT	BENDmax™ Compact Power Bender	42.94"	27.125"	29.625"	500 lbs

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire®

BENDmax™ POWER BENDER POWER BENDER FOR 3/4" - 2" EMT, IMC, & RIGID CONDUIT

- 3/4"-2" EMT,IMC, and Rigid conduit bender
- Easily adjustable to ergonomic working height
- Programmable spring back
- Back lit display
- Durable two-button hand pendant
- 2 degree leveling adjustment
- Industrial grade DC drive, and electrical components
- Push cart mounted platform
- Bends in vertical and horizontal plane
- Free standing conduit support stand included



*BMAS-01 sold separately

BENDmax AutoStop accessory (BMAS-01)* automatically stops bending shoe for consistent, repetitive bends. Great for prefab shops.

 **WE'VE GOT IT
MADE IN AMERICA™**

1-855-798-6657 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire®

MAXIS® HYDRAULIC BENDING MACHINE

A complete solution for bending 2.5" - to 4" Rigid, IMC, and EMT conduit with intelligent, color-organized storage, transport cart, and 90° shoes.

FEATURES & BENEFITS

- A complete bending solution for 2.5" - 4" EMT, IMC, and RIGID conduit
- Dual-action, long-stroke cylinder. Cylinder height never requires adjustment when changing bending shoes
- 3,000 PSI integrated pump offers high bending force and low-maintenance
- Mast hydraulically raises and locks in seconds, offering superior stability
- Smart, efficient organization with color-organized accessories and intelligent storage
- One-shot shoes means no resetting between bends
- Includes Southwire™ easy load conduit hooks
- Huge, highly-visible 60" ruler for quick and accurate measuring



**WE'VE GOT IT
MADE IN AMERICA™**

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire®

SPECIFICATIONS

MODEL #	STOCK #	UPC	DESCRIPTION	HEIGHT	WIDTH	DEPTH	WEIGHT
MHB4000	66978340	032886750496	Complete Maxis® Hydraulic Conduit Bending Machine for 2.5" - 4" EMT, IMC, and RIGID conduit	65"	60"	39.5"	1562 lbs.

ACCESSORIES

MODEL #	STOCK #	UPC	DESCRIPTION	HEIGHT	WIDTH	DEPTH	WEIGHT
MHB4000-NS	66978640	032886750502	Maxis® Hydraulic Bending Machine No-Shoes	65"	60"	39.5"	1000 lbs
MHB4000-250	66978940	032886750519	Maxis® Hydraulic Bender 2.5" Shoe	14.5"	4"	24"	32 lbs
MHB4000-253	66979240	032886750526	Maxis® Hydraulic Bender 2.5" Follow Bar	3"	6"	31"	44 lbs
MHB4000-254	66979540	032886750533	Maxis® Hydraulic Bender 2.5" Hook	7.5"	5"	4.5"	11 lbs
MHB4000-300	66979840	032886750540	Maxis® Hydraulic Bender 3" Shoe	17"	5"	28.5"	44 lbs
MHB4000-303	66980140	032886750557	Maxis® Hydraulic Bender 3" Follow Bar	3.5"	6.5"	36"	62 lbs
MHB4000-304	66980440	032886750564	Maxis® Hydraulic Bender 3" Hook	8.5"	6"	4.5"	14 lbs
MHB4000-350	66980740	032886750571	Maxis® Hydraulic Bender 3.5" Shoe	21"	5"	31"	67 lbs
MHB4000-353	66981040	032886750588	Maxis® Hydraulic Bender 3.5" Follow Bar	5"	6.5"	41"	76 lbs
MHB4000-354	66981340	032886750595	Maxis® Hydraulic Bender 3.5" Hook	10"	6.5"	4.5"	17 lbs
MHB4000-400	66981640	032886750601	Maxis® Hydraulic Bender 4" Shoe	23"	5.5"	36"	78 lbs
MHB4000-403	66981940	032886750618	Maxis® Hydraulic Bender 4" Follow Bar	5"	7"	44"	93 lbs
MHB4000-404	66982240	032886750625	Maxis® Hydraulic Bender 4" Hook	11"	7.5"	5.5"	24 lbs



1-855-798-6657 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire®

BENDstation™ CONDUIT BENDING WORKSTATION

Southwire's BENDstation™ line includes an adaptable cart platform with four shoes for bending a wide variety of conduit. This purpose built tool can increase efficiency up to 30% over traditional hand benders.

COMPREHENSIVE CONDUIT BENDING WORKSTATION

- Measure, bend, clamp, and cut at a comfortable 36" work table height for reduced labor fatigue
- More accurate measurements, bends, and cuts
- Built-in protractor for quick and accurate bends
- Store up to 1000 feet of conduit or strut
- Extra shelf for storage of tools and materials
- Heavy duty casters for easy transportation and mobility
- Multiple bending shoe design accepts bending heads 1/2" - 1 1/4" EMT, 3/4" - 1" IMC and RIGID
- Requires up to 40% less effort than other mechanical benders
- Multi-position Vise for cutting and threading operations
- Built-in 60" ruler for quick and accurate measuring



**WE'VE GOT IT
MADE IN AMERICA™**

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION	LENGTH	WIDTH	HEIGHT	WEIGHT
BSCC-01	64795201	BENDstation™ Common Cart	69"	29"	38.5"	170 lb.
RB1000	59840701	BENDstation™ for 3/4" and 1" RIGID and IMC	69"	29"	38.5"	180 lb.
MB1250	64795101	BENDstation™ for 1" and 1.25" EMT	69"	29"	38.5"	185 lb.
MB1000	64306901	BENDstation™ for 3/4" and 1" EMT	69"	29"	38.5"	150 lb.
MB750	58315201	BENDstation™ for 1/2" and 3/4" EMT	69"	29"	38.5"	189 lb.



BENDING SHOE HEAD KITS

MODEL #	STOCK #	DESCRIPTION	LENGTH	WIDTH	HEIGHT	WEIGHT
RBCCH-1000	64316601	Head Kit for 3/4" - 1" GRC and IMC	9.20"	17.45"	20.80"	80 lb.
MBCCH-750	64601001	Head Kit for 1/2" - 3/4" EMT	7.60"	16.13"	14.87"	32 lb.
MBCCH-1000	64316701	Head Kit for 3/4" - 1" EMT	8.70"	16.63"	16.61"	49 lb.
MBCCH-1250	64795301	Head Kit for 1" - 1.25" EMT	10"	12.75"	15.23"	86 lb.



Southwire®

BENDdolly™ BENDING PLATFORM

- Light weight bending platform
- Interchangeable shoe mounting plate
- Large dolly wheels for easy maneuverability
- Stable bending platform
- Interchangeable EMT shoes and IMC & Rigid shoes
- Durable black powder coating for increased corrosion resistance
- Accepts four different Southwire bending shoes
- Upright storage position



**Shown with RB1000 Rigid Shoe*



**WE'VE GOT IT
MADE IN AMERICA™**

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**




Southwire®

BENDING SHOE HEAD KITS

MODEL #	STOCK #	DESCRIPTION
MBCCH-750	64601001	Head Kit for 1/2"-3/4" EMT
MBCCH-1000	64316701	Head Kit for 3/4"-1" EMT
MBCCH-1250	64795301	Head Kit for 1"-1.25" EMT
RBCCH-1000	64316601	Head Kit for 3/4"-1" Rigid & IMC

	LENGTH	WIDTH	HEIGHT	WEIGHT
MBCCH-750	14.87"	16.13"	7.60"	32 lb.
MBCCH-1000	16.61"	16.63"	8.70"	49 lb.
MBCCH-1250	15.23"	12.75"	10"	85 lb.
RBCCH-1000	20.80"	17.45"	9.20"	80 lb.

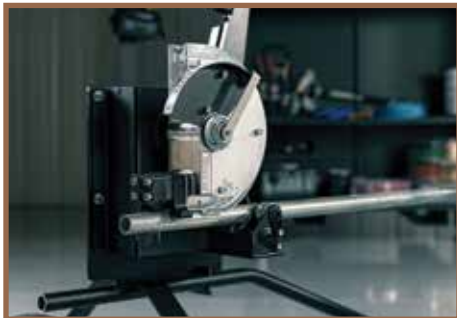

1-855-798-6657 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



Southwire®

PVC CONDUIT HEATING BLANKET BENDERS

PVCHB-13, PVCHB-30, PVCHB-38

- Heats to 300° F
- Wrap blanket around PVC and easily secure with velcro strap
- Make Bends, Offsets Or Saddles In PVC
- Compact for easy storage and transport
- Power Source: 120 Volts



MODEL #	STOCK#	DESCRIPTION	WORKING LOAD	UPC
PVCHB-13	67589540	PVC Heating Blanket 13"	200 WATT	032886720949
PVCHB-30	67589640	PVC Heating Blanket 30"	800 WATT	032886720956
PVCHB-38	67589740	PVC Heating Blanket 38"	1300 WATT	032886720963

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire®

PVCB-06M

1/2" TO 6" MOTORIZED PVC CONDUIT BENDER

- Conduit is rotated by an internal motor to ensure uniform heating
- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"



PVCB-06

1/2" TO 6" PVC CONDUIT BENDER

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"



1-855-798-6657 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & TMTrademark of Southwire Company, LLC.



Southwire®

PVCB-04

1/2" TO 4" PVC CONDUIT BENDER

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright green indicator light to advise when unit is turned "ON"



PVCB-02

1/2" TO 2" PVC CONDUIT BENDER

- Durable black powder coating for increased corrosion resistance
- Chrome plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright green indicator light to advise when unit is turned "ON"



PLUG KIT PVCP

PVCP-01 & PVCP-02

- Prevents conduit from collapsing when heated
- Rugged carrying case to store and transport plugs
- Durable long-lasting neoprene gaskets
- Twist lock design for easy installation and removal
- Provides air tight seal



 **WE'VE GOT IT
MADE IN AMERICA™**

MODEL #	STOCK #	DESCRIPTION	CONDUIT SIZE	UPC
64301301	PVCB-06M	1/2" to 6" Motorized PVC Conduit Bender	1/2" to 6"	032886983627
64301201	PVCB-06	1/2" to 6" PVC Conduit Bender	1/2" to 6"	032886983610
64301101	PVCB-04	1/2" to 4" PCV Conduit Bender	1/2" to 4"	032886983603
64812201	PVCB-02	1/2" to 2" PCV Conduit Bender	1/2" to 2"	032886997693
64301401	PVCP-01	Bending Plug kit for conduit sizes 2" to 4"	2" to 4"	032886983634
64301601	PVCP-02	Bending Plug kit for conduit sizes 2" to 6"	2" to 6"	032886983641

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire®

CONDUIT HAND BENDERS

- Durable cast metal heads
- Swaged steel handle permits insertion of conduit to correct overbends
- Raised and highly visible bender markings are cast on both sides of the bender head
- Large serrated step provides greater control and helps prevent slipping when applying force



SPECIFICATIONS

MODEL #	STOCK #	DESCRIPTION			
MCB1	58281440	1" EMT Conduit Bender with Handle (Ductile Iron Head)			
MCB3/4	58281240	3/4" EMT Conduit Bender with Handle (Aluminum Head)			
MCB1/2	58281340	1/2" EMT Conduit Bender with Handle (Aluminum Head)			
	HEIGHT	WIDTH	DEPTH	WEIGHT	CONDUIT SIZE
MCB1	1.75"	12"	45"	13 lb.	1" EMT, 3/4" Rigid
MCB3/4	1.25"	9"	39"	9 lb.	3/4" EMT, 1/2" Rigid
MCB1/2	1.25"	8"	39"	7 lb.	1/2" EMT

1-855-798-6657 | [SOUTHWIRE.COM](https://www.southwire.com)

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & TMTrademark of Southwire Company, LLC.



Southwire®

SIMpull™ NON-CONDUCTIVE TIP FISH TAPE

- **TAPERED TIP** - Reduces the likelihood of snagging on wires & conduit when reeling-in the fish tape
- **LASER ETCHED FOOT MARKINGS** - Identify conduit run lengths with incremental foot markings
- **IMPROVED PUSH** - 5.5mm tape works well in conduit up to 3 inches and 4.5mm tape works well in conduit up to 2 inches
- **ADVANCED TAPE GUIDE** - Improved housing mechanics for smoother payout & reel-in
- **IMPACT RESISTANT CASE** - Certified Drop Rating of 15 Feet



SIMpull™ FLEXIBLE METAL LEADER FISH TAPE

- **FLEXIBLE METAL LEADER** - Easily glides through conduit bends and around existing wire
- **IMPACT RESISTANT CASE** - Certified Drop Rating of 15 Feet
- **LASER ETCHED FOOT MARKINGS** - Identify conduit run lengths with incremental foot markings
- **ADVANCED TAPE GUIDE** - Improved housing mechanics for smoother payout & reel-in
- **IMPROVED PUSH** - 5.5mm tape works well in conduit up to 3 inches and 4.5mm tape works well in conduit up to 2 inches



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**



Southwire™

**BENDING
MADE EASY**

get social with us:



/SOUTHWIRETOOLS



/SOUTHWIRE-COMPANY



@SOUTHWIRETOOLS



@SOUTHWIRE



WWW.SOUTHWIRE.COM | 1-855-SWT00LS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/®- Trademark or Registered Trademark of Southwire Company.

SCAN TO SEE MORE