




SPEEDMC™ SOLUTIONS FAQs

Q: What is the SPEEDMC™ Solution and where is it located?

A: *The SPEEDMC™ Solution is an agile manufacturing cell located in Bremen, IN, with dedicated equipment offering select size MC constructions at a 50% reduced lead time over standard.*

Q: What MC constructions will be offered through SPEEDMC™ Solutions?

A:

SPEEDMC™ SOLUTIONS			
Phase Size	14, 12, 10, 8, 6, 4, 3, 2 AWG Copper		
Colors	Phases: BLACK, RED, BLUE, BROWN, ORANGE, YELLOW, PINK, PURPLE, TAN		
	Neutrals: WHITE, WHITE-BLACK, WHITE-BLUE, WHITE-RED, GRAY, GRAY-BROWN, GRAY-ORANGE, GRAY-YELLOW, GRAY-PURPLE		
Grounds	Bare or Insulated Copper: SOL or STR: 14, 12, 10, STR 8, 6, 4, 3, 2		Bare Aluminum: SOL 12, 10, 8
Insulation Type	THHN		
Conductor Size	Max # of Conductors based on AWG		
14, 12, 10 AWG	21 conductors (includes ground wire)		
8 AWG	11 conductors (includes ground wire)		
6 AWG	9 conductors (includes ground wire)		
4 AWG	6 conductors (includes ground wire)		
3 AWG	5 conductors (includes ground wire)		
2 AWG	5 conductors (includes ground wire)		
TYPE of MC	MC	MCAP (14-8 AWG only)	MCAP-HCF (14-8 AWG only)
			
Construction Type	NPP - Neutral Per Phase (14-8 AWG only)		
	MN - Multi-Neutral		
	ON - Oversized Neutral		
	IG - Isolated Ground(s)		
	PCS - Power & Control/Signal (14-10 AWG only)		
	Multi-Circuit		
Armor Type	Aluminum ONLY		
Packaging	Reels only - Minimum length = 100'		
Minimum Order Quantity is 1,000'			
NOW AVAILABLE - Optional print legend over armor			


For the fastest response to your Southwire SPEEDMC™ Solutions inquiry please contact your local Southwire representative.

**TURNING "NO QUOTE"
INTO "NO PROBLEM"**



Southwire™

SPEEDMC™
Solutions

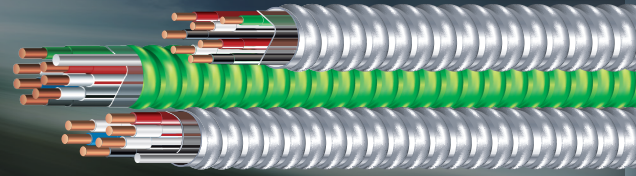

SPEEDMC™ SOLUTIONS FAQs

Q: Are there added costs/fees when using SPEEDMC™ Solutions vs. standard MC?

A: *Yes, just as all Southwire SPEED™ Services offerings require some additional fees to cover added costs, SPEEDMC™ Solution will also require these fees.*

Q: What lead times will be offered through SPEEDMC™ Solutions?


A: *We will be offering reduced manufacturing time of 7-10 days.*

Q: How do you obtain a quote for SPEEDMC™ Solutions?

A: *The same way you request a quote for any Southwire SPEED™ Services opportunity.
Please send all requests to SpeedMC@Southwire.com.*

Q: How are SPEEDMC™ Solutions orders processed?

A: *Orders will be placed through SAP, and processed and shipped from our Bremen (7710) facility.*

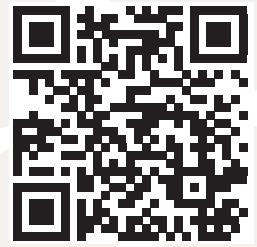

SCAN THE QR CODE TO LEARN
MORE ABOUT SPEED

For the fastest response to your Southwire SPEEDMC™ Solutions inquiry please contact your local Southwire representative.

**TURNING “NO QUOTE”
INTO “NO PROBLEM”**

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.