



Southwire®

SUMNER*

PRODUCT CATALOG



SOUTHWIRE.COM


**Trademark of Sumner Manufacturing Co., LLC. Registered in the U.S.
Copyright © Sumner Manufacturing Co., LLC*



THE COMPLETE SOUTHWIRE® SOLUTION

**WIRE AND CABLE | TOOLS AND EQUIPMENT | POWER MANAGEMENT
ELECTRICAL COMPONENTS | LIGHTING SOLUTIONS**



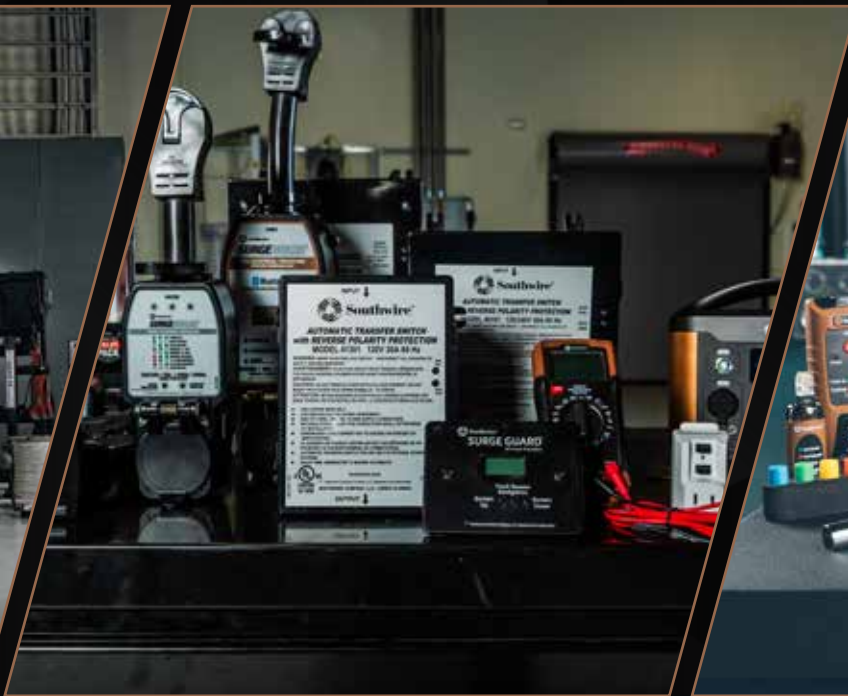

OUR STORY

As a family business, Southwire® proudly continues building on our commitment to environmental stewardship and corporate sustainability by prioritizing stakeholder expectations, and supporting the wellbeing of our communities and the environment in which we live. To help us meet this commitment, we organize our sustainability strategy around five core tenets: Growing Green, Living Well, Giving Back, Doing Right, and Building Worth.

We Deliver Power...Responsibly®

We remain committed to the sustainability of our company for the next 100 years and beyond. As we strengthen this commitment, we continue to work hard every day to discover, develop and distribute sustainable solutions that exceed the expectations of our stakeholders around the world.

OUR MISSION

To be a **preferred provider** of solutions to the electrical industry by providing innovative products and services with exceptional quality.

OUR VALUES

Our **ONE Southwire** culture prioritizes the interests of our team members, customers, and communities through a continuous commitment to empowerment, trust, consistency, and inclusion.

OUR REACH

Nearly one in two new homes built in the United States contains our wire, and we produce half of the cable used to transmit and distribute electricity throughout the nation.

OUR PRODUCTS

Our product teams and dedicated resources work together to listen to and work with our customers, creating solutions that deliver unparalleled value through product innovation, safety and efficiency.

OUR SERVICE

Service is more than a word or a phone number; it's a tangible support system that assists you through the entire project cycle; from our knowledgeable customer service team, to our experienced field sales team, we're there every step of the way.

TABLE OF CONTENTS

PIPE FITTING

Center Punches	7
Clamps.....	8
ULTRA Clamp*.....	8
ULTRA Qwik™ Clamp	8
ULTRA Fit*.....	9
ULTRA Qwik™ Fit	9
Clamp Champ™	10
DX Clamp	11
Internal Fit-Up.....	11
Flange Pins	12
Flange Spreaders	13
Hydraulic Flange Spreader	13
Adjust-A-Fit™	14
Adjust-A-Flange™	14
Nylon Expansion Plugs	15
Purges	16
Weld Gas Analyzer	16
Purge Star*.....	17
Purge Buddy™	18
Welding Gage.....	19
Rotary Ground Clamp.....	19
Fit Kit™	20
Squares	21
Magnetic Fixtures	22
Levels	24
Welder's Stool.....	25

JACKS

Heavy Duty Jacks	27
Pro-Jack*.....	28
Fold-A-Jack*.....	29
FAT Jack™	30
Hi Boy™	31
FAB SAF™	32
Adjust-A-Roll™	33
Mini-Roll™	34
Pro Roll™	35
Big V*.....	36

MAX JAX*.....	37
MAX JAX* 2.....	38
Beam JAX™	39
Reel Mac™	40
Hold Down Device.....	41
Hold-E*	41

CARTS & STORAGE

Cricket*.....	46
Grasshopper*.....	46
Handi-Bench.....	47
Pipe Mac™	48
Hanger Mac™	49
Mac Rack I™	50
Mac Rack II™	50
Bundle Mac™	51
Cylinder Carts	52

LIFTS

EL-405 Stacker	57
Series 1900.....	57
Roust-A-Bout™	58
FAB-MATE™	59
Short Stack™	60
Series 2000.....	61
Series 2100.....	62
Series 2200 Lil Hoister™	63
Series 2300.....	64
Series 2400.....	65
Series 2500.....	66
Series 2600.....	67
Eventer™	68

GANTRIES

GH3/4T	73
GH2T	74
GH5T	75

MATERIAL HANDLING

Pallet Jacks	77
6 Pac Mac™	78
10 Pac Mac™	78
Caddy Mac™	79
Spool Mac™	79
Stor Mac™	80
Knock Down Stor Mac™	80
Tainer Mac™	81
Weldbox™	82
Storage Cabinets	83
Piano Box.....	84
Field Office	85
Compact Chest	86
Utility Carts	87

HOISTS


Lever Hoists.....	90
Premium Lever Hoists	91
Premium Lever Hoists W/ Overload Protection.....	93
Chain Block Hoists.....	94
Premium Chain Block Hoists	95
Premium Chain Block Hoists W/ Overload Protection.....	96
Manual Trolley Beam Clamp	97

WELDING HAND TOOLS

Locking Pliers	99
Mig Pliers.....	101
Locking Clamps	102
Locking Sheet Metal Tool.....	106
Chipping Hammer	107
Wire Brushes	108
Clamps.....	109
Combination Square	110

PIPE FITTING PRODUCTS

Sumner's line of pipe fitting products includes Universal Center Punches, Ultra Clamps, Ultra Fit, Clamp Champs, Flange Spreaders, and more. Pipefitters need reliable tools, and our goal is to provide excellent products that exceed our customer expectations.

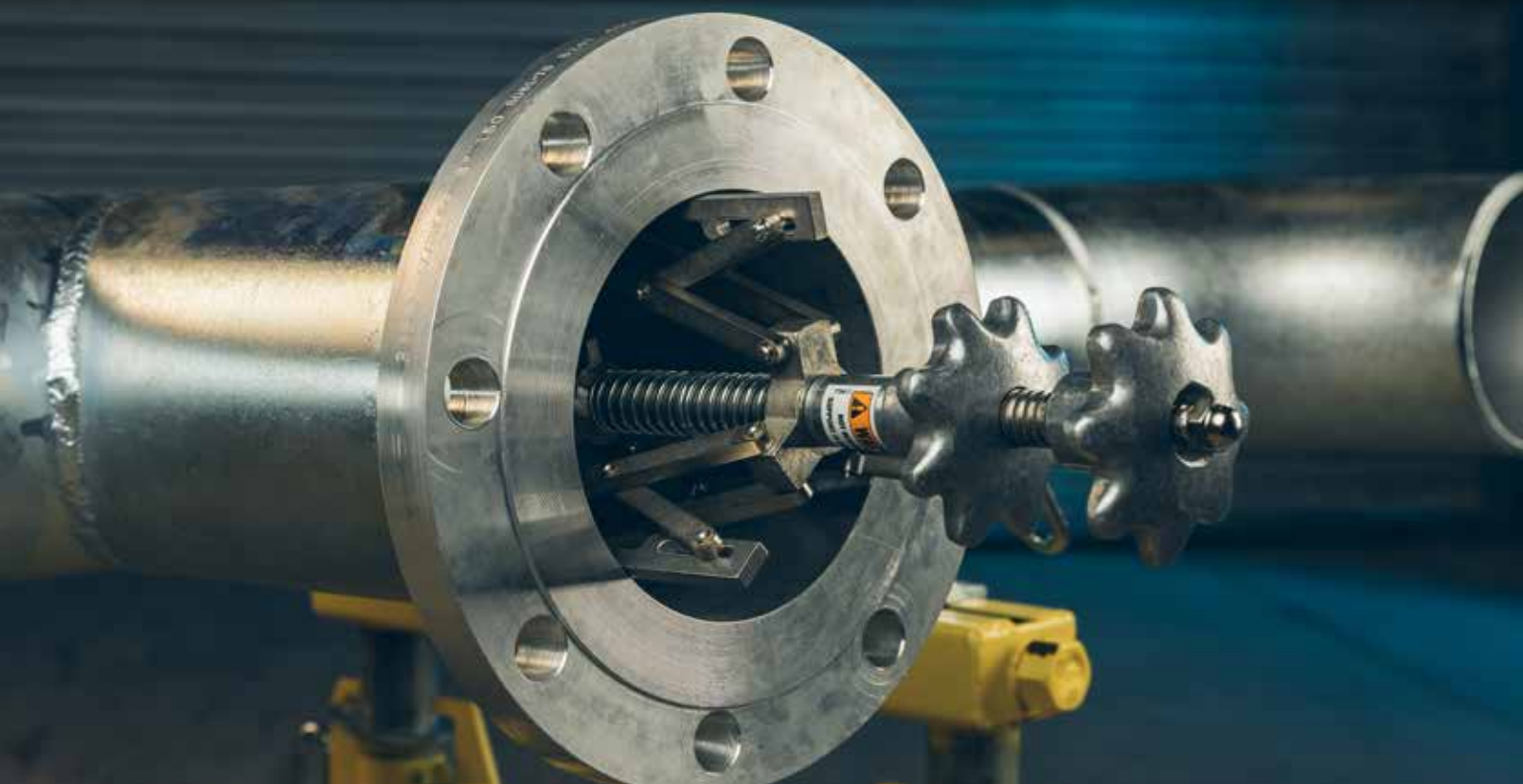

PIPE FITTING

UNIVERSAL CENTER PUNCH



The Sumner Center punches have magnetic arms that attach to the steel surface to assure accurate location when using the punches' spring-loaded striking hammer.

SPECIAL FEATURES:

- Available with fixed or adjustable magnet arms to accommodate steel pipe or tanks
- Push-button spring-loaded striking hammer
- Removable digital leveling gauge with magnetic base
- Alignment marks for centering
- Digital gauge can be used as angle finder



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
784590	Universal Center Punch with Inclinometer	UCPUNCH	661165845907	4"	UNLIMITED
784520	Center Punch with Inclinometer	CPUNCH	661165845204	4"	8"
OPTIONAL ACCESSORY					
779546	Inclinometer Digital Angle Finder	CPINCLINE	661165795462	---	---

PIPE FITTING

ULTRA CLAMP*



The Sumner ULTRA Clamp* device is a fast, accurate fit-up tool for pipe to pipe, pipe to fitting and other fit-up needs.

SPECIAL FEATURES:

- Accurate fit-up of 1" through 12" pipe
- Rugged frame, built for jobsite use
- Stainless-steel alignment screws
- Operating handle repositions for close work
- Fine adjustment screws for quick fit-up
- Lightweight for overhead work
- Available in three sizes



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781130	ULTRA Clamp* for 1-2.5" Pipe	UC1-2.5	661165811308	1"	2.5"
781150	ULTRA Clamp* for 2-6" Pipe	UC2-6	661165811506	2"	6"
781170	ULTRA Clamp* for 5-12" Pipe	UC5-12	661165811704	5"	12"

ULTRA QWIK™ CLAMP



The Sumner ULTRA Qwik™ Clamp is a fast, accurate fit-up tool for pipe to pipe, pipe to fitting and other fit-up needs with a quick button release.

SPECIAL FEATURES:

- Push button design allows for rapid action setting and fine tune thread adjustment
- Accurate fit-up of 1" through 12" pipe
- Rugged frame, built for jobsite use
- Stainless-steel alignment screws
- Operating handle repositions for close work
- Fine adjustment screws for quick fit-up
- Lightweight for overhead work
- Available in three sizes



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781510	ULTRA Qwik™ Clamp for 1-2.5" Pipe	UQC1-2.5	661165815108	1"	2.5"
781520	ULTRA Qwik™ Clamp for 2-6" Pipe	UQC2-6	661165815207	2"	6"
781530	ULTRA Qwik™ Clamp for 5-12" Pipe	UQC5-12	661165815306	5"	12"

PIPE FITTING

ULTRA FIT*



The Sumner ULTRA Fit* is a fast, accurate fit-up tool for pipe to pipe, pipe to fitting and other fit-up needs.

SPECIAL FEATURES:

- Accurate fit-up of 1" through 12" pipe
- Rugged frame, built for jobsite use
- Stainless-steel alignment screws
- Operating handle repositions for close work
- Fine adjustment screws for quick fit-up
- Lightweight for overhead work
- Available in three sizes



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781265	ULTRA Fit* for 1-2.5" Pipe	UF1-2.5	661165812657	1"	2.5"
781275	ULTRA Fit* for 2-6" Pipe	UF2-6	661165812756	2"	6"
781285	ULTRA Fit* for 5-12" Pipe	UF5-12	661165812855	5"	12"

ULTRA QWIK™ FIT



The Sumner ULTRA Qwik™ Fit is a fast, accurate fit-up tool for pipe to pipe, pipe to fitting, and other fit-up needs with a quick button release.

SPECIAL FEATURES:

- Push button design allows for rapid action setting and fine tune thread adjustment
- Accurate fit-up of 1" through 12" pipe
- Rugged frame, built for jobsite use
- Stainless-steel contacts & alignment screws
- Operating handle repositions for close work
- Fine adjustment screws for quick fit-up
- Lightweight for overhead work
- Available in three sizes



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781540	ULTRA Qwik™ Fit for 1-2.5" Pipe	UQF1-2.5	661165815405	1"	2.5"
781550	ULTRA Qwik™ Fit for 2-6" Pipe	UQF2-6	661165815504	2"	6"
781560	ULTRA Qwik™ Fit for 5-12" Pipe	UQF5-12	661165815603	5"	12"

PIPE FITTING

CLAMP CHAMP™



The Sumner Clamp Champ™ kit is an advanced solution for today's problem fit ups! The Clamp Champ™ kit is built for the welder who takes pride in doing his job right the first time. Constructed from years of trouble-free jobsite use, the versatile Clamp Champ™ kit makes pipe fit-up simple and accurate – without the need of a helper. The Clamp Champ™ kit is similar to a pipe vise with fast, easy set up and solid chain engagement.

SPECIAL FEATURES:

- Easy grip knurled adjustment knob works with gloved hands for precision alignment
- Leveling and supporting device quickly and accurately sets gap
- Drop forged handle and wing nuts designed for rough field use and easy adjustment with gloved hands
- Fast action chain lock system for fast set-up
- Flared jack bars are easy to add or remove to accommodate a wide range of pipe diameters
- Jack bar screws allows welder to square and space the fit-up easily

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781000	Clamp Champ™ Standard Kit for 1"-10" Pipe	CCKIT1-10	661165810004	1"	10"
780999	Clamp Champ™ Stainless Steel Kit for 1"-10" Pipe	CCKITSS1-10	661165809992	1"	10"
780998	Clamp Champ™ Standard Kit for 1"-16" Pipe	CCKIT1-16	661165809985	1"	16"
780997	Clamp Champ™ Stainless Steel Kit for 1"-16" Pipe	CCKITSS1-16	661165809978	1"	16"
781250	Clamp Champ™ Standard Kit II for 10"-36" Pipe	CCKIT10-36	661165812503	10"	36"
781251	Clamp Champ™ Stainless Steel Kit II For 10"-36" Pipe	CCKITSS10-36	661165812510	10"	36"

DX CLAMP



The Sumner DX Clamp is a lightweight drop forged pipe fit-up tool.

SPECIAL FEATURES:

- Fit-up tool for 1-14" pipe
- Adjustment screws offer hardened steel ball contact with pipe
- Available in five sizes

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
781570	DX Clamp for 1"-3" Pipe	DX1-3	661165815702	1"	3"
781571	DX Clamp for 2"-5" Pipe	DX2-5	661165815719	2"	5"
781572	DX Clamp for 4"-7" Pipe	DX4-7	661165815726	4"	7"
781573	DX Clamp for 5"-9" Pipe	DX5-9	661165815733	5"	9"
781574	DX Clamp for 10"-14" Pipe	DX10-14	661165815740	10"	14"

INTERNAL FIT-UP CLAMP



The Sumner Internal Fit-Up Clamp is an internal pipe alignment tool that can be used on all standard weld neck and slip-on flanges.

SPECIAL FEATURES:

- Independent adjustment allows for alignment even if internal dimensions differ
- One-piece construction the Internal Fit-Up Clamp is built for durability and reliability
- Simple and quick one-man operation allows for one jaw to clamp the pipe inside diameter and the second jaw to clamp on the flange
- Stainless-steel contact points
- Available in three sizes
- NOTE: The Internal Fit-Up Clamp is an alignment tool. A separate lifting device to support the flange weight is recommended.

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
784100	Internal Fit-Up Clamp for 2"-4" Pipe	IFC2-4	661165841008	2"	4"
784102	Internal Fit-Up Clamp for 4"-8" Pipe	IFC4-8	661165841022	4"	8"
784103	Internal Fit-Up Clamp for 8"-12" Pipe	IFC8-12	661165841039	8"	12"

PIPE FITTING

FLANGE PINS

QWIKP



The Sumner Flange Pins are designed for fast, accurate alignment of pipe flanges.

SPECIAL FEATURES:

- Available Quick installing pins options works to level flange (two-hole) for tack and weld-out
- Toolless install pins work as convenient reference points to level flange for tack and weld-out
- Hardened pins automatically center on 5/8" to 2-5/8" holes
- Features Acme threads for maximum clamping power
- Uses push-button Qwik pin nuts for fast action alignment

ST-258



FLANGLVLR



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM FLANGE HOLE	MAXIMUM FLANGE HOLE
781235	Qwik Pins* for 5/8" to 1-5/8" Flange Holes (set of 2)	QWIKP	661165812350	5/8"	1-5/8"
780430	Flange Pins for 5/8" to 1-5/8" Flanges Holes (set of 2)	ST-106	661165804300	5/8"	1-5/8"
780429	Stainless Steel Flange Pins for 5/8" to 1-5/8" Flanges Holes (set of 2)	ST-206	661165804294	5/8"	1-5/8"
780650	Flange Pins for 1-1/2" to 2-5/8" Flanges Holes (set of 2)	ST-258	661165806502	1-1/2"	2-5/8"
781240	Qwik Pins* Flange Leveler for 5/8" to 1-5/8" Flange Holes (set of 2)	FLANGLVLR	661165812404	5/8"	1-5/8"

FLANGE SPREADER



The Sumner manual flange spreader is designed for use in most pipe-fitting applications.

SPECIAL FEATURES:

- Can be used for 150 lbs. to 1,500 lbs. flanges
- Hardened wedge for safe splitting
- Large feed screw
- Drive can be rotated by 1-3/8" wrench or 1/2" (12 mm) bar
- Compact design - strong enough for touch jobs
- 4 models available to cover flange ranges from 1" to 24"

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	SPREAD	PIN DIAMETER	FLANGE CLASS					
						150 LBS	300 LBS	400 LBS	600 LBS	900 LBS	1,500 LBS
784003	3" Flange Spreader	ST-301	661165840032	3"	5/8"	1"-6"	3/4"-4"	1/2"-2"	---	---	---
784002	4" Flange Spreader	ST-302	661165840025	4"	3/4"	2"-12"	1/1/2"-8"	1"-4"	1"-4"	1"-2"	1"-2"
784001	5" Flange Spreader	ST-303	661165840018	5"	7/8"	5"-24"	2-1/2"-12"	1-1/2"-8"	2"-6"	1"-4"	1"-3"
784000	6-3/8" Flange Spreader	ST-304	661165840001	6-3/8"	1"	10"-24"	7"-24"	3-1/2"-16"	4"-10"	1"-8"	1"-5"

HYDRAULIC FLANGE SPREADER



The Sumner hydraulic flange spreader is designed for use in most heavy-duty pipe fitting applications.

SPECIAL FEATURES:

- 10 ton flange splitter to tackle the tough jobs
- Spreader arms adjust from 2-3/4" to 8-1/2"
- Spring return, single action cylinder
- Hardened wedge for safe splitting
- Hand pump and 6' hose available as accessories

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	CAPACITY	CYLINDER CAPACITY	CYLINDER STROKE	FLANGE PIN SIZE	FLANGE CLASS					
								150 LBS	300 LBS	400 LBS	600 LBS	900 LBS	1,500 LBS
784004	Hydraulic Flange Spreader	ST-310	661165840049	9 X 92 MM	10 TON	2"	1-1/4"-1-5/8"	22"-42"	16"-28"	14"-24"	12"-20"	8"-16"	4"-8"
OPTIONAL HYDRAULIC FLANGE SPREADER ACCESSORY													
ITEM #	DESCRIPTION	MODEL #	UPC	CAPACITY									
777010	Hand Hydraulic Pump for Flange Spreader with Quick Disconnect	HHYDPUMP	661165770100	6 FT									

PIPE FITTING

ADJUST-A-FIT™



The Sumner Adjust-A-Fit™ alignment tool uses gravity to make lining up fittings a trouble-free, one man operation.

SPECIAL FEATURES:

- Uses gravity to align fittings for loads up to 45 degrees
- Fastens directly onto fittings for loads up to 1,000 lbs.
- Threaded shaft assembly is hardened for long tool life
- Cloverleaf setscrew and threaded shaft handle work from either side

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
780420	Adjust-A-Fit™	ST-104	661165804201	1,000 lbs.


ADJUST-A-FLANGE™



The Sumner Adjust-A-Flange™ tool, when used with the Adjust-A-Fit™ tool, is an alignment tool for fittings that uses gravity to make lining up fittings a trouble-free, one man operation.

SPECIAL FEATURES:

- Fits all flanges for 5" pipe and larger with bolt holes 3/4" to 1-5/8" (19 to 42 mm)
- Used in combination with the Adjust-A-Fit to bring pipe flanges to exact plumb for tack and weld-out
- Handles loads up to 1,000 lbs.
- Flange nuts serve as convenient reference points to check level

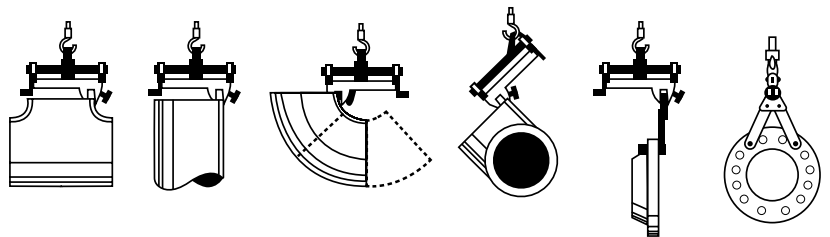

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY	MINIMUM FLANGE HOLE	MAXIMUM FLANGE HOLE
780425	Adjust-A-Flange™	ST-105	661165804256	1,000 lbs.	3/4"	1-5/8"

NYLON EXPANSION PLUGS

Sumner Nylon Expansion Plugs are ideal for pipework leak testing of drains, pools, spas and purging.

SPECIAL FEATURES:

- Rubber rings are resistant to many chemicals and sea water corrosion
- Hollow shaft with screw cap for sealing or venting
- Available individually or as a kit



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	RANGE (INCH)	LENGTH OF SEAL
786055	3/4 - 4" Expansion Plug Kit*	NEP3/4-4KIT	661165860559	.7-4.33	.78-1.38"
786060	3/4" Nylon Expansion Plugs	NEP3/4	661165860603	.7-.95	.78"
786061	1" Nylon Expansion Plugs	NEP1	661165860610	.90-1.26	1"
786062	1-1/4" Nylon Expansion Plugs	NEP1-1/4	661165860627	1.22-1.65	1.22"
786063	1-1/2" Nylon Expansion Plugs	NEP1-1/2	661165860634	1.46-2.13	1.22"
786064	2" Nylon Expansion Plugs	NEP2	661165860641	1.89-2.56	1.18"
786065	2 1/2" Nylon Expansion Plugs	NEP2-1/2	661165860658	2.36-3.03	1.26"
786066	3" Nylon Expansion Plugs	NEP3	661165860665	2.76-3.43	1.18"
786067	3 1/2" Nylon Expansion Plugs	NEP3-1/2	661165860672	3.27-3.82	1.18"
786068	4" Nylon Expansion Plugs	NEP4	661165860689	3.74-4.33	1.38"
779395	10MM X 1/4" HOSE BARB	HBARB10X1/4	661165793956	---	---
779396	1/2" BSP X 3/8" HOSE BARB	HBARB1/2X3/8	661165793963	---	---
OPTIONAL PLUG					
786070	6" Aluminum Expansion Plugs	NEP6	661165860702	5.83-6.38	1.46"

*Includes 2 of each of the Nylon Plugs and Hose Barbs (does not include the 786070)

PIPE FITTING

WELD GAS ANALYZER



The Sumner Argo-Naught Oxygen Analyzer for welding with accuracy to .1%.

SPECIAL FEATURES:

- Compact but durable housing
- Air and water-tight storage case included
- High measurement accuracy
- Quick response time
- Clear, large display

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
779281	Argo-Naught Weld Gas Analyzer	WGA	661165792812
779330	Argo-Naught Replacement Oxygen Sensor	OXYSENS	661165793307

PIPE FITTING

INFLATABLE PURGE STAR*



The Sumner two bag fast install inflatable Purge Star* systems are ideal for pipes 2" to 16".

SPECIAL FEATURES:

- Purge 2"-16" pipe in less than 3 minutes to less than 1% oxygen content
- Reduce argon usage
- Increase weld production rate
- Improve weld quality
- Designed for years of use
- Single inflation or double inflation

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE CAPACITY	HOSE TYPE
788001	2" Inflatable Purge Star*	SHPS2	661165792607	2"	SINGLE
	2.5" Inflatable Purge Star*			2.5"	
788003	3" Inflatable Purge Star*	SHPS3	661165792614	3"	SINGLE
788004	4" Inflatable Purge Star*	SHPS4	661165792621	4"	SINGLE
788005	5" Inflatable Purge Star*			5"	
788006	6" Inflatable Purge Star*	SHPS6	661165792638	6"	SINGLE
788007	8" Inflatable Purge Star*	SHPS8	661165792645	8"	SINGLE
788008	10" Inflatable Purge Star*	SHPS10	661165792652	10"	SINGLE
788009	12" Inflatable Purge Star*	DHPS12	661165792669	12"	DOUBLE
788010	14" Inflatable Purge Star*	DHPS14	661165792676	14"	DOUBLE
788011	16" Inflatable Purge Star*	DHPS16	661165792683	16"	DOUBLE

PIPE FITTING

PURGE BUDDY™ SYSTEMS



Save time and argon with the Sumner Purge Buddy™ systems.

SPECIAL FEATURES:

- Inflatable Pipe Stopper for pipes between 2" - 36"
- Latex bladder surrounded by fire-resistant fabric
- Pull loops for inside of the pipe
- 4.8' inflation hose
- Includes Spreader Valve for easy inflation
- Heat resistant to 210° F

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE CAPACITY
786080	2" Purge Buddy	PB2	661165860801	2"
786081	3" Purge Buddy	PB3	661165860818	3"
786082	4" Purge Buddy	PB4	661165860825	4"
786083	5" Purge Buddy	PB5	661165860832	5"
786084	6" Purge Buddy	PB6	661165860849	6"
786085	8" Purge Buddy	PB8	661165860856	8"
786086	10" Purge Buddy	PB10	661165860863	10"
786087	12" Purge Buddy	PB12	661165860870	12"
786088	14" Purge Buddy	PB14	661165860887	14"
786089	16" Purge Buddy	PB16	661165860894	16"
786090	18" Purge Buddy	PB18	661165860900	18"
786091	20" Purge Buddy	PB20	661165860917	20"
786092	22" Purge Buddy	PB22	661165860924	22"
786093	24" Purge Buddy	PB24	661165860931	24"
786094	28" Purge Buddy	PB28	661165860948	28"
786095	30" Purge Buddy	PB30	661165860955	30"
786096	32" Purge Buddy	PB32	661165860962	32"
786097	36" Purge Buddy	PB36	661165860979	36"

WELDING GAGE



The Sumner welding gage measures internal hi-lo misalignment and root gap spacing.

SPECIAL FEATURES:

- Accurate quick check of internal hi-lo
- Root weld spacing with little effort
- Available in both imperial and metric

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781900	Welding Gage Imperial	WGAGEI	661165819007
781901	Welding Gage Metric	WGAGEM	661165819014

ROTARY GROUND CLAMP



The Sumner Rotary Ground Clamp is designed to put an end to tangled ground leads.

SPECIAL FEATURES:

- Rotary head turns with the pipe - puts an end to ground lead twist, tangle and wear
- Provides quick, positive ground for roll-out welding of pipe and fittings.
- Cuts down on weld pinholes caused by poor grounding
- Attaches and detaches in seconds
- Makes up ground leads three ways lug, clamp-on and bare cable
- Positive anti-arc bearings take loads up to 400
- Clamps on pipe lips up to 1"



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE CAPACITY
780435	Rotary Ground Clamp	ST-107	661165804355	1"

PIPE FITTING

FIT KITS™ TOOLS



The professional pipe fitter's welding clamp kit.

FIT KIT™ 2 - 6"

- A compact pipe fit-up kit containing Sumner's most commonly used fit-up tools
- Each Fit Kit™ 2 - 6" contains:
 - 2-6" Ultra Clamp* (Stock # 781150)
 - 2-6" Ultra Fit* (Stock # 781275)
 - 4-8" Internal Fit-Up Clamp (Stock # 784102)
 - Set of carbon steel Flange Pins (Stock # 780430)
 - MCB Level (Stock # 58281640)
 - Weldbox™ 2008 for storage (Stock # 779910)

FIT KIT™ 2 - 12"

- The Sumner Fit Kit™ 2 - 12" provides everything the pipe fitter needs, complete with Weldbox™ 3617 for storage
- Each Fit Kit™ 2 - 12" contains:
 - Four (4) Fold-A-Jack* (Stock # 781300)
 - 2-6" Ultra Clamp* (Stock # 781150)
 - 5-12" Ultra Clamp* (Stock # 781170)
 - 2-6" Ultra Fit* (Stock # 781275)
 - 5-12" Ultra Fit* (Stock # 781285)
 - 2-4" Internal Fit-Up Clamp (Stock # 784100)
 - 4-8" Internal Fit-Up Clamp (Stock # 784102)
 - 8-12" Internal Fit-Up Clamp (Stock # 784103)
 - MCB Level (Stock # 58281640)
 - Steel Square (Stock # 781920)
 - Set of Qwik Pins* (Stock # 781235)
 - Weldbox™ 3617 for storage (Stock # 779928)



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
780324	Fit Kit™ for 2-6" Pipe	FK2-6	661165803242
780315	Fit Kit™ for 2-12" Pipe	FK2-12	661165803150

MUL-T-SQUARE*



The Sumner Mul-T-Square* tool consists of two 45° blades that slide effortlessly in an industrial-strength plastic handle.

SPECIAL FEATURES:

- Lightweight durable aluminum construction
- Handles up to 8" flanges and up to 14" fittings
- Versatile for measuring 45° and 90° angle
- Blades marked with both imperial and metric units
- Comes with 10" and 14" arms
- Also available with 30" arms



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	ARM LENGTH
790000	Mul-T-Square* w/Standard Blades	MTS	661165900002	10" AND 14"
790030	Mul-T-Square* w/Extended Blade	MTSE	661165900309	30"
790021	Mul-T-Square* Blades only (2)	MTSBLADE	661165900217	10" AND 14"
790026	Mul-T-Square* Extended Blades only (2)	MTSEXTBLADE	661165900262	30"
790001	Mul-T-Square* Handle Only	790001	661165900019	---

ALUMINUM SQUARE



Aluminum standard squares from Sumner are marked with both imperial and metric units.

SPECIAL FEATURES:

- 24" x 16" standard square

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781921	Aluminum Square	ALSQ	661165819212

PIPE FITTING

MAGNETIC HOLDER



Sumner* magnetic holders can be used to position a standard builder's square for layout work or to create an ideal burning guide.

SPECIAL FEATURES:

- Use Magnetic Holders with a standard square to create an ideal torch guide
- Sold in packages of three (3)
- Holds squares up to 1/8" thick



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781895	Magnetic Holders (3)	MAGHOLD	661165818956

MULTI PURPOSE MAGNETIC FIXTURES



The Sumner Angle Welding Fixture accurately positions flat and round ferrous metal for welding and assembly.

SPECIAL FEATURES:

- Holds angles at 30°, 45°, 60°, 75°, and 90°
- Strong magnets allow for a hands-free hold
- Capable of 48.5 lbs. of holding force
- Available in 4 options: small, medium, large and multiple angle fixtures

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781885	Multiple Angle Welding Fixture	MZWF	661165818857
781886	Small Angle Welding Fixture	SAWF	661165818864
781887	Medium Angle Welding Fixture	MAWF	661165818871
781888	Large Angle Welding Fixture	LAWF	661165818888



MAGNETIC TORCH GUIDE KIT

Sumner magnetic torch guide can be used to layout work or to create an ideal burning guide.



SPECIAL FEATURES:

- Use to create an ideal burning guide
- Kit includes a 24" stainless-steel cutting rail and (2) magnetic holders

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781896	Magnetic Torch Guide	MAGTRCH	661165818963

PIPE FITTING

POCKET LEVEL



The Sumner Pocket Level is compact to accommodate many fit-up tasks.

SPECIAL FEATURES:

- Twin vial construction reads 0° and 90°
- Tough ABS plastic with a strong magnetic base
- Easy-to-read high impact acrylic bubble vials

ACCU-LEVEL



The Sumner Accu-level is a high-accuracy, portable level designed for pipe fitting and welding applications.

SPECIAL FEATURES:

- Features three vials (0°, 45°, and 90°)
- Made with rugged die-cast aluminum
- Grooved based that fits on pipe and conduit
- Earthen magnetic base
- Comes with belt holster

TORPEDO LEVEL



The Southwire™ Conduit Bending Level has high-visibility vials that are easy to read.

SPECIAL FEATURES:

- Three leveling vials set at 0°, 45°, and 90°
- Integrated light illuminates vials for better visibility
- Lightweight and durable aluminum construction
- Easy to read high-impact acrylic bubble vials
- V-grooved edge helps hold the level in place on pipe or conduit
- Water and impact resistant

MCBLEVEL



The Sumner Pocket Level is compact to accommodate many fit-up tasks.

SPECIAL FEATURES:

- Four leveling vials set at 0°, 30°, 45°, and 90°
- Four powerful magnets for hands-free operation
- Easy to read high impact acrylic bubble vials
- V-grooved edge helps hold the level in place on pipe or conduit
- Lightweight and durable aluminum construction
- Set screw secures level to conduit

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
781947	Pocket Level	PLVL	661165819472
781950	Accu-level	ALVL	661165819502
58281840	Torpedo Level 9"	LVLTOR9	032886911026
58281640	Conduit Bending Level 6"	MCBLEVEL	032886908606

WELDER'S STOOL



The Sumner tractor style welder's stool is designed specifically for fabrication shops.

SPECIAL FEATURES:

- Stamped steel seat with air holes
- Designed for comfort even during 8 hour shifts
- High strength steel construction
- Uses Sumner lock washer for quick height adjustment
- 300 lbs. capacity
- Max. height: 22"
- Min. height: 15"

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
785800	Welder's Stool	WS1	661165858006

JACK STANDS

Sumner's line of Heavy Duty Jacks sets a new industry standard. With superior support, our product line of Jack Stands can accomplish your goals while saving you time and energy.



HEAVY DUTY JACKS



The Sumner Heavy Duty jacks are a fixed leg stand constructed of rugged 1" steel tubing.

SPECIAL FEATURES:

- Designed for large loads up to 2,500 lbs. depending on the head option
- Patented Fall Guard™ feature allows 1" safety zone around lock washer
- Set screw can lock jack head to stand for transportation - no loose pieces
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Breaks down for easy storage
- Available with 7 head options



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
HI HEAVY DUTY				
780375	Hi Heavy Duty Jack w/Vee Head	ST-801	661165803754	2500 lbs.
780376	Hi Heavy Duty Jack w/Roller Head	ST-802	661165803761	2500 lbs.
780377	Hi Heavy Duty Jack w/Bar Stock Head	ST-803	661165803778	2000 lbs.
780378	Hi Heavy Duty Jack w/Stainless Steel Rollers	ST-804	661165803785	2000 lbs.
780379	Hi Heavy Duty Jack w/Stainless Steel Vee Head	ST-805	661165803792	2500 lbs.
780380	Hi Heavy Duty Jack w/Ball Transfer Head	ST-806	661165803808	1000 lbs.
780381	Hi Heavy Duty Jack w/Phenolic Wheels	ST-807	661165803815	1200 lbs.
LOW-HEAVY DUTY				
780385	Lo Heavy Duty Jack w/Vee Head	ST-901	661165803853	2500 lbs.
780386	Lo Heavy Duty Jack w/Roller Head	ST-902	661165803860	2500 lbs.
780387	Lo Heavy Duty Jack w/Bar Stock Head	ST-903	661165803877	2000 lbs.
780388	Lo Heavy Duty Jack w/Stainless Steel Rollers	ST-904	661165803884	2000 lbs.
780389	Lo Heavy Duty Jack w/Stainless Steel Vee Head	ST-905	661165803891	2500 lbs.
780390	Lo Heavy Duty Jack w/Ball Transfer Head	ST-906	661165803907	1000 lbs.
780391	Lo Heavy Duty Jack w/Phenolic Wheels	ST-907	661165803914	1200 lbs.
HI HEAVY DUTY PLUS				
780326	Hi Heavy Duty Jack Plus w/Ribbed Vee	HIHDPLUS	661165803266	3500 lbs.

JACKS

PRO-JACK*



The Sumner Pro-Jack* stand is an economical fixed leg support stand.

SPECIAL FEATURES:

- Designed for large loads up to 2,500 lbs
- Patented Fall Guard™ feature allows 1" safety zone around lock washer
- Set screw can lock jack head to stand for transportation - no loose pieces
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Available with 7 head options

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
780471	Hi Pro-Jack* w/Vee Head	ST-871	661165804713	2500 lbs.
780472	Hi Pro-Jack* w/Roller Head	ST-872	661165804720	2500 lbs.
780473	Hi Pro-Jack* w/Bar Stock Head	ST-873	661165804737	2000 lbs.
780474	Hi Pro-Jack* w/Stainless Steel Rollers	ST-874	661165804744	2000 lbs.
780475	Hi Pro-Jack* w/Stainless Steel Vee Head	ST-875	661165804751	2500 lbs.
780476	Hi Pro-Jack* w/Ball Transfer Head	ST-876	661165804768	1000 lbs.
780477	Hi Pro-Jack* w/Phenolic Wheels	ST-877	661165804775	1200 lbs.

FOLD-A-JACK*



The Sumner Fold-A-Jack* stand is a light weight, collapsible, tri-leg pipe stand available in two heights to serve most fabrication sites.

SPECIAL FEATURES:

- Designed for large loads up to 2,500 lbs.
- Patented Fall Guard™ feature allows 1" safety zone around lock washer
- Easy grip carrying handle for breakdown and transportation
- Set screw can lock jack head to stand for transportation - no loose pieces
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Available with 7 head options

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
HI FOLD-A-JACK*				
781300	Hi Fold-A-Jack* w/Vee Head	ST-881	661165813005	2500 lbs.
781301	Hi Fold-A-Jack* w/Roller Head	ST-882	661165813012	2500 lbs.
781302	Hi Fold-A-Jack* w/Bar Stock Head	ST-883	661165813029	2000 lbs.
781303	Hi Fold-A-Jack* w/Stainless Steel Rollers	ST-884	661165813036	2000 lbs.
781304	Hi Fold-A-Jack* w/Stainless Steel Vee Head	ST-885	661165813043	2500 lbs.
781305	Hi Fold-A-Jack* w/Ball Transfer Head	ST-886	661165813050	1000 lbs.
781306	Hi Fold-A-Jack* w/Phenolic Wheels	ST-887	661165813067	1200 lbs.
LOW FOLD-A-JACK*				
781310	Lo Fold-A-Jack* w/Vee Head	ST-981	661165813104	2500 lbs.
781311	Lo Fold-A-Jack* w/Roller Head	ST-982	661165813111	2500 lbs.
781313	Lo Fold-A-Jack* w/Stainless Steel Roller Head	ST-983	661165813135	2000 lbs.
781314	Lo Fold-A-Jack* w/Stainless Steel Vee Head	ST-984	661165813142	2500 lbs.
781315	Lo Fold-A-Jack* w/Ball Transfer Head	ST-985	661165813159	1000 lbs.
781316	Lo Fold-A-Jack* w/Phenolic Wheels	ST-986	661165813166	1200 lbs.

JACKS

FAT JACK™



The Sumner Fat Jack™ stand is a collapsible base constructed of rugged 1.25" steel tubing.


SPECIAL FEATURES:

- Designed for large loads up to 6,000 lbs.
- Easy grip carrying handle for breakdown and transportation
- Double locking pin system for fast height adjustment
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Breaks down for easy storage
- Available with 2 head options and 2 sizes

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
MAXI FAT JACK™				
787900	Maxi FAT Jack™ w/ Vee Head	MAXIFJVH	661165852509	6000 lbs.
787903	Maxi FAT Jack™ w/ Roller Head	MAXIFJRH	661165852554	6000 lbs.
MIDI FAT JACK™				
787901	Midi FAT Jack™ w/ Vee Head	MIDIFJVH	661165852516	6000 lbs.
787904	Midi FAT Jack™ w/ Roller Head	MIDIFJRH	661165852561	6000 lbs.
MINI FAT JACK™				
787902	Mini FAT Jack™ w/ Vee Head	MINIFJVH	661165852523	6000 lbs.
787905	Mini FAT Jack™ w/ Roller Head	MINIFJRH	661165852578	6000 lbs.

HI BOY™

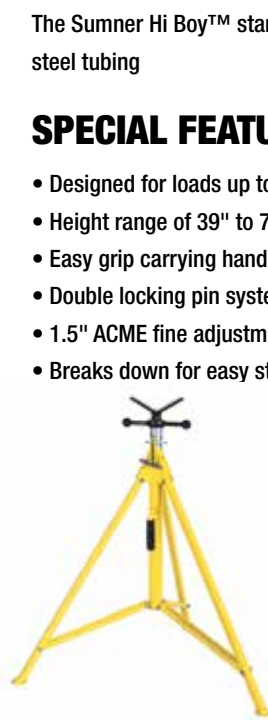

The Sumner Hi Boy™ stand is a collapsible base constructed of rugged 1.25" steel tubing

SPECIAL FEATURES:

- Designed for loads up to 1,000 lbs.
- Height range of 39" to 72"
- Easy grip carrying handle for breakdown and transportation
- Double locking pin system for fast height adjustment
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Breaks down for easy storage

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
783250	Hi Boy™ Jack w/Vee Head	HIBOY	661165832501	1000 lbs.

JACKS

FAB SAF™ JACK



The Sumner FAB SAF™ jacks are a fixed leg wide base stand constructed of rugged 1" steel tubing.

SPECIAL FEATURES:

- Designed for large loads up to 3,500 lbs. capacity on the Vee Head and 2,500 lbs. capacity on the Roller Head
- 30" Wide Heavy Duty Base for added stability
- Patented Fall Guard™ feature allows 1" safety zone around lock washer
- Set screw can lock jack head to stand for transportation - no loose pieces
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Breaks down for easy storage
- Available with 2 head options

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
780395	FAB SAF™ Jack w/Vee Head	FABSAFV	661165803952	3500 lbs.
780400	FAB SAF™ Jack w/Roller Head	FABSAFRH	661165804003	2500 lbs.

ADJUST-A-ROLL™



The Sumner* Adjust-A-Roll™ stand has a wide four-legged base and quick change head making it ideal for pipe rotation and fabrication.

SPECIAL FEATURES:

- Large 1/2" to 36" or 2,500 lbs. pipe capacity
- 30" Wide Heavy Duty Base for added stability
- Bronze bearing design reduces arcing
- Large handle makes for easy adjustment even with a gloved hand
- Smooth roller adjustment accessible from either side
- Quick change head and fine adjustment screw for precise pipe rotation
- Available with 5 head attachments and 3 sizes



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
HI ADJUST-A-ROLL™				
780365	Hi Adjust-A-Roll™ w/ AL Roller Wheels	ST-601	661165803655	2500 lbs.
780366	Hi Adjust-A-Roll™ w/Ball Transfer Head	ST-602	661165803662	1000 lbs.
780367	Hi Adjust-A-Roll™ w/Phenolic Wheels	ST-603	661165803679	1200 lbs.
780368	Hi Adjust-A-Roll™ w/Stainless Steel Wheels	ST-604	661165803686	2000 lbs.
780369	Hi Adjust-A-Roll™ w/Bar Stock Head	ST-605	661165803693	2000 lbs.
780399	Hi Adjust-A-Roll™ Hi, Base Only	ST60BASE	661165803990	2500 lbs.
LO ADJUST-A-ROLL™				
780370	Lo Adjust-A-Roll™ w/ AL Roller Wheels	ST-701	661165803709	2500 lbs.
780371	Lo Adjust-A-Roll™ w/Ball Transfer Head	ST-702	661165803716	1000 lbs.
780372	Lo Adjust-A-Roll™ w/Phenolic Wheels	ST-703	661165803723	1200 lbs.
780373	Lo Adjust-A-Roll™ w/Stainless Steel Wheels	ST-704	661165803730	2000 lbs.
780359	Lo Adjust-A-Roll™ w/Bar Stock Head	ST-705	661165803594	2000 lbs.
780405	Lo Adjust-A-Roll™ Base Only	ST70BASE	661165804058	2500 lbs.
TABLE ADJUST-A-ROLL™				
780360	Table Adjust-A-Roll™ w/ AL Roller Wheels	ST-501	661165803600	2500 lbs.
780361	Table Adjust-A-Roll™ w/Ball Transfer Head	ST-502	661165803617	1000 lbs.
780362	Table Adjust-A-Roll™ w/Phenolic Wheels	ST-503	661165803624	1200 lbs.
780363	Table Adjust-A-Roll™ w/Stainless Steel Wheels	ST-504	661165803631	2000 lbs.
780364	Table Adjust-A-Roll™ w/Bar Stock Head	ST-505	661165803648	2000 lbs.
780500	Table Adjust-A-Roll™ Base Only	ST50BASE	661165805000	2500 lbs.

JACKS

MINI-ROLL™



The Sumner Mini-Roll™ roller has a wide four-legged base and quick change head making it ideal for pipe rotation and fabrication.

SPECIAL FEATURES:

- Large 1/2" to 36" or 3,500 lbs. pipe capacity
- Small footprint of 11" wide by 22" long
- Bronze bearing design reduces arcing
- Large handle makes for easy adjustment even with a gloved hand
- Smooth roller adjustment accessible from either side
- Quick change head and fine adjustment screw for precise pipe rotation
- Available with 3 head attachments

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
785280	Mini-Roll w/AL Roller Wheels	ST-551	661165852806	3500 lbs.
785282	Mini-Roll w/Phenolic Wheels	ST-553	661165852820	1200 lbs.
785283	Mini-Roll w/Stainless Steel Wheels	ST-554	661165852837	2000 lbs.
785285	Mini-Roll, Base Only	ST-55BASE	661165852851	3500 lbs.

PRO ROLL™



The Sumner Pro Roll™ stand has a wide four-legged base and adjustable height making it ideal for pipe rotation and fabrication.

SPECIAL FEATURES:

- Large 1/2" to 36" or 2,500 lbs. pipe capacity
- Bronze bearing design reduces arcing
- Large handle makes for easy adjustment even with a gloved hand
- Smooth roller adjustment accessible from either side
- Quick change head and fine adjustment screw for precise pipe rotation
- Available with 5 head attachments

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
780441	Pro Roll™ w/AL Roller Wheels	ST-401	661165804416	2500 lbs.
780442	Pro Roll™ w/Ball Transfer Head	ST-402	661165804423	1000 lbs.
780443	Pro Roll™ w/Phenolic Wheels	ST-403	661165804430	1200 lbs.
780444	Pro Roll™ w/Stainless Steel Wheels	ST-404	661165804447	2000 lbs.
780446	Pro Roll™ w/Bar Stock Head	ST-405	661165804461	2000 lbs.
780440	Pro Roll™ , Base Only	ST-40BASE	661165804409	2500 lbs.

JACKS

BIG V*



The Sumner Big V* jack stand is a heavy-duty jack stand and is built tough for the demands of larger pipes.

SPECIAL FEATURES:

- Designed for large pipe the Big V* can hold up to 2,500 lbs.
- The large 12" vee head supports pipe sizes ranging from 4" to 36"
- Fast action adjustment handle
- Wide base tri-stand provides superior balance
- 6 different head options available



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
780260	Big V* (Basic) with Standard Big Vee Head	BIGVB	661165802603	2500 lbs.
OPTIONAL BIG V™ ACCESSORIES				
781382	Stainless Steel Sleeves (4)	MJ-SS	661165813821	2500 lbs.
781383	Ball Transfers (2)	MJ-BT	661165813838	1000 lbs.
781394	Phenolic Wheels Kit (4)	MJ-RB	661165813944	1200 lbs.
781397	Stainless Steel Ball Transfers (2)	MJ-BTSS	661165813975	1000 lbs.
781406	Aluminum Roller Head Kit (4)	MJ-RH	661165814064	2500 lbs.
781407	Stainless Steel Roller Head Kit (4)	MJ-RHSS	661165814071	2000 lbs.

MAX JAX*



781403

The Sumner MAX JAX* fabrication stands are the ideal 5-legged stand for fit-up, rotating and welding.

SPECIAL FEATURES:

- Designed for loads up to 4,500 lbs.
- Designed to hold 6" to 36" pipe (781403) or 4" to 36" pipe (781460)
- Large 12" roller vee head included
- 5-leg base construction ensures stability
- Available in fixed base design or with 8" casters
- Optional head attachments available



781460



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
781460	MAX JAX* Basic - includes vee head & leveling pads	MJAXB	661165814606	4500 lbs.
781403	MAX JAX* Kit No. 1 - includes roller head kit and casters	MJAXKIT1	661165814033	4500 lbs.
OPTIONAL MAX JAX* ACCESSORIES				
781382	Stainless Steel Sleeves (4)	MJ-SS	661165813821	4500 lbs.
781383	Ball Transfers (2)	MJ-BT	661165813838	1000 lbs.
781394	Phenolic Wheel Kit (4)	MJ-RB	661165813944	1200 lbs.
781397	Stainless Steel Ball Transfers (2)	MJ-BTSS	661165813975	1000 lbs.
781406	Aluminum Roller Head Kit (4)	MJ-RH	661165814064	4500 lbs.
781407	Stainless Steel Roller Head Kit (4)	MJ-RHSS	661165814071	2000 lbs.
781464	Caster Kit (5) Standard	MJ-CK	661165814644	4500 lbs.
781465	Caster Kit (5) Steel Casters	MJ-CKS	661165814651	4500 lbs.
781050	Hold Down Device	HDD-01	661165810509	---
781056	Hold Down Device Chain Ext. Kit (12")	HDD-EXT	661165810561	---

JACKS

MAX JAX* 2 STAND



786450

The Sumner MAX JAX* 2 upgraded fabrication stands are the ideal high and low stand for fit-up, rotating and welding.

SPECIAL FEATURES:

- Designed for loads up to 4,500 lbs.
- Designed to hold 4" to 36" pipe
- Dual height range of 21.5" to 32" low or 26.5" to 36" high
- 5-leg base construction with adjustable 6" casters ensure stability
- Optional head attachments available



786451

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
786451	MAX JAX* Kit 2 w/Drop Slot Head	MJAX2RR	661165864519	4500 lbs.
786450	MAX JAX* Kit 2 w/Large Vee & Rollers	MJAX2	661165864502	4500 lbs.
OPTIONAL MAX JAX* ACCESSORIES				
781382	Stainless Steel Sleeves (4)	MJ-SS	661165813821	4500 lbs.
781383	Ball Transfers (2)	MJ-BT	661165813838	1000 lbs.
781394	Phenolic Wheel Kit (4)	MJ-RB	661165813944	1200 lbs.
781397	Stainless Steel Ball Transfers (2)	MJ-BTSS	661165813975	1000 lbs.
781406	Aluminum Roller Head Kit (4)	MJ-RH	661165814064	4500 lbs.
781407	Stainless Steel Roller Head Kit (4)	MJ-RHSS	661165814071	2000 lbs.
781464	Caster Kit (5) Standard	MJ-CK	661165814644	4500 lbs.
781465	Caster Kit (5) Steel Casters	MJ-CKS	661165814651	4500 lbs.
781050	Hold Down Device	HDD-01	661165810509	---
781056	Hold Down Device Chain Ext. Kit (12")	HDD-EXT	661165810561	---

BEAM JAX™

The Sumner Beam Jax™ stand is designed to secure beams for fabrication.

SPECIAL FEATURES:

- Designed for loads up to 2,500 lbs.
- Designed for beams up to 24"
- Clamping device centers load on stand and holds material in place
- 5-leg base construction ensures stability
- Reversible beam fork design
- Detachable handle can be rotated out of operator's way
- Available as a kit with leveling pads or casters 8" casters



781486



781485

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
781485	Basic Beam Jax™ - includes leveling pads	BJAX	661165814859	2500 lbs.
781486	Beam Jax™ Kit - includes casters	BJAXKIT	661165814866	2500 lbs.

JACKS

REEL MAC™



The Sumner Reel Mac™ jack stands are a heavy-duty version of the traditional reel stand with capacity up to 3,750 lbs.

SPECIAL FEATURES:

- Designed for large loads up to 3,750 lbs. depending on reel stand
- Height range of 13" - 45" depending on reel stand
- Extra strength double locking pin for quick set up
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Designed to work with the Sumner Reel/Econo Mac Spindles

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
REEL MAC™				
780941	Reel Mac™ No. 60	CJ02	661165809411	2500 lbs.
780942	Reel Mac™ No. 70	CJ01	661165809428	2500 lbs.
780943	Reel Mac™ No. 80	CJ03	661165809435	3750 lbs.
OPTIONAL REEL MAC™ ACCESSORIES				
780229	No. 61 Reel Mac™ Spindle (62")	SA60	661165802290	5000 lbs.
780230	No. 71 Reel Mac™ Spindle (76")	SA70	661165802306	5000 lbs.

HOLD DOWN DEVICE



The Sumner Hold Down Device is ideal for securing material on vee head jacks for transportation and fit-ups.

SPECIAL FEATURES:

- Designed for use on up to 12" pipe
- Heavy-duty design featuring high tensile strength chain
- 12" chain extensions available for increased capacity

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE DIAMETER
781050	Hold Down Device	HDD-01	661165810509	12"
781056	Hold Down Device Chain Ext. Kit (12")	HDD-EXT	661165810561	12"

HOLD-E*



The Sumner Hold-E* Pipe Clamp is designed to quickly secure pipe or tubing to vee head jack stands.

SPECIAL FEATURES:







- Designed for 3/4" to 6" pipe or 1" to 6.5" tubing
- Push button design allows for rapid action setting and fine tune thread adjustment
- Jobsite ready with a heavy duty design
- Large threads and vee jaw provide a secure clamping force
- Available in 2 options

SPECIFICATIONS







ITEM #	DESCRIPTION	MODEL #	UPC	MINIMUM PIPE DIAMETER	MAXIMUM PIPE DIAMETER
785000	Hold-E*	HOLDE	661165850000	3/4"	6"
784999	Stainless Steel Hold-E*	HOLDESS	661165849998	3/4"	6"

JACKS

JACKS | SPECIFICATIONS



PIPE STAND	PART #	DESCRIPTION	LOAD CAPACITY	MIN PIPE CAPACITY	MAX PIPE CAPACITY	MIN. HEIGHT	MAX HEIGHT	WIDTH	LENGTH	WEIGHT
FOLD-A-JACK™										
	781300	HI FAJ - Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)	28" (71 cm)	49" (125 cm)	22" (56 cm)	22" (56 cm)	25 lbs.
	781301	HI FAJ - AL Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					28 lbs.
	781302	HI FAJ - Bar Stock	2,000 lbs.	1/8" (3 mm)	10" (250 mm)					25 lbs.
	781303	HI FAJ - SS Roller	2,000 lbs.	1-1/4" (30 mm)	24" (600 mm)					29 lbs.
	781304	HI FAJ - SS Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					24 lbs.
	781305	HI FAJ - Ball Trans	1,000 lbs.	3/8" (10 mm)	12" (300 mm)					29 lbs.
	781306	HI FAJ - Phenolic Wheels	1,200 lbs.	1-1/2" (40 mm)	24" (600 mm)	21" (51 cm)	36" (89 cm)	15-1/2" (39 cm)	15-1/2" (39 cm)	26 lbs.
	781310	LO FAJ - Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					21 lbs.
	781311	LO FAJ - AL Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					24 lbs.
	781313	LO FAJ - SS Roller	2,000 lbs.	1-1/4" (30 mm)	24" (600 mm)					24 lbs.
	781314	LO FAJ - SS Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					22 lbs.
	781315	LO FAJ - Ball Trans	1,000 lbs.	3/8" (10 mm)	12" (300 mm)					25 lbs.
781316	LO FAJ - Phenolic Whls	1,200 lbs.	1-1/2" (40 mm)	24" (600 mm)	22 lbs.					
HEAVY DUTY JACK™										
	781375	HI HD - Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)	28" (71 cm)	49" (125 cm)	22" (56 cm)	22" (56 cm)	24 lbs.
	781376	HI HD - AL Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					27 lbs.
	781377	HI HD - Bar Stock	2,000 lbs.	1/8" (3 mm)	10" (250 mm)					24 lbs.
	781378	HI HD - SS Roller	2,000 lbs.	1-1/4" (30 mm)	24" (600 mm)					28 lbs.
	781379	HI HD - SS Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					24 lbs.
	781380	HI HD - Ball Trans	1,000 lbs.	3/8" (10 mm)	12" (300 mm)					27 lbs.
	781381	HI HD - Phenolic Wheels	1,200 lbs.	1-1/2" (40 mm)	24" (600 mm)	21" (51 cm)	36" (89 cm)	15-1/2" (39 cm)	15-1/2" (39 cm)	26 lbs.
	781385	LO HD - Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					19 lbs.
	781386	LO HD - AL Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					22 lbs.
	781387	LO HD - Bar Stock	2,000 lbs.	1/8" (3 mm)	24" (600 mm)					18 lbs.
	781388	LO HD - SS Roller	2,000 lbs.	1-1/4" (30 mm)	24" (600 mm)					22 lbs.
	781389	LO FAJ - SS Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					19 lbs.
781390	LO FAJ - Ball Trans	1,000 lbs.	3/8" (10 mm)	12" (300 mm)	22 lbs.					
781391	LO FAJ - Phenolic Whls	1,200 lbs.	1-1/2" (40 mm)	24" (600 mm)	21 lbs.					
HEAVY DUTY JACK™ PLUS										
	780326	HD PLUS - Vee	3,500 lbs.	1/8" (3 mm)	24" (600 mm)	28" (71 cm)	49" (125 cm)	22" (56 cm)	22" (56 cm)	24 lbs.
PRO-JACK™										
	780471	HI PRO - Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)	28" (71 cm)	49" (125 cm)	24" (61 cm)	24" (61 cm)	23 lbs.
	780472	HI PRO - AL Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					26 lbs.
	780473	HI PRO - Bar Stock	2,000 lbs.	1/8" (3 mm)	10" (250 mm)					23 lbs.
	780474	HI PRO - SS Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					26 lbs.
	780475	HI PRO - SS Vee	2,500 lbs.	1/8" (3 mm)	24" (600 mm)					24 lbs.
	780476	HI PRO - Ball Trans	1,000 lbs.	3/8" (10 mm)	12" (300 mm)					28 lbs.
	780477	HI PRO - Phenolic Wheels	1,200 lbs.	1-1/2" (40 mm)	24" (600 mm)					25 lbs.

JACKS

PIPE STAND	PART #	DESCRIPTION	LOAD CAPACITY	MIN PIPE CAPACITY	MAX PIPE CAPACITY	MIN. HEIGHT	MAX HEIGHT	WIDTH	LENGTH	WEIGHT	
FAT JACK™											
	787900	Maxi Fat Jack™ - Vee	6,000 lbs.	1/8" (3 mm)	36" (900 mm)	36"	61" (154.9 cm)	34" (86.3 cm)	34" (86.3 cm)	47 lbs.	
	787901	Midi Fat Jack™ - Vee				26.5"	44.5" (113 cm)	21" (53.3 cm)	21" (53.3 cm)	37 lbs.	
	787902	Mini Fat Jack™ - Vee				16"	28.5" (72.4 cm)	19" (48.3 cm)	19" (48.3 cm)	28 lbs.	
	787903	Maxi Fat Jack™ - AL Roller			24" (600 mm)	36"	61" (154.9 cm)	34" (86.3 cm)	34" (86.3 cm)	47 lbs.	
	787904	Midi Fat Jack™ - AL Roller				26.5"	44.5" (113 cm)	21" (53.3 cm)	21" (53.3 cm)	37 lbs.	
	787905	Mini Fat Jack™ - AL Roller				16"	28.5" (72.4 cm)	19" (48.3 cm)	19" (48.3 cm)	28 lbs.	
FAB SAF™ JACK											
	780395	FAB SAF™ - Vee	3,500 lbs.	1/8" (3 mm)	36" (900 mm)	32" (81 cm)	52" (132 cm)	30" (76 cm)	30" (76 cm)	26 lbs.	
	780400	FAB SAF™ - Roller	2,500 lbs.	1-1/4" (30 mm)	24" (600 mm)					26 lbs.	
HI BOY™											
	783250	HI BOY™	1,000 lbs.	1/8" (3 mm)	24" (600 mm)	39" (98 cm)	72" (180 cm)	38" (97 cm)	38" (97 cm)	45 lbs.	
ADJUST-A-ROLL™											
	780365	HI AAR - Alum Whls	2,500 lbs.	1/2" (12 mm)	36" (900 mm)	31" (78 cm)	23" (58 cm)	32" (81 cm)	35 lbs.		
	780366	HI AAR - Ball Trans	1,000 lbs.						38 lbs.		
	780367	HI AAR - Phenolic Wheels	1,200 lbs.						34 lbs.		
	780368	HI AAR - SS Whls	2,000 lbs.						35 lbs.		
	780369	HI AAR - Bar Stock	2,000 lbs.						39 lbs.		
	780370	LO AAR - Alum Whls	2,500 lbs.	1/2" (12 mm)	36" (900 mm)	24" (61 cm)	22" (56 cm)	31" (79 cm)	24 lbs.		
		780371	LO AAR - Ball Trans						1,000 lbs.	24 lbs.	
		780372	LO AAR - Phenolic Wheels						1,200 lbs.	32 lbs.	
		780373	LO AAR - SS Whls						2,000 lbs.	34 lbs.	
		780359	LO AAR - Bar Stock						2,000 lbs.	37 lbs.	
	780360	TBL AAR - Alum Whls	2,500 lbs.	1/2" (12 mm)	36" (900 mm)	7" (18 cm)	6-1/4" (16 cm)	22" (56 cm)	22 lbs.		
		780361	TBL AAR - Ball Trans						1,000 lbs.	5-3/4" (15 cm)	22 lbs.
		780362	TBL AAR - Phenolic Wheels						1,200 lbs.	7" (18 cm)	20 lbs.
		780363	TBL AAR - SS Whls						2,000 lbs.	7" (18 cm)	22 lbs.
		780364	TBL AAR - Bar Stock						2,000 lbs.	5-3/4" (15 cm)	24 lbs.
	PRO ROLL™										
	780441	PRO ROLL™ - Alum Whls	2,500 lbs.	1/2" (12 mm)	36" (900 mm)	29" (79 cm)	43" (109 cm)	23" (58 cm)	32" (81 cm)	47 lbs.	
	780442	PRO ROLL™ - Ball Trans	1,000 lbs.							49 lbs.	
	780443	PRO ROLL™ - Phenolic Wheels	1,200 lbs.							45 lbs.	
	780444	PRO ROLL™ - SS Whls	2,000 lbs.							47 lbs.	
	780446	PRO ROLL™ - Bar Stock	2,000 lbs.							49 lbs.	
BIG V* JACK											
	780260	BIG V*	2,500 lbs.	4" (100 mm)	36" (900 cm)	29-1/2" (75 cm)	41" (109 cm)	29-1/2" (75 cm)	29-1/2" (75 cm)	36 lbs.	

JACKS

JACKS | SPECIFICATIONS

PIPE STAND	PART #	DESCRIPTION	LOAD CAPACITY	MIN PIPE CAPACITY	MAX PIPE CAPACITY	MIN. HEIGHT	MAX HEIGHT	WIDTH	LENGTH	WEIGHT
MAX JAX* & MAX JAX* 2										
	781460	Max Jax* Basic	4,500 lbs.	4" (100 mm)	36" (900 mm)	21" (53 cm)	33" (84 cm)	29-5/8" (75 cm)	29-5/8" (75 cm)	68 lbs.
	781403	Max Jax* Kit Includes Casters (Roller Head)				30-1/2" (78 cm)	42-1/2" (108 cm)	34" (100 cm)	34" (100 cm)	144 lbs.
	786450	Max Jax* 2 Kit #1 (Vee Head)				33" (133 cm)	21" (188 cm)	37.5" (95 cm)	37.5" (95 cm)	106 lbs.
	786451	Max Jax* 2 Kit #2 (Drop Slot Head)				21.5" (58 cm)	36.5" (91 cm)	37.5" (95 cm)	37.5" (95 cm)	127 lbs.
MAX JAX* & MAX JAX* 2 HEAD STYLES										
	781382	SS Sleeves	4,500 lbs.	4" (100 mm)	36" (900 mm)	---				8 lbs.
	781383	Ball Trans	1,000 lbs.	3/8" (9 mm)	36" (900 mm)					8 lbs.
	781394	Phenolic Wheels	1,200 lbs.	4" (100 mm)	36" (900 mm)					8 lbs.
	781397	SS Ball Trans	1,000 lbs.	3/8" (9 mm)	36" (900 mm)					5 lbs.
	781406	AL Roller	4,500 lbs.	4" (100 mm)	36" (900 mm)					8 lbs.
	781407	SS Roller	2,000 lbs.	4" (100 mm)	36" (900 mm)					8 lbs.
HEAD STYLES FOR SUMNER'S PRO JACK*, HEAVY DUTY & FOLD-A-JACK* STANDS										
HEAD STYLE	PART #	DESCRIPTION	CAPACITY	PIPE SIZE MAXIMUM						
	780518	Standard Vee Head	2,500 lbs.	24" (600 mm)						
	780498	Standard Vee Head w/SS Sleeve								
	780551	Ball Transfer Head	1,000 lbs.	12" (300 mm)						
	780274	Ball Transfer Head (Stainless Steel)								
	780514	Roller Head Assy. w/Steel Wheels	2,500 lbs.	24" (600 mm)						
	780517	Roller Head Assy. w/Aluminum Wheels	2,000 lbs.							
	780499	Phenolic Wheel Head	1,200 lbs.	24" (600 mm)						
	780519	Bar Stock Head for Hi Jack	2,000 lbs.	24" (600 mm)						
	780944	Bar Stock Head for Low Jack								

CARTS & STORAGE

Sumner offers a broad line of products to store and transport materials. With products like the Grasshopper, Handi-Benches, Pipe Macs, Bundle Macs, and many more - we set the standard for carts and storage.



CARTS & STORAGE

CRICKET*



The Sumner Cricket* cart is a versatile material and pipe cart.

SPECIAL FEATURES:

- Transports 20' pipe lengths up to 1,000 lbs.
- Comes with ratchet hold-down strap and 16" tubed tires
- Weighs only 82 lbs.
- Quick handle disconnect for compact storage
- Carries up to 12" diameter pipe
- Also available with Flat Free Tires



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE DIAMETER	LOAD CAPACITY
782699	Cricket*	CRKT	661165826999	12"	1,000 lbs.
782685	Cricket* w/Flat Free Tires	CRKTFF	661165826852	12"	1,000 lbs.

GRASSHOPPER*



The Sumner Grasshopper* dolly is a large capacity manual pipe dolly.

SPECIAL FEATURES:

- Enables one person to lift 2,000 lbs. unassisted
- Special sliding chain block design accommodates long and short loads
- Carries up to 20" diameter pipe, tool boxes, fittings and valves
- Fits through 35" openings
- Large diameter tires allow for construction site mobility
- Chains can be used to lock wheels for security

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	MAXIMUM PIPE DIAMETER	LOAD CAPACITY
780351	Grasshopper*	ST-401	661165803518	20"	2,000 lbs.

CARTS & STORAGE

HANDI-BENCH



The Sumner Handi-Bench is a versatile shop table.

SPECIAL FEATURES:

- Tough #9 expanded metal top
- 600 lbs. load capacity
- 1" square tube frame
- Collapsible design for storage
- Convenient 36" work height
- Compact and lightweight
- 24" x 40" work surface
- Complete with built-in torch holder
- Optional 8" wheel kit



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
783980	Handi-Bench	HB604	661165839807	600 lbs.
OPTIONS				
783965	8" Wheel Kit for Series 600 Handi-Bench	HB604WK	661165839654	---

CARTS & STORAGE

PIPE MAC™



783230



783240

The Sumner Pipe Mac™ cart is purposely built to transport large pipes and pipe bundles.

SPECIAL FEATURES:

- Transports 2,000 lbs. of pipe individually or up to a height of 34"
- Six 6" heavy-duty casters
- Center-positioned casters make rolling the Pipe Mac* cart easy and enables quick cart rotation for tight turns
- Removable posts for compact storage
- Stacks when not in use
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Includes Vee Attachment to prevent pipe from rolling when in motion
- Vee Attachment easily slips over the four post holders – no tools required

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
783230	Pipe Mac™ w/Vee	PMAC	661165832303	2,000 lbs.
OPTIONAL ACCESSORY				
783240	Pipe Mac™ Vee Attachment only	PMACVEE	661165832402	---

CARTS & STORAGE

HANGER MAC™



The Sumner Hanger Mac™ cart is a patented pipe hanger and transportation solution.

SPECIAL FEATURES:

- Eliminates multiple handling and reduces fabrication transport costs
- Available with or without wire mesh base
- Hanger Mac™ cart holds (40) 6-8" and (120) 2-4" pipe hangers
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Folds for compact storage and transportation without tools




SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
785650	Hanger Mac™ without mesh base	HMACI	661165856507
785651	Hanger Mac™ with mesh base	HMACII	661165856514

CARTS & STORAGE

MAC RACK I™ & MAC RACK II™

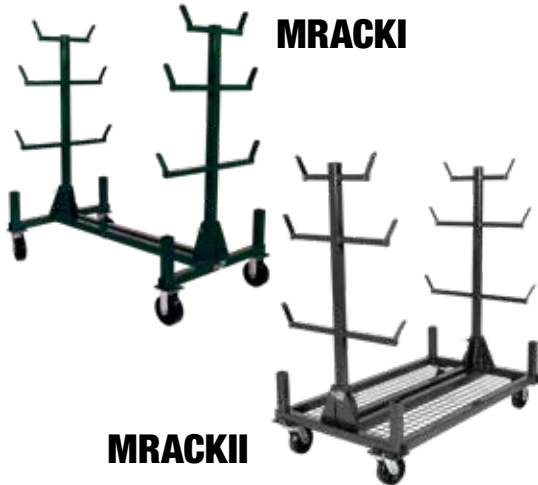

Sumner Mac Rack™ carts are mobile jobsite and conduit and pipe storage carts.

SPECIAL FEATURES:

- 1,000 lbs. weight capacity
- Double wall square tubing
- Eight storage sections
- Arms fold easily with plunger pins for compact storage
- Shipped assembled with 6" heavy-duty casters
- Durable powder coat finish
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Mac Rack II™ cart has a mesh deck for material storage



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
783317	Mac Rack I™	MRACKI	661165833171	1,000 lbs.
783299	Mac Rack II™ with Mesh Base	MRACKII	661165832990	1,000 lbs.

CARTS & STORAGE

BUNDLE MAC™



The Sumner Bundle Mac™ cart is designed to transport large quantities of conduit, strut, threaded rod, PVC pipe or copper tubing in one large cradle.

SPECIAL FEATURES:

- Arms fold easily with plunger pins for compact storage
- 1,000 lbs. load capacity
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Shipped assembled with 6" heavy-duty casters
- Durable powder coat finish



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
783320	Bundle Mac™	BMAC	661165833201	1,000 lbs.

CARTS & STORAGE

SMALL DOUBLE CYLINDER CARTS



782426

782428

The Sumner 209 cylinder carts are rated to carry (2) cylinders up to 9" in diameter.

SPECIAL FEATURES:

- The cylinder carts feature a balanced design for comfortable handling on smooth, level surfaces
- Carts come in a variety of configurations including wheel, accessory and tank support options
- Handle grips offer better control and stability
- Supports a 244-330 CF oxygen tank
- Supports 145 CF acetylene tank
- ** Lifting eye carts comply with ASME B30.20, AWS D14.1 and AISC codes.
- ***Fire-rated wall complies with OSHA 1926.350 & OSHA 1910.253.

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
782422	Cylinder Cart - 209-10P - 10" wheel	209-10P	661165824223
782424	Cylinder Cart - 209-14S - 14" wheel	209-14S	661165824247
782425	Cylinder Cart - 209-14SB - 14" wheel	209-14SB	661165824254
782427	Cylinder Cart - 209-16PB - 16" wheel	209-16PB	661165824278
782439** / ***	Cylinder Cart - 209-14SB-LF - 14" wheel	209-14SB-LF	661165824391
782441**	Cylinder Cart - 209-14SB-L - 14" wheel	209-14SB-L	661165824414
782443** / ***	Cylinder Cart - 209-16PB-LF - 16" wheel	209-16PB-LF	661165824438
782444** / ***	Cylinder Cart - 209-16FB-LF - 16" wheel	209-16FB-LF	661165824445

CARTS & STORAGE

MEDIUM DOUBLE CYLINDER CARTS



The Sumner 213 cylinder carts are rated to carry (2) cylinders up to 13" in diameter.

SPECIAL FEATURES:

- The cylinder carts feature a balanced design for comfortable handling on smooth, level surfaces
- Carts come in a variety of configurations including wheel, accessory, and tank support options
- Handle grips offer better control and stability
- Supports a 244-330 CF oxygen tank
- Supports 145 CF acetylene tank
- Includes Tool Tray
- **Lifting eye carts comply with ASME B30.20, AWS D14.1 and AISC codes
- ***Fire-rated wall complies with OSHA 1926.350 & OSHA 1910.253

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
782475	Cylinder Cart - 213-25W - 25" wheel	213-25W	661165824759
782480	Cylinder Cart - 213-14S - 14" wheel	213-14S	661165824803
782476** / ***	Cylinder Cart - 213-25WB-LF - 25" wheel	213-25WB-LF	661165824766
782491** / ***	Cylinder Cart - 213-14SB-LF - 14" wheel	213-14SB-LF	661165824919
782493**	Cylinder Cart - 213-14SB-L - 14" wheel	213-14SB-L	661165824933
782495** / ***	Cylinder Cart - 213-16PB-LF - 16" wheel	213-16PB-LF	661165824957
782496** / ***	Cylinder Cart - 213-16FB-LF - 16" wheel	213-16FB-LF	661165824964
782497** / ***	Cylinder Cart - 213-25PB-LF - 25" wheel	213-25PB-LF	661165824971
782482	Cylinder Cart - 213-16P - 16" wheel	213-16P	661165824827
782483	Cylinder Cart - 213-16PB - 16" wheel	213-16PB	661165824834

CARTS & STORAGE

SINGLE CYLINDER CART



The Sumner 108 cylinder cart is rated to carry (1) cylinder up to 8" in diameter and the Sumner 112 cylinder cart is rated to carry (1) cylinder up to 12" in diameter.

SPECIAL FEATURES:

- The cylinder carts feature a balanced design for comfortable handling on smooth, level surfaces
- Carts come in a variety of configurations including wheel, accessory, and tank support options
- Handle grips offer better control and stability
- Supports 50-80 CF oxygen tank or 40 CF acetylene tank


SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
782375	Cylinder Cart - 108-8S - 8" wheel	108-8S	661165823752
782385	Cylinder Cart - 112-10S - 10" wheel	112-10S	661165823851
782386	Cylinder Cart - 112-10P - 10" wheel	112-10P	661165823868

CARTS & STORAGE

HOW TO READ SUMNER CYLINDER CART PRODUCT DESCRIPTIONS

X X X - X X X X - X X

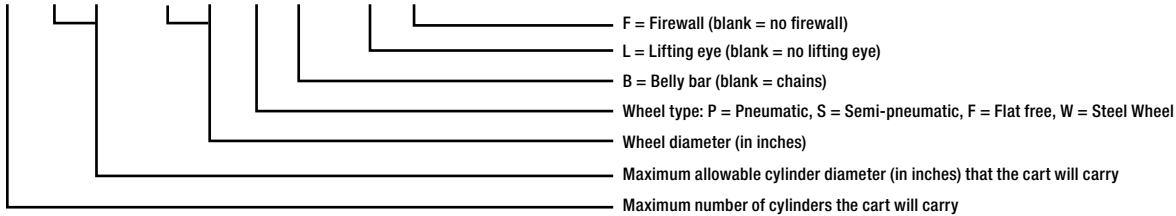

WHEEL	PART #	DESCRIPTION	DIAMETER	WIDTH	BORE	BEARING	LOAD CAPACITY	FITS CARTS
CYLINDER CART WHEELS								
	779024	Semi-pneumatic	8" (200 mm)	1.75" (44 mm)	0.5" (13 mm)	Powder Metal Bushing	80 lbs.	108
	779011	Semi-pneumatic	10" (250 mm)	2.75" (70 mm)	5/8" (16 mm)	Bronze Bushing	400 lbs.	112 207 208 209
	779027	Pneumatic	10" (250 mm)	3.5" (89 mm)	5/8" (16 mm)	Bronze Bushing	350 lbs.	112 209
	779028	Semi-pneumatic	14" (355 mm)	1.75" (44 mm)	5/8" (16 mm)	Bronze Bushing	150 lbs.	209 213
	779104	Flat Free	16" (400 mm)	4.8" (120 mm)	1" (25 mm)	Powder Metal Bushing	380 lbs.	209 213
	779107	Pneumatic	16" (400 mm)	4.8" (120 mm)	1" (25 mm)	Powder Metal Bushing	380 lbs.	209 213
	780521	Pneumatic	25" (50 mm)	4" (100 mm)	1.25" (32 mm)	Bronze Bushing	800 lbs.	213
	782575	Steel	25" (50 mm)	2" (50 mm)	1.25" (32 mm)	Bronze Bushing	800 lbs.	213

2 = Carries two cylinders 13 = 13" Maximum cylinder diameter 16 = 16" Wheel size F = Flat free tire B = Belly bar L = Lifting eye F = Firewall

CARTS & STORAGE | HOW-TO

LIFTS

Sumner continues its tradition of quality, reliability, and value with its line of lifts. Built and designed for the jobsite, these products help position materials safely and easily.



EL-405 STACKER LIFT



The Sumner EL-405 Stacker lift is ideal for warehouse and service departments.

SPECIAL FEATURES:

- Designed for loads up to 400 lbs.
- Lifting height of up to 53"
- Two speed winch handle allows for onsite flexibility
- Quick action wheel brake immobilizes load
- Large lifting surface for boxes and materials
- Extension strap kit available



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
784650	EL-405 Stacker Lift	EL-405	661165846508	53"	400 lbs.

SERIES 1900



The Sumner Series 1900 lift is designed for shipping, receiving, and lifting heavy materials on and off shelves and HVAC work.

SPECIAL FEATURES:

- Designed for loads up to 350 lbs.
- Forks reverse to maximize lifting height
- Easily breaks down for transport and storage
- 2-position straddle base
- 5" wheels to transport over rough terrain
- Two-speed winch handle offers leverage and speed



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
782051	Series 1910	1910	661165820515	10 ft.	350 lbs.

ROUST-A-BOUT™



The Sumner Roust-A-Bout™ lift enables one man to lift and place loads in tight locations that would be impossible with other lifts.

SPECIAL FEATURES:

- Designed for loads up to 1,500 lbs.
- Rugged 8" casters for horizontal movement
- Vertical adjustments made by 2-winch system allowing for separate operation of load and mast elevation
- Variable 4-speed load winch
- Ideal for use in the shop or on the jobsite
- Quickly breaks down for storage and transportation
- Available in 4 models in powder coating or galvanized finish



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
780300	R-100 Roust-A-Bout™	R-100	661165803006	15 ft.	1,500 lbs.
780301	R-150 Roust-A-Bout™	R-150	661165803013	15 ft.	1,500 lbs.
780302	R-180 Roust-A-Bout™	R-180	661165803020	18 ft.	1,500 lbs.
780303	R-250 Roust-A-Bout™	R-250	661165803037	25 ft.	1,500 lbs.
780195	R-100G Roust-A-Bout™ - Galvanized	R-100G	661165801958	15 ft.	1,500 lbs.
780194	R-150G Roust-A-Bout™ - Galvanized	R-150G	661165801941	15 ft.	1,500 lbs.
780197	R-180G Roust-A-Bout™ - Galvanized	R-180G	661165801972	18 ft.	1,500 lbs.
780196	R-250G Roust-A-Bout™ - Galvanized	R-250G	661165801965	25 ft.	1,500 lbs.
OPTIONAL ROUST-A-BOUT™ ACCESSORIES					
781060	R/Z-100/Z-150 Tee Head Ext.	THE100/150	661165810608	---	---
781061	R/Z-180/Z-200 Tee Head Ext.	THE180/200	661165810615	---	---
781062	R/Z-250 Tee Head Ext.	THE250	661165810622	---	---
781545	R Z-100 Z-150 Tee Head Ext. - Galvanized	THE100/150G	661165815450	---	---
781061	R/Z-180/Z-200 Tee Head Ext. - Galvanized	THE180/200G	661165810615	---	---
781547	R/Z-250 Tee Head Ext. - Galvanized	THE250G	661165815474	---	---

FAB-MATE™ LIFT



The Sumner FAB-MATE™ lift is a versatile lift designed so one person can position fittings, align flanges, or move plate.

SPECIAL FEATURES:

- Sumner built winch with lifting capacity up to 1,000 lbs.
- Lifting height of up to 7 ft.
- Rugged 8" casters for horizontal movement
- Designed for use with the Sumner Adjust-A-Fit™ and Adjust-A-Flange™ lifts

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
783900	FAB-MATE™ Lift	FMATE	661165839005	7 ft.	1,000 lbs.

SHORT STACK



The Sumner 2000 Series Short Stack Lifts offer a more compact design without compromising lifting capacity.

SPECIAL FEATURES:

- Designed for loads up to 800 lbs. & fits easily through doorways
- Easily flown in using the integrated lifting eye
- Pulley Guard provides 360° of cable protection
- Forks reverse to maximize lifting height
- Plunger pins eliminate extra tools and loose parts
- Quickly breaks down for storage and transportation
- Load cable that feeds inside mast - no more exposed cable just inches away from operator's face
- Multiple accessories available
- Available in 2 models in powder coating or galvanized finish

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
786383	2012S Short Stack Lift	2012S	661165840940	12 ft.	800 lbs.
786382	2016S Short Stack Lift	2016S	661165840858	16 ft.	800 lbs.
784093	2012S Short Stack Lift - Galvanized	2012SG	661165840933	12 ft.	800 lbs.
784087	2016S Short Stack Lift - Galvanized	2016SG	661165840865	16 ft.	800 lbs.
OPTIONAL ACCESSORIES					
783705	Pipe Cradle (pair)	PCRADLE	661165837056	---	---
783642	Boom Assembly	BOOMA	661165836424	---	---
786320	Tray Assembly	TA	661165863208	---	---
783691	Fork Extension Kit	CFEXTKIT	661165836912	---	---

SERIES 2000



The Sumner Series 2000 lifts are ideal for wider, heavier loads in the construction and HVAC markets

SPECIAL FEATURES:

- Designed for loads up to 650 lbs., 800 lbs., or 1000 lbs.
- Fits easily through doorways
- Easily flown in using the integrated lifting eye
- Pulley Guard provides 360° of cable protection
- Forks reverse to maximize lifting height
- Plunger pins eliminate extra tools and loose parts
- Quickly breaks down for storage and transportation
- Load cable that feeds inside mast - No more exposed cable just inches away from operator's face
- Multiple accessories available
- Available in 4 models in powder coating or galvanized finish

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
783700	2010 Material Lift	2010	661165837001	10 ft.	1,000 lbs.
783701	2015 Material Lift	2015	661165837018	15 ft.	800 lbs.
783702	2020 Material Lift	2020	661165837025	20 ft.	800 lbs.
783703	2025 Material Lift	2025	661165837032	25 ft.	650 lbs.
783223	2010 Material Lift - Galvanized	2010G	661165832235	10 ft.	1,000 lbs.
786781	2015 Material Lift - Galvanized	2015G	661165832242	15 ft.	800 lbs.
786782	2020 Material Lift - Galvanized	2020G	032886293559	20 ft.	800 lbs.
786783	2025 Material Lift - Galvanized	2025G	032886299636	25 ft.	650 lbs.
OPTIONAL ACCESSORIES					
783705	Pipe Cradle (pair)	PCRADLE	661165837056	---	---
783642	Boom Assembly	BOOMA	661165836424	---	---
786320	Tray Assembly	TA	661165863208	---	---
783691	Fork Extension Kit	CFEXTKIT	661165836912	---	---
783736	10" Wheel Kit	WHLKIT2000	661165837360	---	---

SERIES 2100



The Sumner Series 2100 Contractor lifts are ideal for construction, HVAC and industrial work.

SPECIAL FEATURES:

- Designed for loads up to 650 lbs.
- Fits easily through doorways
- Easily flown in using the integrated lifting eye
- Pulley Guard provides 360° of cable protection
- Forks reverse to maximize lifting height
- Plunger pins eliminate extra tools and loose parts
- Quickly breaks down for storage and transportation
- Load cable that feeds inside mast - no more exposed cable just inches away from operator's face
- Multiple accessories available
- Available in 3 models in powder coating or galvanized finish

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
783650	2112 Contractor Lift	2112	661165836509	12 ft.	650 lbs.
783651	2118 Contractor Lift	2118	661165836516	18 ft.	650 lbs.
783652	2124 Contractor Lift	2124	661165836523	24 ft.	650 lbs.
783225	2112 Contractor Lift - Galvanized	2112G	661165832259	12 ft.	650 lbs.
783226	2118 Contractor Lift - Galvanized	2118G	661165832266	18 ft.	650 lbs.
783227	2124 Contractor Lift - Galvanized	2124G	661165832273	24 ft.	650 lbs.
OPTIONAL ACCESSORIES					
783705	Pipe Cradle (pair)	PCRADLE	661165837056	---	---
783642	Boom Assembly	BOOMA	661165836424	---	---
786320	Tray Assembly	TA	661165863208	---	---
783691	Fork Extension Kit	CFEXTKIT	661165836912	---	---
783736	10" Wheel Kit	WHLKIT2000	661165837360	---	---

SERIES 2200 LIL HOISTER™

The Sumner Series 2210 Lil Hoister™ lifts are compact feature rich lifts making them an ideal tool in a variety of applications.

SPECIAL FEATURES:

- Designed for loads up to 300 lbs.
- Forks reverse to maximize lifting height
- Plunger pins eliminate extra tools and loose parts
- Two 2" casters permit easy handling of heavy loads
- Quickly breaks down for storage and transportation
- Load strap that feeds inside mast - No more exposed cable just inches away from operator's face
- Highly adaptable with multiple accessories available



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
784310	2210 Lil Hoister™	2210	661165843101	10 ft.	300 lbs.
OPTIONAL ACCESSORIES					
784240	Aluminum Tray	ALTRAY2200	661165842401	---	---
784218	Wheel Brake Assembly	WBA2200	661165842180	---	---
784258	Dually Wheel Kit	DUALWKIT	661165842586	---	---

SERIES 2300

The Sumner Series 2300 Drywall/HVAC lift are ideal for lifting drywall and lighter HVAC ducts.

SPECIAL FEATURES:

- Lifts loads up to 150 lbs. up to 11' 2-3/4" or 14' 9-3/4"
- Solid, safe construction
- Lightweight - 99 lbs.
- Two speed winch handle
- Quick, tool free assembly
- One person operation
- Tilts 65° for drywall installation
- Available in 2 models



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
710010	2311 DRYWALL LIFT with CART	2311KIT	661165100105	11' - 2.75"	150 lbs.
710011	2315 DRYWALL LIFT with CART	2315KIT	661165900484	14' - 9.75"	150 lbs.
710012	2311 HVAC LIFT with CART	2311-HVAC KIT	032886301162	11' - 2.75"	150 lbs.
710013	2315 HVAC LIFT with CART	2315-HVAC KIT	032886300189	14' - 9.75"	150 lbs.
OPTIONAL ACCESSORIES					
784355	Drywall Cradle Only	DWCRADLE	661165843552	---	---
784474	HVAC/Electrical Cradle Only	HVACCRADL	661165844740	---	---
784510	Drywall Lift Cart	DWCART	661165845105	---	---

SERIES 2400



The Sumner Series 2400 Contractor lifts are compact with a rugged design for a variety of construction applications.

SPECIAL FEATURES:

- Designed for loads up to 450 lbs.
- Easily breaks down to just over 5' for easy storage and transportation
- Plunger pins eliminate extra tools and loose parts
- Compact design fits in most vans and SUVs
- Forks reverse to maximize lifting height
- Pulley Guard provides 360° of cable protection
- Load cable that feeds inside mast - no more exposed cable just inches away from operator's face
- Multiple accessories available
- Available in 2 models in powder coating or galvanized finish



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
784750	2412 Contractor Lift	2412	661165847505	12 ft.	450 lbs.
784751	2416 Contractor Lift	2416	661165847512	16 ft.	450 lbs.
784752	2412 Contractor Lift - Galvanized	2412G	661165847529	12 ft.	450 lbs.
784763	2416 Contractor Lift - Galvanized	2416G	661165847536	16 ft.	450 lbs.
OPTIONAL ACCESSORIES					
784695	Fork Extension Install Kit	FEXTKIT2400	661165846959	---	---
784830	Mast Hold-Down, Bar Type 2412	MHDBAR2412	661165848304	---	---
783705	Pipe Cradle (pair)	PCRADLE	661165837056	---	---
784320	Steel Tray	STRAY2400	661165843200	---	---

SERIES 2500



The Sumner Series 2500 lifts is an innovative counter balance lift that features a compact design.

SPECIAL FEATURES:

- Designed for loads up to 650 lbs., 800 lbs.
- Fits easily through doorways
- Easily flown in using the integrated lifting eye
- Pulley Guard provides 360° of cable protection
- Forks reverse to maximize lifting height
- Plunger pins eliminate extra tools and loose parts
- Quickly breaks down for storage and transportation
- Load cable that feeds inside mast - No more exposed cable just inches away from operator's face
- Multiple accessories available
- Available in 3 models in a galvanized finish

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
786511	Series 2515 Lift - Galvanized	2515G	661165865110	15 ft.	800 lbs.
786512	Series 2520 Lift - Galvanized	2520G	661165865127	20 ft.	800 lbs.
786513	Series 2525 Lift - Galvanized	2525G	661165865134	25 ft.	650 lbs.
OPTIONAL ACCESSORIES					
783705	Pipe Cradle (pair)	PCRADLE	661165837056	---	---
784320	Steel Tray	STRAY2400	661165843200	---	---
786645	Boom Assembly, CB Lift	BOOMACB	661165866452	---	---
786750	Glass Boom Assembly, CB Lift	GBACB	661165867503	---	---

SERIES 2600



The Sumner Series 2600 Big Lifts is ideal for any job with confined spaces and large lifting requirements.

SPECIAL FEATURES:

- Designed for loads up to 1,100 lbs.
- Forks reverse to maximize lifting height
- Sumner built 2-speed winch system
- Quickly breaks down for storage and transportation
- Fast adjusting steering handle for centering lift
- Plunger pins eliminate extra tools and loose parts
- Multiple accessories available
- Available in 2 models in powder coating or galvanized finish

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
783067	2615 The Big Lift	2615	661165830675	15 ft.	1,100 lbs.
783068	2615 The Big Lift - Galvanized	2615G	661165830682	15 ft.	1,100 lbs.
OPTIONAL ACCESSORIES					
783163	Fork Extension Kit, 2600 Series Lifts	FEK2600	661165831634	---	---
784569	Pipe Cradle Assembly, 2600 Lift (1 Pair)	PCA2600	661165845693	---	---

EVENTER™ SERIES



The Sumner Eventer™ black bodied lift series is specifically designed to meet the needs of theatrical and entertainment industries.

SPECIAL FEATURES:

- Available accessories for lifting and support speakers, lights, and other stage equipment
- Eventer™ has a lifting capacity of 500 lbs. to 800 lbs.
- Compact design with quick assembly and breakdown
- Forks reverse to maximize lifting height
- Included leveling pads to ensure stability
- Black, anodized aluminum telescoping masts fade out on the stage
- Available in 3 models









SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LIFTING HEIGHT	LOAD CAPACITY
784760	Eventer™ 16 ft.	EV16	661165847604	16 ft.	500 lbs.
783801	Eventer™ 20 ft.	EV20	661165838015	20 ft.	800 lbs.
78380040	Eventer™ 25 ft.	EV25	661165838008	25 ft.	650 lbs.
OPTIONAL EVENTER™ 16 FT ACCESSORIES					
784880	Eventer™ 16 ft. Boom (fully extended)	B00M16	661165848809	---	---
784915	Eventer™ 16 ft. Hook Block Kit	HBK16	661165849158	---	---
784055	Eventer™ 16 ft. Sound Array Bar	SAB16	661165840551	---	---
OPTIONAL EVENTER™ 20 FT AND 25 FT ACCESSORIES					
783766	Eventer™ 20 ft. and 25 ft. Hook Block Kit	HBK20	661165837667	---	---
784060	Eventer™ 20 ft. and 25 ft. Sound Array Bar	SAB20	661165840605	---	---






OPTIONS FOR SUMNER LIFTS		
LIFT MODEL	AVAILABLE OPTIONS	
<p>ROUST-A-BOUT R-SERIES</p> 	<p>R/Z-100/Z-150 Tee Head Ext. - 781060 R/Z-180/Z-200 Tee Head Ext. - 781061 R/Z-250 Tee Head Ext. - 781062</p>  <p>Galvanized Finish - R-100G 780195 R-150G 780194 R-180G 780197 R-250G 780196</p> 	
<p>SERIES 2000 MATERIAL Lift</p> 	<p>Pipe Cradle - PN 783705</p> 	
	<p>Boom Carriage - PN 783642</p> 	<p>Tray - PN 786320</p> 
	<p>Fork Extensions - PN 783691</p> 	

LIFTS

LIFTS | OPTIONS FOR LIFTS

OPTIONS FOR SUMNER LIFTS		
LIFT MODEL	AVAILABLE OPTIONS	
<p>SERIES 2100 CONTRACTOR Lift</p> 	<p>Pipe Cradle - PN 783705</p> 	
	<p>Boom Carriage - PN 783642</p> 	<p>Tray - PN 786320</p> 
	<p>Fork Extensions - PN 783691</p> 	<p>Two Speed Winch Handle - PN 783759</p> 

OPTIONS FOR SUMNER LIFTS		
LIFT MODEL	AVAILABLE OPTIONS	
<p>SERIES 2300</p> 	<p>Drywall Cradle Only - PN 784355</p> 	
	<p>HVAC/Electrical Cradle Only - PN 784474</p> 	<p>Drywall Lift Cart - PN 784510</p> 

OPTIONS FOR SUMNER LIFTS		
LIFT MODEL	AVAILABLE OPTIONS	
<p>SERIES 2400 CONTRACTOR Lift</p> 	<p>Pipe Cradle - PN 783705</p> 	<p>Tray - PN 784320</p> 
	<p>Fork Extensions - PN 784695</p> 	
<p>SERIES 2500</p> 	<p>Pipe Cradle - 783705</p> 	<p>Steel Tray - 784320</p> 
	<p>Boom Assembly - 786645</p> 	<p>Glass Boom Assembly - 786750</p> 
<p>SERIES 2600 "Axel" the Big Lift</p> 	<p>Fork Extensions - PN 783163</p> 	
	<p>Pipe Cradle - PN 784569</p> 	

GANTRIES

Sumner offers a full line of Gantries that can fit a variety of applications. With industry-leading compact design, this line of products make a difference on real-world jobsites.



GH3/4T



The Sumner 3/4 Ton Gantry offers an industry leading compact 3-piece design to fit a variety of applications.

SPECIAL FEATURES:

- Designed for loads up to 3/4 metric tons (1,650 lbs.)
- Lightweight & portable; aluminum frames & beam
- Quick two-person assembly & pinch point free
- Adjustable span
- Minimum pieces - (2) A-Frames with casters, trolley, cross beam and attaching hardware *Chain hoist not included
- Available with 8" locking casters or 10" flat free double locking casters
- Unassisted height adjustment
- Available in 8 models

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
785305	GANTRY GH-3/4T 10FT/3M W/8" CSTR	GH3/4T-8x15	661165853018	3/4 TON
785304	GANTRY GH-3/4T 10FT/3M W/FF TIRES	GH3/4T-8X12	661165853032	3/4 TON
785303	GANTRY GH-3/4T 13FT/4M W/8" CSTR	GH3/4T-8x10	661165853056	3/4 TON
785302	GANTRY GH-3/4T 13FT/4M W/FF TIRES	GH3/4T-8x8	661165853070	3/4 TON
785301	GANTRY GH-3/4T 16FT/5M W/8" CSTR	GH3/4T-10X15	661165853001	3/4 TON
785300	GANTRY GH-3/4T 16FT/5M W/FF TIRES	GH3/4T-10X12	661165853025	3/4 TON
785307	GANTRY GH-3/4T 8FT W/8" CSTR	GH3/4T-10X10	661165853049	3/4 TON
785306	GANTRY GH-3/4T 8FT W/FF TIRES	GH3/4T-10X8	661165853063	3/4 TON
OPTIONAL GH3/4T GANTRY ACCESSORIES				
786960	GANTRY CART 3/4T, 2T	GSS-01	661165869606	---
785320	GH3/4T 15' Beam	3/4TBEAM15	661165853209	---
785321	GH3/4T 12' Beam	3/4TBEAM12	661165853216	---
785322	GH3/4T 10' Beam	3/4TBEAM10	661165853223	---
785323	GH3/4T 8' Beam	3/4TBEAM8	661165853230	---
785600	GH3/4T Trolley Assembly	GH3/4TROL	661165856002	---
779040	GH3/4T - Caster Kit, 8" Casters w/ Brake	GH3/4TCK8	661165790405	---
779041	GH3/4T- Caster Assembly, Swivel W/ Brake 8 x 2	GH3/4TCKS8	661165790412	---

GANTRIES

GH2T



The Sunner 2 Ton Gantry offers an industry leading compact 3-piece design to fit a variety of applications.

SPECIAL FEATURES:

- Designed for loads up to 2 metric tons (4,400 lbs.)
- Lightweight & portable; aluminum frames & beam
- Quick two-person assembly, pinch point free & adjustable span
- Minimum pieces - (2) A-Frames with casters, trolley, cross beam and attaching hardware *Chain hoist not included
- 8" locking casters & available in 4 models

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
785102	GANTRY GH-2T 10FT/3M	GH2T-10x10	661165851021	2.0 TON
785101	GANTRY GH-2T 13FT/4M	GH2T-12x12	661165851014	2.0 TON
785100	GANTRY GH-2T 16FT/5M	GH2T-15x15	661165851007	2.0 TON
785103	GANTRY GH-2T 8FT	GH2T-8x8	661165851038	2.0 TON
OPTIONAL GH2T GANTRY ACCESSORIES				
786960	GANTRY CART 3/4T, 2T	GSS-01	661165869606	---
785074	GH2T 12' Beam	2TBEAM12	661165850741	---
785075	GH2T 10' Beam	2TBEAM10	661165850758	---
785076	GH2T 8' Beam	2TBEAM8	661165850765	---
785160	GH2T Trolley Assembly	GH2TROL	661165851601	---

GANTRIES

GH5T



The Sumner 5 Ton Gantry offers an industry leading compact 3-piece design to fit a variety of applications.

SPECIAL FEATURES:


- Designed for loads up to 5 metric tons (11,000 lbs.)
- Lightweight & portable; aluminum frames & beam
- Quick two-person assembly, pinch-point free, and adjustable span
- Minimum pieces - (2) A-Frames with casters, trolley, cross beam, and attaching hardware *Chain hoist not included
- 8" locking casters & available in 3 models

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
785807	GANTRY GH-5T 10FT/3M	GH2T-15x15	661165858051	5 TON
785806	GANTRY GH-5T 13FT/4M	GH2T-12X12	661165858068	5 TON
785805	GANTRY GH-5T 16FT/5M	GH2T-10x10	661165858075	5 TON
OPTIONAL GH5T GANTRY ACCESSORIES				
785895	GH5T Trolley Assembly	GH5TROL	661165858952	---
785815	GH5T 15'	5TBEAM15	661165858150	---
785816	GH5T 12'	5TBEAM12	661165858167	---
785817	GH5T 10'	5TBEAM10	661165858174	---

MATERIAL HANDLING

Sumner has provided material handling solutions that move material quickly, easily, and safely. Transport, lift, store, and secure any item you need with our line of Material Handling products.

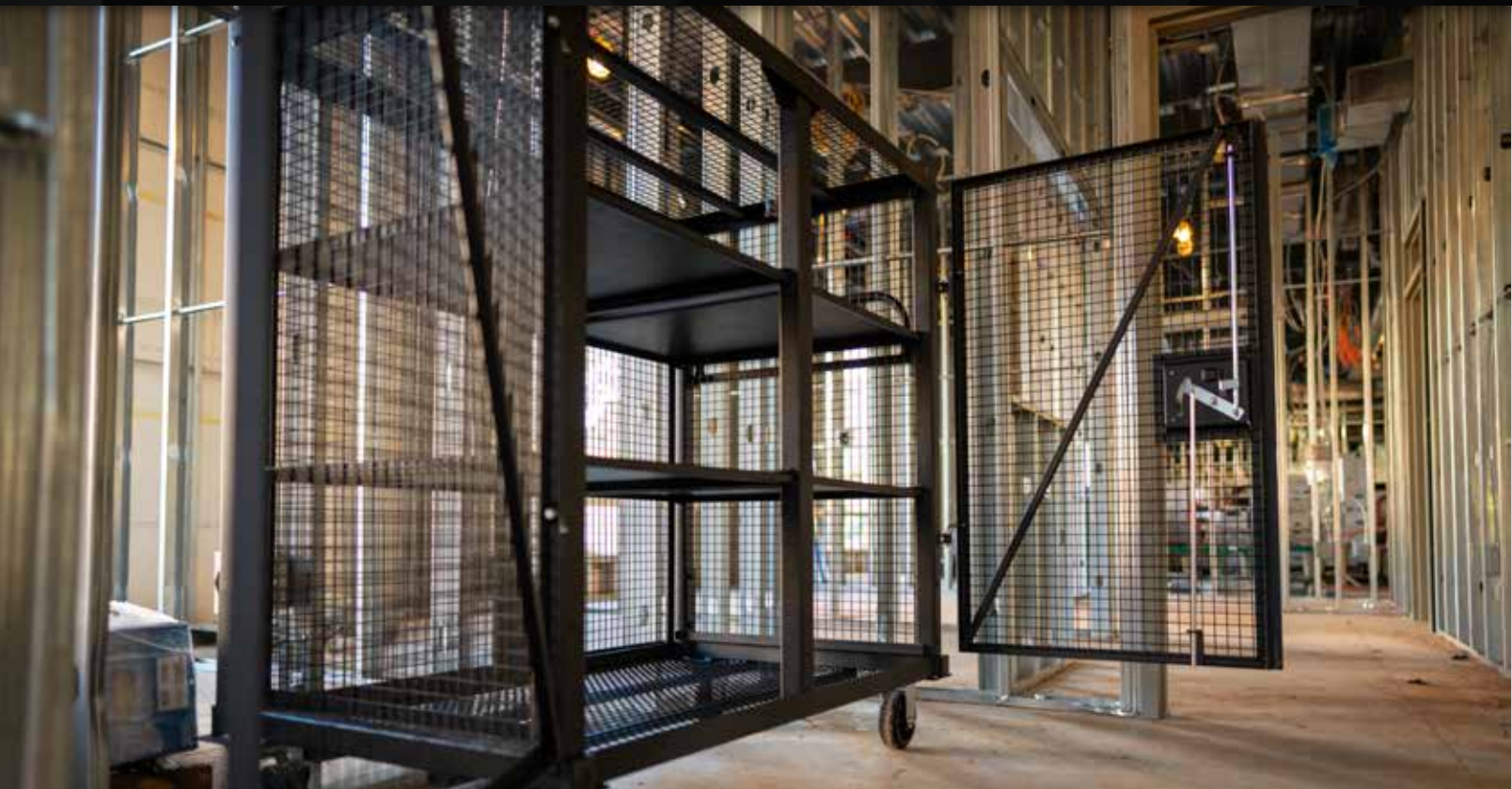

MATERIAL HANDLING

PALLET JACKS



779765



779766

The Sumner low profile 20" or 27" pallet jack will handle heavy lifting for you with it's 2.5" low profile fork height allowing for easy engagement of most pallets.

SPECIAL FEATURES:

- 6,600 lbs. weight capacity
- Three-function handle controls raising, lowering, and neutral
- Welded all-steel frame and tough powder coat finish provides maximum durability and protection
- Minimum fork height of 2.5"
- Maximum lift height of 6.25"
- 180° turning radius
- 2.5" inch low profile allows for easy engagement of pallets

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	LOAD CAPACITY
779765	27" x 48" Pallet Jack	PJ27	661164797657	6,600 lbs.
779766	20" x 48" Pallet Jack	PJ20	661164797664	6,600 lbs.

MATERIAL HANDLING | PALLET JACKS

MATERIAL HANDLING

6 PACK MAC™



PM06

The 6 Pack Mac™ is a compact mobile wire dispensing cart that provides convenient storage, easy maneuverability, and seamless payoff for overall convenient use.

SPECIAL FEATURES:

- Stores in one-third the space of conventional dispensers
- Reel spindles fold and lock for convenient storage
- Fits through 30" doorway
- Two 10" wheels with locking 8" caster for easy maneuverability
- Welded wire guides for easy payoff
- Stores up to (6) 2,500 ft. spools (18" diameter) of wire



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
783350	6 PACK MAC™	PM06	661165833508

10 PACK MAC™



PM10

The 10 Pack Mac™ is a mobile wire dispensing cart that provides convenient storage, easy maneuverability, and seamless payoff for overall convenient use.

SPECIAL FEATURES:

- Handle/guide loop position controlled by plunger: 4-positions, no loose parts
- Spindles fold up and lock
- Mast swivels 360°, but can be locked in a fixed position
- Stores up to (10) 2500 ft. spools (18" diameter) of wire
- 4-heavy duty, 8" locking casters
- Feed handle and guide loops are built into one part



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
783366	10 PACK MAC™	PM10	661165833669

MATERIAL HANDLING | WIRE CARTS

MATERIAL HANDLING

CADDY MAC™

CMAC1



CMAC3



CADDY MAC™ #1: Transports spools on spindles and works as a dolly. Wire is dispensed while laying flat.
CADDY MAC™ #2: Hinged design allows easy access to all spools for wire dispensing and folds for compact storage.
CADDY MAC™ #3: A versatile wire cart that doubles as a dolly.

SPECIAL FEATURES:

- Made in America
- Removable spindles swing out for convenient loading of wire spools
- Unique spindle locking system means no loose pieces
- Rugged 8" wheels for easy transportation



CMAC2



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
783398	CADDY MAC™ #1	CMAC1	661165833980
783395	CADDY MAC™ #2	CMAC2	661165833959
783400	CADDY MAC™ #3	CMAC3	661165834000
OPTIONAL CADDY MAC™ ACCESSORY			
783490	HANDI MAC™ WIRE DISPENSER	HM-01	661165834901

SPOOL MAC™



The Sumner SPOOL MAC™ is a convenient wire payoff cart that provides easy transport, reel rotation, and payoff.

SPECIAL FEATURES:

- Made in America
- All steel frame construction
- 10" wheels for easy transport over rough terrain
- Rollers on spool arm allow for smooth reel rotation and easy payoff
- No loose pieces to account for
- Folding design allows for compact storage
- Fits through 32" doorways



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC
783444	SPOOL MAC™	SM-01	661165834444

MATERIAL HANDLING | WIRE CARTS

MATERIAL HANDLING

STOR MAC™

SM60



SM30



STOR MAC™ lockable security storage cabinets come a variety of sizes.

SM48



SPECIAL FEATURES:

- Made in America
- Four 6" heavy-duty casters (standard)
- For high visibility storage
- Removable shelves for adjustable storage
- Lockable doors
- Load capacity 1,500 lbs.



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
784920	STOR MAC™ 60	SM60	661165849202	58.5"	62.5"	32"	362 lbs.
785921	STOR MAC™ 48	SM48	661165859218	58"	51.5"	33.75"	310 lbs.
785920	STOR MAC™ 30	SM30	661165859201	58"	31.5"	33.75"	210 lbs.

KNOCK DOWN STOR MAC™

KDSM-60



A collapsible security storage cabinet for those who require high visibility of contents.

SPECIAL FEATURES:

- Quickly collapses and assembles in under 5 minutes
- Made In America
- Four 6" heavy duty casters (standard)
- Reinforced frame and door
- Removable shelves for adjustable storage
- 1,500 lbs. load capacity
- Lockable doors work with puck or pad locks



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
786920	KNOCK DOWN STOR MAC™	KDSM-60	661165901078	58.5"	62.5"	32"	425 lbs.

MATERIAL HANDLING | STOR MAC™

MATERIAL HANDLING

TAINER MAC™ 60

TMAC60



A mobile, heavy-duty stacking container.

SPECIAL FEATURES:

- Made in America
- Transports 1,500 lbs. of material
- Large storage capacity
- Four 6" heavy duty lockable casters
- Posts for stacking and steering
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts



 **WE'VE GOT IT
MADE IN AMERICA™**

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
784990	TAINER MAC™ 60	TMAC60	661165849905	40"	32"	56"	200 lbs.

MATERIAL HANDLING | TAINER MAC™

MATERIAL HANDLING

WELDBOX™

WB3617



The Sumner weldbox is the ideal storage chest for all welders and electricians.

SPECIAL FEATURES:

- Two-point latching system requires only one lock
- 16 gauge steel construction
- Reinforced frame and door
- Power-coat finish for superior durability and corrosion resistance
- WB3617 is caster ready

WB2008



WB3010



SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
779928	WELDBOX™ 3617	WB3617	661165799286	17"	36"	22.5"	97.9 lbs.
779910	WELDBOX™ 2008	WB2008	661165799101	8.5"	20.125"	9.5"	12.1 lbs.
799910	WELDBOX™ 3010	WB3010	032886299476	10"	29.5"	13.5"	30.4 lbs.

MATERIAL HANDLING

STORAGE CABINETS

CB603065

CB602460

Southwire storage cabinets have heavy-duty shelves and large vertical storage area, you can easily organize and secure your tools.



SPECIAL FEATURES:

- Recessed locking system for protection against theft with one-time lock installation
- Heavy-duty 16 gauge steel construction with fully arc-welded seams
- Powder-coat finish for superior durability and corrosion resistance
- The Southwire Bi-Fold Cabinet includes casters
- Welded shelves
- Heavy-duty hinges to resist break in

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
59822701	Bi-Fold Storage Cabinet	CB603065	032886959943	63.5"	30"	62.5"	503 lbs.
59822801	Two-Door Storage Cabinet	CB602460	032886959950	60.75"	24.25"	60.125"	366 lbs.

MATERIAL HANDLING | **STORAGE CABINETS**

MATERIAL HANDLING

PIANO BOX

PB603049



Southwire Piano Boxes feature shelves, gas spring guards to protect springs from shifting-load damage, and easy access for small and large tools, equipment and supplies. With 3 size options available, this box is ideal for storage and security on the jobsite, workshop or in the plant.

SPECIAL FEATURES:

- Recessed lock housing for protection against theft with one-time lock installation
- Single padlock security system
- Heavy duty 16 gauge box construction with fully arc-welded seams
- Powder-coat finish for superior durability and corrosion resistance
- Welded shelves
- Heavy-duty hinges to resist break in
- Recessed handles
- Gas spring guards to prevent damage from shifting loads
- Four-way caster-ready skids allow access from any side, making it easier and faster to transport (casters not included)

PB603034



PB483048

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
59822401	Piano Box	PB603049	032886959912	49.5"	31.34"	60"	377 lbs.
59822301	Piano Box	PB483048	032886959905	49.5"	31.34"	48.87"	304 lbs.
59822201	Piano Box	PB603034	032886959899	37"	30.125"	60.87"	278 lbs.

MATERIAL HANDLING

FIELD OFFICE



F0604482



The Southwire Field Office Field office offers a large workstation with shelved storage and a single locking point, allowing you to control and secure any jobsite.

SPECIAL FEATURES:

- Recessed lock housing for protection against theft with one-time lock installation
- Single padlock security system.
- Heavy-duty 16 gauge steel construction with fully arc-welded seams
- Powder-coat finish for superior durability and corrosion resistance
- Adjustable and removable split shelves let you organize your storage in the lower cabinets
- Heavy-duty hinges to resist break in
- Dual gas springs for smooth, one-handed lift, one spring locks securely in place
- Four-way caster-ready skids allow access from any side, making it easier and faster to transport (Casters not included)

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
59822501	Field Office	F0604482	032886959929	80"	42.5"	63.5"	772 lbs.

MATERIAL HANDLING | FIELD OFFICE

MATERIAL HANDLING

COMPACT CHEST

CC482423



Southwire Compact Chests are highly mobile storage solutions that store easily in nearly any location.

SPECIAL FEATURES:

- Recessed locking system for protection against theft with one-time lock installation
- Heavy-duty 16 gauge steel construction with fully arc-welded seams
- Powder coat finish for superior durability and corrosion resistance
- Four-way caster ready skids allow access from any side, making it easier and faster to transport (casters not included)
- The Mini Compact Chest includes a built-in tool tray



CC191932

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
59822601	Compact Chest	CC482423	032886959936	27.75"	24"	48"	170 lbs.
63036001	Mini Compact Chest	CC191932	032886963612	17.5"	18"	31"	82 lbs.

MATERIAL HANDLING

TWO SHELF UTILITY CARTS

UCTS-LG



Designed to help make transporting materials and items around the jobsite easier and more efficient.

SPECIAL FEATURES:

- 550 Lbs. load capacity
- Non-marking 5" casters for ease of mobility
- Handle includes built in storage for nuts, bolts, screws, and other small items



UCTS-SM

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
65240240	Large Utility Cart	UCTS-LG	032886722707	33.5"	46.75"	25.5"	45 lbs.
65240340	Small Utility Cart	UCTS-SM	032886722714	33.5"	40.7"	16.9"	33 lbs.

MATERIAL HANDLING

CARTLOCKER™ KITS

UCLX-LG



Make your Southwire two shelf utility cart a mobile lockable storage solution with Southwire's CartLocker™ Kits. Specifically designed to fit and install to your Southwire utility cart easily and keep items safe, secure, and out of sight.

SPECIAL FEATURES:

- Designed to fit Southwire's large and small two shelf utility carts
- Keep items safe, secure, and out of sight
- Heavy-duty powder coated steel panels and door
- Lockable door works with puck and pad locks
- No drilling required. Easily install CartLocker™ Kit using pre-existing holes in utility cart
- Xtreme™ option has accessories including 2 bolt on trays, 2 large hooks, and 2 small hooks

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	WIDTH	DEPTH	WEIGHT
66101840	CartLocker™ Xtreme™ Large Kit	UCLX-LG	032886747403	4.5"	19"	35"	60 lbs
66222140	CartLocker™ Xtreme™ Small Kit	UCLX-SM	032886747410	4.5"	19"	28"	51 lbs
66321440	CartLocker™ Large Kit	UC-LGCL	032886747427	4.5"	19"	35"	52 lbs
66351740	CartLocker™ Small Kit	UC-SMCL	032886747434	4.5"	19"	28"	42 lbs
66777440	Large Utility Cart with CartLocker™ Xtreme™ Large Kit	TSUCLX-LG	032886747809	33.5"	25.5"	46.75"	105 lbs
66149040	Small Utility Cart with CartLocker™ Xtreme™ Small Kit	TSUCLX-SM	032886747793	33.5"	16.9"	40.7"	84 lbs.
66149640	Large Utility Cart with CartLocker™ Large Kit	TSUCL-LG	032886748264	33.5"	25.5"	46.75"	97 lbs.
66159540	Small Utility Cart with CartLocker™ Small Kit	TSUCL-SM	032886748271	33.5"	16.9"	40.7"	75 lbs.
66165240	Large Hooks for CartLocker™ (2 pack)	LHCL	032886748509	10.5"	5"	1"	.4 lbs
66179340	Small Hooks for CartLocker™ (2 pack)	SMCL	032886748516	6"	3.5"	1"	.2 lbs
66183540	Spray Can and Drill Holder Tray for Large CartLocker™	SCDTCL-LG	032886748523	1"	16"	3.75"	2.4 lbs.
66185040	Spray Can and Drill Holder Tray for Small CartLocker™	SCDTCL-SM	032886748530	1"	9.5"	3.5"	1.5 lbs
66186840	Tool Holder Tray for Large CartLocker™	THTCL-LG	032886748547	3"	16"	3.5"	.8 lbs
66201540	Tool Holder Tray for Small CartLocker™	THTCL-SM	032886748554	3"	9.5"	3"	.5 lbs

HOISTS

Sumner's line of Hoists offer an innovative, heavy-duty, manual design to tackle your toughest lifts. Our Hoist line includes a variety of options such as standard Lever and Chain hoists, Premium Lever and Chain hoists, Premium Lever and Chain hoists with overload protection.



HOISTS

LEVER HOIST



Sumner Lift Lever Hoists arm you with the strength you need to lift, move and hold heavy materials on a jobsite or in a work shop! Sumner lever hoists all come with a steel construction and 360° ratchet with short strokes. Available in 1/4 to 6 ton lifting weight capacities.

SPECIAL FEATURES:

- Meet all ANSI/ASME, OSHA and CE hoisting standards
- Top hook is easily removable
- Hard steel load sheave rollers
- 1.5x safety tested

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787536	LH025C05	1/4 Ton Lever Hoist with 5 ft. Chain Fall	1/4 TON
787537	LH025C10	1/4 Ton Lever Hoist with 10 ft. Chain Fall	1/4 TON
787538	LH025C15	1/4 Ton Lever Hoist with 15 ft. Chain Fall	1/4 TON
787539	LH050C05	1/2 Ton Lever Hoist with 5 ft. Chain Fall	1/2 TON
787540	LH050C10	1/2 Ton Lever Hoist with 10 ft. Chain Fall	1/2 TON
787541	LH050C15	1/2 Ton Lever Hoist with 15 ft. Chain Fall	1/2 TON
787542	LH075C05	3/4 Ton Lever Hoist with 5 ft. Chain Fall	3/4 TON
787543	LH075C10	3/4 Ton Lever Hoist with 10 ft. Chain Fall	3/4 TON
787544	LH075C15	3/4 Ton Lever Hoist with 15 ft. Chain Fall	3/4 TON
787545	LH075C20	3/4 Ton Lever Hoist with 20 ft. Chain Fall	3/4 TON
787546	LH150C05	1-1/2 Ton Lever Hoist with 5 ft. Chain Fall	1-1/2 TON
787547	LH150C10	1-1/2 Ton Lever Hoist with 10 ft. Chain Fall	1-1/2 TON
787548	LH150C15	1-1/2 Ton Lever Hoist with 15 ft. Chain Fall	1-1/2 TON
787549	LH150C20	1-1/2 Ton Lever Hoist with 20 ft. Chain Fall	1-1/2 TON
787550	LH300C05	3 Ton Lever Hoist with 5 ft. Chain Fall	3 TON
787551	LH300C10	3 Ton Lever Hoist with 10 ft. Chain Fall	3 TON
787552	LH300C15	3 Ton Lever Hoist with 15 ft. Chain Fall	3 TON
787553	LH300C20	3 Ton Lever Hoist with 20 ft. Chain Fall	3 TON
787554	LH600C05	6 Ton Lever Hoist with 5 ft. Chain Fall	6 TON
787555	LH600C10	6 Ton Lever Hoist with 10 ft. Chain Fall	6 TON
787556	LH600C15	6 Ton Lever Hoist with 15 ft. Chain Fall	6 TON
787557	LH600C20	6 Ton Lever Hoist with 20 ft. Chain Fall	6 TON

PREMIUM LEVER HOISTS



Sumner Lift Premium Lever Hoists offer an innovative and heavy-duty design to tackle your toughest lifts of various sizes! Our premium lever hoists include a single fused brake design and zinc phosphate load chain for superior corrosion resistance. Available in .8 to 9 ton lifting weight capacities.

SPECIAL FEATURES:

- No preload required
- Meet all ANSI/ASME, OSHA and CE hoisting standards
- Top hook is easily removable
- Hard steel load sheave rollers
- 1.5x safety tested
- Unique zinc phosphate chain design

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787480	PLH080C05	.8 Ton Lever Hoist with 5 ft. Chain Fall	.8 TON
787481	PLH080C10	.8 Ton Lever Hoist with 10 ft. Chain Fall	.8 TON
787482	PLH080C15	.8 Ton Lever Hoist with 15 ft. Chain Fall	.8 TON
787483	PLH080C20	.8 Ton Lever Hoist with 20 ft. Chain Fall	.8 TON
787484	PLH100C05	1 Ton Lever Hoist with 5 ft. Chain Fall	1 TON
787485	PLH100C10	1 Ton Lever Hoist with 10 ft. Chain Fall	1 TON
787486	PLH100C15	1 Ton Lever Hoist with 15 ft. Chain Fall	1 TON
787487	PLH100C20	1 Ton Lever Hoist with 20 ft. Chain Fall	1 TON
787488	PLH160C05	1.6 Ton Lever Hoist with 5 ft. Chain Fall	1.6 TON
787489	PLH160C10	1.6 Ton Lever Hoist with 10 ft. Chain Fall	1.6 TON
787490	PLH160C15	1.6 Ton Lever Hoist with 15 ft. Chain Fall	1.6 TON
787491	PLH160C20	1.6 Ton Lever Hoist with 20 ft. Chain Fall	1.6 TON
787496	PLH320C05	3.2 Ton Lever Hoist with 5 ft. Chain Fall	3.2 TON
787497	PLH320C10	3.2 Ton Lever Hoist with 10 ft. Chain Fall	3.2 TON
787498	PLH320C15	3.2 Ton Lever Hoist with 15 ft. Chain Fall	3.2 TON
787499	PLH320C20	3.2 Ton Lever Hoist with 20 ft. Chain Fall	3.2 TON
787500	PLH630C05	6.3 Ton Lever Hoist with 5 ft. Chain Fall	6.3 TON
787501	PLH630C10	6.3 Ton Lever Hoist with 10 ft. Chain Fall	6.3 TON
787502	PLH630C15	6.3 Ton Lever Hoist with 15 ft. Chain Fall	6.3 TON
787503	PLH630C20	6.3 Ton Lever Hoist with 20 ft. Chain Fall	6.3 TON
787504	PLH900C05	9 Ton Lever Hoist with 5 ft. Chain Fall	9 TON
787505	PLH900C10	9 Ton Lever Hoist with 10 ft. Chain Fall	9 TON
787506	PLH900C15	9 Ton Lever Hoist with 15 ft. Chain Fall	9 TON
787507	PLH900C20	9 Ton Lever Hoist with 20 ft. Chain Fall	9 TON

HOISTS

PREMIUM LEVER HOIST WITH OVERLOAD PROTECTION

Sumner Lift Premium Lever Hoists with Overload Protection offers an innovative and heavy-duty design to tackle your toughest lifts of various sizes! Our Premium Lever Hoists include a single fused brake design and zinc phosphate load chain for superior corrosion resistance. Available in .8 to 9 ton lifting weight capacities.

SPECIAL FEATURES:

- No preload required
- Meet all ANSI/ASME, OSHA and CE hoisting standards
- Top hook is easily removable
- Hard steel load sheave rollers
- 1.5x safety tested
- Unique zinc phosphate chain design

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787508	PLH080C05WO	.8 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	.8 TON
787509	PLH080C10WO	.8 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	.8 TON
787510	PLH080C15WO	.8 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	.8 TON
787511	PLH080C20WO	.8 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	.8 TON
787512	PLH100C05WO	1 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	1 TON
787513	PLH100C10WO	1 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	1 TON
787514	PLH100C15WO	1 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	1 TON
787515	PLH100C20WO	1 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	1 TON
787516	PLH160C05WO	1.6 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	1.6 TON
787517	PLH160C10WO	1.6 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	1.6 TON
787518	PLH160C15WO	1.6 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	1.6 TON
787519	PLH160C20WO	1.6 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	1.6 TON
787520	PLH250C05WO	2.5 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	2.5 TON
787521	PLH250C10WO	2.5 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	2.5 TON
787522	PLH250C15WO	2.5 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	2.5 TON
787523	PLH250C20WO	2.5 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	2.5 TON
787524	PLH320C05WO	3.2 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	3.2 TON
787525	PLH320C10WO	3.2 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	3.2 TON
787526	PLH320C15WO	3.2 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	3.2 TON
787527	PLH320C20WO	3.2 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	3.2 TON
787528	PLH630C05WO	6.3 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	6.3 TON
787529	PLH630C10WO	6.3 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	6.3 TON
787530	PLH630C15WO	6.3 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	6.3 TON
787531	PLH630C20WO	6.3 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	6.3 TON
787532	PLH900C05WO	9 Ton Lever Hoist with 5 ft. Chain Fall w/ Overload Protection	9 TON
787533	PLH900C10WO	9 Ton Lever Hoist with 10 ft. Chain Fall w/ Overload Protection	9 TON
787534	PLH900C15WO	9 Ton Lever Hoist with 15 ft. Chain Fall w/ Overload Protection	9 TON
787535	PLH900C20WO	9 Ton Lever Hoist with 20 ft. Chain Fall w/ Overload Protection	9 TON



HOISTS | PREMIUM LEVER HOISTS

CHAIN BLOCK HOISTS

Sumner Lift Chain Block Hoists are designed to thrive in light industrial applications work with capacities ranging from 1/2-10 tons. Sumner Lift Chain Block Hoist build on our legacy of reliable vertical lifting.

SPECIAL FEATURES:

- Meet all ANSI/ASME, OSHA and CE hoisting standards
- Top hook is easily removable
- Hard steel load sheave rollers
- 1.5x safety tested

SPECIFICATIONS



ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787558	CB050C10	1/2 Ton Chain Hoist with 10 ft. Chain Fall	1/2 TON
787559	CB050C15	1/2 Ton Chain Hoist with 15 ft. Chain Fall	1/2 TON
787560	CB050C20	1/2 Ton Chain Hoist with 20 ft. Chain Fall	1/2 TON
787561	CB050C30	1/2 Ton Chain Hoist with 30 ft. Chain Fall	1/2 TON
787562	CB100C10	1 Ton Chain Hoist with 10 ft. Chain Fall	1 TON
787563	CB100C15	1 Ton Chain Hoist with 15 ft. Chain Fall	1 TON
787564	CB100C20	1 Ton Chain Hoist with 20 ft. Chain Fall	1 TON
787565	CB100C30	1 Ton Chain Hoist with 30 ft. Chain Fall	1 TON
787566	CB150C10	1-1/2 Ton Chain Hoist with 10 ft. Chain Fall	1-1/2 TON
787567	CB150C15	1-1/2 Ton Chain Hoist with 15 ft. Chain Fall	1-1/2 TON
787568	CB150C20	1-1/2 Ton Chain Hoist with 20 ft. Chain Fall	1-1/2 TON
787569	CB150C30	1-1/2 Ton Chain Hoist with 30 ft. Chain Fall	1-1/2 TON
787570	CB200C10	2 Ton Chain Hoist with 10 ft. Chain Fall	2 TON
787571	CB200C15	2 Ton Chain Hoist with 15 ft. Chain Fall	2 TON
787572	CB200C20	2 Ton Chain Hoist with 20 ft. Chain Fall	2 TON
787573	CB200C30	2 Ton Chain Hoist with 30 ft. Chain Fall	2 TON
787574	CB300C10	3 Ton Chain Hoist with 10 ft. Chain Fall	3 TON
787575	CB300C15	3 Ton Chain Hoist with 15 ft. Chain Fall	3 TON
787576	CB300C20	3 Ton Chain Hoist with 20 ft. Chain Fall	3 TON
787577	CB300C30	3 Ton Chain Hoist with 30 ft. Chain Fall	3 TON
787578	CB500C10	5 Ton Chain Hoist with 10 ft. Chain Fall	5 TON
787579	CB500C15	5 Ton Chain Hoist with 15 ft. Chain Fall	5 TON
787580	CB500C20	5 Ton Chain Hoist with 20 ft. Chain Fall	5 TON
787581	CB500C30	5 ton Chain Hoist with 30 ft. Chain Fall	5 TON
787582	CB1KC10	10 ton Chain Hoist with 10 ft. Chain Fall	10 TON
787583	CB1KC15	10 ton Chain Hoist with 15 ft. Chain Fall	10 TON
787584	CB1KC20	10 ton Chain Hoist with 20 ft. Chain Fall	10 TON
787585	CB1KC30	10 ton Chain Hoist with 30 ft. Chain Fall	10 TON

HOISTS

PREMIUM CHAIN BLOCK HOISTS



Sumner Lift Premium Chain Block Hoists low headroom design is ideal for your 1/4-20 ton lifting needs. Meets all ANSI/ASME, OSHA and CE Hoisting Standards.

SPECIAL FEATURES:

- Fused Brake Design
- 360 Degree Alloy Steel hooks
- Top Hook is easily removable
- Heat Treated Load Plates and internal Components
- Hard steel load sheave rollers
- 1.5x safety tested
- Unique zinc phosphate chain design

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787440	PCB025C10	1/4 Ton Chain Hoist with 10 ft. Chain Fall	1/4 TON
787441	PCB025C15	1/4 Ton Chain Hoist with 15 ft. Chain Fall	1/4 TON
787442	PCB025C20	1/4 Ton Chain Hoist with 20 ft. Chain Fall	1/4 TON
787443	PCB025C30	1/4 Ton Chain Hoist with 30 ft. Chain Fall	1/4 TON
787444	PCB050C10	1/2 Ton Chain Hoist with 10 ft. Chain Fall	1/2 TON
787445	PCB050C15	1/2 Ton Chain Hoist with 15 ft. Chain Fall	1/2 TON
787446	PCB050C20	1/2 Ton Chain Hoist with 20 ft. Chain Fall	1/2 TON
787447	PCB050C30	1/2 Ton Chain Hoist with 30 ft. Chain Fall	1/2 TON
787408	PCB100C10	1 Ton Chain Hoist with 10 ft. Chain Fall	1 TON
787409	PCB100C15	1 Ton Chain Hoist with 15 ft. Chain Fall	1 TON
787410	PCB100C20	1 Ton Chain Hoist with 20 ft. Chain Fall	1 TON
787411	PCB100C30	1 Ton Chain Hoist with 30 ft. Chain Fall	1 TON
787412	PCB150C10	1-1/2 Ton Chain Hoist with 10 ft. Chain Fall	1-1/2 TON
787413	PCB150C15	1-1/2 Ton Chain Hoist with 15 ft. Chain Fall	1-1/2 TON
787414	PCB150C20	1-1/2 Ton Chain Hoist with 20 ft. Chain Fall	1-1/2 TON
787415	PCB150C30	1-1/2 Ton Chain Hoist with 30 ft. Chain Fall	1-1/2 TON
787416	PCB200C10	2 Ton Chain Hoist with 10 ft. Chain Fall	2 TON
787417	PCB200C15	2 Ton Chain Hoist with 15 ft. Chain Fall	2 TON
787418	PCB200C20	2 Ton Chain Hoist with 20 ft. Chain Fall	2 TON
787419	PCB200C30	2 Ton Chain Hoist with 30 ft. Chain Fall	2 TON
787420	PCB300C10	3 Ton Chain Hoist with 10 ft. Chain Fall	3 TON
787421	PCB300C15	3 Ton Chain Hoist with 15 ft. Chain Fall	3 TON
787422	PCB300C20	3 Ton Chain Hoist with 20 ft. Chain Fall	3 TON
787423	PCB300C30	3 Ton Chain Hoist with 30 ft. Chain Fall	3 TON
787424	PCB500C10	5 Ton Chain Hoist with 10 ft. Chain Fall	5 TON
787425	PCB500C15	5 Ton Chain Hoist with 15 ft. Chain Fall	5 TON
787426	PCB500C20	5 Ton Chain Hoist with 20 ft. Chain Fall	5 TON
787427	PCB500C30	5 Ton Chain Hoist with 30 ft. Chain Fall	5 TON

PREMIUM CHAIN BLOCK HOISTS CONT.



SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787428	PCB1KC10	10 Ton Chain Hoist with 10 ft. Chain Fall	10 TON
787429	PCB1KC15	10 Ton Chain Hoist with 15 ft. Chain Fall	10 TON
787430	PCB1KC20	10 Ton Chain Hoist with 20 ft. Chain Fall	10 TON
787431	PCB1KC30	10 Ton Chain Hoist with 30 ft. Chain Fall	10 TON
787432	PCB1.5KC10	15 Ton Chain Hoist with 10 ft. Chain Fall	15 TON
787433	PCB1.5KC15	15 Ton Chain Hoist with 15 ft. Chain Fall	15 TON
787434	PCB1.5KC20	15 Ton Chain Hoist with 20 ft. Chain Fall	15 TON
787435	PCB1.5KC30	15 Ton Chain Hoist with 30 ft. Chain Fall	15 TON
787436	PCB2KC10	20 Ton Chain Hoist with 10 ft. Chain Fall	20 TON
787437	PCB2KC15	20 Ton Chain Hoist with 15 ft. Chain Fall	20 TON
787438	PCB2KC20	20 Ton Chain Hoist with 20 ft. Chain Fall	20 TON
787439	PCB2KC30	20 Ton Chain Hoist with 30 ft. Chain Fall	20 TON

HOISTS

PREMIUM CHAIN BLOCK HOISTS WITH OVERLOAD PROTECTION



Sumner Lift Premium Chain Block Hoists low headroom design is ideal for your 1-20 ton lifting needs. Meets all ANSI/ASME, OSHA and CE Hoisting Standards.

SPECIAL FEATURES:

- Top hook is easily removable
- Hard steel load sheave rollers
- 1.5x safety tested
- Unique zinc phosphate chain design

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787448	PCB100C10WO	1 Ton Chain Hoist with 10 ft. Chain Fall w/ Overload Protection	1 TON
787449	PCB100C15WO	1 Ton Chain Hoist with 15 ft. Chain Fall w/ Overload Protection	1 TON
787450	PCB100C20WO	1 Ton Chain Hoist with 20 ft. Chain Fall w/ Overload Protection	1 TON
787451	PCB100C30WO	1 Ton Chain Hoist with 30 ft. Chain Fall w/ Overload Protection	1 TON
787452	PCB150C10WO	1-1/2 Ton Chain Hoist with 10 ft. Chain Fall w/ Overload Protection	1-1/2 TON
787453	PCB150C15WO	1-1/2 Ton Chain Hoist with 15 ft. Chain Fall w/ Overload Protection	1-1/2 TON
787454	PCB150C20WO	1-1/2 Ton Chain Hoist with 20 ft. Chain Fall w/ Overload Protection	1-1/2 TON
787455	PCB150C30WO	1-1/2 Ton Chain Hoist with 30 ft. Chain Fall w/ Overload Protection	1-1/2 TON
787456	PCB200C10WO	2 Ton Chain Hoist with 10 ft. Chain Fall w/ Overload Protection	2 TON
787457	PCB200C15WO	2 Ton Chain Hoist with 15 ft. Chain Fall w/ Overload Protection	2 TON
787458	PCB200C20WO	2 Ton Chain Hoist with 20 ft. Chain Fall w/ Overload Protection	2 TON
787459	PCB200C30WO	2 Ton Chain Hoist With 30 ft. Chain Fall w/ Overload Protection	2 TON
787460	PCB300C10WO	3 Ton Chain Hoist With 10 ft. Chain Fall w/ Overload Protection	3 TON
787461	PCB300C15WO	3 Ton Chain Hoist With 15 ft. Chain Fall w/ Overload Protection	3 TON
787462	PCB300C20WO	3 Ton Chain Hoist With 20 ft. Chain Fall w/ Overload Protection	3 TON
787463	PCB300C30WO	3 Ton Chain Hoist With 30 ft. Chain Fall w/ Overload Protection	3 TON
787464	PCB500C10WO	5 Ton Chain Hoist With 10 ft. Chain Fall w/ Overload Protection	5 TON
787465	PCB500C15WO	5 Ton Chain Hoist With 15 ft. Chain Fall w/ Overload Protection	5 TON
787466	PCB500C20WO	5 Ton Chain Hoist With 20 ft. Chain Fall w/ Overload Protection	5 TON
787467	PCB500C30WO	5 Ton Chain Hoist With 30 ft. Chain Fall w/ Overload Protection	5 TON
787468	PCB1KC10WO	10 Ton Chain Hoist With 10 ft. Chain Fall w/ Overload Protection	10 TON
787469	PCB1KC15WO	10 Ton Chain Hoist With 15 ft. Chain Fall w/ Overload Protection	10 TON
787470	PCB1KC20WO	10 Ton Chain Hoist With 20 ft. Chain Fall w/ Overload Protection	10 TON
787471	PCB1KC30WO	10 Ton Chain Hoist With 30 ft. Chain Fall w/ Overload Protection	10 TON
787472	PCB1.5KC10WO	15 Ton Chain Hoist With 10 ft. Chain Fall w/ Overload Protection	15 TON
787473	PCB1.5KC15WO	15 Ton Chain Hoist With 15 ft. Chain Fall w/ Overload Protection	15 TON
787474	PCB1.5KC20WO	15 Ton Chain Hoist With 20 ft. Chain Fall w/ Overload Protection	15 TON
787475	PCB1.5KC30WO	15 Ton Chain Hoist with 30 ft. Chain Fall w/ Overload Protection	15 TON
787476	PCB2KC10WO	20 Ton Chain Hoist with 10 ft. Chain Fall w/ Overload Protection	20 TON
787477	PCB2KC15WO	20 Ton Chain Hoist with 15 ft. Chain Fall w/ Overload Protection	20 TON
787478	PCB2KC20WO	20 Ton Chain Hoist with 20 ft. Chain Fall w/ Overload Protection	20 TON
787479	PCB2KC30WO	20 Ton Chain Hoist with 30 ft. Chain Fall w/ Overload Protection	20 TON

HOISTS | PREMIUM CHAIN BLOCK HOISTS

MANUAL TROLLEY



1/2, 1, 2, 3, 5 and 10 Ton Manual Trolley.

SPECIAL FEATURES:

- Dual pawl brake system
- 360° alloy steel hooks
- Heat treated load plates and internal components
- Complies with ANSI /ASME, and OSHA standards

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787586	MT050C	1/2 Ton Manual Trolley	1/2 TON
787587	MT100C	1 Ton Manual Trolley	1 TON
787588	MT200C	2 Ton Manual Trolley	2 TON
787589	MT300C	3 Ton Manual Trolley	3 TON
787590	MT500C	5 Ton Manual Trolley	5 TON
787591	MT1KC	10 Ton Manual Trolley	10 TON

BEAM CLAMP



1, 2, 3 and 5 Ton Beam Clamp.

SPECIAL FEATURES:

- Dual Pawl brake system
- 360° alloy steel hooks
- Heat treated load plates and internal components
- Complies with ANSI /ASME, and OSHA standards
- Jet, Lift, Sumner, Southwire, Hoist, Come along, Chain hoist, harrington, CM hoist

SPECIFICATIONS

ITEM #	STOCK #	DESCRIPTION	LIFTING WEIGHT CAPACITY
787592	BC100C	1 Ton Beam Clamp	1 TON
787593	BC200C	2 Ton Beam Clamp	2 TON
787594	BC300C	3 Ton Beam Clamp	3 TON
787595	BC500C	5 Ton Beam Clamp	5 TON

WELDING HAND TOOLS

At Sumner Manufacturing, our welding customers inform our manufacturing process every step of the way. One of our primary goals is to provide our customers with high quality, competitively priced tools. We learn from welders in the field about what products are needed to make their jobs easier. These ideas help us to design and build new and improved products. In essence, our customers are part of our Research & Development department, and without their input, we would be unable to continually offer great new products.



WELDING HAND TOOLS

CURVED LOCKING PLIERS



CLP4W

Perfect for gripping and torquing various surface shapes, including round pipes, square or hex bolts, and more.

- Curved jaw with hardened teeth to grip a variety of shapes from any angle
- Trigger release for maximum locking force
- Includes wire cutter
- Constructed of high-grade, heat-treated alloy steel for durability



CLP5W



CLP7W



CLP10W

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781612	4" Curved Locking Pliers with Cutter	CLP4W	661165816129	4.33"	0.4"	1.37"	0.2 lbs	12
781615	5" Curved Locking Pliers with Cutter	CLP5W	661165816150	5.51"	0.4"	1.57"	0.34 lbs	12
781614	7" Curved Locking Pliers with Cutter	CLP7W	661165816143	7.08"	0.79"	2.36"	0.7 lbs	6
781613	10" Curved Locking Plier with Cutter	CLP10W	661165816136	9.05"	1"	2.36"	1.11 lbs	6

WELDING HAND TOOLS

STRAIGHT JAW LOCKING PLIERS



SLP7

Straight jaw pliers with heavy-duty jaws offer maximum grip on flat or square surfaces.

- Straight jaw with hardened teeth to grip a variety of shapes from any angle
- Trigger release for maximum locking force
- Includes wire cutter
- Constructed of high-grade, heat-treated alloy steel for durability



SLP10

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781617	7" Straight Jaw Locking Pliers	SLP7	661165816174	7.08"	0.79"	2.36"	0.83 lbs	6
781616	10" Straight Jaw Locking Pliers	SLP10	661165816167	9.06"	1"	2.36"	1.2 lbs	6

WELDING HAND TOOLS

MIG PLIERS

MIGP8



Perfect for spatter removal (inside or outside a nozzle), both bushing installation and removal, as well as wire cutting.

- Nose designed for easy removal of welding spatter
- Induction-hardened cutting edge stays sharp longer
- Multiple jaws for drawing out wire and removing tips and nozzles

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781618	8" MIG Pliers	MIGP8	661165816181	8.46"	0.5"	1.97"	0.66 lbs	12

WELDING HAND TOOLS

LOCKING CLAMPS

LC6



Wide-opening jaws provide more flexibility than standard locking clamps.

- Strong rivet connecting arms to prevent joint integrity from being compromised
- Jaw opening capacity provides versatility in clamping a variety of shapes
- Trigger release for maximum locking force
- Constructed of high-grade, heat-treated alloy steel for durability
- Stays adjusted for repetitive use



LC11



LC18



LC18R

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781621	6" Locking Clamp	LC6	661165816211	7.1"	1"	3.35"	0.46 lbs	6
781619	11" Locking Clamp	LC11	661165816198	10.83"	0.79"	5.51"	1.63 lbs	6
781623	18" Locking Clamp	LC18	661165816235	18.3"	0.79"	5.9"	3 lbs	6
781624	18" Deep Reach Locking Clamp	LC18R	661165816242	18.3"	0.79"	9.6"	3.15 lbs	6

WELDING HAND TOOLS

LOCKING CLAMPS WITH SWIVEL PADS



LCS6

Swivel pads provide a larger and more stable gripping surface to hold your work securely.

- Strong rivet connecting arms to prevent joint integrity from being compromised
- Jaw opening capacity provides versatility in clamping a variety of shapes
- Trigger release for maximum locking force
- Constructed of high-grade, heat-treated alloy steel for durability
- Stays adjusted for repetitive use



LCS9



LCS11




LCS18

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781622	6" Locking Clamp with Swivel Pads	LCS6	661165816228	7.1"	1"	3.35"	0.46 lbs	6
781626	9" Locking Clamp with Swivel Pads	LCS9	661165816266	9.45"	1.18"	4.33"	1.28 lbs	6
781620	11" Locking Clamp with Swivel Pads	LCS11	661165816204	10.83"	0.79"	5.51"	1.63 lbs	6
781625	18" Locking Clamp with Swivel Pads	LCS18	661165816259	18.3"	0.79"	5.9"	3 lbs	6

WELDING HAND TOOLS

LOCKING WELDING CLAMP

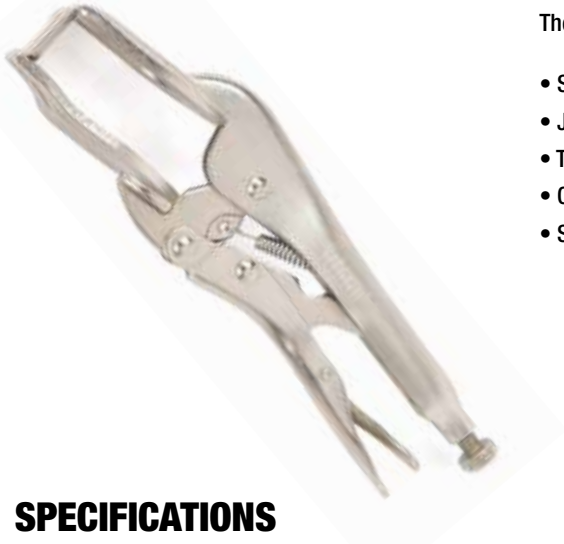

The Locking Welding Clamp has U-shaped jaws for high visibility and access.

- Strong rivet connecting arms to prevent joint integrity from being compromised
- Jaw opening capacity provides versatility in clamping a variety of shapes
- Trigger release for maximum locking force
- Constructed of high-grade, heat-treated alloy steel for durability
- Stays adjusted for repetitive use

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781627	9" Locking Welding Clamp	LWC9	661165816273	9.06"	2.56"	3.35"	1.21 lbs	6

WELDING HAND TOOLS

LOCKING CHAIN CLAMP



The Locking Chain Clamp holds and locks around any shape or any size of object and adjusts quickly.

- Strong rivet connecting arms to prevent joint integrity from being compromised
- Jaw opening capacity provides versatility in clamping a variety of shapes
- Trigger release for maximum locking force
- Constructed of high-grade, heat-treated alloy steel for durability
- Stays adjusted for repetitive use

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781628	20" Locking Chain Clamp	LCCH20	661165816280	17.7"	0.79"	2.4"	1.55 lbs	6

WELDING HAND TOOLS

LOCKING SHEET METAL TOOL



The Locking Sheet Metal tool locks on to flat surfaces with a secure grip.

- Strong rivet connecting arms to prevent joint integrity from being compromised
- Jaw opening capacity provides versatility in clamping a variety of shapes
- Trigger release for maximum locking force
- Constructed of high-grade, heat-treated alloy steel for durability
- Stays adjusted for repetitive use

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781629	8" Locking Sheet Metal Tool	LSM8	661165816297	8.07"	2.56"	3.15"	1.1 lbs	6

WELDING HAND TOOLS

CHIPPING HAMMERS



Solid construction yet lightweight, this chipping hammer provides excellent balance and control for precise chipping.

- Forged in one piece for durability
- Ergonomic grip that reduces impact vibration

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781630	Chipping Hammer	CHMR	661165816303	11"	1.38"	6.1"	1.1 lbs	12

WELDING HAND TOOLS

WIRE BRUSHES

WBCH



These wire brushes are comfortable to use and built to last.

CHIPPING HAMMER WITH WIRE BRUSH

- Durable hardened head construction for long life
- Replaceable wire brush
- Vibration reducing spring handle

BRASS WIRE BRUSH

- Strong and durable with securely imbedded brass bristles
- Long curved wood handle with pre-drilled hole for hanging
- Rust resistant

STEEL WIRE BRUSH

- Durable scratch brush with securely imbedded stainless-steel bristles.
- Long curved wood handle with pre-drilled hang hole.

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781631	Chipping Hammer with Wire Brush	WBCH	661165816310	11"	1.38"	6.1"	1.2 lbs	12
781632	Brass Wire Brush	BWB	661165816327	13.8"	1"	1.968"	0.35 lbs	12
781633	Steel Wire Brush	SWB	661165816334	13.8"	1"	1.77"	0.33 lbs	12

BWB



SWB



WELDING HAND TOOLS

GROUND CLAMPS

SGC500



These ground clamps provide a secure connection between the ground cable and your work piece. Large contact surface provides positive grounding.

500 AMP STEEL GROUND CLAMP

- Rugged and reliable steel lever design
- 500-Amp Capacity

200 AMP COPPER GROUND CLAMP

- Rugged and reliable copper cast design
- Ball point screw secures the welding cable to the ground clamp
- 200-AMP capacity
- Heavy-duty insulated spring

CGC200

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781634	500 Amp Steel Ground Clamp	SGC500	661165816341	7.48"	1"	3.15"	0.4 lbs	12
781635	200 Amp Copper Ground Clamp	CGC200	661165816358	6.9"	1"	3.1"	0.87 lbs	12

F CLAMP



Professional grade F-clamp offers smooth adjustment and high clamping capacity.

- Copper-coated steel screw with pivoting pressure cap
- Large 4-3/4" throat depth
- 1,000 lb. maximum clamping capacity

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781637	12" F Clamp	FC12	661165816372	15"	1.38"	7.87"	3.95 lbs	3

WELDING HAND TOOLS

COMBINATION SQUARE



A precise, easy to read, and well-built combination square for professional results every time.

- Hi-contrast black precision-etched scales
- Rust-proof stainless steel blade

SPECIFICATIONS

ITEM #	DESCRIPTION	MODEL #	UPC	HEIGHT	LENGTH/ DEPTH	WIDTH	WEIGHT	# ITEMS IN MASTER PACK
781636	12" Combination Square	CSQ12	661165816365	12"	0.79"	4.7"	0.13 lbs	6





Southwire®

SUMNER*

**PRODUCT
CATALOG**

get social with us:



[/SOUTHWIRETOOLS](#)



[/SOUTHWIRE-COMPANY](#)



[@SOUTHWIRETOOLS](#)



[@SOUTHWIRE](#)



SCAN TO LEARN MORE

WWW.SOUTHWIRE.COM | 1-855-SWTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/®- Trademark or Registered Trademark of Southwire Company.