

**LESS THAN STANDARD LEAD TIME**



**CUSTOM CONFIGURATION AND PRINT OPTIONS**






**LESS THAN STANDARD MOQ**




**EXPEDITED DELIVERY**




**SPEEDMC™ SOLUTIONS**

Phase Size	14, 12, 10, 8, 6, 4, 3, 2 AWG Copper		
Colors	Phases: BLACK, RED, BLUE, BROWN, ORANGE, YELLOW, PINK, PURPLE, TAN		
	Neutrals: WHITE, WHITE-BLACK, WHITE-BLUE, WHITE-RED, GRAY, GRAY-BROWN, GRAY-ORANGE, GRAY-YELLOW, GRAY-PURPLE		
Grounds	Bare or Insulated Copper: SOL or STR: 14, 12, 10, STR 8, 6, 4, 3, 2		Bare Aluminum: SOL 12, 10, 8
Insulation Type	THHN		
<b>Conductor Size</b>	<b>Max # of Conductors based on AWG</b>		
14, 12, 10 AWG	21 Conductors (includes ground wire)		
8 AWG	11 Conductors (includes ground wire)		
6 AWG	9 Conductors (includes ground wire)		
4 AWG	6 Conductors (includes ground wire)		
3 AWG	5 Conductors (includes ground wire)		
2 AWG	5 Conductors (includes ground wire)		
TYPE of MC	MC	MCAP (14-8 AWG only)	MCAP-HCF (14-8 AWG only)
	  		
	<p>NPP - Neutral Per Phase (14-8 AWG only)</p> <p>MN - Multi-Neutral</p> <p>ON - Oversized Neutral</p> <p>IG - Isolated Ground(s)</p> <p>PCS - Power &amp; Control/Signal (14-10 AWG only)</p> <p>Multi-Circuit</p>		
Armor Type	Aluminum and Steel		
Packaging	Reels and Coils - Minimum Length = 100'		
Minimum Order Quantity is 1,000'			
<b>NOW AVAILABLE</b> - Optional print legend over armor			

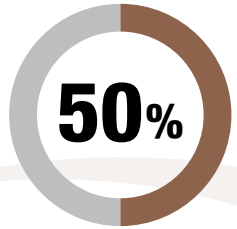

**LEAD TIME REDUCTION**

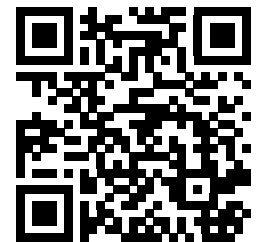

**SCAN THE QR CODE TO LEARN MORE**

For the fastest response to your Southwire SPEEDMC™ Solutions inquiry please contact your local Southwire representative.

**TURNING “NO QUOTE” INTO “NO PROBLEM”**