







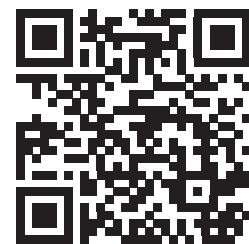


<b>LESS THAN STANDARD LEAD TIME</b> 	<b>CUSTOM CONFIGURATION AND PRINT OPTIONS</b> 	<b>LESS THAN STANDARD MOQ</b> 	<b>EXPEDITED DELIVERY</b> 
--	--	---	--

SPEEDMC™ SOLUTIONS			
Phase Size	14, 12, 10, 8, 6, 4, 3, 2 AWG Copper		
Colors	Phases: BLACK, RED, BLUE, BROWN, ORANGE, YELLOW, PINK, PURPLE, TAN		
	Neutrals: WHITE, WHITE-BLACK, WHITE-BLUE, WHITE-RED, GRAY, GRAY-BROWN, GRAY-ORANGE, GRAY-YELLOW, GRAY-PURPLE		
Grounds	Bare or Insulated Copper: SOL or STR: 14, 12, 10, STR 8, 6, 4, 3, 2	Bare Aluminum: SOL 12, 10, 8	
Insulation Type	THHN		
Conductor Size	Max # of Conductors based on AWG		
14, 12, 10 AWG	21 Conductors (includes ground wire)		
8 AWG	11 Conductors (includes ground wire)		
6 AWG	9 Conductors (includes ground wire)		
4 AWG	6 Conductors (includes ground wire)		
3 AWG	5 Conductors (includes ground wire)		
2 AWG	5 Conductors (includes ground wire)		
TYPE of MC	MC 	MCAP (14-8 AWG only) 	MCAP-HCF (14-8 AWG only) 
Construction Type	NPP - Neutral Per Phase (14-8 AWG only)		
	MN - Multi-Neutral		
	ON - Oversized Neutral		
	IG - Isolated Ground(s)		
	PCS - Power & Control/Signal (14-10 AWG only)		
	Multi-Circuit		
Armor Type	Aluminum and Steel		
Packaging	Reels and Coils - Minimum Length = 100'		
Minimum Order Quantity is 1,000'			
 <span style="float: right;"><b>Print Legend Over Armor Available</b></span>			



SCAN THE QR CODE TO LEARN MORE

For the fastest response to your Southwire SPEEDMC™ Solutions inquiry please contact your local Southwire representative.

**TURNING “NO QUOTE” INTO “NO PROBLEM”**