

Southwire Reel Return Program

For Electrical Distributors, EPC Partners and End Users

Definition of a Returnable Reel

A returnable reel is a reel for which a refundable deposit charge is paid to Southwire at the time of purchase, or at an arranged, deferred date. Title to returnable reels shall remain in the name of Southwire.

A returnable reel can be wood or steel with a returnable reel metal tag showing the unique serial number and Southwire barcode. All other reels without a metal tag are non-returnable.

An example of a returnable reel tag is shown in *Appendix A Figure 1*.
Plywood reels are NOT returnable and are not charged to customer.

Following are the size restrictions on returnable wood reels (also known as Q reels).

1. Wood reels up to and including 36-inch diameter have no refundable charge and are not returnable.
2. Wood reels 40-inch diameter and larger are subject to a refundable deposit charge and are returnable for a 93% deposit refund.

Non returnable reels may returned to the nearest Southwire Recycling Centre on a freight-prepaid basis upon arrangement with Southwire, provided they are in excellent, re-usable condition. **No credit for these reels will be paid.**

General Policies on Returnable Reels

Reel Credit Policy

Reels must be returned with metal tag showing a legible serial number affixed to the reel flange. Returnable Steel reels returned without an illegible label will not be eligible for a refund.

Customer is responsible for tracking serial number on returned reels. Customer is required to provide the serial number of the returned reel when deducting on account for reel return. The serial number must be documented either on the remittance details or on a separate deduction explanation. **In the event a customer cannot provide a serial number, the deduction will be deemed invalid and chargeback to customer.**

Condition of Returned Reels

If a returnable steel reel is sent back to Southwire that is not repairable due to extensive damage, then no reel deposit charges will be refunded to the customer. If Southwire has not yet invoiced for the non-repairable reel then it will be invoiced to customer for the full value of this reel upon receipt of the non-repairable reel. All returned reels should be free of nails to ensure safety during handling and transport.

Freight on Returnable Reels

Reels must be returned “freight pre-paid” to one of the Southwire Recycling Centers listed in *Appendix B*. If shipments are returned “collect”, then the freight charges will be deducted from the reel credit.

Recycling Centers

Returns must be accompanied by a packing slip and bill of lading. Questions regarding the return of reels should be directed to the nearest Southwire Sales Office. Reels can only be returned directly to a Southwire manufacturing facility with prior approval from the Southwire Canada Sales Office.

Billing Policy

The terms of the policy on returnable reels differ by the type of reel.

Cash discounts and rebates do not apply to reel charges. Reel charges will be subject to Harmonized Sales Tax (HST/QST), where applicable. Terms of payment are Net 30, or same as regular invoices.

Wood Reels

At the time of shipment, all chargeable wood reels will be billed at 100% of their refundable deposit charge value. See *Appendix C* for Wood Reel Size and Value Chart.

Customer have up to 24 months (2 years) to return after the ship date. When the reel is returned to a Southwire designated Recycling Centre, a reel credit will be issued at 93% of the original refundable deposit charge amount, provided they have no significant damage, and has a label showing a legible serial number affixed to the reel flange. Returnable reels returned without a label or with an illegible label will not be eligible for a refund. The refund will be paid to the party who paid the original refundable charge.

For example, the deposit charge for a 50” wood reel (\$420.00) will be invoiced at the date of shipment of the cable. When the reel is returned to the Southwire recycling center within 2 years from the ship date, the customer will be credited at \$390.60 equals to 93% of the original charge.

Steel Reels

At the time of shipment, Southwire will not invoice customer the value of the steel reel(s). See *Appendix D* for Steel Reel Size and Value Chart.


Customer have up to 12 months (1 year) to return after the ship date. When the Steel reel is returned to a Southwire designated Recycling Centre within one year, no charge will be placed on customer, provided the returned reels have no significant damage, and has a label showing a legible serial number affixed to the reel flange. Upon one year after shipment, if the reel has not been returned, Southwire will invoice for 100% the value of the Steel reel(s).

For example, the deposit charge for a 60” Steel reel (\$1,500.00) will have costs deferred for one (1) year at the date of shipment of the cable. When the reel is returned to the Southwire recycling center in the first year, customer is not charged. If the reel is not returned after one year, customer will be invoiced for \$1,500.00, full value of the reel.

Appendix A



Figure 1: Returnable Reel Tag

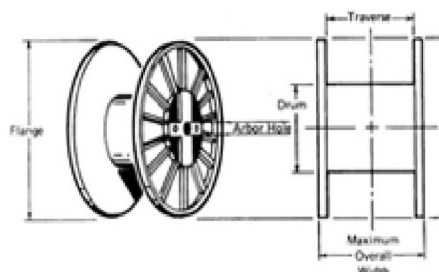

Appendix B

The following locations are identified as designated Southwire Recycling Centers:

Province	Reel Recycling Center	Province	Reel Recycling Center
British Columbia	Tenold Transportation 19470 94-Ave. Surrey, BC, V4N 4E5 Tel: 604-888-7822	Ontario	Tenold Transportation 138 Commerce Drive, Johnstown, ON K0E 1T0 Tel: 613-925-3131 Toll Free: 800-267-4325
Alberta	Tenold Transportation 4503 17 th Street Edmonton, AB, T6P 1X5 Tel: 780 453 2761	Quebec	Tenold Transportation 138 Commerce Drive, Johnstown, ON K0E 1T0 Tel: 613-925-3131 Toll Free: 800-267-4325
Saskatchewan	Tenold Transportation 54 Queen Street Weyburn, SK, S4H 2L3 Tel: 306-848-1700	Atlantic Canada (Newfoundland, Nova Scotia, New Brunswick & PEI)	Classic Truck & Trailer Attention: Dave Cassell 33 John Snook Blvd. Debert, NS, B0M 1G0 Tel: 902-662-5100
Manitoba	Tenold Transportation 2800 McGillivray Blvd. Winnipeg, MB, R3Y 1N3 Tel: 204 694 4138		

Appendix C

RETURNABLE WOOD REELS: SIZE AND VALUE CHART									
South- wire Reel Number	Flange Diameter	Traverse Width	Drum Diameter	Max Overall Width	Arbor Hole	<i>Weight</i>		Deposit Charge	93% Refund
	Inches					Kgs	LBS	CDN \$	CDN \$
Q18	40	18	18	23.5	3.06	91	200	\$552.50	\$513.83
Q25	40	24	17	30	3.06	95	209	\$552.50	\$513.83
Q22	42	24	24	30	3.06	108	239	\$552.50	\$513.83
Q33	48	24	24	30	3.06	132	291	\$682.50	\$634.73
Q50	50	32	23	38	3.06	142	314	\$682.50	\$634.73
Q52	50	32	21	38	3.125	151	333	\$682.50	\$634.73
Q56	54	32	26	38	3.06	175	386	\$796.25	\$740.51
Q65	58	32	28	38	3.06	197	434	\$910.00	\$846.30
Q64.5	60	32	32	38	3.06	215	474	\$910.00	\$846.30
Q87	66	36	36	42	3.06	263	579	\$1381.25	\$1284.56
Q115	68	38	28	44	3.06	264	583	\$1381.25	\$1284.56
Q81	72	36	48	43	4	397	876	\$2258.75	\$2100.64
Q107	78	36	48	43	4	437	963	\$2258.75	\$2100.64
Q157	84	42	48	49	4	506	1116	\$3445.00	\$3203.85
Q179	90	46	56	55	5	786	1732	\$4550.00	\$4231.50
Q229	90	52	50	63	5	944	2082	\$4550.00	\$4231.50
Q294	90	59	42	70	5	725	1599	\$4550.00	\$4231.50
Q220	96	46	56	55	5.25	865	1906	\$4550.00	\$4231.50

Appendix D

RETURNABLE STEEL REELS: SIZE AND VALUE CHART								
South- wire Reel Number	Flange Diameter	Traverse Width	Drum Diameter	Max Overall Width	Arbor Hole	Weight		Reel Value
	Inches					Kgs	LBS	CDN \$
S62	60	28	28	34.5	3	154	340	\$2250.00
S77	66	32	36	38	3	181	400	\$2625.00
S99	68	38	36	44.75	3.125	201	444	\$3000.00
S120	84	36	42	43	5.25	406	895	\$5250.00
S153	84	45	42	52.5	5.25	422	930	\$5250.00
S187	90	45	42	52.5	5.25	467	1030	\$5850.00
S224	90	45	42	52.5	5.25	446	984	\$5850.00
S249	90	60	42	68	5.25	534	1176	\$6150.00
S282	90	60	46	68	5.25	575	1268	\$6150.00
S299	90	60	42	68	5.25	461	1016	\$6150.00
S300	96	60	42	68	5.25	491	1082	\$6600.00
S300A	96	60	42	68	5.313	713	1573	\$6600.00
S435	108	68	47	77.37	5.25	580	1278	\$6600.00
S422	108	74	56	85	5.25	799	1762	\$9000.00
S400	110	70	60	78	5.25	803	1770	\$9000.00
S431	118	85	78	94.5	7.625	1668	3677	\$14400.00
S600	118	85	60	94.5	7.625	1281	2825	\$14400.00
S622	126	86	72	95	7.625	1585	3494	\$15750.00
S650	138	85	88	94.5	7.625	1848	4075	\$15750.00
S740	138	85	80	94.5	7.625	1657	3654	\$15750.00
S869	158	86	110	95.5	7.625	1589	3504	\$21750.00
S906	158	88	100	94.6	5.25	3150	6945	\$21750.00
S1013	158	86	90	95.5	7.625	2085	4598	\$21750.00
S1100	158	83	80	94.5	7.625	1788	3941	\$21750.00

