



Southwire™

BENDDOLLY™ BENDING PLATFORM

Mechanical bending platform.




LIGHT WEIGHT BENDING PLATFORM

INTERCHANGEABLE SHOE MOUNTING PLATE

LARGE DOLLY WHEELS FOR EASY MANEUVERABILITY

STABLE BENDING PLATFORM

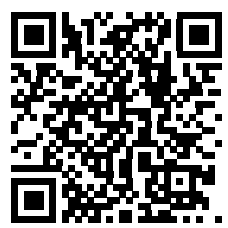

SCAN TO SEE MORE

MODEL #	STOCK #	DESCRIPTION	CAPACITY	HEIGHT	WIDTH	DEPTH	WEIGHT
BD-01	64601101	BENDdolly™ Bending Platform	Works with EMT, IMC/ GRC Bending	28.75"	26"	55"	60 lbs.
BD750E	64602301	BENDdolly™ 1/2"-3/4" EMT Bender	1/2"-3/4" EMT Conduit	28.75"	26"	55"	92 lbs.
BD1000E	64602401	BENDdolly™ 3/4"-1" EMT Bender	3/4"-1" EMT Conduit	28.75"	26"	55"	110 lbs.
BD1250E	64602401	BENDdolly™ 1"-1.25" EMT Bender	1"-1.25" EMT Conduit	28.75"	26"	55"	145 lbs.
BD1000R	64602501	BENDdolly™ 3/4"-1" GRC/IMC Bender	3/4"-1" GRC/IMC Conduit	28.75"	26"	55"	140 lbs.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2021 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.