




CATEGORY CABLE WITH LP LISTING

CAT 6E 550 MHZ 23 AWG 4 PAIR SOLID COPPER TYPE CMP-LP (0.6A) 105C UL LISTED

SPECS

- Limited Power Rated Data Cable
- PoE Applications
- Designed for indoor and plenum installations
- Unshielded twisted pair cable
- TIA/EIA 568-C.2
- NEC ARTICLE 800
- IEEE802.3bt
- UL 444 CMP
- NFPA 262 (UL 910)
- RoHS 3 Directive (EU) 2015/863
- C(UL)US LISTED

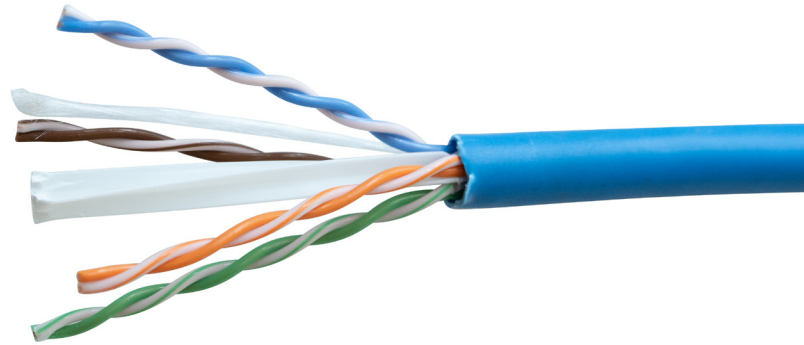

Model #	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan
Stock #	I99997-1A	I99997-1H	I99997-2A	I99997-2H	I99997-3A	I99997-3H	I99997-13A	I99997-13H
UPC	032886885815	032886885839	032886885846	032886885853	029892498160	029892498108	032886907197	029892498405
Description	CAT 6E 550 MHZ 23/4P w/Spline Be CMP 1000R	CAT 6E 550 MHZ 23/4P w/Spline Be CMP 1000RB	CAT 6E 550 MHZ 23/4P w/Spline We CMP 1000R	CAT 6E 550 MHZ 23/4P w/Spline We CMP 1000RB	CAT 6E 550 MHZ 23/4P w/Spline Yw CMP 1000R	CAT 6E 550 MHZ 23/4P w/Spline Yw CMP 1000RB	CAT 6E 550 MHZ 23/4P w/Spline Bk CMP 1000R	CAT 6E 550 MHZ 23/4P w/Spline Bk CMP 1000RB
Package	Reel	Reel In Box	Reel	Reel In Box	Reel	Reel In Box	Reel	Reel In Box
Weight	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 LBS.
Jacket Color	Blue	Blue	White	White	Yellow	Yellow	Black	Black
Insulation Type	HDPE	HDPE	HDPE	HDPE	HDPE	HDPE	HDPE	HDPE
Jacket Type	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC



CATEGORY CABLE WITH LP LISTING

CAT6 250 MHZ 23 AWG 4 Pair Solid Copper TYPE CMP-LP (0.5A) 75C

SPECS

- Limited Power Rated Data Cable
- PoE Applications
- Designed for indoor and plenum installations
- Unshielded twisted pair cable
- TIA/EIA 568-C.2
- NEC ARTICLE 800
- IEEE 802.3af
- UL 444 CMP
- NFPA 262 (UL 910)/CSA FT6
- RoHS 3 Directive (EU) 2015/863
- C(UL)US LISTED



Model #	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan
Stock #	I99993-1B	I99993-1H	I99993-2B	I99993-2H	I99993-10B	I99993-10H	I99993-11B	I99993-11H	I99993-12B
UPC	032886885730	032886885747	032886768200	032886757006	032886906558	029892498467	032886906633	032886906657	032886906671
Description	CAT6 250 MHZ 23/4P SOL BC CMP BE 1000PB	CAT6 250 MHZ 23/4P SOL BC CMP BE 1000RIB	CAT6 250 MHZ 23/4P SOL BC CMP WHT 1000PB	CAT6 250 MHZ 23/4P SOL BC CMP WHT 1000RIB	CAT6 250 MHZ 23/4P SOL BC CMP GRY 1000PB	CAT6 250 MHZ 23/4P SOL BC CMP GRY 1000RIB	CAT6 250 MHZ 23/4P SOL BC CMP YEL 1000PB	CAT6 250 MHZ 23/4P SOL BC CMP YEL 1000RIB	CAT 6 250 MHZ 23/4P SOL BC CMP OE 1000PB
Package	Pullbox	Reel In Box	Pullbox	Reel In Box	Pullbox	Reel In Box	Pullbox	Reel In Box	Pullbox
Weight	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 LBS.	26 lbs.
Jacket Color	Blue	Blue	White	White	Gray	Gray	Yellow	Yellow	Orange
Insulation Type	FEP	FEP	FEP	FEP	FEP	FEP	FEP	FEP	FEP
Jacket Type	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC

Model #	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	Tappan	
Stock #	I99993-12H	I99993-9B	I99993-8B	I99993-8H	I99993-4B	I99993-4H	I99993-13B	I99993-13H	
UPC	032886906695	032886895302	032886895319	029892498689	032886906596	029892498566	032886906732	029892498801	
Description	CAT 6 250 MHZ 23/4P SOL BC CMP OE 1000RIB	CAT 6 250 MHZ 23/4P SOL BC CMP GN 1000PB	CAT 6 250 MHZ 23/4P SOL BC CMP RD 1000PB	CAT 6 250 MHZ 23/4P SOL BC CMP RD 1000RIB	CAT 6 250 MHZ 23/4P SOL BC CMP PK 1000PB	CAT 6 250 MHZ 23/4P SOL BC CMP PK 1000RIB	CAT 6 250 MHZ 23/4P SOL BC CMP BK 1000PB	CAT 6 250 MHZ 23/4P SOL BC CMP BK 1000RIB	CAT 6 250 MHZ 23/4P SOL BC CMP BK 1000RIB
Package	Reel In Box	Pullbox	Pullbox	Reel In Box	Pullbox	Reel In Box	Pullbox	Reel In Box	
Weight	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	26 lbs.	
Jacket Color	Orange	Green	Green	Red	Red	Pink	Black	Black	
Insulation Type	FEP	FEP	FEP	FEP	FEP	FEP	FEP	FEP	
Jacket Type	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	LS-PVC	