

# SIMpull BARRELS<sup>TM</sup> CABLE DRUMS

MANUFACTURED IN 2 WEEKS & MOQ REDUCED TO 1 BARREL

**LESS THAN STANDARD  
LEAD TIME**



**CUSTOM  
CONFIGURATION**



**LESS THAN  
STANDARD MOQ**



**EXPEDITED  
DELIVERY**



## SIMpull BARREL<sup>TM</sup> 1/C up to 7/C

**SIZES:**

12 & 10 STR Phases

**COLORS:**

Black, Red, Blue, White, White-Black, White-Blue, White-Red, Green, Brown, Orange, Yellow, Gray, Gray-Brown, Gray-Orange, Gray-Yellow


**LEAD TIME & MOQ:**

2-Week LT and 1 Barrel MOQ for Constructions with the Above Colors




Increase productivity and reduce the potential for injury while avoiding broken spools and excess material.

- Reduce material handling
- Less physical effort to pull wire
- SIMpull<sup>®</sup> NoLube<sup>®</sup> wire jacket
- Pays off directly out of package
- Optional carts and accessories available

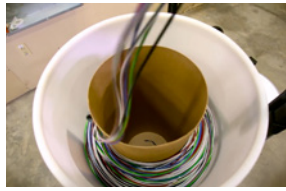

**1 BARREL  
MINIMUM  
ORDER QUANTITY**

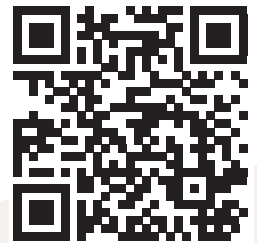

SCAN THE QR CODE TO LEARN  
MORE ABOUT SPEED

Lead time refers to manufacturing time. Please allow additional time for shipment and delivery.  
To request a quote or place an order, reach out to [SWSpeed@southwire.com](mailto:SWSpeed@southwire.com) and copy your Southwire sales representative.

# SIMpull BARRELS<sup>TM</sup> CABLE DRUMS

Stock No.	# Conductors	Description	Color Combination	WIREbarrel Length (ft)	Total Wire Length (ft)
1/C	1	12 STR THHN SIMpull	Single conductor barrel of any stnd. color*	15,000	15,000
58612002	2	12 STR THHN SIMpull	Brn/Gry-Brn	7,500	15,000
58610002	2	12 STR THHN SIMpull	Org/Gry-Org	7,500	15,000
58610102	2	12 STR THHN SIMpull	Yel/Gry-Yel	7,500	15,000
58536702	3	12 STR THHN SIMpull	Blk/Wht-Blk/Grn	7,500	22,500
58537102	3	12 STR THHN SIMpull	Red/Wht-Red/Grn	7,500	22,500
58536802	3	12 STR THHN SIMpull	Blu/Wht-Blu/Grn	7,500	22,500
58536902	3	12 STR THHN SIMpull	Brn/Gry-Brn/Grn	7,500	22,500
58537002	3	12 STR THHN SIMpull	Org/Gry-Org/Grn	7,500	22,500
58537402	3	12 STR THHN SIMpull	Yel/Gry-Yel/Grn	7,500	22,500
58103401	4	12 STR THHN SIMpull	Blk/Red/Blu/Wht	5,000	20,000
58116001	4	12 STR THHN SIMpull	Brn/Org/Yel//Gry	5,000	20,000
58139301	4	12 STR THHN SIMpull	Blk/Red/Blu/Grn	5,000	20,000
58104001	5	12 STR THHN SIMpull	Blk/Red/Blu/Wht/Grn	5,000	25,000
58117401	5	12 STR THHN SIMpull	Brn/Org/Yel//Gry/Grn	5,000	25,000
58120801	6	12 STR THHN SIMpull	Blk/Red/Blu/Wht-Blk/Wht-Red/Wht-Blu	3,000	18,000
58120601	6	12 STR THHN SIMpull	Brn/Org/Yel/Gry-Brn/Gry-Org/Gry-Yel	3,000	18,000
58104701	7	12 STR THHN SIMpull	Brn/Org/Yel/Gry-Brn/Gry-Org/Gry-Yel/Grn	3,000	21,000

1/C		10 STR THHN SIMpull	Single conductor barrel of any stnd. color*	15,000	15,000
58725702	2	10 STR THHN SIMpull	Brn/Gry-Brn	7,500	15,000
58725502	2	10 STR THHN SIMpull	Org/Gry-Org	7,500	15,000
58725602	2	10 STR THHN SIMpull	Yel/Gry-Yel	7,500	15,000
58318301	3	10 STR THHN SIMpull	Blk/Wht-Blk/Grn	5,000	15,000
58620401	3	10 STR THHN SIMpull	Red/Wht-Red/Grn	5,000	15,000
58620501	3	10 STR THHN SIMpull	Blu/Wht-Blu/Grn	5,000	15,000
58710901	3	10 STR THHN SIMpull	Brn/Gry-Brn/Grn	5,000	15,000
58711001	3	10 STR THHN SIMpull	Org/Gry-Org/Grn	5,000	15,000
58711101	3	10 STR THHN SIMpull	Yel/Gry-Yel/Grn	5,000	15,000
58115501	4	10 STR THHN SIMpull	Brn/Org/Yel//Gry	3,000	12,000
58167601	4	10 STR THHN SIMpull	Blk/Red/Blu/Grn	3,000	12,000
58116901	5	10 STR THHN SIMpull	Brn/Org/Yel//Gry/Grn	3,000	15,000
58120001	6	10 STR THHN SIMpull	Brn/Org/Yel/Gry-Brn/Gry-Org/Gry-Yel	2,500	15,000

Lead time refers to manufacturing time. Please allow additional time for shipment and delivery.  
To request a quote or place an order, reach out to [SWSpeed@southwire.com](mailto:SWSpeed@southwire.com) and copy your Southwire sales representative.

# CIRCUIT MANAGEMENT

## THE COMPLETE SOUTHWIRE SOLUTION



WG-01

### SIMpull® GUIDEit™ CIRCUIT ROUTER

- Unique adapter for feeding circuit wire hands free
- Mounts easily to the panel can and helps guide conductors into the panel without damage



SPR-183  
1/8" X 300'



SPR-143  
1/4" X 300'



SPR-146  
1/4" X 600'

### QWIKrope® PULLING ROPE

- Up to 24% reduction in coefficient of friction
- Ultra-low stretch and UV resistant



SBT-01

### SIMpull BARREL™ HAND TRUCK

- Designed to transport the SIMpull BARREL™ package anywhere on the jobsite
- Fits through narrow electrical room doors and easily rolls over cords or construction grave
- Includes built-in payoff feature



SBT-02

### SIMpull BARREL™ TRIPOD

- Allows wire to pay off directly from the package with no additional tools or equipment



XD1

### MAXIS® XD1 EXTREME DUTY CIRCUIT PULLER

- Lightweight, handheld puller that is compatible with most drills
- Combines 600lbs of constant pulling force with 1000lbs peak pulling force
- One person set up and operation



CSPH1HD

### SIMpull® GRIPIT™ CIRCUIT PULLING HEAD

- Re-usable pulling head eliminated need for head make-up
- Easily attached up to 7 wires without stripping or taping

Lead time refers to manufacturing time. Please allow additional time for shipment and delivery.

To request a quote or place an order, reach out to [SWSpeed@southwire.com](mailto:SWSpeed@southwire.com) and copy your Southwire sales representative.