



Southwire™

TOOLS & EQUIPMENT CATALOG



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**


SOUTHWIRE.COM



THE COMPLETE SOUTHWIRE® SOLUTION

WIRE AND CABLE | TOOLS AND EQUIPMENT | POWER MANAGEMENT
ELECTRICAL COMPONENTS | LIGHTING SOLUTIONS



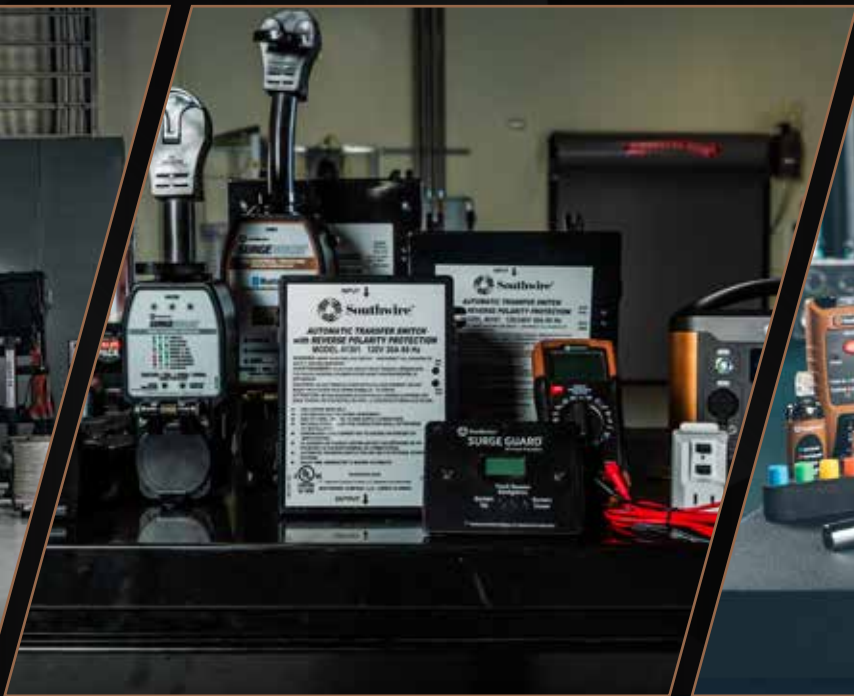

OUR STORY

As a family business, Southwire proudly continues building on our commitment to environmental stewardship and corporate sustainability by prioritizing stakeholder expectations, and supporting the wellbeing of our communities and the environment in which we live. To help us meet this commitment, we organize our sustainability strategy around five core tenets: Growing Green, Living Well, Giving Back, Doing Right, and Building Worth.

We Deliver Power...Responsibly®

We remain committed to the sustainability of our company for the next 100 years and beyond. As we strengthen this commitment, we continue to work hard every day to discover, develop and distribute sustainable solutions that exceed the expectations of our stakeholders around the world.

OUR MISSION

To be a **preferred provider** of solutions to the electrical industry by providing innovative products and services with exceptional quality.

OUR VALUES

Our **ONE Southwire** culture prioritizes the interests of our team members, customers, and communities through a continuous commitment to empowerment, trust, consistency, and inclusion.

OUR REACH

Nearly one in two new homes built in the United States contains our wire, and we produce half of the cable used to transmit and distribute electricity throughout the nation.

OUR PRODUCTS

Our product teams and dedicated resources work together to listen to and work with our customers, creating solutions that deliver unparalleled value through product innovation, safety and efficiency.

OUR SERVICE

Service is more than a word or a phone number; it's a tangible support system that assists you through the entire project cycle; from our knowledgeable customer service team, to our experienced field sales team, we're there every step of the way.



TABLE OF CONTENTS

HAND TOOLS

| | |
|--|----|
| Pliers..... | 7 |
| Wounded Warrior Project® Limited Edition Pliers..... | 14 |
| Wounded Warrior Project® Limited Edition Wire Strippers..... | 15 |
| Stripping & Cutting | 16 |
| Cutters | 18 |
| Wounded Warrior Project® Limited Edition Cutters | 19 |
| Blades..... | 21 |
| Knives..... | 22 |
| Drivers | 23 |
| Hex Keys..... | 32 |
| Levels | 33 |
| Bags..... | 34 |
| Accessories | 36 |
| Kits..... | 37 |

VOICE • DATA • VIDEO

| | |
|---------------------------------|----|
| Test Set | 43 |
| Mappers & Testers | 44 |
| Phone Outlet Tester | 47 |
| Data & Video Cable Tester | 48 |
| Tone & Probe Kit..... | 49 |
| Wire Tracing Kit..... | 50 |
| Cutters | 51 |
| Cutting & Stripping | 52 |
| Prep Tool | 54 |
| Punch Down Tools | 55 |
| Crimping Tools..... | 56 |

FISHING & BENDING

| | |
|---------------------------------|----|
| SIMpull™ Fishtapes..... | 63 |
| Stainless Steel Fishtapes | 66 |
| Steel Fishtapes | 67 |
| Fishtape Leader | 68 |
| Fish Sticks | 68 |
| Conduit Hand Benders..... | 69 |

TEST & MEASUREMENT

| | |
|-----------------------|-----|
| Multimeters | 78 |
| Clamp Meters | 88 |
| Voltage Testers..... | 94 |
| NCVs | 97 |
| Testers..... | 101 |
| IR Thermometers | 105 |
| Test Kits..... | 107 |

CABLE PULLING

| | |
|-----------------------------|-----|
| Pullers..... | 111 |
| Pulling Accessories | 118 |
| Pulling Rope..... | 121 |
| Conduit Measuring Tape..... | 124 |
| Pulling Grips | 125 |
| Reel Rollers | 132 |
| Accessories | 133 |

TERMINATION

| | |
|----------------------|-----|
| Cable Strippers..... | 135 |
|----------------------|-----|

CONDUIT BENDING

| | |
|--------------------|-----|
| Benders | 138 |
| PVC Blankets | 143 |
| Plug Kits..... | 144 |

HOLE MAKING

| | |
|-------------------|-----|
| Knockouts..... | 146 |
| Layout Tool | 152 |
| Drive Units | 153 |
| Hole Saws..... | 154 |
| Auger Bits | 155 |
| Drill Bits | 158 |
| Hole Cutter..... | 159 |

MATERIAL HANDLING

| | |
|---|-----|
| Flange..... | 161 |
| Reel Stands | 162 |
| Axle & Riser | 166 |
| Pallet Jacks | 167 |
| SIMpull™ CoilPak™ Utility Carts..... | 168 |
| SIMpull™ Barrel™ Hand Truck & Tripod..... | 169 |
| Wire Wagon® Carts | 170 |
| Wire Carts..... | 173 |
| Caddy Mac™ | 174 |
| Caddies..... | 176 |
| Mac Racks™ I & Mac Racks™ II | 177 |
| Hanger Mac™ | 178 |
| Pipe Mac™ & Bundle Mac™ | 179 |
| Stor Mac™ Storage Cabinets | 180 |
| Tainer Mac™ | 182 |
| Weldbox™ | 183 |
| Cabinets..... | 184 |
| Piano Boxes | 185 |
| Field Office | 186 |
| Compact Chests..... | 187 |
| Utility Carts | 188 |

HAND TOOLS

Your hands are your most valuable asset on the job. That's why we're here to equip them with high-quality, durable hand tools from Southwire. With a strong yet comfortable design and no-hassle lifetime warranty, you can rely on these tools to make your life easier and last through years of hard work.



HAND TOOLS

HIGH LEVERAGE SIDE CUTTING PLIERS

SCP9TPCB



SCP9TPC



SCP9C



SCP9



SCP9D



SCP9CD



Our high leverage side cutting pliers offer a streamlined design with sure-gripping, cross-hatched knurled jaws.

- Induction-hardened cutting blades ensure efficient and lasting cutting surfaces for hard and soft wire
- Drop forged CRV steel for durability
- File teeth on jaws help remove burrs in conduit
- Curved ergonomic handle for comfortable use


SPECIFICATIONS

COMFORT GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---|-------|----------|
| SCP9TPC | 58993140 | High Leverage Side Cutting Pliers w/ Fish Tape Puller & Crimper | | |
| SCP9C | 58993040 | High Leverage Side Cutting Pliers w/ Crimper | | |
| SCP9 | 58992940 | High Leverage Side Cutting Pliers | | |
| SCP9TPCB | 65028940 | High Leverage Side Cutting Combo Pliers | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| SCP9TPC | 9.5" | 2.5" | 0.88" | 1.19 lb. |
| SCP9C | 9.5" | 2.5" | 0.88" | 1.19 lb. |
| SCP9 | 9.5" | 2.5" | 0.88" | 1.19 lb. |
| SCP9TPCB | 9.00" | 2.5" | 0.79" | 1.16 lb. |

DIPPED GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|----------|
| SCP9D | 58289840 | High Leverage Diagonal Cutting Pliers w/ Dipped Handle | | |
| SCP9CD | 58749140 | High Leverage Diagonal Cutting Pliers w/ Crimper Dipped Handles | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SCP9D | 9.5" | 2.13" | 0.75" | 1.19 lb. |
| SCP9CD | 9.5" | 2.13" | 0.75" | 1.19 lb. |

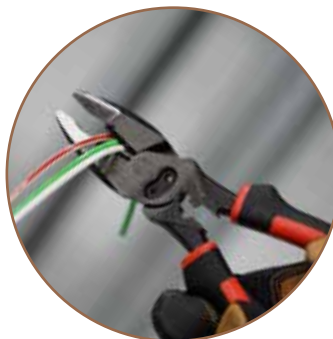

HAND TOOLS

LONG NOSE PLIERS

LNP8SD



LNP7D





Southwire long nose pliers provide a better grip without sacrificing tool strength or durability.

- Knurled jaws for sure-gripping
- Drop forged CRV steel for durability
- High leverage, hot rivet design for smooth action and no handle wobble
- Long nose design for forming and looping wire and handling small parts
- Precision induction-hardened cutting knives for long-lasting cutting edge
- 12 AWG solid wire stripper on LNP8SD

SPECIFICATIONS

DIPPED GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|--------|----------|
| LNP8SD | 58289740 | 8" Hvy. Dty. Long Nose Pliers Side Cutting Stripper Dipped Handle | | |
| LNP7D | 58749040 | 7" Long Nose Pliers w/ Side Cut Dipped Handle | | |
| HEIGHT | WIDTH | DEPTH | WEIGHT | |
| LNP8SD | 8.38" | 2.13" | 0.63" | 0.64 lb. |
| LNP7D | 7.38" | 2.13" | 0.63" | 0.38 lb. |

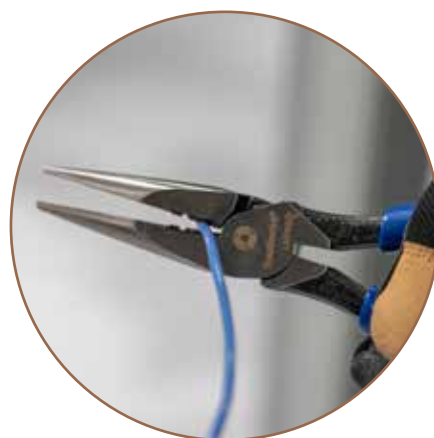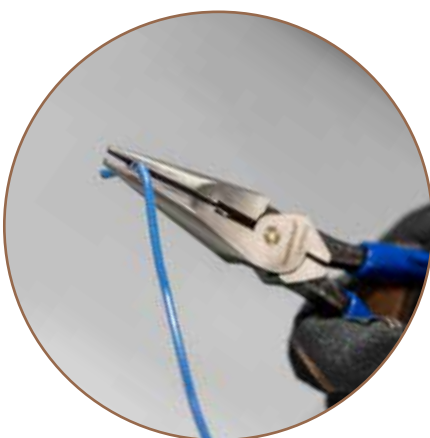

HAND TOOLS

HIGH LEVERAGE DIAGONAL CUTTING PLIERS

DCP8



DCPA8



DCP8D



DCPA8D



The high leverage design of these diagonal cutting pliers provides greater cutting power while the hot riveted joint ensures smooth action with no handle wobble.

- Drop forged CRV steel for durability
- Induction hardened cutting blades ensure efficient and lasting cutting surfaces
- High leverage design provides maximum cutting power
- Hot riveted pivot joint provides smooth action and no wobble
- Effectively cuts most hardened wire, ACSR, bolts, screws, and nails
- Available in dual molded comfort grips and plastic dipped handles



*DCPA8 and DCPA8D

SPECIFICATIONS

COMFORT GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|----------|
| DCP8 | 58993340 | 8" High Leverage Diagonal Cutting Pliers | | |
| DCPA8 | 58993240 | 8" High Leverage Diagonal Cutting Pliers w/ Angled Head | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| DCP8 | 8.25" | 2.25" | 0.75" | 0.73 lb. |
| DCPA8 | 8.25" | 2.25" | 0.75" | 0.73 lb. |

DIPPED GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|----------|
| DCP8D | 58289440 | 8" High Leverage Diagonal Cutting Pliers w/ Dipped Handle | | |
| DCPA8D | 58289540 | 8" High Leverage Diagonal Cutting Pliers w/ Angled Head and Dipped Handle | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| DCP8D | 8" | 2" | 0.63" | 0.61 lb. |
| DCPA8D | 8" | 2" | 0.63" | 0.61 lb. |



HAND TOOLS

CABLE CUTTERS

CCP9



CCP9DE



CCPR400



CCP350



CCPR400S



CCP750



CCPR1K



CCP6D



The hook jaws grab and hold cable while the shear cutting action allows for clean cuts.

- Heat treated, precision ground blades ensure clean cuts
- Comfortable cushion grips reduce hand fatigue
- Forged steel with black-oxide finish for long life
- High leverage pivot joint ensures smooth action and no handle wobble

SPECIFICATIONS

COMFORT GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|--|--------|----------|
| CCP9 | 58993540 | 9" High Leverage Cable Cutter | | |
| CCP350 | 59158540 | 350 MCM 16" Cable Cutter | | |
| CCP750 | 58738240 | 750 MCM 31" Fiberglass Handle Cable Cutter | | |
| CCPR400 | 58277740 | 750 MCM Ratcheting Cable Cutter | | |
| CCPR400S | 59556240 | 600 MCM Ratcheting Cable Cutter | | |
| CCPR1K | 58738340 | 1K MCM Ratcheting with Telescoping Handles | | |
| HEIGHT | WIDTH | DEPTH | WEIGHT | |
| CCP9 | 9.38" | 2.13" | 0.63" | 0.94 lb. |
| CCP350 | 18.90" | 4.53" | 1.18" | 2.55 lb. |
| CCP750 | 31" | 5.32" | 1.23" | 5.50 lb. |
| CCPR400 | 13.78" | 6.81" | 1.57" | 0.51 lb. |
| CCPR400S | 9.25" | 5.71" | 1.57" | 1.54 lb. |
| CCPR1K | 16.20" | 7.10" | 2.70" | 7.33 lb. |

DIPPED GRIP

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|----------|
| CCP9DE | 64323040 | 9" High-Leverage Cable Cutters w/ Ergonomic Dipped Handle | | |
| CCP6D | 58748940 | 6 1/2" Cable Cutting Shears w/ Dipped Handle | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| CCP9DE | 9.25" | 1.8" | 0.62" | 1 lb. |
| CCP6D | 6.75" | 2" | 0.75" | 0.51 lb. |



HAND TOOLS

TERMINAL CRIMPING | CUTTING PLIERS

TCC9

TCC9D



These high leverage crimping pliers have two die positions that permit the tool to crimp insulated and non-insulated terminals and ferrules.

- Tapered nose for working in confined spaces
- Crimps 10-22 AWG solderless terminals and connectors
- Specially hardened wire cutter in nose
- Curved handle and ergonomic molded grip for comfortable use
- Crimps insulated and non-insulated terminals and connectors

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|-------|----------|
| TCC9 | 58993640 | Terminal Crimper Cutter w/ Comfort Grip Handle | | |
| TCC9D | 58289940 | Terminal Crimper Cutter w/ Dipped Handle | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| TCC9D | 9.75" | 2.38" | 0.63" | 0.79 lb. |
| TCC9 | 9.38" | 1.88" | 0.75" | 0.86 lb. |



HAND TOOLS

MULTI-TOOL PLIERS

S7N1HD



S816SOLHD



SNM1214HD



S5N1



Versatile spring action pliers that perform multiple functions.

- Grip, strip, crimp, ream, shear, and cut
- Narrow knurled jaw allows access to tight spaces
- Cuts small gauge copper wire and communication cables
- Crimps common size wire ferrules
- Easily strips 10-14 AWG solid wire
- Durable forged construction for lasting performance
- Comfortable grips minimize hand wear and fatigue
- Strips:
 - S7N1HD: 10-14 AWG Solid, 12-16 Stranded
 - S816SOLHD: 8-16 AWG Solid, 10-18 Stranded
 - SNM1214HD: 12/2 and 14/2 Romex

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|-----------|----------|--|-------|----------|
| S7N1HD | 65028440 | 7-in-1 Long Nose Multi-Tool Plier | | |
| S5N1 | 58993940 | 5-in-1 Multi-Tool Plier | | |
| S816SOLHD | 65028140 | Forged Wire Stripper 8-16 AWG Solid 10-18 AWG Stranded | | |
| SNM1214HD | 65028240 | Forged Romex Stripper 12-14 AWG Solid w/ Ergo Grip | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| S7N1HD | 10.24" | 3.54" | 0.98" | 0.79 lb. |
| S5N1 | 10.10" | 3.54" | 0.70" | 0.65 lb. |
| S816SOLHD | 10.24" | 3.54" | 0.98" | 0.71 lb. |
| SNM1214HD | 10.04" | 3.54" | 0.79" | 0.74 lb. |



MULTI-PURPOSE SIDE CUTTING PLIER

MPSCP



Multi-purpose side cutting plier cuts ACSR, screws, nails, and most hardened wire.

- Drop forged construction for durability
- High-leverage pivot joint for easier cuts
- Strips 8-14 AWG solid and 10-16 stranded
- 6-32 and 8-32 screw shearing

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|----------------------------------|-------|---------|
| MPSCP | 59724440 | Multi-Purpose Side Cutting Plier | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| MPSCP | 11.38" | 3.75" | 1.50" | 0.6 lb. |



HAND TOOLS

MADE IN USA PLIERS - WOUNDED WARRIOR PROJECT®

SCP9TPCD-WW



DCPA8D-WW



Made from American forged steel, these tools are built to withstand jobsite wear and tear. Assembled with hot rivet technology, these pliers are designed to be the livelihood of every professional. Proudly supporting Wounded Warrior Project®.

- Hot riveted pivot joint for smooth action
- Induction hardened
- Hand sharpened blades
- Drop forged USA steel for durability

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|-------------|----------|--|--------|----------|
| SCP9TPCD-WW | 67038040 | Made in USA 9" High-Leverage Side Cutting Pliers w/ Fish Tape Puller, Crimper, & Dipped Grip Handles | | |
| DCPA8D-WW | 67038340 | Made in USA 8" Angled Head High-Leverage Diagonal Cutting Pliers w/ Dipped Handles | | |
| CCP9D-WW | 67038940 | Made in USA 9" High-Leverage Cable Cutters w/ Dipped Grip Handles | | |
| TCC9D-WW | 67038640 | Made in USA 9" Terminal Crimper/Cutter w/ Dipped Grip Handles | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| SCP9TPCD-WW | 11.75" | 3.88" | 11.75" | 1.1 lb. |
| DCPA8D-WW | 10.13" | 3.88" | 10.13" | 0.6 lb. |
| CCP9D-WW | 11.75" | 3.88" | 11.75" | 1.05 lb. |
| TCC9D-WW | 11.75" | 3.88" | 11.75" | 0.9 lb. |

CCP9D-WW



TCC9D-WW



WE'VE GOT IT
MADE IN AMERICA™



HAND TOOLS

MADE IN USA WIRE STRIPPERS - WOUNDED WARRIOR PROJECT®

S1018SOL-WW

S1020SOL-WW



Made from durable, heat-treated steel, the Made in USA wire strippers & cutters are equipped to handle day-to-day jobsite demands. Proudly supporting the Wounded Warrior Project®.

- Double-dipped grip for comfortable fit
- Serrated nose holds cable for easy twisting and pulling
- Spring-loaded for self-opening action

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|--------------|----------|---|-------|----------|
| S1018SOL-WW | 67039540 | 10-18 AWG Solid Wire Stripper Ergo Handles | | |
| S1020SOL-WW | 67039240 | 10-20 AWG Solid Wire Stripper Compact Handles | | |
| SNM1214HH-WW | 67039840 | Romex® Brand BOXJaw™ Wire Stripper | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| S1018SOL-WW | 8.5" | 4" | 0.5" | 0.37 lb. |
| S1020SOL-WW | 8.5" | 4" | 0.5" | 0.32 lb. |
| SNM1214HH-WW | 9.75" | 4" | 1.5" | 0.4 lb. |

SNM1214HH-WW



 **WE'VE GOT IT
MADE IN AMERICA™**

HAND TOOLS | **WOUNDED WARRIOR PROJECT®**
LIMITED EDITION PRODUCTS

HAND TOOLS

WIRE STRIPPERS & CUTTERS

S1018SOL



S612STR



S1018STR



S1626STR



Made of stainless steel, these wire strippers have precision ground stripping holes and are fitted with comfortable double-dipped plastic grips.

- Stainless steel construction is durable and rust proof
- Serrated nose grasps the cable for easy twisting and pulling
- Double-dipped grip provides comfortable feel
- Spring loaded for self-opening action
- Specially designed cutting blades provide fast and clean wire stripping and cutting

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---|-------|----------|
| S1018SOL | 58278040 | Wire Stripper Cutter 10-18SOL;12-20 Stranded Ergonomic Handle | | |
| S1018STR | 58278140 | Compact Stripper Cutter 10-18 AWG Solid | | |
| S612STR | 58277940 | Wire Stripper Cutter 6-12 AWG Stranded Ergonomic Handle | | |
| S1626STR | 58278240 | Compact Stripper Cutter 16-26 AWG Stranded | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| S1018SOL | 7.63" | 2.38" | 0.69" | 0.33 lb. |
| S1018STR | 6.25" | 2.5" | 0.69" | 0.29 lb. |
| S612STR | 7.38" | 2.5" | 0.63" | 0.33 lb. |
| S1626STR | 6.25" | 2" | 0.69" | 0.28 lb. |



HAND TOOLS

WIRE STRIPPERS & CUTTERS

SNM1012



SNM1214



MP61



MPLN



SVN



Made of stainless steel, these wire strippers have precision ground stripping holes and are fitted with comfortable double-dipped plastic grips.

- Stainless steel* construction is durable and rust-proof
- Serrated nose grasps the cable for easy twisting and pulling
- Specially designed cutting blades provide fast and clean wire stripping and cutting
- Double-dipped grip provides comfortable fit
- Spring loaded for self-opening action (on models SNM1012, SNM1214)

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|----------|
| SNM1012 | 58278440 | NM Cable Stripper Cutter 10-12 AWG Ergonomic Handle | | |
| SNM1214 | 58278540 | NM Cable Stripper Cutter 12-14 AWG Ergonomic Handle | | |
| MP61 | 58278940 | 6-in-1 Multipurpose Stripper | | |
| MPLN | 58278840 | Long Nose Multipurpose Tool | | |
| SVN | 58278740 | Wire Stripper V-Notch | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SNM1012 | 8.13" | 2.19" | 0.69" | 0.36 lb. |
| SNM1214 | 7.88" | 2.19" | 0.69" | 0.36 lb. |
| MP61 | 9" | 2.38" | 0.69" | 0.43 lb. |
| MPLN | 8.5" | 2.38" | 0.75 | 0.36 lb. |
| SVN | 5.25" | 2.31" | 0.44" | 0.14 lb. |

*Excludes SVN

HAND TOOLS

ELECTRICIAN'S SCISSORS

ES001



Unlike regular scissors or shears, the serrated blades keep wire from slipping out of the jaws, so that cutting through hardware cloth, cable, wire netting, and other difficult-to-cut materials becomes an easy task.

- Durable nickel-plated steel for resistance from rust and corrosion
- Strips 19 AWG & 23 AWG
- Scraper and file on outside of both blades

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|------------------------|-------|----------|
| ES001 | 58283540 | Electrician's Scissors | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| ES001 | 5.38" | 2.19" | 0.38" | 0.19 lb. |

PLASTIC PIPE CUTTER

PLACUT



Our plastic pipe and tube cutter has non-slip grips and a strong stainless steel blade that makes cutting plastic tubing easy.

- Easily performs flush cuts on rigid plastic tubing
- Durable design for rugged use
- Locking latch allows easy one-handed operation
- Cuts up to 3/4" PVC and 1-5/8" flexible tubing

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------|-------|----------|
| PLACUT | 58282140 | Plastic Pipe Cutter | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| PLACUT | 8.75" | 1.83" | 1.17" | 0.35 lb. |

HAND TOOLS

ROTO-SPLIT® CUTTERS - WOUNDED WARRIOR PROJECT®



RS-101A-WW

 **WE'VE GOT IT
MADE IN AMERICA™**

The RS-101A-WW and MCCUT-WW will become your everyday cutters for MC Cable. They feature a thumb screw to clamp and release the cable. You'll never do another MC Cable job without it. Proudly made in the USA.

- Cuts or strips any armored cable from AWG 14-2 to 10-4, including AC MC, BX, & HCF
- Cuts 3/8" trade size Flex
- Stores up to 6 extra blades in handle knob
- Durable die cast epoxy-enameled body

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|------------|----------|-------------------------------------|----------------|----------------------|------------------------|
| RS-101A-WW | 66978140 | RS-101A-WW Super Roto-Split® Cutter | | | |
| MCCUT-WW | 66979340 | BX MC Rotary Cutter w/Lever | | | |
| | WEIGHT | MIN OPENING | MAX OPENING | FLEX (TRADE SIZE) | AWG SOL OR MC RANGE |
| RS-101A-WW | 1.2 lb. | 0.375" | 0.75" | 3/8" | 14/2 to 8/4 |
| MCCUT-WW | 1.2 lb. | 0.375" | 0.75" | 3/8" | 14/2 to 8/4 |



RS-101AC-WW

 **WE'VE GOT IT
MADE IN AMERICA™**

The RS-101AC-WW features a clamping system that covers the complete cable size range without using a thumb screw. The self-tightening blade system prevents you from damaging the cable. Proudly made in the USA.

- Automatically adjusts the clamping pin to the correct diameter
- Safely cut any type of armored cable by automatically adjusting to the cable diameter
- Self-tightening blade system and ergonomic crank handle with offset for maximum hand clearance
- Stores up to 6 extra blades in handle knob
- Depth of cut adjustment for standard MC cable and smaller diameter MC cable

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|-------------|----------|--|----------------|----------------------|------------------------|
| RS-101AC-WW | 66978440 | RS-101AC-WW Automatic Roto-Split® Cutter | | | |
| | WEIGHT | MIN OPENING | MAX OPENING | FLEX (TRADE SIZE) | AWG SOL OR MC RANGE |
| RS-101AC-WW | 1.2 lb. | 0.375" | 0.75" | 3/8" | 14/2 to 8/4 |

HAND TOOLS | **WOUNDED WARRIOR PROJECT®**
LIMITED EDITION PRODUCTS

HAND TOOLS

ROTO-FLEX® CUTTERS - WOUNDED WARRIOR PROJECT®



RF-120A-WW



The RF-120A-WW provides clean cuts and does not require adjustments after the initial setting. Cutting in tight quarters is easy and fast. The self-tightening blade system prevents you from damaging the cable. The RF-120A includes a blade storage cartridge in the knob with room for up to 6 spare blades. Proudly made in the USA.

- Cuts 1/2" to 3/4" O.D. flex
- Strips large AC, BX, MC cables ranging from AWG 2-3, 3-4, & 4-3
- Blade storage cartridge in knob with storage for 6 blades
- Requires no adjustment after initial setting - quick clamp lever does it all
- Die cast epoxy-enamel body

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|------------|----------|--|----------------|----------------------|------------------------|
| RF-120A-WW | 66978740 | RF-120A-WW 1/2" – 3/4" Roto-Flex™ Cutter | | | |
| | WEIGHT | MIN OPENING | MAX OPENING | FLEX (TRADE SIZE) | AWG SOL OR MC RANGE |
| RF-120A-WW | 1.25 lb. | 0.75" | 1.13" | 1/2" - 3/4" | 4/2 to 2/4 |



RF-170-WW



The RF-170 cuts up to 1-1/2" flex or armored cable in seconds leaving a clean end. It makes cutting BX and Greenfield conduit easy and precise. The self-tightening blade system prevents you from damaging the cable. The RF-170 includes a blade storage cartridge in the knob with room for up to 6 spare blades. Proudly made in the USA.

- Cuts 1/2" – 1-1/2" O.D. flex and cuts 4-2 to 2-4 MC cable
- Sliding top with three cutting positions to cut across the convolutions of large diameter cables
- Unique adjustable cable clamping bracket with 1 inch
- Blade storage cartridge in knob with storage for 6 blades
- Die cast epoxy-enamel body

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|-----------|----------|-----------------------------------|----------------|----------------------|------------------------|
| RF-170-WW | 66979040 | RF-170-WW Giant Roto-Flex™ Cutter | | | |
| | WEIGHT | MIN OPENING | MAX OPENING | FLEX (TRADE SIZE) | AWG SOL OR MC RANGE |
| RF-170-WW | 1.25 lb. | 0.82" | 1.13" | 1/2" - 1-1/2" | 4/2 to 2/4 |

ROTO-SPLIT® AND ROTO-FLEX™ STANDARD BLADE

B-102



The Southwire B-102 Standard Blade is the replacement blade for all Roto-Split® and Roto-Flex™ models. This is an essential when installing MC cable. The B-102 is the perfect backup blade for your Roto-Split® and Roto-Flex™ cutters. Great for the electrician. Proudly made in the USA.

- Sold in packs of 2
- Blade used to cut steel casing
- Replacement blade for RS-101A-WW, RS-101AC-WW, and RF-120A-W

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|--------|----------|
| B-102 | 59814401 | Replacement Blade for RS-101A-WW, RS-101AC-WW, RF-120A-WW | | |
| MCBLADE | 58282340 | Replacement Blade for MCCUT-WW (1 Blade Per Pack) | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| B-102 | 1.26" | 1.26" | 0.025" | .006 lb. |
| MCBLADE | 1.26" | 1.26" | 0.025" | .006 lb. |

OFFSET TEETH BLADE

B-107



The Southwire B-107 is a heavy-duty, universal blade that can be used on all Roto-Flex™ tools. It cuts through aluminum armor clad with minimal effort. It can also cut through steel armor on 1/2" and larger trade size flex. This is a great replacement blade for aluminum casing. Perfect for the electrician. Proudly made in the USA.

- Offset teeth to prevent clogging
- Used to cut aluminum casing
- For use with RF-170-WW
- Not for use with the RS-101AC-WW

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------------------|--------|----------|
| B-107 | 59814901 | Replacement Blade for RF-170-WW | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| B-107 | 1.26" | 1.26" | 0.025" | .006 lb. |

HAND TOOLS

EDGEFORCE™ & STAINLESS STEEL KNIVES

UTILQ0



CDPK



HBKN



HBKND2



UTILAR



TBKND2-CAMO



CSPKD2



DPKD2




Our knives feature a durable 8CR13MOV stainless-steel blade with a black-oxide finish and liner lock that keeps the blade secure. Our compact pocket knife is perfect for everyday carry and our hawk bill knife is the perfect pocket knife for pull cuts and splicing.

- Corrosion resistant
- Liner lock keeps blade secure
- Dual thumb studs for right or left hand opening
- Comfort grip for maximum hold and comfort
- Edgeforce™ D2 steel

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|-------------|----------|-------------------------------|-------|----------|
| UTILQ0 | 65029040 | Folding Utility Knife | | |
| CDPK | 65029340 | Compact Pocket Knife | | |
| HBKN | 65029440 | Hawkbill Folding Knife | | |
| HBKND2 | 65029640 | EDGEFORCE™ Hawk Bill Knife | | |
| UTILAR | 65029240 | Auto Retracting Utility Knife | | |
| TBKND2-CAMO | 65029840 | EDGEFORCE™ Tanto Knife | | |
| CSPKD2 | 65029740 | EDGEFORCE™ Sheepfoot Knife | | |
| DPKD2 | 65029540 | EDGEFORCE™ Drop Point Knife | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| UTILQ0 | 6.85" | 1.61" | 0.45" | 0.30 lb. |
| CDPK | 6.74" | 1.05" | 0.45" | 0.10 lb. |
| HBKN | 7.24" | 1.57" | 0.45" | 0.25 lb. |
| HBKND2 | 7.24" | 1.57" | 0.45" | 0.25 lb. |
| UTILAR | 6.01" | 0.45" | 0.45" | 0.30 lb. |
| TBKND2-CAMO | 8.18" | 1.5" | 0.45" | 0.25 lb. |
| CSPKD2 | 7.28" | 1.05" | 0.79" | 0.23 lb. |
| DPKD2 | 7.09" | 1.05" | 0.79" | 0.33 lb. |

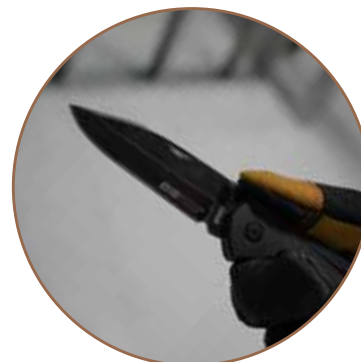

KEYSTONE TIP SCREWDRIVERS

SD1/4K4US



SD5/16K6US



**WE'VE GOT IT
MADE IN AMERICA™**

Our USA keystone tip screwdrivers are constructed to handle the toughest jobs with ease. The cushion grip handles allow for maximum torque and comfort. These screwdrivers come with high-quality, precision-machined tips for an exact fit.

- 22% larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion-resistant shank
- Tether hole for tether or lanyard attachment
- No-hassle lifetime warranty

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|------------|------------|--------------------------------|--------------|----------|
| SD1/4K4US | 65139240 | 1/4" Keystone Tip Screwdriver | | |
| SD5/16K6US | 65139340 | 5/16" Keystone Tip Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SD1/4K4US | 9" | 1.35" | 1.1" | 0.30 lb. |
| SD5/16K6US | 9" | 1.35" | 1.1" | 0.45 lb. |
| | SHANK TYPE | | SHANK LENGTH | TIP TYPE |
| SD1/4K4US | Round | | 4" | Keystone |
| SD5/16K6US | Round | | 6" | Keystone |



HAND TOOLS

CABINET TIP SCREWDRIVERS

SD1/4C4US



SD1/4C6US



SD3/16C4US



SD3/16C6US



SD3/16C8US



 **WE'VE GOT IT
MADE IN AMERICA™**

Our USA cabinet tip screwdrivers are constructed to handle the toughest jobs with ease. The cushion grip handles allow for maximum torque and comfort. These screwdrivers come with high quality—precision machined tips for an exact fit.

- 22% larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion-resistant shank
- Tether hole for tether or lanyard attachment
- No-hassle lifetime warranty

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|------------|----------|-------------------------------|-------|----------|
| SD1/4C4US | 65138740 | 1/4" Cabinet Tip Screwdriver | | |
| SD1/4C6US | 65138840 | 1/4" Cabinet Tip Screwdriver | | |
| SD3/16C4US | 65138940 | 3/16" Cabinet Tip Screwdriver | | |
| SD3/16C6US | 65139040 | 3/16" Cabinet Tip Screwdriver | | |
| SD3/16C8US | 65139140 | 3/16" Cabinet Tip Screwdriver | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| SD1/4C4US | 8.5" | 1.35" | 1.35" | 0.30 lb. |
| SD1/4C6US | 10.5" | 1.35" | 1.35" | 0.35 lb. |
| SD3/16C4US | 8.5" | 1.28" | 1.35" | 0.20 lb. |
| SD3/16C6US | 10.5" | 1.28" | 1.35" | 0.20 lb. |
| SD3/16C8US | 12.5" | 1.28" | 1.35" | 0.20 lb. |
| SHANK TYPE | | SHANK LENGTH | | TIP TYPE |
| SD1/4C4US | Round | 4" | | Cabinet |
| SD1/4C6US | Round | 6" | | Cabinet |
| SD3/16C4US | Round | 4" | | Cabinet |
| SD3/16C6US | Round | 6" | | Cabinet |
| SD3/16C8US | Round | 8" | | Cabinet |



PHILLIPS TIP SCREWDRIVERS

SD1P3US



Our USA Phillip tip screwdrivers are constructed to handle the toughest jobs with ease. The cushion grip handles allow for maximum torque and comfort. These screwdrivers come with high quality, precision machined tips for an exact fit.

SD2P4US



- 22% larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion-resistant shank
- Tether hole for tether or lanyard attachment
- No-hassle lifetime warranty

SD2P6US



SPECIFICATIONS



**WE'VE GOT IT
MADE IN AMERICA™**

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|------------|------------------------------|--------------|-------------|
| SD1P3US | 65139440 | #1 Phillips Head Screwdriver | | |
| SD2P4US | 65139540 | #2 Phillips Head Screwdriver | | |
| SD2P6US | 65139640 | #2 Phillips Head Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SD1P3US | 8.5" | 1.28" | 1.35" | 0.25 lb. |
| SD2P4US | 9" | 1.35" | 1.35" | 0.30 lb. |
| SD2P6US | 14" | 1.35" | 1.35" | 0.05 lb. |
| | SHANK TYPE | | SHANK LENGTH | TIP TYPE |
| SD1P3US | Round | | 3" | #1 Phillips |
| SD2P4US | Round | | 4" | #2 Phillips |
| SD2P6US | Round | | 6" | #2 Phillips |



HAND TOOLS

SQUARE TIP SCREWDRIVER

SDQ2P4US




The USA #2 square tip driver has a 22% larger cushion grip handle that provides ultimate comfort and maximum torque *as compared to previous generations. The corrosion-resistant shank ensures durability to withstand rust, allowing for a longer life. This screwdriver comes with a high quality–precision machined tip for an exact fit. A tether hole is provided for tether/lanyard attachment for added convenience. Patent pending.

- 22% larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion-resistant shank
- Tether hole for tether or lanyard attachment
- No-hassle lifetime warranty


SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|------------|---------------------------|--------------|----------|
| SDQ2P4US | 58281640 | #2 Square Tip Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SDQ2P4US | 8.5" | 1.35" | 1.35" | 0.35 lb. |
| | SHANK TYPE | | SHANK LENGTH | TIP TYPE |
| SDQ2P4US | Square | | 4" | Square |

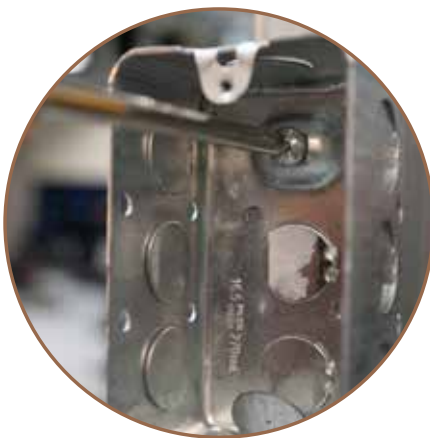

HAND TOOLS

8-PIECE CUSHION GRIP SCREWDRIVER SET

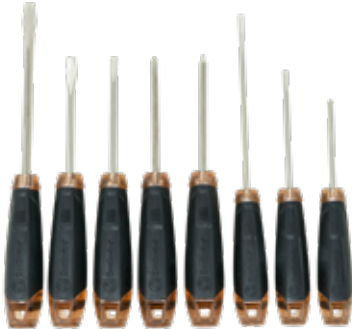


SDSET8US

All-purpose assortment of frequently used screwdrivers.

- Comfortable cushion grip handle offers slip resistance and greater torque
- Precision tips for an exact fit
- Handles marked for easy identification
- Includes 8 pieces: 3/16" x 4", 3/16" x 6" and 1/4" x 4" slotted tip, 1/4" x 4" and 5/16" x 6" keystone tip, #1 x 3", #2 x 4", Phillips tip, and #2 x 4" square tipped screwdrivers

3-PIECE INSULATED SCREWDRIVER SET

SDISET3

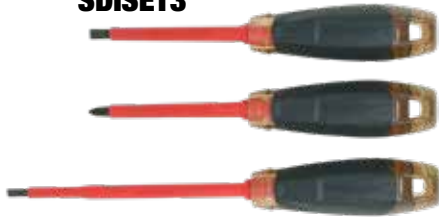

This screwdriver set comes with 3 insulated drivers that are tested to the ASTM F1505 international standard and provide 1000 volt insulated protection.

- 1000 volt insulated protection
- Tested to ASTM F1505 international standard
- Durable molded insulation offers visual wear indication
- Includes #2 Phillips x 4" shank, 1/4" slotted x 4" shank, and 3/16" slotted x 6" shank

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | HEIGHT | WIDTH | DEPTH | WEIGHT | INCLUDES |
|----------|----------|--------------------------------------|--------|-------|-------|----------|--|
| SDSET8US | 65139940 | 8-Piece Cushion Grip Screwdriver Set | 8.5" | 1.25" | 1.25" | 0.13 lb. | SD3/16C4, SD3/16C6, SD1/4K4HD, SD1/4C4, SD5/16K6HD, SD1P3, SD2P4HD, SDQ2P4 |
| SDISET3 | 65172040 | 3 Piece Insulated Screwdriver Set | 9" | 1.35" | 1.35" | 0.13 lb. | #2 Phillips x 4" shank, 1/4" Slotted x 4" shank, 3/16" Slotted x 6" shank |



HAND TOOLS

CONDUIT FITTING REAMING SCREWDRIVER

SDCFR



Removable conduit reaming screwdriver deburs thin wall conduit with speed and ease.

- Reams and smooths 1/2", 3/4", and 1" thin-wall conduit ends to protect wire and permit correct installation of fittings
- Reams inside and outside of conduit simultaneously
- Cushion grip handles for comfort and use
- Detachable head can also be used in a drill

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------------|-------|----------|
| SDCFR | 58283740 | Conduit Fitting Reaming Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SDCFR | 7.5" | 1.25" | 1.25" | 0.59 lb. |

6-IN-1 STUBBY MULT-BIT SCREWDRIVER

SDS6N1



The 6-in-1 multi-bit screwdriver features precision-machined, quick change bits.

- Includes 2 double sided screwdriver bits and 1 double sided nut driver
- Sizes include 5/16" & 1/2" hex, #1 & #2 Phillips, & 3/16" & 1/4" slotted tips
- Cushion grip handles for added comfort and improved torque
- Durable chrome-plated shaft is rust and corrosion resistant

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------------|-------|---------|
| SDS6N1 | 58739740 | 6-in-1 Stubby Multi-Bit Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SDS6N1 | 3.50" | 1.25" | 1.25" | .20 lb. |

MULTI-BIT/ADJUSTABLE/ROTARY SCREWDRIVERS

SD4N1P



SD4N1P

- Precision screwdrivers make work in small spaces easier.
- Includes: 1/8" and 3/32" slotted, #0 and #00 phillips
- Spinning cap for controlled one handed use
- Patent pending cushion grip handle

SD6N1P



SD6N1P

- Comes with a precision bit allowing easier work in small spaces.
- #0 Phillips bit for precision work
- Chrome-plated finish for corrosion resistance
- Comfort grip handle provides extra comfort and maximum torque

SD9N1



SD9N1

- Convenient multi-tool screwdriver with nine tools in one.
- Comfortable cushioned grip allows firm grip and greater torque.
- Precision-machined tips reduce slipping
- Integral flanges provide a solid, twist-resistant blade anchor

SD2N1AL



SD2N1AL

- Allows for extending and shortening of the shank for work in different places
- Adjustable from 4" to 8"
- Pull collar down to extend shank and pull up to shorten
- Zinc-plated finish for corrosion resistance

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---|--|-------|----------|
| SD4N1C | 65028540 | 4-in-1 Magnetic Rotary Driver | | |
| SD4N1P | 65117240 | 4-in-1 Magnetic Screwdriver w/ Precision Bit | | |
| SD6N1P | 65028840 | 6-in-1 Screwdriver w/ Precision Bit | | |
| SD9N1 | 58285640 | 9-in-1 Multi Tool Screwdriver | | |
| SD2N1AL | 65028640 | 2-in-1 Adjustable Length Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SD4N1C | 9.30" | 1.28" | 1.38" | 0.75 lb. |
| SD4N1P | 7.99" | 0.67" | 0.39" | 0.16 lb. |
| SD6N1P | 11.06" | 1.28" | 1.30" | 0.60 lb. |
| SD9N1 | 11.02" | 1.25" | 1.57" | 0.55 lb. |
| SD2N1AL | 11.02" | 1.2" | 1.57" | 0.75 lb. |
| | TIP TYPE | | | |
| SD4N1C | #1 & #2 Phillips, 3/16" & 1/4" Slotted | | | |
| SD4N1P | 1/8" and 3/32" slotted, #0 and #00 phillips | | | |
| SD6N1P | 5/16" & 1/4" nut drivers, #1 & #0 Phillips, 1/4" & 3/16" Slotted | | | |
| SD9N1 | 1/4", 3/8", & 5/16" Hex, #1 & #2 Phillips, 1/4" & 3/16" Slotted, #1 & #2 Square | | | |
| SD2N1AL | #2 Phillips, 1/4" Slotted | | | |

HAND TOOLS

12-IN-1 MULTI-BIT SCREWDRIVER



The 12-in-1 multi-bit screwdriver has precision-machined, quick change bits.

- Precision-machined, quick change bits for driving hex, Phillips, slotted, and square head screws
- Handles 3/16", 1/4", 5/16" slotted; #1, #2, #3 Phillips; #1, #2, square recessed; and 1/4", 5/16", 3/8", 1/2" hex drive
- Cushion grip handle provides extra comfort and maximum torque
- Premium chrome-plated shaft is durable as well as rust and corrosion resistant
- Meets ANSI/ASME specifications

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------|-------|----------|
| SD12N1 | 59723940 | 12-in-1 Multi-Bit Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SD12N1 | 11.75" | 3.25" | 1.38" | 0.85 lb. |

9-IN-1 RATCHETING SCREWDRIVER



The 9-in-1 ratcheting multi-tool screwdriver allows for quick driving of screws and nuts.

- Precision-machined, quick change bits for driving hex, Phillips, slotted, and square head screws
- Handles 1/4", 3/8", 5/16" hex; #1 and #2 Phillips; 1/2" and 3/16" slotted; #1 and #2 square
- Cushion grip handle provides extra comfort and maximum torque
- Premium chrome-plated shaft is durable as well as rust and corrosion resistant
- Meets ANSI/ASME specifications

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------|-------|---------|
| SDR9N1 | 59724040 | 9-in-1 Ratcheting Screwdriver | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| SDR9N1 | 11.75" | 3.25" | 1.50" | 0.6 lb. |

HAND TOOLS

NUT DRIVERS

ND7/16-3US



ND1/2-3US



ND1/4-3US



ND3/8-3US



ND11/32-3US



ND3/16-3US



ND5/16-3US



**WE'VE GOT IT
MADE IN AMERICA™**

ND6N1HD



NDS5N1



This line of USA nut drivers includes a 7-piece set. The nut drivers have 22% larger cushion grip handles that provides ultimate comfort and maximum torque *as compared to previous generations. The corrosion-resistant shank ensures durability to withstand damage, allowing for a longer life. A tether hole is provided for tether/lanyard attachment for added convenience. Patent pending.

- 22% larger cushion grip handle provides ultimate comfort and maximum torque
- Corrosion-resistant shank
- Tether hole for tether or lanyard attachment
- No-hassle lifetime warranty

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|-------------|----------|------------------------------|-------|--|--------------|
| ND7/16-3US | 65138340 | 7/16" Nut Driver | | | |
| ND1/2-3US | 65137840 | 1/2" Nut Driver | | | |
| ND1/4-3US | 65137940 | 1/4" Nut Driver | | | |
| ND3/8-3US | 65138140 | 3/8" Nut Driver | | | |
| ND11/32-3US | 65138540 | 11/32" Nut Driver | | | |
| ND3/16-3US | 65138440 | 3/16" Nut Driver | | | |
| ND5/16-3US | 65138240 | 5/16" Nut Driver | | | |
| ND6N1HD | 65028740 | 6-in-1 Heavy Duty Nut Driver | | | |
| NDS5N1 | 65116540 | 5-in-1 Stubby Nut Driver | | | |
| NDSET7US | 65138640 | 7 Piece Nut Driver Set | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | SHANK LENGTH |
| ND7/16-3US | 8" | 1.35" | 1.2" | 0.35 lb. | 3" |
| ND1/2-3US | 8" | 1.35" | 1.2" | 0.40 lb. | 3" |
| ND1/4-3US | 8" | 1.28" | 1.2" | 0.25 lb. | 3" |
| ND3/8-3US | 8" | 1.28" | 1.2" | 0.30 lb. | 3" |
| ND11/32-3US | 8" | 1.28" | 1.2" | 0.30 lb. | 3" |
| ND3/16-3US | 8" | 1.28" | 1.2" | 0.25 lb. | 3" |
| ND5/16-3US | 8" | 1.28" | 1.2" | 0.30 lb. | 3" |
| ND6N1HD | 11.42" | 1.25" | 1.77" | 1.00 lb. | - |
| NDS5N1 | 5.91" | 1.77" | 1.18" | 0.28 lb. | - |
| NDSET7US | 6" | 1.40" | 1.18" | 2.00 lb. | - |
| SHANK TYPE | | SHANK LENGTH | | TIP TYPE | |
| ND7/16-3US | Round | 3" | | 7/16" | |
| ND1/2-3US | Round | 3" | | 1/2" | |
| ND1/4-3US | Round | 3" | | 1/4" | |
| ND3/8-3US | Round | 3" | | 3/8" | |
| ND11/32-3US | Round | 3" | | 11/32" | |
| ND3/16-3US | Round | 3" | | 3/16" | |
| ND5/16-3US | Round | 3" | | 5/16" | |
| ND6N1HD | - | - | | 3/16", 1/4", 5/16", 3/8", 7/16", 9/16" | |
| NDS5N1 | - | - | | 3/16", 1/4", 5/16", 3/8", 1/2" | |
| NDSET7US | - | - | | 1/2", 1/4", 3/8", 5/16", 7/16", 3/16", and 11/32" | |



HAND TOOLS

T-HANDLE HEX KEYS



Designed to efficiently tighten and loosen hex screws.

- T-handle design allows for greater torque application
- Hex key blade - long and short for flexible use
- Forged heavy-duty steel blade for durable usage
- Over molded grip for comfortable feel

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|-----------|----------|-----------------------------------|-------|----------|------------|
| THEX6-1/2 | 58287840 | 1/2" T-Handle Hex Key w/ 8" Shank | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | SET LENGTH |
| THEX6-1/2 | 9.75" | 4.75" | 1" | 0.91 lb. | 8" |

FOLDING HEX KEY SETS



Convenient and reliable, these folding hex key sets will help you get the job done quickly and easily.

- Precision made hex keys reduce slipping and stripping
- Set easily stores in metal case to reduce lost keys and damage
- Strong durable body doubles as a handle

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|-----------------------------|-------|----------|--|
| HEX-8 | 58287640 | 8-Piece Folding Hex Key Set | | | |
| HEX-5 | 58287540 | 5-Piece Folding Hex Key Set | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | SET LENGTH |
| HEX-5 | 5.25" | 1.5" | 0.75" | 0.68 lb. | 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", & 1/4" |
| HEX-8 | 5.25" | 1.5" | 0.75" | 0.89 lb. | 3/16", 7/32", 1/4", 5/16", & 3/8" |



CONDUIT BENDING LEVEL

MCBLEVEL



High visibility vials are easy to read and set for measurements at 0°, 30°, 45°, and 90°.

- Set screw secures level to conduit
- Four powerful magnets for hands free operation
- Easy-to-read, high impact, acrylic bubble vials
- V-grooved edge helps hold the level in place on pipe or conduit
- Lightweight and durable aluminum construction

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|--------------------------|-------|----------|---|
| MCBLEVEL | 58281640 | 6" Conduit Bending Level | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | SET INCLUDES |
| MCBLEVEL | 6.31" | 1.88" | 0.63" | 0.31 lb. | Magnets, thumb screw for attaching to conduit |

HAND TOOLS

ELECTRICIAN'S SHOULDER POUCH

BAGESP



Convenient shoulder bag provides a lightweight, durable tool carrier that can be hand-carried, slung over your shoulder, or attached to a belt. Features 16 storage pockets.

- Multiple carrying options: shoulder strap, padded handle, belt loop tunnel
- Constructed from 2400D ballistic weave for durability
- 16 tool storage pockets

SPECIFICATIONS

| MODEL # STOCK # DESCRIPTION | | | | |
|-----------------------------|----------|------------------------------|-------|---------------------------|
| BAGESP | 58738740 | Electrician's Shoulder Pouch | | |
| HEIGHT | | WIDTH | DEPTH | INTERNAL CAPACITY |
| BAGESP | 12" | 8.5" | 6.5" | 247 Cubic Inches/4 Liters |

TOOL BACKPACK

PROBAGBP



Our tool backpack allows you to comfortably carry your tools on your back or by hand. Easy opening zippers allow access to the numerous tool storage compartments. Enclosed pouches are located on both external and internal surfaces to provide additional tool storage security.

- Constructed from 2400D ballistic weave for durability
- 58 storage pockets, zippered pouches, and tool loops
- Non-tipping rubber base is wear and water resistant
- Fully molded base allows bag to stand freely

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---------------|-------|---------------------|
| PROBAGBP | 67599040 | Tool Backpack | | |
| | HEIGHT | WIDTH | DEPTH | INTERNAL CAPACITY |
| PROBAGBP | 18.7" | 13.78" | 7.87" | 1, 235 Cubic Inches |

HAND TOOLS

5-POCKET LEATHER TOOL POUCH

POUCH4



The 5-pocket leather tool pouch with electrical tape chain is designed for easy storage and tool access.

- Saddle leather is resistant to fading and staining
- Washer rivets for extra strength
- Fits belts up to 3" wide

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|----------------------|-------|----------|
| POUCH4 | 58283140 | 5 Pocket Tool Pouch* | | |
| | HEIGHT | WIDTH | DEPTH | MATERIAL |
| POUCH4 | 9.25" | 7" | 3" | Leather |

*tools not included.

ELECTRICIAN'S WORK GLOVES

GLOVE1L



High dexterity electrician's gloves with anti-slip fingertips.

- Anti-slip finger tips for secure holding of wire and tools
- Padded palm for protection and secure grip
- Wrapped index finger for durability
- Breathable spandex back for comfortable fit and feel
- Touchscreen compatible index finger and thumb

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|--------------------|-----------------------------------|
| GLOVE1L | 58739040 | Electrician's Work Gloves - Large |
| | PRIMARY MATERIAL | SECONDARY MATERIAL |
| GLOVE1L | Breathable Spandex | Synthetic Leather |

HAND TOOLS

CANVAS ZIPPER BAG

BAG12



Our canvas zipper bag is a very convenient storage place for pliers, wrenches, and other tools that you use daily.

BAG12

- Durable, heavy-duty cotton canvas bag
- Sturdy plastic resin zipper

BAG4P

- 4-Pack of durable polyester bags with sturdy resin zipper
- Perfect for storing Pliers, screwdrivers, staples or electrical connectors.

BAG4P



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------|-------|----------|
| BAG12 | 58282840 | 12" Canvas Zipper Bag | | |
| BAG4P | 59724140 | Polyester Zippered Bag 4-Pack | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| BAG12 | 7" | 12" | 0.25" | 0.13 lb. |
| BAG4P | 7" | 11.5" | 1.00" | 0.35 lb. |

HAND TOOLS

ELECTRICAL MAINTENANCE KIT



With Southwire's Electrical Maintenance Kit, you will be prepared for any bumps in the road. From loose connections to a dark campsite, our EM-KIT has you covered to perform basic electrical testing in addition to providing tools for maintenance and quick repairs.

MULTIMETER

- Measure battery & outlet voltage, check fuses, test heating element



7-IN-1 MULTI-TOOL PLIER

- Perfect for wire cutting, stripping, gripping in addition to crimping new terminals

MULTI-BIT SCREWDRIVER

- Slotted: 3/16", 1/4"
- Phillips: #1, #2
- Square Recessed: #1, #2
- Hex Driver: 1/4", 5/16", 3/8"

LED HEADLAMP

- Illuminate work environment hands-free
- Adjustable strap



BUSS BLADE FUSES

- 10A, 15A, 20A, & 30A rated fuses

COMPACT POCKET KNIFE

- Folding blade with liner lock belt clip

ELECTRICAL TAPE

- 30 foot length

CABLE TIES

- 14 inch length



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|----------------------------|-------|--------|
| EM-KIT | 66983440 | Electrical Maintenance Kit | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| EM-KIT | 17" | 11" | 3" | 12 lb. |

HAND TOOLS

APPRENTICE KITS

Southwire is excited to introduce our new apprentice kits! The tools in these kits are built to withstand jobsite wear and tear. Constructed with Fire Rivet™ technology, our pliers are designed to provide clean cuts with no wobble while our wire stripper is made with stainless steel cutting blades for fast and clean wire stripping. Our screwdrivers and nut drivers feature a comfortable hex shaped handle for maximum torque and a tether hole for lanyard attachment. The compact voltage and GFCI tester measures AC and DC voltage, tests GFCI outlets and circuits, and has an easy to read LED display. The non-contact voltage detector includes a built-in flashlight and pocket clip for easy storage. Both kits include a tool bag for storing these essential tools!

14PC APPRENTICE KIT

- SCP9TPC: 9" Side Cutting Pliers
- LNP8SD: 8" Long Nose Pliers
- DCPA8D: 8" Diagonal Cutting Pliers
- S1018STR: Wire Stripper
- SD1/4C6US: 1/4" Cabinet Tip Screwdriver
- SD2P4US: #2 Phillip's Head Screwdriver
- SD3/16C6US: 3/16" Cabinet Tip Screwdriver
- SD1P3US: #1 Phillip's Head Screwdriver
- SDQ2P4US: #2 Square Tip Screwdriver
- ND5/16-3US: 5/16" Nut Driver
- ND1/4-3US: 1/4" Nut Driver
- 41151S: Voltage and GFCI Tester
- 40136N: Non-Contact Voltage Detector
- BAGESP: Electrician's Shoulder Pouch

10PC APPRENTICE KIT

- SCP9TPC: 9" Side Cutting Pliers
- LNP8SD: 8" Long Nose Pliers
- DCPA8D: 8" Diagonal Cutting Pliers
- S1018STR: Wire Stripper
- SD1/4C6US: 1/4" Cabinet Tip Screwdriver
- SD2P4US: #2 Phillip's Head Screwdriver
- SD3/16C6US: 3/16" Cabinet Tip Screwdriver
- SD1P3US: #1 Phillip's Head Screwdriver
- 40136N: Non-Contact Voltage Detector
- BAGESP: Electrician's Shoulder Pouch

14PKIT



10PKIT



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | HEIGHT | WIDTH | DEPTH | WEIGHT |
|---------|----------|---------------------------|--------|-------|-------|----------|
| 14PKIT | 65187640 | 14PKIT, 14 Piece Tool Kit | 17.38" | 11.5" | 7.38" | 8.30 lb. |
| 10PKIT | 65187840 | 10PKIT, 10 Piece Tool Kit | 17.38" | 11.5" | 7.38" | 6.75 lb. |

HAND TOOLS

USA TOOL KIT



**WE'VE GOT IT
MADE IN AMERICA™**

Southwire is proud to introduce our new made in the USA apprentice kit! The tools in this kit are built to withstand jobsite wear and tear. Constructed with Fire Rivet™ technology, our pliers are designed to provide clean cuts with no wobble while our wire stripper is made from durable heat-treated steel for longer life. Our screwdrivers feature a comfortable hex shaped handle for maximum torque and a tether hole for lanyard attachment. Proudly supporting the Wounded Warrior Project®.

6PCUSAKIT-WW

- SCP9TPCD-WW: 9" Side Cutting Pliers
- DCPA8D-WW: 8" Diagonal Cutting Pliers
- TCC9D-US: 9" Terminal Crimper Cutter
- S1018SOL-WW: Wire Stripper
- SD1/4C6US: 1/4" Cabinet Tip Screwdriver
- SD2P4US: #2 Phillip's Head Screwdriver

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|-------------|----------|-----------------------|--------|--------|
| 6PUSAKIT-WW | 67035140 | USA Tool Kit, 6 Piece | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| 6PUSAKIT-WW | 14.00" | 10.38" | 2.125" | 5 lb. |



HAND TOOLS

**WOUNDED WARRIOR PROJECT®
LIMITED EDITION PRODUCTS**

HAND TOOLS

4-PIECE ELECTRICIAN'S TOOL KIT

EKIT-4



Complete with 10-18 AWG wire stripper, 9-in-1 multi-bit screwdriver, high leverage side cutting pliers, and nylon carrying pouch.

10-18 AWG WIRE STRIPPER - MODEL # S1018STR

- Strips and cuts 10-18 AWG solid and 12-20 AWG stranded wire
- Stainless steel construction is durable and corrosion resistant
- Double-dipped grip provides comfortable fit
- Specially designed stainless steel cutting blades provide fast and clean wire stripping
- Serrated nose grasps the cable for easy twisting and pulling
- Spring loaded for self-opening action
- Not intended for cutting bolts or steel cable

HIGH LEVERAGE SIDE CUTTING PLIERS - MODEL # SCP9

- Induction hardened cutting blades ensure efficient and lasting cutting surfaces for hard and soft wire
- File teeth on jaws help remove burrs in conduit
- Cuts ACSR, screws, nails, and most hardened wire
- Curved handle and ergonomic molded grip for comfortable use
- Drop forged CRV steel for durability

9-IN-1 MULTI-BIT SCREWDRIVER - MODEL # SD9N1

- Includes 6 bits and 3 nut drivers for multi-purpose use
- Cushion grip handle for comfortable use and maximum torque application

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|--------------------------------|-------|----------|---------------------------|
| EKIT-4 | 59158740 | 4-Piece Electrician's Tool Kit | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | INCLUDES |
| EKIT-4 | 9.75" | 4.25" | 2.25" | 0.35 lb. | S1018STR, SCP9, and SD9N1 |

CABLE SPLICERS KIT

CSK5



Cable splicers kit is ideal for prepping category cable installation.

- Lock holds blades closed for storage
- Serrated lower blades grip wire for non-slip cutting action
- Includes marking pen
- Includes leather carrying pouch
- Includes boot knife for sheathing and removing cable jackets

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--------------------|-------|---------|
| CSK5 | 59724240 | Cable Splicers Kit | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| CSK5 | 8.25" | 3.8" | 2.2" | 0.8 lb. |



BASIC ELECTRICIAN'S KIT

BEKIT-3



The perfect start to your electrical work tool box. These three tools are exactly what you need to get started on any simple electrical task.

- The S1018STR stainless steel wire stripper is rust resistant
- The SD9N1 Multi-Bit Screwdriver includes #1 & #2 Phillips tips, 1/4", 5/16", & 3/8" hex drivers, 3/16" & 1/4" slotted tips, and #1 & #2 square tips
- The 40116N NCV has a detection range of 100-600V AC

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------|-------|--------|
| BEKIT-3 | 63136840 | Basic Electrician's Kit | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| BEKIT-3 | 10.25" | 7.88" | 0.75" | 2 lb. |

VOICE DATA VIDEO

Southwire offers a full line of VDV tools including cable cutters, strippers, crimpers and punchdown tools, as well as cable tracers and testers. Our goal is to provide professional tools that exceed customers' expectations for quality, performance and features — tools that make a difference on the real-world jobsite.



VDV TESTERS

PROFESSIONAL TELEPHONE TEST SET

B600



The B600 Professional Telephone Test Set features Hi-Z monitoring, Pulse and Tone (DTMF), 10 number speed dial, and polarity indication in a rugged, double-molded housing.

- Hi-Z monitoring will not disrupt network traffic
- High and low volume settings, polarity LED, tone & pulse modes
- ABN (angled bed of nails) clips with rugged RJ45 and RJ11 plug
- Last number redial and memory to store up 10 phone numbers
- Double-molded housing for comfort and durability



ELECTRICAL

| | |
|-----------------------------|---|
| Humidity | 10% to 90% non-condensing |
| Loop Limit | 2.4K Ω maximum at 48VDC (nominal 15 mA minimum loop current) |
| DC Resistance (Talk Mode) | 150 Ω typical at 80mA current |
| AC Impedance (Monitor Mode) | HI-Z: 100k Ω @ 1KHz RING: 600 Ω @ 1KHz |

ROTARY DIAL OUTPUT

| | |
|----------------------|-----------------|
| Pulsing Rate | 20pps +/-0.5pps |
| Percent Break | 60% +/-2% |
| Interdigit Interval | 500 ms typical |
| Leakage During Break | >50K Ω |

PHYSICAL

| | |
|------------|--|
| Dimensions | 10.12" x 2.43" x 2.49" (25.7cm x 6.17cm x 6.33 cm) |
| Weight | 0.6875 lb. |
| Battery | CR2032 (included) |

SPECIFICATIONS

MODEL # STOCK # DESCRIPTION

| | | |
|-------|----------|---------------------------------|
| B600 | 58742940 | Professional Telephone Test Set |
| B610C | 58743040 | Replacement Leads for Buttset |



VDV TESTERS

PROFESSIONAL VOICE DATA VIDEO CABLE MAPPER & TESTER



M300P

The M300P Cable Mapper quickly tests voice, data, and video cabling for common wiring faults including split pairs. Rugged, double-molded body includes silicone port covers to protect the ports and an easy-to-read backlit LCD screen.

- Quickly checks for faults on voice, data, and video cables
- Identifies correct wiring, opens, shorts, reversals, miswires, split pairs, and shielded cables
- Test patch cables or installed cables
- Built for durability: Double injection-molded housing provides a soft, impact absorbing rubber over a strong ABS frame
- Maps multiple cable runs with included RJ45 & Coax "F" ID remotes (5 of each are included)
- Built-in tone generator for cable tracing (separate amplifier probe required)

REMOTE ID KITS AVAILABLE SEPARATELY:

- M310 Replacement Kit of ID Remotes (5 RJ45 and 5 Coax "F", Remote Numbers 1 - 5)
- M310-F Expansion Kit of 11 "F" Coax ID Remotes (Remote Numbers 6-16)
- M310-RJ Expansion Kit of 11 RJ45 ID Remotes (Remote Numbers 6-16)



RJ45



**RJ11
RJ12**



F-CONNECTOR

| | |
|--|--|
| CABLE TYPES | Shielded or Unshielded: Cat 7, Cat 7a, Cat 6a, Cat 6, Cat 5e, Cat 5, Cat 3, Coax |
| MINIMUM CABLE LENGTH FOR SPLIT PAIR DETECTION | 1.6' (0.5m) |
| MAXIMUM COAX CABLE LENGTH | 1000' (305m) |
| MAXIMUM COAX CABLE RESISTANCE | 100 ohms maximum DC |
| DIMENSIONS | 7.13" x 2.86" x 1.61" (18.1cm x 7.3cm x 4.1 cm) |
| WEIGHT | 0.78 lb. |

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-------------------------------|
| M300P | 58744340 | Professional VDV Cable Mapper |

VDV TESTERS

PROFESSIONAL DATA CABLE MAPPER & TESTER



M400TP

The M400TP Mapper for Data Cable quickly tests twisted pair data cable for common wiring faults including split pairs. It even sends a tone and features a backlit LCD screen, double-molded housing, and silicone port cover.

- Easy-to-read LCD display with backlight
- Port cover protects RJ45 port from dust and debris
- Rugged double-molded housing with snap-in remote
- Identifies correct wiring, opens, shorts, reversals, miswires, split pairs, and shielded cables
- Built-in tone generator for tracing cables (separate amplifier probe required)



| | |
|--|--|
| CABLE TYPES | Shielded or Unshielded: Cat 7, Cat 7a, Cat 6a, Cat 6, Cat 5e, Cat 5, Cat 3 |
| MINIMUM CABLE LENGTH FOR SPLIT PAIR DETECTION | 1.6' (0.5m) |
| BATTERIES | Two "AAA" 1.5V |
| DIMENSIONS | 4.80" X 2.05" X 1.30" (12.2cm X 5.2cm X 3.3 cm) |
| WEIGHT | 0.281 lb. |

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---|
| M400TP | 58744840 | Professional Data Cable Mapper & Tester |



VDV TESTERS

VIDEO CABLE MAPPER & TESTER



M500CX4

The M500CX4 speeds troubleshooting and installation by testing and identifying up to four cable TV remote wall outlets at a time. It includes four color-coded remotes.

- Easy-to-understand LED display
- Test patch cables or installed cables
- Identify up to four coax cable remote locations - includes 4 color-coded ID remotes
- Double-molded housing for durability and grip
- Auto power off



| | |
|----------------------------|---|
| MAX. TESTING LENGTH | 10,000 feet (3km) maximum |
| BATTERIES | Four LR44 Batteries |
| DIMENSIONS | 5.4" x 1.26" x 0.98" (13.7cm x 3.2cm x 2.5cm) |
| WEIGHT | 0.196 lb. |

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-----------------------------|
| M500CX4 | 58744940 | Video Cable Mapper & Tester |



VDV TESTERS

PHONE OUTLET TESTER



P700

The P700 checks phone outlets - Lines 1 and 2 - for correct wiring, line reversed, AC ring voltage, and dead line conditions.

- Quickly checks phone outlets for correct wiring
- Identifies correct wiring, line reversed, AC ring voltage, and dead line conditions
- Tri-color LED display
- Color legend printed on tester makes interpreting results simple
- Tests both Line 1 and Line 2
- Double-molded housing for durability and grip



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---------------------|
| P700 | 58745340 | Phone Outlet Tester |



VDV TESTERS

DATA & VIDEO CABLE TESTER



M550

The M550 gives instant continuity status for both twisted pair and coaxial cables. Features rugged, double-molded tester body with on-board remote storage and an easy-to-interpret LED display.

- Quickly detects wiring faults in network and coax cables
- Test patch cables or installed cables
- Identifies correct wiring, opens, shorts, reversals, miswires, split pairs, and shielded cables
- Auto power off
- Tests shielded and unshielded twisted pair and coax
- Includes adapter cables



| | |
|--|--|
| CABLE TYPES | Shielded or Unshielded: Cat 7, Cat 7a, Cat 6a, Cat 6, Cat 5e, Cat 5, Cat 3, Coax |
| MINIMUM CABLE LENGTH FOR SPLIT PAIR DETECTION | 1.6' (0.5m) |
| MAXIMUM COAX CABLE LENGTH | 1000' (305m) |
| BATTERIES | Two "AAA" 1.5V |
| DIMENSIONS | 5.11" x 2.05" x 1.30" (13.0cm x 5.2cm x 3.3cm) |
| WEIGHT | 0.281 lb. |

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-------------------------|
| M500CX4 | 58745040 | Data/Video Cable Tester |




VDV TESTERS

PROFESSIONAL TONE & PROBE KIT



The T100PK Professional Tone & Probe Kit quickly traces non-energized cabling. It is powerful enough to trace cables behind walls but sensitive enough to identify individual conductors.

- Quickly trace non-energized cables - even behind walls
- Positive cable detection: tone changes when wires are shorted
- Toner features on-board test lead storage
- Probe features replaceable tip, LED flashlight, LED signal strength indicator, rear facing speaker, and stereo headphone jack
- T100PK includes T110TG and T120AP

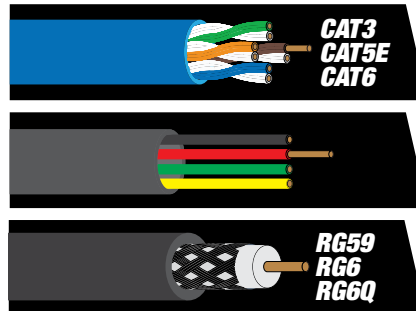

T110TG TONE GENERATOR

| | |
|---|--|
| Continuous Tone Frequency | 1.06kHz nominal |
| Over Voltage Protection | 60VDC in Toner/Polarity Mode |
| Output Power in Tone Mode | +9.65dbm into 600 ohms |
| Auto-Off | 30 minutes |
| Open Circuit Voltage in Continuity Mode | 8.2VDC with fresh battery |
| Battery | One 9V battery |
| Case Dimensions | 4.02" x 2.58" x 2.36" (10.2cm x 6.5cm x 6cm) |
| Weight | 0.50 lb. |

T120AP ANALOG PROBE

| | |
|-----------------|--|
| Battery | One 9V battery |
| Case Dimensions | 9.33" x 1.70" x 1.51" (23.7cm x 4.3cm x 3.8cm) |
| Weight | 0.313 lb. |

SPECIFICATIONS

MODEL # STOCK # DESCRIPTION

| | | |
|--------|----------|-------------------------------|
| T100PK | 58746340 | Professional Tone & Probe Kit |
| T110TG | 58746440 | Tone Generator |
| T120AP | 58746540 | Amplifier Probe |

VDV TESTERS

 
UNIVERSAL WIRE TRACING KIT



T200K

The T200K is a self-contained kit for tracing a variety of cable types. It includes a belt-mount case with five adapter cables, separate toner, and probe. The probe features an LED flashlight for cable tracing in low-light areas.

- Belt-mount, rugged carrying case
- Double-molded housings for durability and grip
- Provides audible and visual indication
- Five adapter cables can be stored in the case and plugged into RJ11 jack on transmitter
- Traces non-energized low-voltage cables



| | |
|---|--|
| tone signal frequency | 2.72kHz nominal |
| tone output power | +24dbm into 600 ohms |
| tone auto-off | 30 minutes |
| BATTERY (TRANSMITTER AND RECEIVER) | Two "AAA" 1.5V Batteries in each unit |
| CASE DIMENSIONS | 7.06" x 3.19" x 2.04" (17.9cm x 8.1cm x 5.2cm) |
| tone dimensions | 5.17" x 0.94" x 1.32" (13.2cm x 2.4cm x 3.4cm) |
| probe dimensions | 6.18" x 0.94" x 1.32" (15.7cm x 2.4cm x 3.4cm) |
| weight | 0.70 lb. |

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-------------------------------|
| T200K | 58746640 | Multipurpose Wire Tracing Kit |

VDV HAND TOOLS

PROFESSIONAL DATACOMM SNIPS

ESP-1



These snips provide very precise control and offer a patented design with unique spring-loaded action.

- Ergonomic, spring-loaded design for precise control
- Lock holds snips closed for storage
- Double-dipped, textured grip
- Strips 19 AWG and 23 AWG
- Serrated blade grips wire as it cuts



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-----------------------------|
| ESP-1 | 58743740 | Professional DataComm Snips |

VDV HAND TOOLS

KEY STRIP TOOL FOR TWISTED PAIR

SK-T1



The key strip tool for twisted pair quickly strips outer cable jackets from CAT 3, 5, 5e and 6 data cable.

- Quickly removes outer cable jacket
- Three positions for different size cables
- Cost effective



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---------------------------------------|
| SK-T1 | 58746140 | SK-T1 Key Strip Tool for Twisted Pair |

 
COAX TRIGGER STRIP TOOL

ST-C1



The rotary-style coax stripper performs a fast and precise two-level strip in one easy step.

- Standard two-level strip exposes 1/4" of center conductor and 1/4" of shield braid
- Innovative "trigger" design improves control and fits comfortably in hand
- Use with RG59, RG6 and RG6 quad shield coax



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-------------------------|
| ST-C1 | 58746240 | Coax Trigger Strip Tool |

VDV HAND TOOLS

 
AUTOMATIC WIRE STRIPPER FOR COAX

SA-C1



The SA-C1 automatic wire stripper for coax allows for quick, two-step stripping of RG6 and RG6Q cable.

- Traditional automatic design preferred by many installers
- 2-level strip: Center conductor and outer jacket



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|----------------------------------|
| SA-C1 | 58745940 | Automatic Wire Stripper for Coax |


COAX CUTTER/STRIPPER

XS-C1



The XS-C1 coax cutter/stripper cuts and strips coax cable and features a cable tie cutting tip.

 - Cuts and strips RG59, RG6, and RG6Q quad shield coax
- Stainless steel for corrosion resistance
- Textured double dip handles for better grip and comfort
- Tip is designed to cleanly cut cable ties



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|----------------------|
| XS-C1 | 58746840 | Coax Cutter/Stripper |

VDV HAND TOOLS

 
COAX PREP TOOL

CPT-CF1



The time-saving coax prep tool is a 3-in-1 tool for loosening/tightening cable TV "F" connectors from jacks. It also flares the cable jacket and holds the connector during assembly.

- Easily loosens stubborn connectors
- Flares coax jacket for easy connector insertion
- Holds cable TV "F" connector during cable insertion
- Double-molded grip for long-lasting comfort



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|---------|-------------|
|---------|---------|-------------|

| | | |
|---------|----------|----------------|
| CPT-CF1 | 58743440 | Coax Prep Tool |
|---------|----------|----------------|

VDV HAND TOOLS

PROFESSIONAL IMPACT PUNCHDOWN TOOL


PDTP-K1



*Includes both 110 and 66 style blades
Easy to pull out wire hook and spudger tools*

The professional impact punchdown tool includes 110 & 66 twist-to-lock blades and features unique pull-out accessory tools in a comfortable, durable tool body.

- Terminates twisted pair category cable into wall jacks and patch panels for phone and data communications
- Includes both 110 and 66-style, long life, metal injection molded blades
- Comfortable double-molded tool body
- Wire hook and spudger accessory tools pull out one-handed with easy-to-use thumb studs
- Covered blade storage

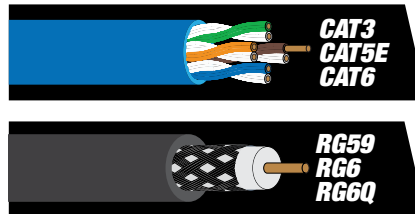

BLADES AVAILABLE SEPARATELY

- B1 Reversible 66 Punch/110 Cut-Only Punchdown Blade
- B2 Reversible 110 Cut/Punch Punchdown Blade
- B3 Reversible 66 Cut/Punch Punchdown Blade

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|------------------------------------|
| PDTP-K1 | 58745540 | Professional Impact Punchdown Tool |

COMFORT GRIP 110-STYLE PUNCHDOWN TOOL

PDTC-1



The comfort grip 110-style punchdown tool easily terminates 110-style blocks on patch panels and wall jacks.

- Punch down 110-style jacks or patch panels
- Soft rubber comfort grip
- 110-style blade terminates cable and trims excess wire



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---------------------------------------|
| PDTC-1 | 58745440 | Comfort Grip 110-Style Punchdown Tool |

VDV HAND TOOLS

 
RATCHETING PHONE & DATA CRIMP TOOL

RJCR-T1



The RJCR-T1 ratcheting phone & data crimp tool cuts and strips voice and data cable. It also crimps RJ45 data connectors as well as RJ11/RJ12 phone modular plugs.

- Ratcheting tool cuts, strips, and crimps phone and data cable
- Comfortable double-molded grips help to orient the tool
- Compatible with standard RJ45, RJ11/RJ12, and RJ22 modular plugs
- Locks closed for easy storage



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|------------------------------------|
| RJCR-T1 | 58745840 | Ratcheting Phone & Data Crimp Tool |

VDV HAND TOOLS

RATCHET CRIMP TOOL – COAX CABLE TV "F" HEX CONNECTORS

RCT-D1



The compound leverage design delivers high crimp force with low hand force, and the near-parallel jaw action delivers precision crimps. The RCT-D1 is where power meets precision.

- Compound leverage design provides powerful crimping with low hand force
- Near-parallel travel crimping jaw for precise crimps
- Precision ratchet with release
- Convenient handle lock for easy storage
- Die set available separately:
 - D1 Die Set - Cable TV F Coax

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|--|
| RCT-D1 | 58745640 | RCT-C1 Ratchet Crimp Tool – Coax |
| D1 | 58743540 | D1 Replacement Die Set – Cable TV "F" Coax |

NETWORK TOOL KIT

KIT-TP1



This 13-piece network tool kit includes the tools you need to cut, strip, terminate, and install data cabling.

- Complete 13 piece kit for terminating data cable
- Make custom length patch cables
- Includes tools to cut, strip, and terminate data cabling
- Kit includes:
 - Compact 3-in-1 Cut/Strip/Crimp Tool
 - Comfort Grip Punchdown Tool
 - Reversible Screwdriver
 - 10 RJ45 Connectors
 - Rugged Tool Case



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|------------------|
| KIT-TP1 | 58744140 | Network Tool Kit |

VDV HAND TOOLS


MULTI-CONNECTOR COMPRESSION COAX CRIMP TOOL

CCM-C1



When you need versatility, multi-connector compression coax crimp tool is 3-way adjustable to work with F, BNC, and RCA compression connectors as well as RG59/6/6Q and RG7/11 coax cable.

- 3-way chuck can be positioned for cable TV "F", RCA, and BNC connectors
- Rotatable connector cradle accommodates RG59, RG6Q, RG6 as well as larger RG7 and RG11 cable
- Thumb-wheel for fine-tuning crimping length
- For cable TV, satellite, security, and home theater applications
- Comfortable double-molded grips are indexed to help orient the tool

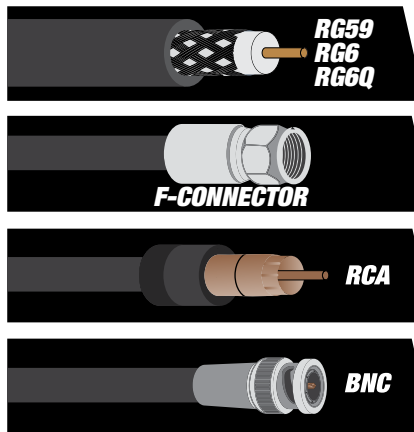

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---|
| CCM-C1 | 58743240 | Multi-Connector Compression Coax Crimp Tool |

VDV HAND TOOLS


COMPACT COMPRESSION COAX CRIMP TOOL FOR "F" CONNECTORS

CCF-C1



The CCF-C1 compact compression coax crimp tool securely attaches "F" type connectors to coax cable in one easy step. CCF-C1 features double-molded handles to provide a comfortable grip and powerful crimping force.

- Compatible with RG59, RG6, and RG6Q coaxial cable
- Simple, compact, and powerful
- Double-molded handles for durability and grip

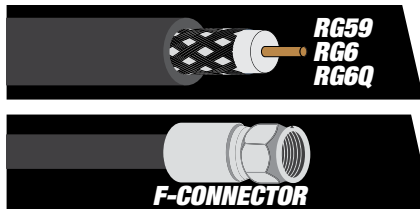

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|--|
| CCF-C1 | 58743140 | Compact Compression Coax Crimp Tool - Cable TV "F" |



VDV HAND TOOLS


CABLE TV TOOL KIT

KIT-C1



This 13-piece cable TV tool kit includes all the tools you need to cut, strip, crimp, and install "F" connectors onto coax cable.

- Complete 13-piece kit for terminating coax
- Make custom length coax patch cables
- All 3 tools included to cut, strip, and crimp coax
- Kit includes:
 - Round Cable Cutter
 - Radial "Trigger" Stripper
 - Compression Crimper for "F" Connectors
 - 10 "F" Connectors for RG6 Coax
 - Rugged Tool Case

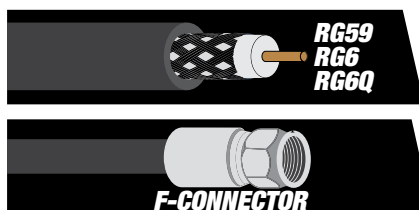

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-------------------|
| KIT-C1 | 58744040 | Cable TV Tool Kit |



VDV HAND TOOLS


COAX 3-IN-1 CRIMP TOOL

HCT-C1



The stainless-steel Southwire 3-in-1 crimp tool cuts and strips coax as well as crimps Cable TV "F" hex-style connectors.

- One tool cuts, strips, and crimps coax cable
- Crimps "F" connectors
- Stainless steel for corrosion resistance
- Double-dipped textured grip

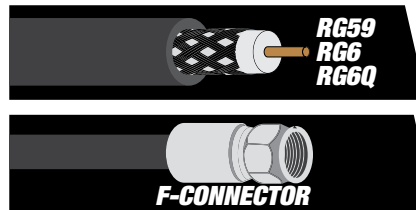

SPECIFICATIONS


| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|------------------------|
| HCT-C1 | 58743940 | Coax 3-in-1 Crimp Tool |



FISHING & BENDING

Introducing our unique line of fish tapes, featuring a spiral extruded polymer design that reduces the amount of effort required to push or pull the fish tape through EMT and PVC conduit. Unlike fiberglass, the SIMpull™ fish tapes are kink resistant, ensuring maximum efficiency*.

**As compared to Southwire steel and fiberglass fish tapes.*

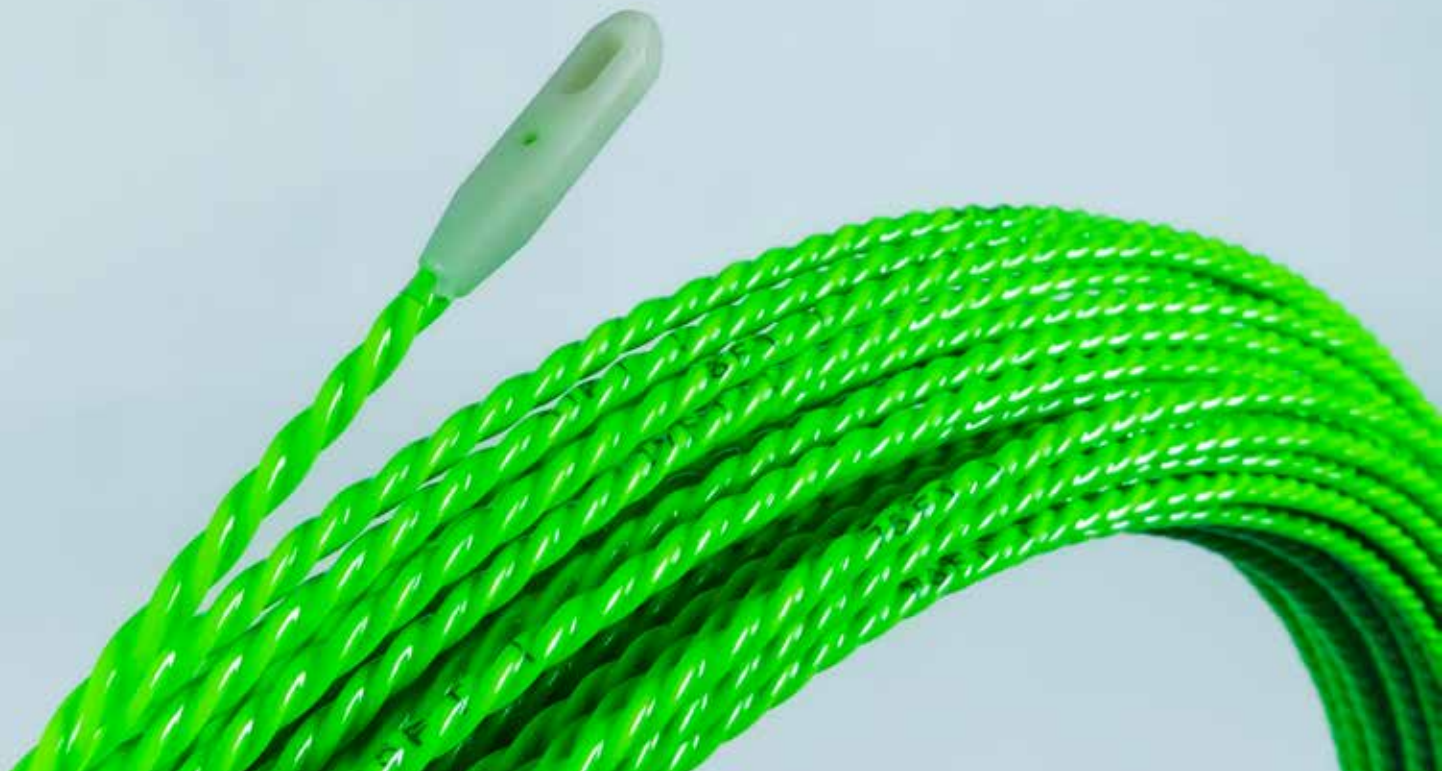

FISHING & BENDING

SIMpull™ NON-CONDUCTIVE TIP FISH TAPE



FTSP55-125NCT


The SIMpull™ non-conductive fish tape is our best option to safely install new wire in conduit with existing wire. The spiral extruded polymer tape reduces the amount of effort required to push or pull the tape through EMT or PVC conduit.

- Tapered tip – reduces the chances of snagging on wire & conduit
- Improve push – bonded 4.5mm and 5.5mm diameter tape works well in conduit up to 3 inches
- Advanced tape guide & housing – improved internal mechanics to greatly increase efficiency of payout & reel-in
- Non-conductive – allows for safe installation over existing wires
- Durability certified – drop rating of 15 feet
- Laser etched foot markings
- Versatile handle positioning



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------------|----------|--|-------|----------|---------|
| FTSP55-125NCT | 67015540 | SIMpull™ Non-Conductive Tip Fish Tape 5.5mm 125' | | | |
| FTSP45-125NCT | 63163740 | SIMpull™ Non-Conductive Tip Fish Tape 4.5mm 125' | | | |
| FTSP45-75NCT | 63029840 | SIMpull™ Non-Conductive Tip Fish Tape 4.5mm 75' | | | |
| | HEIGHT | WIDTH | DEPTH | DIAMETER | WEIGHT |
| FTSP55-125NCT | 16" | 12" | 2" | 5.5mm | 2.5 lb. |
| FTSP45-125NCT | 16" | 12" | 2" | 4.5mm | 2.5 lb. |
| FTSP45-75NCT | 16" | 12" | 1.5" | 4.5mm | 2.0 lb. |

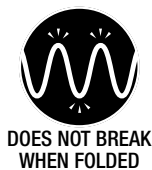

FISHING & BENDING | SIMpull™ FISH TAPE

FISHING & BENDING

SIMpull™ FLEXIBLE METAL LEADER FISH TAPE



FTSP55-125FML

The SIMpull™ flexible metal leader tape excels at gliding through conduit with multiple bends. The spiral extruded polymer tape reduces the amount of effort required to push or pull the tape through EMT or PVC conduit.

- Swiveling flexible leader – easily glides through conduit bends and around existing wire
- Improve push – bonded 4.5mm or 5.5 mm diameter tape works well in conduit up to 3 inches
- Advanced tape guide & housing – improved internal mechanics to greatly increase efficiency of payout & reel-in
- Durability certified – drop rated of 15 feet
- Laser etched foot markings
- Versatile handle positioning



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------------|----------|---|-------|----------|---------|
| FTSP55-125FML | 67015240 | SIMpull™ Flexible Metal Leader Fish Tape 5.5mm 125' | | | |
| FTSP45-125FML | 59896940 | SIMpull™ Flexible Metal Leader Fish Tape 4.5mm 125' | | | |
| FTSP45-75FML | 59897040 | SIMpull™ Flexible Metal Leader Fish Tape 4.5mm 75' | | | |
| | HEIGHT | WIDTH | DEPTH | DIAMETER | WEIGHT |
| FTSP55-125FML | 16" | 12" | 2" | 5.5mm | 2.5 lb. |
| FTSP45-125FML | 16" | 12" | 2" | 4.5mm | 2.5 lb. |
| FTSP45-75FML | 16" | 12" | 1.5" | 4.5mm | 2.0 lb. |



NON-CONDUCTIVE
LEADER



DOES NOT BREAK
WHEN FOLDED



SWIVELING
LEADER



FASTER INSTALL
TIME



FISHING & BENDING

SIMpull™ FISH TAPE TUBE

FTSP45-240FMLT





The SIMpull™ tube is designed for long runs over 125'. This model has the added benefit of both leader types within the same unit. The spiral extruded polymer tape reduces the amount of effort required to push or pull the tape through EMT or PVC.

- Includes both a 360° swiveling flexible metal leader and a non-conductive glow in the dark leader, one on either end
- Swiveling flexible leader – easily glides through conduit bends and around existing wire
- Improve push – bonded 5.5mm diameter tape works well in conduit up to 3 inches
- Length markings – quickly identify the approximate length of a conduit run

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------------|----------|--|-------|----------|---------|
| FTSP55-240FMLT | 67015840 | SIMpull™ Tube Fish Tape with both FML & NCT Tips 5.5mm, 240' | | | |
| FTSP45-240FMLT | 63164740 | SIMpull™ Tube Fish Tape with both FML & NCT Tips 4.5mm, 240' | | | |
| | HEIGHT | WIDTH | DEPTH | DIAMETER | WEIGHT |
| FTSP55-240FMLT | 24" | 24" | 4" | 5.5mm | 4.3 lb. |
| FTSP45-240FMLT | 24" | 24" | 4" | 4.5mm | 4.3 lb. |

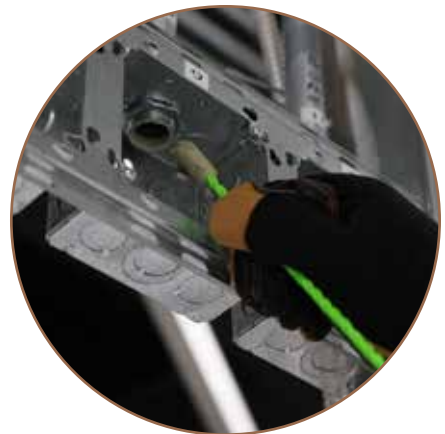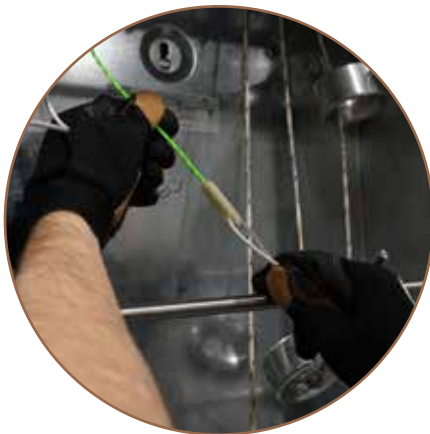

FISHING & BENDING

STAINLESS STEEL FISH TAPE



FTS1/8-125SS


Stainless steel tape incorporates the same benefits of steel but with added life.

- Stainless steel – highly resistant to rust & corrosion. Increasing the product's lifespan.
- Advanced tape guide & housing – improved internal mechanics to greatly increase efficiency of payout & reel-in.
- Durability certified – drop rating of 15 Feet
- Laser etched foot markings
- Versatile handle positioning



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|--------------|----------|-------------------------------------|-------|---------|------------|
| FTS1/8-125SS | 67014640 | 125' Stainless Steel Fish Tape 1/8" | | | |
| FTS1/8-240SS | 67014940 | 240' Stainless Steel Fish Tape 1/8" | | | |
| | LENGTH | WIDTH | DEPTH | WEIGHT | TAPE WIDTH |
| FTS1/8-125SS | 17" | 12" | 2" | 4.5 lb. | 1/8" |
| FTS1/8-240SS | 17" | 12" | 2" | 7.3 lb. | 1/8" |

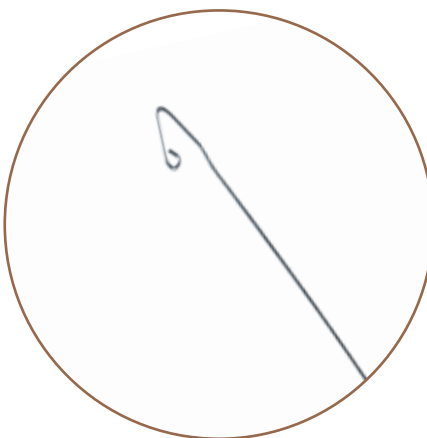

FISHING & BENDING

STEEL FISH TAPE



FTS1/8-240

Southwire's steel fish tape reaches easily above ceilings, under carpets, and through walls to install wire. The fish tape is available in multiple lengths.

- Easy pulls – specially treated steel fish tape for longer life and easier pulling.
- Better accuracy – laser etched footage markings to help identify length of pull
- Rugged design – high impact, durable case for long lasting performance and use.
- Laser etched foot markings
- Versatile handle positioning



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|------------|----------|---------------------------|-------|---------|------------|
| FTS1/8-240 | 58279840 | 1/8" Fish Tape Steel 240' | | | |
| FTS1/8-125 | 58279940 | 1/8" Fish Tape Steel 125' | | | |
| FTS1/8-25 | 58280240 | 1/8" Fish Tape Steel 25' | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | TAPE WIDTH |
| FTS1/8-240 | 17" | 12" | 2" | 7.3 lb. | 1/8" |
| FTS1/8-125 | 17" | 12" | 2" | 4.5 lb. | 1/8" |
| FTS1/8-25 | 8.5" | 7" | 1" | 1.0 lb. | 1/8" |

FISHING & BENDING

FISH TAPE LEADER



FTFL13

Flexible leader guides steel tapes through conduit and helps reduce the challenge of pulling and pushing.

- Flexible 13" leader easily attaches to 1/8" steel fish tapes
- Assists in guiding steel fish tapes through conduit turns and bends

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | | |
|---------|----------|---|-------|--------|------------|---|
| FTFL13 | 58280640 | Fish Tape Leader 13' for Steel Fish Tapes | | | | |
| | LENGTH | WIDTH | DEPTH | WEIGHT | TAPE WIDTH | EYELET CAPACITY |
| FTFL13 | 14.25" | 0.38" | 0.25" | 2 oz. | 3/16 | 5 x 12 AWG Upstripped, 7 x 10 AWG Bare |

GLOW-IN-THE-DARK FISH STICK



Make fishing through walls or over ceilings easier with our Glow-in-the-Dark Fish Sticks.

- Luminescent fiberglass rods glow in the dark and recharge with most available light sources
- 3/16" flexible rods resist splintering and cracking
- Individual sections easily screw together to form single rod
- Includes bullet nose with eyelet and hook attachments

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|------------------|---|-------|----------|--------------|
| FS15 | 58279340 | 15' Glow-in-the-Dark Fish Stick (Includes Bullet Nose with Eyelet & Hook Attachments) | | | |
| FS12 | 58279440 | 12' Glow-in-the-Dark Fish Stick (Includes Bullet Nose with Eyelet & Hook Attachments) | | | |
| FS8 | 58279540 | 8' Glow-in-the-Dark Fish Stick (Includes Bullet Nose with Eyelet & Hook Attachments) | | | |
| | ASSEMBLED LENGTH | WIDTH | DEPTH | WEIGHT | STICK LENGTH |
| FS15 | 180" | 0.19" | 0.19" | 13.3 oz. | 3x5' Pieces |
| FS12 | 144" | 0.19" | 0.19" | 13.9 oz. | 3x4' Pieces |
| FS8 | 96" | 0.19" | 0.19" | 8 oz. | 4x2' Pieces |

FISHING & BENDING

CONDUIT BENDERS



Reliably and repeatedly perform common bends, such as stub-ups, offsets, back-to-back, and saddle bends. Available in 1", 3/4", and 1/2" sizes.

- Durable cast metal heads
- Swaged steel handle permits insertion of conduit to correct overbends
- Raised and highly visible bender markings are cast on both sides of the bender head
- Large serrated step provides greater control and helps prevent slipping when applying force

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|---|-------|--------|------------------------|
| MCB1 | 58281440 | 1" EMT Conduit Bender with Handle (Ductile Iron Head) | | | |
| MCB3/4 | 58281240 | 3/4" EMT Conduit Bender with Handle (Aluminum Head) | | | |
| MCB1/2 | 58281340 | 1/2" EMT Conduit Bender with Handle (Aluminum Head) | | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT | CONDUIT SIZE |
| MCB1 | 1.75" | 12" | 45" | 13 lb. | 1" EMT 3/4" Rigid |
| MCB3/4 | 1.25" | 9" | 39" | 9 lb. | 3/4" EMT 1/2" Rigid |
| MCB1/2 | 1.25" | 8" | 39" | 7 lb. | 1/2" EMT |

TEST & MEASUREMENT

When there's no room for error, depend on our reliable test and measurement tools to get the job done. Backed by a five year warranty, these tools withstand the elements and provide accurate, versatile, and professional results that every electrician can count on.



METER SELECTION GUIDE

CAT IV MULTIMETERS

**5 YEAR
WARRANTY**



| Family | TechnicianPRO™ | | | Compact Series | |
|---|----------------------------|----------------------------|----------------------------|----------------|-------------|
| Model # | 14090T | 14070T | 14060S | 16020N | 16030A |
| Safety Rating | CAT IV 600V, CAT III 1000V | CAT IV 600V, CAT III 1000V | CAT IV 600V, CAT III 1000V | CAT IV 600V | CAT IV 600V |
| AC/DC Voltage | 1000V | 1000V | 1000V | 600V | 600V |
| AC/DC Current | 10A | 10A | 10A | 200mA | |
| True RMS | X | X | | | X |
| Low Z | X | X | | | |
| Bluetooth® | X | | | | |
| Backlighting Display=D Controls=C | C,D | C,D | C,D | D | D |
| Waterproof IP67 | X | X | X | | X |
| Work Light | X | X | X | X | |
| MAX/MIN/AVG | MAX/MIN/AVG | MAX/MIN/AVG | MAX/MIN | | |
| Temperature | X | X | X | | |
| Built-In NCV* | | | | 100V - 600V | 100V - 600V |
| Resistance | 60MΩ | 60MΩ | 60MΩ | 40MΩ | 40MΩ |
| Diode Test | X | X | X | X | |
| Capacitance | 6000μF | 6000μF | 4000μF | 100μF | |
| Frequency | 10kHz | 10kHz | 10kHz | 10kHz | |
| Duty Cycle | X | X | X | X | |
| Peak Hold | X | X | | | |
| Drop Protection | 2m | 2m | 2m | 2m | 2m |

*All Southwire multimeters, clamp meters, and NCV's are UL listed



METER SELECTION GUIDE

CAT III MULTIMETERS

**5 YEAR
WARRANTY**



| Family | ResidentialPRO™ | | | General Purpose | |
|---|-----------------|--------------|--------------|-----------------|---------------------------|
| Model # | 13090T | 13070T | 13050S | 10041N | 10031S |
| Safety Rating | CAT III 600V | CAT III 600V | CAT III 600V | CAT III 600V | CAT III 300V, CAT II 600V |
| AC/DC Voltage | 600V | 600V | 600V | 600V | 600V |
| AC/DC Current | 10A | 10A | 10A | 10A | 10A (DC Only) |
| True RMS | X | X | | | |
| Low Z | X | X | | | |
| Bluetooth® | X | | | | |
| Backlighting Display=D Controls=C | D | D | D | D | |
| Waterproof IP67 | X | X | X | | |
| Work Light | X | X | X | | |
| MAX/MIN/AVG | MAX/MIN | MAX/MIN | MAX/MIN | | |
| Temperature | X | X | X | X | |
| Built-In NCV* | | | | 50V to 600V | |
| Resistance | 40MΩ | 40MΩ | 40MΩ | 40MΩ | 2.0MΩ |
| Diode Test | X | X | X | X | |
| Capacitance | 1000μF | 4000μF | 4000μF | 100μF | |
| Frequency | 10MHz | 10MHz | 10MHz | 10MHz | |
| Duty Cycle | X | X | X | X | |
| Drop Protection | 2m | 2m | 2m | 2m | 2m |

*All Southwire multimeters, clamp meters, and NCV's are UL listed



METER SELECTION GUIDE

CAT III CLAMP METERS



| Model # | 21550T | 21530T | 21510N |
|-----------------|--------------|--------------|--------------|
| Safety Rating | CAT III 600V | CAT III 600V | CAT III 600V |
| AC/DC Voltage | 600V | 600V | 600V |
| AC Current | 400A | 400A | 400A |
| DC Current | 400A | | |
| True RMS | X | X | |
| Worklight | X | X | X |
| Backlit Display | X | X | X |
| Drop Protection | 2m | 2m | 2m |
| Display Count | 4,000 | 4,000 | 4,000 |
| Bar Graph | | | |
| MAX/MIN/AVG | MAX/MIN | MAX/MIN | |
| Temperature | X | X | X |
| Built-in NCV* | 50-600V AC | 50-600V AC | 50-600V AC |
| Resistance | 40MΩ | 40MΩ | 40MΩ |
| Continuity | X | X | X |
| Diode Test | X | X | X |
| Capacitance | 1000μF | 1000μF | 1000μF |
| Frequency | | | |
| Duty Cycle | | | |
| Auto Power Off | X | X | X |

*All Southwire multimeters, clamp meters, and NCV's are UL listed 

METER SELECTION GUIDE

CAT IV CLAMP METERS

**5 YEAR
WARRANTY**



| Model # | 23090T | 23070T | 23030T |
|-----------------|----------------------------|----------------------------|----------------------------|
| Safety Rating | CAT IV 600V, CAT III 1000V | CAT IV 600V, CAT III 1000V | CAT IV 600V, CAT III 1000V |
| AC/DC Voltage | 1000V | 1000V | 1000V |
| AC Current | 1000A | 1000A | 1000A |
| DC Current | 1000A | 1000A | |
| True RMS | X | X | X |
| Bluetooth® | X | | |
| Worklight | X | X | X |
| Backlit Display | X | X | X |
| Drop Protection | 1.5m | 1.5m | 1.5m |
| Display Count | 50,000 | 6,000 | 6,000 |
| Bar Graph | X | X | X |
| MAX/MIN/AVG | MAX/MIN | MAX/MIN | MAX/MIN |
| Temperature | X | X | X |
| Built-in NCV* | 110-1000V AC | 100-1000V AC | 100-1000V AC |
| Resistance | 50MΩ | 60MΩ | 60MΩ |
| Continuity | X | X | X |
| Diode Test | X | X | X |
| Capacitance | 5mF | 6000μF | 6000μF |
| Frequency | 10MHz | 10MHz | 10MHz |
| Duty Cycle | X | X | X |
| Inrush | X | | |

*All Southwire multimeters, clamp meters, and NCV's are UL listed



METER SELECTION GUIDE

CAT IV NON-CONTACT VOLTAGE DETECTORS

**5 YEAR
WARRANTY**



| Model # | 40150N | 40136N | 40126N | 40116N |
|----------------------------|-------------|------------|------------|------------|
| Voltage Detection Range(s) | 12-1000 | 50-600 | 24-600 | 100-600 |
| | 100-1000 | | 100-600 | |
| Safety Rating | CAT IV 1000 | CAT IV 600 | CAT IV 600 | CAT IV 600 |
| Forward Worklight | Yes | No | No | No |
| Rear Facing Light | Yes | Yes | Yes | Yes |
| On/Off Button | Yes | Yes | Yes | Yes |
| Low Batt Self Test | Yes | Yes | Yes | Yes |
| Auto Power Off | Yes | Yes | Yes | Yes |
| Silent Mode | Yes | Yes | No | No |
| Variable Flash & Beep Rate | Yes | Yes | | |
| Ingress Protection | IP67 | | | |
| Drop Protection | 2m | 1.5m | 1.5m | 1.5m |

*All Southwire multimeters, clamp meters, and NCV's are UL listed



MAPP™ MOBILE APP

MAPP™ MOBILE APP



Download on the
App Store



GET IT ON
Google Play

Mobile app for connecting to Southwire Bluetooth® enabled meters.

- View readings from a safe distance right from your mobile phone
- Set up recording sessions
- Add photos and notes to create a detailed report
- Pop-up menu to modify meter settings remotely
- Communicate critical equipment issues by email

The Bluetooth word mark and logos are registered trademarks of Bluetooth® SIG, Inc. and any use of such marks by Southwire Company, LLC is under license. Apple & the Apple logo are trademarks of Apple, INC, registered in the U.S. and other countries. App Store is a service mark of Apple, Inc.

MAPP™ MOBILE APP




**VIEW READINGS AND
SET UP RECORDING
SESSIONS FROM
MOBILE DEVICE**



**JOB VALIDATION: ADD
PHOTOS, NOTES AND
GPS LOCATION**



**POP-UP MENU
MODIFIES METER
SETTINGS REMOTELY**

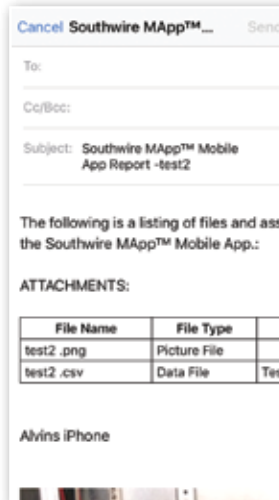

**E-MAIL REPORTS
TO MAINTENANCE
TEAM ON CRITICAL
EQUIPMENT ISSUES**

TEST & MEASUREMENT

TECHNICIANPRO™ BLUETOOTH® CAT IV MULTIMETER

14090T



LOW-Z



This Bluetooth® enabled multimeter in combination with Southwire's MApp™ mobile app allows you to view, record, and share readings on your smartphone. It is designed for demanding environments. Features include a CAT IV safety rating, a rugged IP67 waterproof and dust tight housing, TrueRMS and Low-Z readings, backlit controls, and a powerful built-in work light.

- Features automatic power-off
- Bluetooth® interface for viewing, recording, and sharing using Southwire's MApp™ mobile app
- Lighted controls and backlit display allow use in dimly lit areas
- TrueRMS readings provide higher accuracy on AC circuits
- Low-Z function eliminates false readings from "ghost" voltage
- Includes magnetic hanging strap for hands-free operation
- Powerful LED work light for added convenience
- CAT IV 600V/CAT III 1000V safety rating and IP67 waterproof and dust-tight housing
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Magnetic hanging strap
 - Carrying case
 - Four AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|--------------------|----------------------------------|---|------------------------------|
| 14090T | 63018440 | TechnicianPRO™ Bluetooth® CAT IV Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 1000V | 1mV | ±1.0% |
| Low-Z (AC Voltage) | 600V | 1mV | ±3.0% |
| DC Voltage | 1000V | 0.1mV | ±0.9% |
| Low-Z (DC Voltage) | 600V | 0.1mV | ±3.0% |
| AC + DC Voltage | 1000V | 1mV | ±2.0% |
| AC Current | 10A | 0.1µA | ±1.0% |
| DC Current | 10A | 0.1µA | ±1.0% |
| Resistance | 60MΩ | 0.1Ω | ±1.5% |
| Capacitance | 6000µF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.0% |
| Duty Cycle | 20 to 80% | 0.1% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 780°C | 0.1° | ±1.5% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 6.7 x 3.0 x 1.9 in. | | |
| Weight | 0.85 lb. | | |

TEST & MEASUREMENT

TECHNICIANPRO™ TRUERMS CAT IV MULTIMETER

14070T



This rugged multimeter offers a CAT IV safety rating and an IP67 waterproof and dust tight housing. With TrueRMS readings, a Low-Z measurement function, backlit controls, and a powerful built-in work light, it has the features needed for the professional electrician.

- Features automatic power-off
- Lighted controls and backlit display allow use in dimly lit areas
- Low-Z function eliminates false readings from "ghost" voltage
- TrueRMS readings provide higher accuracy on AC circuits
- Includes magnetic hanging strap for hands free operation
- Powerful LED work light for added convenience
- CAT IV 600V/CAT III 1000V safety rating and IP67 waterproof and dust tight housing
- Built-in test lead storage
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Magnetic hanging strap
 - Carrying case
 - Four AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|--------------------|----------------------------------|--|------------------------------|
| 14070T | 63018240 | TechnicianPRO™ TrueRMS CAT IV Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 1000V | 1mV | ±1.0% |
| Low-Z (AC Voltage) | 600V | 1mV | ±3.0% |
| DC Voltage | 1000V | 0.1mV | ±1.0% |
| Low-Z (DC Voltage) | 600V | 0.1mV | ±3.0% |
| AC Current | 10A | 0.1µA | ±1.5% |
| DC Current | 10A | 0.1µA | ±1.0% |
| Resistance | 60MΩ | 0.1Ω | ±1.5% |
| Capacitance | 6000µF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.0% |
| Duty Cycle | 20 to 80% | 0.1% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 780°C | 0.1° | ±2.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 6.7 x 3.0 x 1.9 in. | | |
| Weight | 0.85 lb. | | |

TEST & MEASUREMENT

TECHNICIANPRO™ AUTO RANGING CAT IV MULTIMETER

14060S



This rugged multimeter offers a CAT IV safety rating and an IP67 waterproof and dust tight housing. With 11 measuring functions, backlit controls, and a powerful built-in work light, it's fully equipped for a wide range of applications.

- Features automatic power-off
- 11 measuring functions plus MAX/MIN
- Lighted controls and backlit display allow use in dimly lit areas
- Powerful LED work light for added convenience
- Includes magnetic hanging strap for hands free operation
- Rugged IP67 waterproof and dust tight housing
- CAT IV 600V/CAT III 1000V safety rating, UL listed
- Built-in test lead storage
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Magnetic hanging strap
 - Carrying case
 - Four AAA batteries



DURABILITY CERTIFIED



| MODEL # | STOCK # | DESCRIPTION | |
|-------------|----------------------------------|---|------------------------------|
| 14060S | 63028740 | TechnicianPRO™ Auto-ranging CAT IV Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 1000V | 1mV | ±1.0% |
| DC Voltage | 1000V | 0.1mV | ±1.0% |
| AC Current | 10A | 0.1µA | ±1.5% |
| DC Current | 10A | 0.1µA | ±1.0% |
| Resistance | 60MΩ | 0.1Ω | ±1.5% |
| Capacitance | 4000µF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.0% |
| Duty Cycle | 1 to 99.9% | 0.1% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 780°C | 0.1° | ±3.0% |
| Continuity | Audible threshold approx. 30Ω | | |
| Diode Test | Yes | | |
| Dimensions | 6.7 x 3.0 x 1.9 in. | | |
| Weight | 0.85 lb. | | |

TEST & MEASUREMENT

RESIDENTIALPRO™ BLUETOOTH® CAT III MULTIMETER

13090T



This Bluetooth® enabled multimeter in combination with Southwire's MApp™ mobile app allows you to view, record, and share readings on your smartphone. With TrueRMS and Low-Z readings, a rugged waterproof and dust proof housing, and built-in flashlight, this compact multimeter can be used in a wide range of applications.

- Features automatic power-off
- Bluetooth® interface for viewing, recording and sharing using Southwire's MApp™ mobile app
- TrueRMS readings provide higher accuracy on AC circuits
- Low-Z function eliminates false readings from "ghost" voltage
- Powerful LED work light for added convenience
- Rugged IP67 waterproof and dust tight housing
- CAT III 600V safety rating, UL listed
- Built-in test lead storage
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Three AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|--------------------|---------------------------------|---|------------------------------|
| 13090T | 63016040 | ResidentialPRO™ Bluetooth® CAT III Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 1mV | ±1.0% |
| Low-Z (AC Voltage) | 300V | 1mV | ±1.5% |
| DC Voltage | 600V | 0.1mV | ±1.0% |
| Low-Z (DC Voltage) | 300V | 0.1mV | ±1.5% |
| AC Current | 10A | 1mA | ±2.5% |
| DC Current | 10A | 1mA | ±2.0% |
| Resistance | 40MΩ | 0.1Ω | ±1.5% |
| Capacitance | 4000μF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.0% |
| Duty Cycle | 1.0 to 99.9% | 0.1% | ±1.2% |
| Temperature | 0°F to 1400°F -18°C to 760°C | 0.1° | ±2.0% |
| Continuity | Audible threshold: approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 5.8 x 2.7 x 2.0 in. | | |
| Weight | 0.70 lb. | | |

TEST & MEASUREMENT

RESIDENTIALPRO™ TRUERMS CAT III MULTIMETER

13070T



LOW-Z



TRUE RMS



With 11 measurement functions including TrueRMS readings, Low-measurement features, and a rugged waterproof and dust-proof housing, this compact multimeter has the features needed to get the job done. A built-in flashlight provides added convenience.

- Features automatic power-off
- TrueRMS readings provide higher accuracy on AC circuits
- Low-Z function eliminates false readings from "ghost" voltage
- 11 measuring functions plus MAX/MIN
- Powerful LED work light for added convenience
- Rugged IP67 waterproof and dust tight housing
- CAT III 600V safety rating, UL listed
- Built-in test lead storage
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Three AAA batteries



DURABILITY CERTIFIED



| MODEL # | STOCK # | DESCRIPTION | |
|--------------------|----------------------------------|--|------------------------------|
| 13070T | 63015040 | ResidentialPRO™ TrueRMS CAT III Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 1mV | ±1.5% |
| Low-Z (AC Voltage) | 300V | 1mV | ±1.5% |
| DC Voltage | 600V | 0.1mV | ±0.8% |
| Low-Z (DC Voltage) | 300V | 0.1mV | ±0.8% |
| AC Current | 10A | 1mA | ±3.0% |
| DC Current | 10A | 1mA | ±2.5% |
| Resistance | 40MΩ | 0.1Ω | ±1.2% |
| Capacitance | 4000μF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.2% |
| Duty Cycle | 0.1 to 99.9% | 0.1% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 760°C | 0.1° | ±3.0% |
| Continuity | Audible threshold approx. 40Ω | | |
| Diode Test | Yes | | |
| Dimensions | 5.8 x 2.7 x 2.0 in. | | |
| Weight | 0.70 lb. | | |

TEST & MEASUREMENT

RESIDENTIALPRO™ AUTO RANGING CAT III MULTIMETER

13050S



With 11 measuring functions, an easy-to-read backlit display, and a rugged IP67 waterproof and dust-proof housing, this compact multimeter is perfect for general use. A built-in flashlight provides added convenience.

- Features automatic power-off
- 11 Measuring functions plus MAX/MIN
- Backlit 4,000-count display with bar graph
- Powerful LED work light for added convenience
- Rugged IP67 waterproof and dust tight housing
- CAT III 600V safety rating UL listed
- Built-in test lead storage
- Includes
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Three AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|-------------|----------------------------------|---|------------------------------|
| 13050S | 63014540 | ResidentialPRO™ Auto ranging CAT III Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 1mV | ±1.5% |
| DC Voltage | 600V | 0.1mV | ±0.8% |
| AC Current | 10A | 1mA | ±3.0% |
| DC Current | 10A | 1mA | ±3.0% |
| Resistance | 40MΩ | 0.1Ω | ±1.2% |
| Capacitance | 4000μF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±1.2% |
| Duty Cycle | 0.1 to 99.9% | 0.1% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 760°C | 0.1° | ±3.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 5.8 x 2.7 x 2.0 in. | | |
| Weight | 0.70 lb. | | |

TEST & MEASUREMENT

AUTOSELECTING CAT IV MULTIMETER

16030A



Easy-to-use TrueRMS CAT IV multimeter automatically selects AC or DC voltage when connected to live circuits. Added features include a rugged IP67 waterproof and dust tight housing, a built-in flashlight and non-contact AC voltage detector, and auto hold for fast touch-and-hold readings.

- Features automatic power-off
- Automatically selects AC or DC voltage
- Auto hold function for quick touch and hold readings
- TrueRMS readings provide higher accuracy on AC circuits
- Easy-to-read 4,000-count backlit display
- Built-in, non-contact AC voltage detector and powerful work light
- Rugged IP67 waterproof/dust-tight housing
- CAT IV 600V safety rating, UL listed
- Built-in test lead storage
- Includes
 - Test leads
 - Two AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------|-------------------------------|---------------------------------|------------------------------|
| 16030A | 63019140 | Autoselecting CAT IV Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 0.1V | ±1.0% |
| DC Voltage | 600V | 0.1V | ±1.0% |
| Non-Contact AC Voltage | 100 to 600V AC | — | — |
| Resistance | 400kΩ | 0.1Ω | ±2.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Dimensions | 5.5 x 3.0 x 1.6 in. | | |
| Weight | 0.50 lb. | | |

TEST & MEASUREMENT

COMPACT 3-IN-1 CAT IV MULTIMETER

16020N



Designed for the electrician on the go, this compact CAT IV 3-in-1 combination multimeter with built-in flashlight and non-contact AC voltage detector is a great fit for a crowded tool bag.

- Features automatic power-off
- 3-in-1 Combination: multimeter, work light and non-contact AC voltage detector
- Compact size with integrated test leads is perfect for crowded tool bag
- 10 measuring functions
- Fuse automatically resets itself
- Rugged double-molded housing
- CAT IV 600V safety rating, UL listed
- Built-in test lead storage
- Includes:
 - Multimeter with integrated test leads
 - Two AAA batteries



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------|--------------------------------|----------------------------------|------------------------------|
| 16020N | 63018640 | Compact 3-in-1 CAT IV Multimeter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 0.1mA | ± 1.0% |
| DC Voltage | 600V | 0.1mA | ± 0.5% |
| Non-Contact AC Voltage | 100 to 600V AC | — | — |
| AC Current | 200mA | 0.1µA | ±2.5% |
| DC Current | 200mA | 0.1µA | ±2.0% |
| Resistance | 40MΩ | 0.1Ω | ±0.8% |
| Capacitance | 100µF | 10pF | ±3.0% |
| Frequency | 10kHz | 0.001Hz | ±2.0% |
| Duty Cycle | 0.5 to 99% | 0.1% | ±2.0% |
| Continuity | Audible threshold approx. 100Ω | | |
| Diode Test | Yes | | |
| Dimensions | 4.6 x 2.3 x 1.4 in. | | |
| Weight | 0.32 lb. | | |

TEST & MEASUREMENT | MULTIMETERS

TEST & MEASUREMENT

AUTO-RANGING MULTIMETER

10041N



The Southwire 10041N multimeter provides all the features & functions you'll ever need in an affordable multimeter. Features include a rugged double-molded housing, CAT III 600V safety rating, and a built-in non-contact AC voltage tester. Meets the latest UL safety standards.

- Measures AC/DC voltage up to 600V, Resistance up to 2MΩ, and AC and DC current up to 10A
- CAT III 600V Safety Rating
- Measures capacitance, frequency, temperature and duty cycle. Tests batteries, continuity, and diodes.
- Built-In Non-Contact AC Voltage Detector
- Convenience features include built-in test probe holder, kickstand, easy-change fuses, and accepts Southwire magnetic hanging strap (available separately)
- Built to withstand a 6-foot drop
- Meets the latest UL safety standard
- Backlit LCD Display
- Auto power-off preserves battery life



DURABILITY CERTIFIED

6' DROP TESTED

| MODEL # | STOCK # | DESCRIPTION | |
|---------------|---------------------|-------------------------|------------------------------|
| 10041N | 65031240 | Auto-Ranging Multimeter | |
| | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 1mV | +/- (1.2%+5) |
| DC Voltage | 600V | 0.1mV | +/- (0.8%+8) |
| NCV | 50-600V | | |
| AC Current | 10A | 0.1μA | +/- (1.5%+5) |
| DC Current | 10A | 0.1μA | +/- (1.0%+5) |
| Resistance | 40.00MΩ | 0.1Ω | +/- (1.2%+5) |
| Capacitance | 100μF | 10pF | +/- (5.0%+/- 7) |
| Frequency | 10MHz | 0.01Hz | +/- (1.0%+5) |
| Duty Cycle | 99.90% | 0.10% | +/- 1.5% +/- 5 |
| Temperature | -22 to 140°F | 1°F | +/- 3% |
| Diode Test | | .001V | |
| Continuity | | 0.1Ω | |
| Diode Test | | .001V | |
| Battery Test | 1.5V | 1mV | +/- (1.0%+5) |
| Battery Test | 9V | 10mV | +/- (1.0%+5) |
| Dimensions | 6.1 x 2.9 x 2.1 in. | | |
| Weight | 0.5lb. | | |
| Safety Rating | CAT III 600V | | |

TEST & MEASUREMENT

MANUAL RANGING MULTIMETER

10031S



This Southwire general purpose multimeter is perfect for basic electrical repairs & troubleshooting. Features include a rugged double-molded housing, large LCD display, and battery test function. Meets the latest UL safety standards.

- Measures AC/DC voltage up to 600V, Resistance up to 2M Ω , and DC current up to 10A
- CAT III 300V Safety Rating
- Tests batteries and continuity
- Built to withstand a 6-foot drop
- Meets the latest UL safety standard
- Convenience features include built-in test probe holder, kickstand, easy-change fuses, and accepts Southwire magnetic hanging strap (available separately)
- Auto power-off preserves battery life



DURABILITY CERTIFIED



| MODEL # | STOCK # | DESCRIPTION | |
|---------------|---------------------|---------------------------|------------------------------|
| 10031S | 65031140 | Manual-Ranging Multimeter | |
| | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 100mV | +/- (1.2%+10) |
| DC Voltage | 600V | 0.1mV | +/- (0.8%+8) |
| DC Current | 10A | 1 μ A | +/- (1.0%+5) |
| Resistance | 2.000M Ω | 0.1 Ω | +/- (0.8%+5) |
| Continuity | | 0.1 Ω | |
| Battery Test | 1.5V | 1mV | +/- (1.0%+5) |
| Battery Test | 9V | 10mV | +/- (1.0%+5) |
| Dimensions | 6.1 x 2.9 x 2.1 in. | | |
| Weight | 0.6lb. | | |
| Safety Rating | CAT III 300V | | |

TEST & MEASUREMENT

MAINTENANCEPRO™ SMART 1000A CLAMP METER

23090T



Southwire's new MaintenancePRO™ 23090T adds Bluetooth® connectivity to a rugged, high-end clamp meter. Used with our MApp™ mobile app, the 23090T lets electricians safely get the measurements they need even in hostile environments. The app can be used to view readings, set up recording sessions, and assemble complete reports right from your mobile phone. The feature set of the 23090T make this the optimal choice for the professional electrician.

- Features automatic power-off
- Bluetooth® interface for viewing, saving and sharing using Southwire's MApp™ mobile app
- Inrush function captures motor start-up current
- 11 measuring functions, plus MAX/MIN
- Precision TrueRMS meter
- Hi-Res 50,000-count backlit display with bargraph
- Built-in, non-contact AC voltage detector and powerful LED work light
- Rugged meter with CAT IV 600V / CAT III 1000V safety rating, UL listed
- Includes:
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Carrying case
 - 9 volt battery



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------|--------------------------------------|--|------------------------------|
| 23090T | 59686840 | MaintenancePRO™ Bluetooth® 1000A Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Current | 1000A | 10mA | ±2.5% |
| DC Current | 1000A | 10mA | ±2.5% |
| Jaw Opening | 1.9" (48mm) | — | — |
| AC Voltage | 1000V | 0.01mV | ±1.0% |
| DC Voltage | 1000V | 0.01mV | ±1.0% |
| Non-Contact AC Voltage | 110 to 1000V AC | — | — |
| Resistance | 50MΩ | 0.01Ω | ±1.0% |
| Capacitance | 5mF | 10pF | ±3.5% |
| Frequency | 10MHz | 0.001Hz | ±0.3% |
| Duty Cycle | 5 to 95% | 0.01% | ±1.0% |
| Temperature | -148°F to 1832°F -100°C to 1000°C | 0.1° | ±1.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 9.0 x 3.0 x 1.6 in. | | |
| Weight | 0.69 lb. | | |

TEST & MEASUREMENT

MAINTENANCEPRO™ 1000A AC/DC CLAMP METER

23070T



The MaintenancePRO™ 23070T clamp meter is a rugged, high-end AC/DC clamp meter for the professional electrician who needs both AC and DC current measurements. With a UL listed safety rating of CAT IV 600V/CAT III 1000V, this clamp meter is built to get the tough jobs done.

- Features automatic power-off
- 11 measuring functions plus MAX/MIN
- TrueRMS readings provide higher accuracy on AC circuits
- Measures both AC and DC current
- Built-in, non-contact AC voltage detector and powerful LED work light
- 6,000-count backlit display with bar graph
- Rugged meter with CAT IV 600V/CAT III 1000V safety rating, UL listed
- Includes:
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Carrying case
 - 9 volt battery



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------|----------------------------------|---|------------------------------|
| 23070T | 59686740 | MaintenancePRO™ 1000A AC/DC Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Current | 1000A | 10mA | ±2.5% |
| DC Current | 1000A | 10mA | ±2.5% |
| Jaw Opening | 1.9" (48mm) | — | — |
| AC Voltage | 1000V | 1mV | ±1.5% |
| DC Voltage | 1000V | 0.1mV | ±1.0% |
| Non-Contact AC Voltage | 100 to 1000V AC | — | — |
| Resistance | 60MΩ | 0.1Ω | ±1.0% |
| Capacitance | 6000μF | 10pF | ±3.0% |
| Frequency | 10MHz | 0.001Hz | ±1.0% |
| Duty Cycle | 0.5 to 99.9% | 0.01% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 760°C | 0.1° | ±3.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 9.0 x 3.0 x 1.6 in. | | |
| Weight | 0.69 lb. | | |

TEST & MEASUREMENT | CLAMP METERS

TEST & MEASUREMENT

MAINTENANCEPRO™ 1000A AC CLAMP METER

23030T



The MaintenancePRO™ 23030T clamp meter is a rugged, high-end AC clamp meter. With a UL listed safety rating of CAT IV 600V/CAT III 1000V, this clamp meter is built to get the tough jobs done. The feature set of the 23030T make it the new standard in residential, commercial, and maintenance clamp meters.

- Features automatic power-off
- 10 measuring functions plus MAX/MIN
- TrueRMS readings provide higher accuracy on AC circuits
- Powerful LED work light for added convenience
- Built-in, non-contact AC voltage detector
- 6,000-count backlit display with bar graph
- Rugged meter with CAT IV 600V/CAT III 1000V safety rating, UL listed
- Includes:
 - Test leads
 - Type K temperature probe with banana plug adapter
 - Carrying case
 - 9 volt battery



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------|----------------------------------|--------------------------------------|------------------------------|
| 23030T | 59686640 | MaintenancePRO™ 1000A AC Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Current | 1000A | 10mA | ±2.5% |
| Jaw Opening | 1.9" (48mm) | — | — |
| AC Voltage | 1000V | 1mV | ±1.5% |
| DC Voltage | 1000V | 0.1mV | ±1.0% |
| Non-Contact AC Voltage | 100 to 1000V AC | — | — |
| Resistance | 60MΩ | 0.1Ω | ±1.0% |
| Capacitance | 6000μF | 10pF | ±3.0% |
| Frequency | 10MHz | 0.001Hz | ±1.0% |
| Duty Cycle | 0.5 to 99.9% | 0.01% | ±1.2% |
| Temperature | -4°F to 1400°F -20°C to 760°C | 0.1° | ±3.0% |
| Continuity | Audible threshold approx. 50Ω | | |
| Diode Test | Yes | | |
| Dimensions | 9.0 x 3.0 x 1.6 in. | | |
| Weight | 0.69 lb. | | |

TEST & MEASUREMENT

400A AC/DC TRUE RMS CLAMP METER

21550T



The Southwire 21550T 400A AC/DC clamp meter with True RMS offers the features needed for the professional electrician including True RMS accuracy, the ability to measure both AC and DC current, and a built-in, non-contact, AC voltage detector. Other features included are REL and max/min functions in addition to standard multimeter functions such as resistance, capacitance, continuity, temperature, and diode. This clamp meter also has a third-hand test probe holder and a bright LED worklight. The 21550T is built-to-last and is guaranteed to survive a 6-foot drop.

- 400A AC/DC Current Range
- CAT III 600V Safety Rating
- True RMS Accuracy
- Built-In Non-Contact Voltage Tester
- Third-Hand Test Probe Holder



| MODEL # | STOCK # | DESCRIPTION | |
|---------------|------------------|---------------------------------|------------------------------|
| 21550T | 65031840 | 400A AC/DC True RMS Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Current | 400A | 0.01A | +/- (2.0%+9) |
| DC Current | 400A | 0.01A | +/- (2.0%+5) |
| AC Voltage | 600V | 0.001V | +/- (1.0%+5) |
| DC Voltage | 600V | 0.1mV | +/- (1.0%+8) |
| NCV | Yes | | |
| Resistance | 40MΩ | 0.1Ω | +/- (1.0%+4) |
| Capacitance | 1000μF | 0.1nF | +/- (5.0%+/- 7) |
| Temperature | -5 - 750°F | 1°F | +/- 3.0% |
| Continuity | | 0.1Ω | |
| Diode Test | | .001V | |
| Jaw Opening | 1.1 in. (28mm) | | |
| Dimensions | 9" x 2.7" x 1.4" | | |
| Weight | 0.6lb. | | |
| Safety Rating | CAT III 600V | | |

TEST & MEASUREMENT

400A AC TRUE RMS CLAMP METER

21530T



The Southwire 21530T 400A AC clamp meter with True RMS offers the features needed for the professional electrician. It provides True RMS accuracy, AC current up to 400A, and a built-in, non-contact, AC voltage detector. Common multimeter functions include AC/DC voltage up to 600V, resistance, capacitance, continuity, temperature, and diode. The 21530T also provides a third-hand test probe holder and LED worklight for added convenience. The 21530T is built-to-last and is guaranteed to survive a 6-foot drop. Great for the professional.

- 400A AC Current Range
- CAT III 600V Safety Rating
- True RMS Accuracy
- Built-In Non-Contact Voltage Tester
- Third-Hand Test Probe Holder



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------------|------------------|------------------------------|-------------------------------|
| 21530T | 65031640 | 400A AC True RMS Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| Feature | Range | Max. Resolution | Max. Accuracy (% of Reading) |
| AC Current | 400A | 0.01A | +/- (2.0%+9) |
| AC Voltage | 600V | 0.001V | +/- (1.0%+5) |
| DC Voltage | 600V | 0.1mV | +/- (1.0%+8) |
| NCV (non-contact AC Voltage) | Yes | | |
| Resistance | 40MΩ | 0.1Ω | +/- (1.0%+4) |
| Capacitance | 1000μF | 0.1nF | +/- (3.0%+5) |
| Temperature | -5°F - 750°F | 1°F | +/- 3.0% |
| Continuity | | 0.1Ω | |
| Diode Test | | 0.001V | |
| Jaw Opening | 1.1 in. (28mm) | | |
| Dimensions | 9" x 2.7" x 1.4" | | |
| Weight | 0.6 lb. | | |
| Safety Rating | CAT III 600V | | |

TEST & MEASUREMENT

400A AC CLAMP METER

21510N



The Southwire 21510N 400A AC clamp meter offers the features needed for routine electrical repairs. In addition to measuring AC current up to 400A, the 21510N measures AC and DC voltage up to 600V plus provides common multimeter functions such as resistance, capacitance, continuity, temperature, and diode. The 21510N offers a built-in, non-contact AC voltage detector and a powerful LED worklight for working in dimly lit areas. The 21510N also features a third-hand test probe holder for added convenience. This CAT III clamp meter is designed to survive a 6-foot drop, making it built to last. Great for basic electrical work.

- 400A AC current range
- CAT III 600V safety rating
- Built-in non-contact voltage tester
- Third-hand test probe holder



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------------|------------------|---------------------|-------------------------------|
| 21510N | 65031540 | 400A AC Clamp Meter | |
| FUNCTION | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| Feature | Range | Max. Resolution | Max. Accuracy (% of Reading) |
| AC Current | 400A | 0.01A | +/- (2.0%+9) |
| AC Voltage | 600V | 0.001V | +/- (1.0%+5) |
| DC Voltage | 600V | 0.1mV | +/- (1.0%+8) |
| NCV (non-contact AC Voltage) | Yes | | |
| Resistance | 40MΩ | 0.1Ω | +/- (1.0%+4) |
| Capacitance | 1000μF | 0.1nF | +/- (3.0%+5) |
| Temperature | -5°F - 750°F | 1°F | +/- 3.0% |
| Continuity | | 0.1Ω | |
| Diode Test | | 0.001V | |
| Jaw Opening | 1.1 in. (28mm) | | |
| Dimensions | 9" x 2.7" x 1.4" | | |
| Weight | 0.6 lb. | | |
| Safety Rating | CAT III 600V | | |

TEST & MEASUREMENT

LCD VOLTAGE TESTER 600V AC/DC

41171N



Get a multimeter and non-contact voltage detector in one pocket tester. Great for beginner or experienced electricians. Features one of the largest backlit LCD displays in this category. Performs three essential electrician tasks: voltage detection, voltage testing, and continuity. Tests AC and DC voltage up to 600V. Features a built-in non-contact voltage detector and tests continuity with both visual and audible indicators. Fits comfortably in the pocket and has replaceable test leads. 5-year, no hassle warranty.

- Backlit LCD Display
- Built-in Non Contact Voltage Detector with Self Test
- Tests Continuity with visual & audible confirmation
- Bright LED Flashlight
- 0-600V AC measurement range
- 0-600V DC measurement range
- Replaceable Test Leads
- CAT IV 600V Safety Rated
- 6.5' drop tested



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|-------------------------------|
| 41171N | 65112140 | LCD Voltage Tester 600V AC/DC |
| Voltage | 6-600V AC/DC | |
| Safety Rating | CAT IV 600 V, Class 2, Double Insulation | |
| NCV Detection Range | 100 V AC to 1000 V AC | |
| Drop Protection | 6.5 feet (2 meters) | |
| AC Frequency Range | 50 Hz/60 Hz | |
| Operating Temperature | 32 °F to 104 °F (0°C to 40°C) | |
| Storage Temperature | 14 °F to 122 °F (-10°C to 50°C) | |

TEST & MEASUREMENT

VOLTAGE TESTER 600V AC 400V DC

41161N



An ideal test tool for the beginning electrician or for use as a back-up tester for more experienced electricians. Perfect for trade schools too. Performs three essential functions: voltage detection, voltage testing, and continuity. Features an easy-to-read LED display and tests AC voltage up to 600V and DC voltage up to 400V. Has a built-in non-contact voltage detector and tests continuity. Fits comfortably in the pocket, accepts a hanging strap, and has replaceable test leads. 5-year, no hassle warranty.

- Bright LED Display
- Built-in Non Contact Voltage Detector with Self Test
- Tests Continuity with visual & audible confirmation
- Bright LED Flashlight
- Indicates AC voltage from 12-600V AC in 9 steps
- Indicates DC voltage from 9-400V in 9 steps with polarity indication
- Replaceable Test Leads
- CAT IV 600V Safety Rated
- 6.5' drop tested



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|--------------------------------|
| 41161N | 65112040 | Voltage Tester 600V AC 400V DC |
| Voltage LED Steps | AC: 12, 24, 48, 120, 208, 240, 277, 480, 600 DC: 9, 12, 24, 36, 48, 60, 110, 220, 400 | |
| Safety Rating | CAT IV 600 V, Class 2, Double Insulation | |
| NCV Detection Range | 100 V AC to 1000 V AC | |
| Drop Protection | 6.5 feet (2 meters) | |
| AC Frequency Range | 50 Hz/60 Hz | |
| Operating Temperature | 32 °F to 104 °F (0°C to 40°C) | |
| Storage Temperature | 14 °F to 122 °F (-10°C to 50°C) | |

TEST & MEASUREMENT

VOLTAGE TESTER 480V AC 110V DC

41151S



The 41151S compact voltage and GFCI tester features a LED display. It's a simple and safe way to test for live circuits, measure voltage, and test if GFCI circuits are functioning properly. This pocket tester tests AC voltage up to 480V and DC voltage up to 110V.

- Bright LED Display
- Indicates AC voltage from 12-480V in 6 steps
- Indicated DC voltage from 9-110V in 6 steps with polarity indication
- Tests GFCI outlets and circuits
- CAT III 600V safety rating
- Tamper resistant outlet compatible
- Test probes store concealed
- 6.5' drop tested



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|---|--------------------------------|
| 41151S | 65111940 | Voltage Tester 480V AC 110V DC |
| Voltage LED Steps | AC: 12, 24, 48, 120, 240, 480 DC: 9, 12, 24, 36, 48, 110 | |
| Safety Rating | CAT III 600V | |
| Drop Protection | 6.5 feet (2 meters) | |
| AC Frequency Range | 50 Hz - 60 Hz | |
| Operating Temperature | 32 °F to 104 °F (0°C to 40°C) | |
| Storage Temperature | 14 °F to 122 °F (-10°C to 50°C) | |

TEST & MEASUREMENT

ADVANCED DUAL RANGE NCV 12-1000V AC

40150N



Advanced dual range NCV 12-1000V & 100-1000V AC.

- Features automatic power-off
- High power rear flashlight and forward facing flashlight
- Thinner probe tip for working with wall outlets
- Power switch (standard)
- Green LED means Power on
- Flashing red LED with beeper means voltage is detected
- Low-Battery self test
- High voltage and low voltage modes
- Silent mode
- IP67 Waterproof



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|--|
| 40150N | 63020740 | 40150N Advanced Dual Range NCV 12-1000V AC |
| AC Detection Range | 12-1000V & 100-1000V AC | |
| Safety Rating | CAT IV 1000V | |
| Frequency Range | 50/60Hz | |
| Batteries | Two AAA | |
| Operating Temperature | 32°F to 104°F (0°C to 40°C) | |
| Storage Temperature | 14°F to 140°F (-10°C to 60°C) | |
| Dimensions | 6.23 x 0.83 x 0.99 in (158 x 21 x 25 mm) | |
| Humidity | 80% max | |

TEST & MEASUREMENT | NCV

TEST & MEASUREMENT

NCV DETECTOR 50-600V AC PRO

40136N

NCV detector 50-600V AC Pro

- Features automatic power-off
- Flashlight now 2X brighter
- Thinner probe tip for working with wall outlets
- Power switch (standard)
- Green LED means power-on
- Flashing red LED with beeper means voltage detected
- Low battery self test
- Silent mode
- Flash and beep rate increase as the detector gets closer to the voltage source helping the user pinpoint live circuits



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|------------------------------------|
| 40136N | 59992440 | 40136N NCV Detector 48-600V AC Pro |
| AC Detection Range | 50-600V AC | |
| Safety Rating | CAT IV 600V | |
| Frequency Range | 50/60Hz | |
| Batteries | Two AAA | |
| Operating Temperature | 32°F to 104°F (0°C to 40°C) | |
| Storage Temperature | 14°F to 140°F (-10°C to 60°C) | |
| Dimensions | 6.23 x 0.83 x 0.99 in (158 x 21 x 25 mm) | |
| Humidity | 80% max | |

TEST & MEASUREMENT

40126N NCV DUAL RANGE 24-600V AC

40126N



NCV dual range 24-600V & 100-600V AC.

- Flashlight now 2X brighter
- Thinner probe tip for working with wall outlets
- Power switch (standard)
- Green LED means Power on
- Flashing red LED with beeper means voltage detected
- Low battery self test
- High voltage and low voltage mode



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|----------------------------------|
| 40126N | 59992240 | 40126N NCV Dual Range 24-600V AC |
| AC Detection Range | 24-600V & 100-600V AC | |
| Safety Rating | CAT IV 600V | |
| Frequency Range | 50/60Hz | |
| Batteries | Two AAA | |
| Operating Temperature | 32°F to 104°F (0°C to 40°C) | |
| Storage Temperature | 14°F to 140°F (-10°C to 60°C) | |
| Dimensions | 6.23 x 0.83 x 0.99 in (158 x 21 x 25 mm) | |
| Humidity | 80% max | |

TEST & MEASUREMENT

NCV DETECTOR 100-600V AC

40116N



NCV detector 100-600V AC.

- Flashlight now 2X brighter
- Thinner probe tip for working with wall outlets
- Power switch (standard)
- Green LED means power on
- Flashing red LED with beeper means voltage detected
- Low battery self test



| MODEL # | STOCK # | DESCRIPTION |
|-----------------------|--|---------------------------------|
| 40116N | 59992040 | 40116N NCV Detector 100-600V AC |
| AC Detection Range | 100-600V AC | |
| Safety Rating | CAT IV 600V | |
| Frequency Range | 50/60Hz | |
| Batteries | Two AAA | |
| Operating Temperature | 32°F to 104°F (0°C to 40°C) | |
| Storage Temperature | 14°F to 140°F (-10°C to 60°C) | |
| Dimensions | 6.23 x 0.83 x 0.99 in (158 x 21 x 25 mm) | |
| Humidity | 80% max | |

TEST & MEASUREMENT

GFCI RECEPTACLE TESTER

40022S



GFCI receptacle tester quickly identifies the most common wiring faults associated with 3-wire 120V outlets. Just plug it into the outlet and the indicator lights quickly tell you if the outlet is wired correctly. Press the red button to verify that a GFCI circuit is functioning properly.

- Tests standard 120V outlets
- Tests ground fault circuit interrupter (GFCI) outlets & circuits
- Three light indicators identify wiring faults
- Wiring legend on the top and bottom of the tester so it's always easy to see
- UL listed



| MODEL # | STOCK # | DESCRIPTION |
|--|----------------------|--|
| 40022S | 65032040 | GFCI Receptacle Tester |
| <input type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> | Open Ground | Ground contact is not connected |
| <input type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> | Open Neutral | Neutral contact is not connected |
| <input type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> | Open Hot | Hot contact is not connected |
| <input checked="" type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> | Hot/Ground Reversed | Hot and ground connections are interchanged |
| <input checked="" type="checkbox"/> <input type="checkbox"/> <input type="checkbox"/> | Hot/Neutral Reversed | Hot and neutral connections are interchanged |
| <input type="checkbox"/> <input checked="" type="checkbox"/> <input checked="" type="checkbox"/> | Correct | Receptacle is wired correctly |

TEST & MEASUREMENT

RECEPTACLE TESTER

40012S



Receptacle Tester quickly identifies the most common wiring faults associated with 120V outlets. Just plug it in and the indicator lights quickly tell you if the outlet is wired correctly.

- Tests standard 120V outlets Performs 6 tests: open ground, open neutral, open hot, hot/ground reversed, hot/neutral reversed, or wired correctly
- Three light indicators identify wiring faults
- Wiring legend on the top and bottom of the tester so it's always easy to see
- UL listed



| MODEL # | STOCK # | DESCRIPTION |
|--|----------------------|--|
| 40012S | 65031940 | Receptacle Tester |
| <div> <div></div> <div></div> <div></div> </div> | Open Ground | Ground contact is not connected |
| <div> <div></div> <div></div> <div></div> </div> | Open Neutral | Neutral contact is not connected |
| <div> <div></div> <div></div> <div></div> </div> | Open Hot | Hot contact is not connected |
| <div> <div></div> <div></div> <div></div> </div> | Hot/Ground Reversed | Hot and ground connections are interchanged |
| <div> <div></div> <div></div> <div></div> </div> | Hot/Neutral Reversed | Hot and neutral connections are interchanged |
| <div> <div></div> <div></div> <div></div> </div> | Correct | Receptacle is wired correctly |

TEST & MEASUREMENT

PRO CONTINUITY TESTER WITH REMOTE

40040S



The Southwire 40040S provides a simple way of checking continuity on wire and cables. The bright LEDs and loud pulsating beeper provide a positive indication of continuity and polarity. A detachable remote indicator is included for tracing multiple cable runs.

- Bi-color LEDs determine polarity
- Color coded alligator clips for easy connection
- Wiring legend on tester provides simple operation
- Rugged double-molded housing



| MODEL # | STOCK # | DESCRIPTION |
|------------|----------------------|-----------------------------------|
| 40040S | 59724840 | Pro Continuity Tester with Remote |
| FUNCTION | RANGE | |
| Dimensions | 4.0 x 2.1 x 1.3 inch | |
| Weight | 0.42 lb. (191g) | |

TEST & MEASUREMENT

4-WAY VOLTAGE TESTER

40141S



The 4-Way Voltage Tester is a handy, pocket sized tester that checks live AC voltage from 120 to 480 volts and DC voltage from 160 to 600 volts in four easy steps. The 40141S is easy-to-read and features a convenient, compact design.

- Tests AC voltage from 120V to 480V
- Tests DC voltage from 160V to 600V
- CAT III 600V safety rating
- Built-in test leads and handy pocket clip
- No batteries required
- Test probes conveniently store in the back of the tester and are spaced to fit standard AC outlets
- UL listed
- Built to withstand a 6-foot drop



| MODEL # | STOCK # | DESCRIPTION |
|------------------------|--|----------------------|
| 40141S | 65032240 | 4-Way Voltage Tester |
| Voltage LED Steps | AC: 120, 240, 277, 480 DC: 160, 330, 380, 600 | |
| AC Operating Frequency | 60Hz | |
| Safety Rating | CAT III 600V | |
| Drop Protection | 6.5 feet (2 meters) | |
| Operating Temperature | 32 °F to 104 °F (0°C to 40°C) | |
| Storage Temperature | 14 °F to 122 °F (-10°C to 50°C) | |

TEST & MEASUREMENT

930°F 12:1 IR THERMOMETER

31212S



Southwire's newest dual-laser IR thermometer, the 31212S, is designed for the professional because it's accurate, rugged, and easy-to-use. Perfect for everyday use but loaded with advanced features for ultimate flexibility. Customers appreciate the extra-large, backlit temperature display that's easy to see in almost any environment.

- Designed for the professional
- Dual-laser targeting for precise aiming
- 12:1 optics for extra-long distance accuracy
- Extra large, uncluttered, backlit temperature display
- Adjustable emissivity - higher accuracy when measuring different materials
- Displays temperature in °F or °C
- Protective carrying pouch included
- Continuous Measurement. Built-in tripod mount and LOCK Mode
- High and Low Temperature Alarms
- MAX, MIN, AVE, DIF Mode



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------------|---|--|---------------------|
| 31212S | 65111840 | 930°F 12:1 IR Thermometer | |
| | | | |
| Measurement Range | -26°F - 932°F (-32°C - 500°C) | | |
| Working Temperature | 32°F - 122°F (0°C - 50°C) | | |
| Working Relative Humidity | <90% RH (non-condensing) | | |
| Storage Temperature | -4°F - 140°F (-20°C - 60°C) | | |
| Accuracy | SURFACE TEMPERATURE | | AMBIENT TEMPERATURE |
| | -26°F ≤ t 32°F | +/- (3.6°F + 0.1°F/°F) | 69.8°F - 77 °F |
| | 32°F < t ≤ 932°F | +/- 3.6°F or 1.8% of reading, whichever is greater | |
| | -32°C ≤ t 0°C | +/- (1.8°C + 0.1°C/°C) | 21°C - 25 °C |
| | 0°C < t ≤ 500°C | +/- 1.8°C or 1.8% of reading, whichever is greater | |
| D:S Ratio (Distance to Spot) | 12:1 (Applies for 90% for the measuring signal) | | |
| Emissivity | 0.1 ~ 1.0 (Adjustable) | | |
| Display Resolution | 0.1°F (0.1°C) | | |

TEST & MEASUREMENT

750°F 10:1 IR THERMOMETER

31011F



When you need an IR thermometer that's simple and economical, the Southwire 31011F is the right model for you. Just point-and-shoot for accurate and repeatable temperature measurements around the house or on the job.

- Simple & economical
- Single-laser targeting
- 10:1 optics for long distance accuracy
- Fixed emissivity (0.95)
- Displays temperature in °F or °C
- Low-battery indicator
- Built for the Work Environment: 6-Ft Drop Rating



| MODEL # | STOCK # | DESCRIPTION | |
|------------------------------|---|---|---------------------|
| 31011F | 65111640 | 750°F 10:1 IR Thermometer | |
| | | | |
| Measurement Range | -4°F - 752°F (-20°C - 400°C) | | |
| Working Temperature | 32°F - 122°F (0°C - 50°C) | | |
| Working Relative Humidity | <90% RH (non-condensing) | | |
| Storage Temperature | -4°F - 140°F (-20°C - 60°C) | | |
| Accuracy | SURFACE TEMPERATURE | | AMBIENT TEMPERATURE |
| | -4°F ≤ t 32°F | +/- (4°F + 0.1°F/°F) | 69.8°F - 77 °F |
| | 32°F < t ≤ 752°F | +/- 4°F or +/- 2% of reading, whichver is greater | |
| | -20°C ≤ t 0°C | +/- (2°C + 0.1°C/°C) | 21°C - 25 °C |
| | 0°C < t ≤ 400°C | +/- 2.0°C or 2% of reading, whichver is greater | |
| D:S Ratio (Distance to Spot) | 10:1 (Applies for 90% for the measuring signal) | | |
| Emissivity | Fixed at 0.95 | | |
| Display Resolution | 0.1°F (0.1°C) | | |

TEST & MEASUREMENT

41210S CIRCUIT BREAKER FINDER WITH GFCI

41210S



The circuit breaker finder pinpoints the specific breaker powering the circuit being worked on. Eliminates guessing and unwanted power outages caused by tripping the wrong breaker.

- Advanced design quickly and reliably pinpoints single breaker without service interruption
- Tests GFCI outlets
- For use on energized circuits
- Includes:
 - 41210S Transmitter and Receiver
 - 3-prong to 2-prong adapter
 - 9 volt battery
- Available accessory: 60030S Adapter Kit

| MODEL # | STOCK # | DESCRIPTION |
|------------|--------------------------------|----------------------------------|
| 41210S | 58292140 | Circuit Breaker Finder with GFCI |
| Dimensions | 7.56 in. x 2.52 in. x 1.65 in. | |

TEST & MEASUREMENT

TYPE K TEMPERATURE CLAMP

60020S



The 60020S Type K temperature clamp allows quick maintenance checks on heating and air-conditioning systems. It's the perfect accessory for clamp meters and multimeters with a temperature function.

- For multimeters, clamp meters and thermometers that accept a type K temperature probe
- Spring-loaded jaw clamps around heating/cooling pipes up to 1.5" in diameter
- Temperature range: -4° to 200°F (-20° to 93°C)

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|--------------------------|
| 60020S | 58293140 | Type K Temperature Clamp |

TEST LEAD KIT

60010S



60010S Test lead kit includes universal replacement leads for all Southwire meters.

- UL listed
- CAT IV 600V/CAT III 1000V
- Includes alligator clip attachments (CAT III 600V)

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---------------|
| 60010S | 58292940 | Test Lead Kit |

ADAPTER KIT FOR CIRCUIT BREAKER FINDER

60030S



This adapter kit includes a light socket adapter that allows for rapid location of circuit breakers connected to lighting fixtures. Also includes alligator clips that allow the transmitter to be connected to unterminated branch circuit wiring.

- For use with 41210S circuit breaker finder

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|--|
| 60030S | 58292240 | Adapter Kit for Circuit Breaker Finder |

TEST & MEASUREMENT

ELECTRICAL TEST KIT

10037K



The Southwire electrical test kit combines three of Southwire's most popular test and measurement products into one convenient kit. Ideal for household repairs and electrical troubleshooting.

- 10031S Manual ranging multimeter is CAT III 300V safety rated. It measures AC/DC voltage, resistance, and DC current. Also tests batteries and continuity.
- 40117N Non-contact AC voltage detector has a 90-1000V detection range, CAT IV 1000V safety rating, automatic self test, and features a bright LED flashlight
- 40012S Receptacle tester verifies wiring errors in standard 3-wire AC outlets. Just plug it into the receptacle. LED indicators and wiring legend identify faults
- All products are UL listed and meet the latest UL safety standards
- All products are built to withstand a 6-foot drop

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---------------------|
| 10037K | 65031340 | Electrical Test Kit |

| MODEL # | STOCK # | DESCRIPTION | |
|---------------|---------------------|---------------------------|------------------------------|
| 10031S | 65031140 | Manual-Ranging Multimeter | |
| FEATURE | RANGE | MAX. RESOLUTION | MAX. ACCURACY (% OF READING) |
| AC Voltage | 600V | 100mV | +/- (1.2%+10) |
| DC Voltage | 600V | 0.1mV | +/- (0.8%+8) |
| DC Current | 10A | 1μA | +/- (1.0%+5) |
| Resistance | 2.000MΩ | 0.1Ω | +/- (0.8%+5) |
| Continuity | | 0.1Ω | |
| Battery Test | 1.5V | 1mV | +/- (1.0%+5) |
| Battery Test | 9V | 10mV | +/- (1.0%+5) |
| Dimensions | 6.1 x 2.9 x 2.1 in. | | |
| Weight | 0.6lb. | | |
| Safety Rating | CAT III 300V | | |

| MODEL # | STOCK # | DESCRIPTION |
|-------------------------|--------------------|---------------------------|
| 40117N | N/A | 1000V AC Voltage Detector |
| Detection Voltage Range | 90V AC to 1000V AC | |
| Frequency Range | 50/60Hz | |
| Safety Rating | CAT IV 1000V | |

| MODEL # | STOCK # | DESCRIPTION |
|------------|--|-------------------|
| 40012S | 65031940 | Receptacle Tester |
| Identifies | Open Ground, Open Neutral, Open Hot, Hot/Ground Reversed, Hot/Neutral Reversed, Correct Wiring | |

CABLE PULLING

Southwire cable pulling equipment sets the industry standard. We've revolutionized these tools to make them faster, safer, and smarter than ever before. With Southwire cable pulling equipment on your jobsite, experience an increase in safety, efficiency, and profitability.



CABLE PULLING

MAXIS® XD10 EXTREME DUTY CABLE PULLER

XD10



WE'VE GOT IT
MADE IN AMERICA™



LVFS-01
Footswitch
Included



The MAXIS® XD10 EXTREME duty cable puller is designed to get the job done, thriving in the most extreme pulling conditions. The XD10 allows you to pull faster and safer up to 10,000 lbs.

- Vertical capstan design - allows operator to safely stand to the side during cable pulls
- Smooth elevation control: operates with handle or 18V cordless drill helping to eliminate any lifting
- Pulls up to 10 ft. of extra wire without extending the boom
- Gear reducer design allows for increased efficiency, durability, and power while maintaining low operating temperature
- 10,000 lb. peak pulling force with a continuous pulling rate of 7,000 lbs.
- Conduit adapter sizes 2" - 4" included, 5" & 6" adapters sold separately
- Includes LVFS-01 low voltage footswitch
- Self contained: ready to pull with no need for additional parts or equipment for set up
- Single person set up and operation: quickly adapts from underground to overhead pulls
- Collapsible down to 40"H x 26"W x 70"L to fit through standard doorways and ease of transport
- Add Southwire's Triggers Wireless Safety Switch System (sold separately) for complete control over the cable pulling application

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|--------------------|--------------------|---------------------------------------|---------------------|--------------------|
| XD10 | 59190402 | MAXIS® XD10 EXTREME Duty Cable Puller | | |
| HEIGHT | LENGTH | WIDTH | WEIGHT | WARRANTY |
| 40" | 70" | 26" | 598 lb. | 1 year |
| CAPACITY | | | | |
| Pulling Speed Low: | | | Pulling Speed High: | |
| at 2,000 lb. | 11 feet per minute | | at 2,000 lb. | 21 feet per minute |
| at 4,000 lb. | 10 feet per minute | | at 4,000 lb. | 18 feet per minute |
| at 6,000 lb. | 9 feet per minute | | - | - |
| at 8,000 lb. | 8 feet per minute | | - | - |
| at 10,000 lb. | 7 feet per minute | | - | - |

XD10 BOLT DOWN ADAPTER

XD10BD



WE'VE GOT IT
MADE IN AMERICA™

Floor mount adapter for XD10.

- Easily attaches to the XD10
- Does not require disassembly of cable puller
- Simple bolt down adapter for when overhead pulling is required

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------------|-------|--------|
| XD10BD | 59727001 | Maxis® XD10 Bolt Down Kit | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| XD10BD | 18" | 14" | 16" | 35 lb. |

CABLE PULLING

MAXIS® 6K CABLE PULLER

**M6K-M
M6K
PC100**



LVFS-01 Footswitch



MAXIS® 6K with motor and puller cart

A 6,000 pound cable puller that sets up in less than 2 minutes.

- One person, 2 minute set up
- 2 pulling speeds: 12 feet per minute on low (at no load) and 44 feet per minute on high (at no load)
- Quickly adapts from underground to overhead pulls
- No need to bolt to the ground on most pulls
- 6,000 lb. peak capacity with continuous rating of 3,500 lb. on low
- Can adapt to virtually any wire pull
- Vertical capstan design - allows operator to safely stand to the side during cable pulls
- Can be anchored to most trucks' standard 2" receiver hitch
- Able to pull up to 9 ft. of wire out of the conduit
- Includes 5 conduit adapters 2" - 4" Included, 5" and 6" sold separately
- Includes puller cart with tool bag
- Includes puller cart with tool bag and LVFS-01 Low Voltage Footswitch
- Add Southwire's Triggers Wireless Safety Switch System (sold separately) for complete control over the cable pulling application

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|-------|-----------|
| M6K-M | 57648501 | MAXIS® 6K (with motor) - includes five conduit adapters (2", 2.5", 3", 3.5", 4"), PC100 cart, and LVFS-01 footswitch | | |
| M6K | 57142901 | MAXIS® 6K (no motor) - includes five conduit adapters (2", 2.5", 3", 3.5", 4"). PC100 cart, and LVFS-01 footswitch | | |
| PC100 | 56829601 | Puller cart for M3K and M6K pullers | | |
| LVFS-01 | 64602801 | Low-voltage footswitch | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| M6K-M | 45" | 21" | 20" | 194.5 lb. |
| PC100 | 50" | 21" | 17.5" | 40 lb. |

Milwaukee, Super Hawg, Hole Hawg are trademarks, service marks, or trade names of Milwaukee Electric Tool Corporation ("Milwaukee Electric Tool Corporation's Intellectual Property").



Conduit Adapters (included): 4", 3.5", 3", 2.5", 2"

CABLE PULLING

CORDLESS MAXIS® 3K CABLE PULLER



Southwire's M3K-BAT is your complete solution for a truly cordless cable pulling experience. Eliminates the need to be near an electrical outlet on the jobsite or having to run long extension cords. No additional hardware required.

- One person, 2 minute set up
- 2 pulling speeds: 25 feet per minute on low (at no load) and 100 feet per minute on high (at no load)
- Quickly adapts from underground to overhead pulls
- No need to bolt to the ground on most pulls
- Able to pull up to 8 ft. of wire out of the conduit
- 3,000 lb. peak capacity with continuous rate of 1,500 lb. on low
- Can adapt to virtually any wire pull
- Vertical capstan design - allows operator to safely stand to the side during cable pulls
- Can be anchored to most trucks' standard 2" receiver hitch
- Includes 5 conduit adapters: 2", 2.5", 3", 3.5", and 4"
- Puller cart with tool bag
- Completely cordless cable puller. No outlet? No problem!
- No additional hardware required.
- 12.0 AH capacity for extended run life.

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|-------|-----------|
| M3K-BAT | 65242040 | Includes Maxis M3K cable puller, PC-100 puller cart, cordless motor, rapid charger, and 12A battery pack | | |
| PC100 | 56829601 | Puller cart for M3K and M6K pullers | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| M3K-BAT | 45" | 20" | 20" | 148.5 lb. |
| PC100 | 50" | 21" | 17.5" | 40 lb. |

Milwaukee, Super Hawg, Hole Hawg are trademarks, service marks, or trade names of Milwaukee Electric Tool Corporation ("Milwaukee Electric Tool Corporation's Intellectual Property").



CABLE PULLING

MAXIS® 3K CABLE PULLER



M3K-M
M3K
PC100



LVFS-01
Footswitch

The MAXIS® 3K is a smaller and more lightweight version of Southwire's 6K puller but shares the same design features and functionality.

- One person, 2-minute set-up
- 2 pulling speeds: 25 feet per minute on low (at no load) and 100 feet per minute on high (at no load)
- Quickly adapts from underground to overhead pulls
- No need to bolt to the ground on most pulls
- Able to pull up to 8 additional feet of wire out of the conduit
- 3,000 lb. peak capacity with continuous rate of 1,500 lb. on low
- Can adapt to virtually any wire pull
- Can be anchored to most trucks' standard 2" receiver hitch
- Includes 5 conduit adapters: 2", 2.5", 3", 3.5", and 4"
- Includes puller cart with tool bag and LVFS-01 Low Voltage Footswitch

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|-------|-----------|
| M3K-M | 57648401 | MAXIS® 3K (with motor) - includes cable puller, motor, PC100 cart, five conduit adapters (2", 2.5", 3, 3.5", 4"), and LVFS-01 low voltage footswitch | | |
| M3K | 57143101 | MAXIS® 3K (no motor) - includes cable puller, PC100 cart, five conduit adapters (2", 2.5", 3, 3.5", 4"), and LVFS-01 low voltage footswitch | | |
| PC100 | 56829601 | Puller cart for M3K and M6K pullers | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| M3K-BAT | 45" | 20" | 20" | 148.5 lb. |
| PC100 | 50" | 21" | 17.5" | 40 lb. |

Milwaukee, Super Hawg, Hole Hawg are trademarks, service marks, or trade names of Milwaukee Electric Tool Corporation ("Milwaukee Electric Tool Corporation's Intellectual Property").



CABLE PULLING

MAXIS® XD1 CABLE PULLER

XD1



Safer, faster, and more efficient way to pull low voltage, branch home runs, lighting cables, and small circuit sized wires.

- Continuous pulling up to 600 lbs.
- Lightweight and portable
- One person setup and operation
- Accepts most commercial 18V cordless drills (drill not included)
- Removable capstan to facilitate polyline removal
- Expandable length up to 34.5 inches
- Polyline pin on capstan to prevent slippage during the pull
- Anodized for corrosion resistance
- Field replaceable chuck adapter
- 600 lbs of constant pulling force with 1000 lbs peak pulling force

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------|-------|---------|
| XD1 | 65090901 | Maxis® XD1 Cable Puller | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| XD1 | 8.75" | 8" | 28.5" | 8.8 lb. |



CABLE PULLING

XDTM EXTREME DUTY TENSION MONITOR

XDTM



10,000 lb. in-line tension monitor.

- Records elapsed time, tension, pull speed, and distance pulled
- Working load: 10,000 lbs
- Large, soft touch button controls
- Built-in USB port with USB flash drive (included) for easy data extraction
- Back lit screen allows for easy viewing
- Anodized aluminum frame for durability
- Tie-off slots
- Covers full range of rope sizes
- Built-in rechargeable battery for long life
- Includes padded hard-shell case with wheels and extendable handle for easy transport to the jobsite
- No disassembly for rope insertion
- Includes mounting pins for fast and easy assembly to Southwire's XD10 cable puller

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|-------|--------|
| XDTM | 65111501 | Extreme Duty Tension Monitor - 10,000 lb. | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| XDTM | 10.50" | 20.50" | 7.50" | 41 lb. |



CABLE PULLING

MAXIS® CABLE FEEDER

MCF01



Designed and built specifically to accommodate Southwire *SIMpull*™ wire, the Maxis® Cable Feeder is a revolutionary way to feed wire quickly and efficiently.

- Designed and built specifically to accommodate Southwire *SIMpull*™ wire
- Quick 1 person, 2 minute set up and operate
- Forward and reverse, variable speed, and feeds up to 30' per minute
- May be used with Triggers® Safety System for simultaneous feeder/puller control
- Easily adjust wire tension, even during operation
- Feeds wire sizes from 1/2" - 3 1/2" cable
- Solid rubber tires and swivel casters that will never go flat for easy jobsite maneuverability
- Digital footage meter allows easy monitoring of approximate conductor length being fed
- Uses grooved roller design with increased surface area for greater traction force (no pneumatic tires)
- Dual anchoring mechanism
- Maximum traction force: single conductor 800 lb., 4 *SIMpull*™ THHN 500 MCM conductors 1,600 lb. capacity
- Cable capacity: 8 x 250 MCM, 6 x 500 MCM, 5 x 750 MCM
- Triggers Adapter FB-01 (sold separately) allows Southwire's Triggers Wireless Safety Switch System to be used with the Maxis Cable Feeder

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------|-------|---------|
| MCF01 | 58133301 | MAXIS® Cable Feeder | | |
| FB-01 | 63159401 | Triggers Adapter | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| MCF01 | 35" | 26" | 44" | 366 lb. |
| FB-01 | 2.5" | 4" | 12" | 2 lb. |

FB-01



CABLE PULLING

TRIGGERS® WIRELESS SAFETY SWITCH SYSTEM

TSS01



Allows members at each end of the pull, as well as the observers, the ability to stop the pull instantaneously if needed. Offers your crew the highest level of safety, allowing full control over pulling and feeding applications

- Works with all brands of electrically driven equipment
- Saves time by avoiding unnecessary stops and restarts
- High-visibility LED status lights
- Monitors amperage draw indicating when to switch puller to low speed
- Triggers® Wireless safety switch system is UL and FCC certified and carries an IP55 rating
- Foot controls contain dual redundant activation switches
- Military grade 3.4 amps per hour lithium-ion battery packs
- Handheld remotes can control pull from any location
- High range: communicates up to 1500' between walls and 1.5 miles line of sight

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---|--------|--------|
| TSS01 | 59713201 | Triggers® Wireless Safety Switch System | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| TSS01 | 12.54" | 21.5" | 16.42" | 30 lb. |

LOW VOLTAGE FOOT SWITCH

LVFS01



- Works with all brands of electrically driven equipment
- Shuts off equipment when over amperage condition is indicated
- Monitors for under voltage condition which can cause an over amperage condition
- Bright LED lights for easy viewing in bright sunlight
- Redundant switches for added reliability
- Impact-resistant metal construction
- Low voltage indicator light for detecting low voltage situations
- Built-in over amperage protection to protect equipment and motors

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------|--------|--------|
| LVFS01 | 64602801 | Low Voltage Foot Switch | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| LVFS01 | 4.25" | 6.25" | 12.25" | 4 lb. |

CABLE PULLING

SIMpull™ CABLE GUIDE SYSTEM

CGS01



WE'VE GOT IT
MADE IN AMERICA™

Integrated guidance system allowing wire and cable to be routed from a reel into a conduit or cable tray without human intervention.

- Designed to eliminate the manual handling of service and feeder conductors during wire pulls
- Completely customizable for any wire and cable installation
- Minimizes labor effort during installation
- Reduces the risk of jobsite injuries
- Specialized storage cart for ease of transportation
- Roller guides direct and protect wire and cable along any desired path
- Universal clamps attach the system to the reel jacks, switch gear or panel box

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------------|-------|---------|
| CGS01 | 59893101 | SIMpull™ Cable Guide System | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| CGS01 | 43" | 25" | 67" | 300 lb. |



CABLE PULLING

CABLE PULLER TRIPODS

P3T01
P6T02



M3K and M6K Tripods attach to MAXIS® cable pullers to make underground wire pulls simple and easy.

- Easily attaches to the M3K or M6K cable pullers
- Helps when pulling from transformer pads, vaults and meter bases
- Set up in two minutes
- Helps to pull out extra wire

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | |
|---------|------------------------------|-----------------------------------|--------|
| P3T01 | 56822201 | Tripod for MAXIS® 3K | |
| P6T02 | 56829401 | Tripod for MAXIS® 6K | |
| MODEL # | SIZE | | WEIGHT |
| P3T01 | Adjustable height: 3ft - 6ft | Adjustable leg width: 13in - 50in | 43 lb. |
| P6T02 | Adjustable height: 3ft - 6ft | Adjustable leg width: 13in - 50in | 45 lb. |

Milwaukee, Super Hawg, Hole Hawg are trademarks, service marks, or trade names of Milwaukee Electric Tool Corporation ("Milwaukee Electric Tool Corporation's Intellectual Property").



CABLE PULLING

QWIKrope®



An innovative, high performance pulling rope that is UV-resistant, lightweight, and ultra low-stretch for all of your feeder and circuit wire needs.

- High performance pulling rope made from ultra high molecular weight polyethylene fibers
- 24% reduction in the coefficient of friction, as compared to traditional pulling ropes
- 12 strand single braided 9/16" pulling rope with a breaking strength of 32,000 lb., pound for pound stronger than steel
- 2 sizes for all your circuit wire pulls: 1/8" pulling rope with 1,100 lb. of breaking strength, and 1/4" pulling rope with 7,500 lb. of breaking strength
- Dual factory installed pulling eyes
- Does not absorb water, no rope rot
- Need only one size rope (9/16") for feeder conductor that pulls up to 10,000 pounds
- 1/8" QWIKrope® can easily be vacuumed into any conduit run up to 290 ft.
- 9/16" QWIKrope® recommended for use with all MAXIS® cable pullers

SPECIFICATIONS

| MODEL # | STOCK # | DIAMETER | LENGTH | AVG. BREAKING STRENGTH | TOTAL WEIGHT |
|---------|----------|----------|-----------|------------------------|--------------|
| SPR183 | 58387401 | 1/8" | 300 ft. | 1,100 lb. | 2.5 lb. |
| SPR186 | 64865701 | 1/8" | 600 ft. | 1,100 lb. | 5 lb. |
| SPR143 | 58387501 | 1/4" | 300 ft. | 7,500 lb. | 6.5 lb. |
| SPR146 | 58526301 | 1/4" | 600 ft. | 7,500 lb. | 11 lb. |
| SPR963 | 58305601 | 9/16" | 300 ft. | 32,000 lb. | 26 lb. |
| SPR966 | 58305701 | 9/16" | 600 ft. | 32,000 lb. | 52 lb. |
| SPR969 | 58305801 | 9/16" | 900 ft. | 32,000 lb. | 77 lb. |
| SPR9612 | 58305901 | 9/16" | 1,200 ft. | 32,000 lb. | 103 lb. |

CABLE PULLING

STRAIGHT AND SWIVEL CLEVISES



Connects pulling head and pulling rope to eliminate winding and tangling of rope and wire during cable pulls.

MS158

- Swivel diameter 1 5/8"
- Maximum rope size: 1"
- Designed to pass over sheaves, pulleys and rollers
- Pin roller design added for larger diameter rope and for added strength by evenly spreading load pressure

MS114

- Swivel diameter 1 1/4"
- Maximum rope size: 5/8"
- Designed to pass over sheaves, pulleys and rollers
- Pin roller design added for larger diameter rope and for added strength by evenly spreading load pressure

RC114

- Clevis diameter 1 1/4"
- Maximum rope size: 5/8"
- Connects to cable grip and pulling rope
- Designed to pass over sheaves, pulleys, and rollers

RC158

- Clevis diameter 1 5/8"
- Maximum rope size: 1"
- Connects to cable grip and pulling rope
- Designed to pass over sheaves, pulleys, and rollers

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | |
|---------|----------|---------------------------|--------|
| MS158 | 57178001 | 10,000 LB Swivel Clevis | |
| MS114 | 57178101 | 6,000 LB Swivel Clevis | |
| RC114 | 56830601 | 6,000 LB Straight Clevis | |
| RC158 | 56830701 | 10,000 LB Straight Clevis | |
| HEIGHT | WIDTH | DEPTH | WEIGHT |
| 4" | 4" | 4" | 2 lb. |
| 4" | 4" | 4" | 1 lb. |
| 2" | 2" | 4" | 1 lb. |
| 2" | 2" | 4" | 1 lb. |

CABLE PULLING

DOUBLE BRAIDED PULLING ROPE



Cable pulling rope designed for high breaking strength. The double braid weave provides enhanced strength and increased pulling capability.

- Polyester double braid
- High strength

SPECIFICATIONS

| MODEL # | STOCK # | DIAMETER | LENGTH | AVG. BREAKING STRENGTH | TOTAL WEIGHT |
|---------|----------|----------|----------|------------------------|--------------|
| P-963 | 56823501 | 9/16" | 300 ft. | 14,000 lb. | 50 lb. |
| P-966 | 56823601 | 9/16" | 600 ft. | 14,000 lb. | 75 lb. |
| P-583 | 56823701 | 5/8" | 300 ft. | 18,000 lb. | 63 lb. |
| P-586 | 56823901 | 5/8" | 600 ft. | 18,000 lb. | 85 lb. |
| P-786 | 56824001 | 7/8" | 600 ft. | 31,000 lb. | 240 lb. |
| P-789 | 57791301 | 7/8" | 900 ft. | 31,000 lb. | 269 lb. |
| P-7812 | 56824101 | 7/8" | 1200 ft. | 31,000 lb. | 298 lb. |

HIGH TENSILE STRENGTH QWIKLINE™ POLY LINE

PL500



PL6500



Tangle resistant poly line for light-duty cable or rope pulling applications.

- Ready-to-use storage containers quickly dispense a tangle-free line
- Line is resistant to rot and mildew
- Used to pull electrical and communication wire
- Made in the USA

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|---|-------|----------|------------------|
| PL6500 | 58280540 | QWIKline™ POLY LINE 6500' 210 lb Tensile Strength | | | |
| PL2200 | 65130440 | QWIKline™ POLY LINE 2200' 500 lb Tensile Strength | | | |
| PL500 | 58280640 | QWIKline™ POLY LINE 500' 210 lb Tensile Strength | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | TENSILE STRENGTH |
| PL6500 | 13" | 11" | 13" | 11.3 lb. | 210 lb. |
| PL2200 | 13" | 11" | 11" | 8.0 lb. | 500 lb. |
| PL500 | 7.9" | 3" | 8" | 0.5 lb. | 210 lb. |



WE'VE GOT IT
MADE IN AMERICA™

CABLE PULLING

CONDUIT MEASURING TAPE

SWCMT160-3000S



The conduit measuring tape measures 3,000 ft. and has easy-to-read markings in sequential, one-foot increments.

- Provides quick and accurate measurement of conduit runs
- Printed with accurate sequential footage markings
- Will not rot or promote the growth of mildew

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | PALLET QUANTITY | LENGTH (FT.) | WIDTH (IN.) | TENSILE STRENGTH (LBS.) |
|-----------------|----------|--|-----------------|--------------|-------------|-------------------------|
| SWCMT160-3000S | 64584901 | Conduit Measuring Tape 160-LB x 3000-FT Spool | 144 | 3000 | 3/16 | 160 |
| SWMT400-4500P | 64585001 | QWIKtape™ 400-LB x 4500-FT Bucket | 36 | 4500 | 3/16 | 400 |
| SWMT1250-3000S | 64585101 | QWIKtape™ 1250-LB x 3000-FT Spool | 36 | 3000 | 1/2 | 1250 |
| SWQT1250-500S | 65128740 | QWIKtape™ 1250-LB x 500-FT Spool | 128 | 500 | 1/2 | 1250 |
| SWQT1250-1000S | 65128840 | QWIKtape™ 1250-LB x 1000-FT Spool | 128 | 1000 | 1/2 | 1250 |
| SWQT1250-1500S | 65128940 | QWIKtape™ 1250-LB x 1500-FT Spool | 96 | 1500 | 1/2 | 1250 |
| SWQT1250-5000S | 65129040 | QWIKtape™ 1250-LB x 5000-FT Spool | 18 | 5000 | 1/2 | 1250 |
| SWDQT1250-3000S | 65129140 | QWIKtape™ 1250-LB x 3000-FT Spool - DETECTABLE | 36 | 3000 | 1/2 | 1250 |
| SWMT1800-3000S | 64585201 | QWIKtape™ 1800-LB x 3000-FT Spool | 36 | 3000 | 5/8 | 1800 |
| SWQT1800-500S | 65129240 | QWIKtape™ 1800-LB x 500-FT Spool | 128 | 500 | 5/8 | 1800 |
| SWQT1800-1000S | 65129340 | QWIKtape™ 1800-LB x 1000-FT Spool | 128 | 1000 | 5/8 | 1800 |
| SWQT1800-1300P | 67594540 | QWIKtape™ 1800-LB x 1000-FT Spool | 128 | 1000 | 5/8 | 1800 |
| SWQT1800-1500S | 65129440 | QWIKtape™ 1800-LB x 1300-FT Bucket | 36 | 1300 | 5/8 | 1800 |
| SWQT1800-5000S | 65129540 | QWIKtape™ 1800-LB x 5000-FT Spool | 12 | 5000 | 5/8 | 1800 |
| SWDQT1800-3000S | 65129640 | QWIKtape™ 1800-LB x 3000-FT Spool - DETECTABLE | 36 | 3000 | 5/8 | 1800 |
| SWMT2500-3000S | 64585401 | QWIKtape™ 2500-LB x 3000-FT Spool | 36 | 3000 | 3/4 | 2500 |
| SWQT2500-500S | 65129740 | QWIKtape™ 2500-LB x 500-FT Spool | 96 | 500 | 3/4 | 2500 |
| SWQT2500-1000S | 65129840 | QWIKtape™ 2500-LB x 1000-FT Spool | 96 | 1000 | 3/4 | 2500 |
| SWQT2500-1500S | 65130040 | QWIKtape™ 2500-LB x 1500-FT Spool | 64 | 1500 | 3/4 | 2500 |
| SWQT2500-5000S | 65130140 | QWIKtape™ 2500-LB x 5000-FT Spool | 12 | 5000 | 3/4 | 2500 |
| SWDQT2500-3000S | 65130340 | QWIKtape™ 2500-LB x 3000-FT Spool - DETECTABLE | 36 | 3000 | 3/4 | 2500 |
| PL6500 | 58280540 | QWIKline™ 210-LB x 6500-FT Bucket | 36 | 6500 | N/A | 210 |
| PL500 | 58280640 | QWIKline™ 210-LB x 500-FT Canister | N/A | 500 | N/A | 210 |
| PL2200 | 65130440 | QWIKline™ 500-LB x 2200-FT Bucket | 36 | 2200 | N/A | 500 |

CABLE PULLING

MAXIS® GRIPS PULLING HEADS



The MAXIS® grips pulling heads are a dual-lock pulling system that uses both a cam lock head and a double braided wire to quickly secure cable to rope without the fear of losing a conductor. These pulling heads provide increased efficiency with 2 minute head preparation.

- Rated at 4,000 lbs. per conductor.
- Holds securely to NO-LUBE® wire
- Disconnect wire from pulling heads in 2 minutes without cutting the wire
- No cutting, stripping or weaving of wire to make pulling head
- Easily moves through conduit and around 90° bends
- Staggered lengths for easier movement
- Keeps pulling head tight for easier movement through conduit

SPECIFICATIONS

| MODEL # | STOCK # | MAXIS GRIPS | GRIPS | WIRE | PULLING JACKET | | ROPE SWIVEL | | CARRYING BAG | DOUBLE LOCKING HEAD |
|---------|----------|--------------|--------------|--------------|----------------|------|-------------|------|--------------|---------------------|
| | | | | | MED. | LRG. | LRG. | SML. | | |
| GP110 | 56822701 | Complete Set | Complete Set | 1/0 - 750MCM | X | X | X | X | X | --- |
| GP00AA | 56822801 | Group AA | 4 Grips | 1/0 - 4/0 | | | | | | --- |
| GP101A | 56822901 | Group A | 4 Grips | 3/0 - 4/0 | | | | X | X | X |
| GP102B | 56823001 | Group B | 4 Grips | 250 - 350MCM | X | | | X | X | X |
| GP103C | 56823101 | Group C | 4 Grips | 400 - 500MCM | | X | X | | X | X |
| GP104D | 56823201 | Group D | 4 Grips | 600 - 750MCM | | X | X | | X | X |

CABLE PULLING

SIMpull HEAD® PULLING DEVICE



Available in sizes from 8 AWG to 1000 KCMIL the SIMpull Head® pulling device eliminates the need to make up a pulling head on the job site and reduces waste.

- Factory and Field installable pulling grip
- Eliminates the need to make up a pulling head on the job site and reduces waste
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Patented gripping system — factory installed conductors guaranteed not to pull loose during your pull
- available in 6", 12", 18", 24", and 30" lanyard lengths

SPECIFICATIONS

| DESCRIPTION | AVAILABLE IN |
|---|---|
| 8 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 6 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 4 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 3 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 2 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 1 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 1/0 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 2/0 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 3/0 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 4/0 AWG SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 250 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 300 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 350 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 400 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 500 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 600 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 700 KCMIL SIMpull Head® Pulling Device | Available in 6", 12", 18", 24", & 30" staggered lengths |
| 750 KCMIL SIMpull Head® Pulling Device | Available in 9", 15", 21", 27", & 33" staggered lengths |
| 900 KCMIL SIMpull Head® Pulling Device | Available in 9", 15", 21", 27", & 33" staggered lengths |
| 1000 KCMIL SIMpull Head® Pulling Device | Available in 9", 15", 21", 27", & 33" staggered lengths |

*Individual SIMpull Head® Pulling Device model #'s begins with SPH.
Visit www.southwire.com for full product listing.

CABLE PULLING

BASKET GRIPS



Southwire's basket grips will save you time by eliminating cutting, stripping or weaving to make your own pulling head. It features a durable galvanized weather-resistant steel mesh that will not corrode and comes in a variety of sizes to fit your application.



- Flexible/low-profile
- Reusable/durable
- Galvanized for corrosion/weather resistance

| MODEL # | UPC | STOCK # | DESCRIPTION | WORKING LOAD LBS. | CABLE DIAMETER RANGER |
|----------|-----------------|----------|--------------------------------------|------------------------------|-----------------------|
| JBG-024 | 0-32886-69795-1 | 65017301 | Junior Basket Grip 0.19" - 0.24" | Max Rated Capacity: 80 lb. | 0.19" - 0.24" |
| JBG-036 | 0-32886-69796-8 | 65017401 | Junior Basket Grip 0.25" - 0.36" | Max Rated Capacity: 90 lb. | 0.25" - 0.36" |
| JBG-049 | 0-32886-69797-5 | 65017501 | Junior Basket Grip 0.37" - 0.49" | Max Rated Capacity: 180 lb. | 0.37" - 0.49" |
| JBG-061 | 0-32886-69798-2 | 65017701 | Junior Basket Grip 0.50" - 0.61" | Max Rated Capacity: 260 lb. | 0.50" - 0.61" |
| JBG-074 | 0-32886-69799-9 | 65017801 | Junior Basket Grip 0.62" - 0.74" | Max Rated Capacity: 390 lb. | 0.62" - 0.74" |
| JBG-099 | 0-32886-69800-2 | 65017901 | Junior Basket Grip 0.75" - 0.99" | Max Rated Capacity: 560 lb. | 0.75" - 0.99" |
| JBG-124 | 0-32886-69801-9 | 65018001 | Junior Basket Grip 1.00" - 1.24" | Max Rated Capacity: 780 lb. | 1.00" - 1.24" |
| LBG-061 | 0-32886-69802-6 | 65018101 | Light Duty Basket Grip 0.50" - 0.61" | Max Rated Capacity: 560 lb. | 0.50" - 0.61" |
| LBG-074 | 0-32886-69803-3 | 65018201 | Light Duty Basket Grip 0.62" - 0.74" | Max Rated Capacity: 560 lb. | 0.62" - 0.74" |
| LBG-099 | 0-32886-69804-0 | 65018301 | Light Duty Basket Grip 0.75" - 0.99" | Max Rated Capacity: 800 lb. | 0.75" - 0.99" |
| LBG-124 | 0-32886-69805-7 | 65018501 | Light Duty Basket Grip 1.00" - 1.24" | Max Rated Capacity: 1360 lb. | 1.00" - 1.24" |
| LBG-149 | 0-32886-69806-4 | 65018601 | Light Duty Basket Grip 1.25" - 1.49" | Max Rated Capacity: 1360 lb. | 1.25" - 1.49" |
| LBG-199 | 0-32886-69807-1 | 65018701 | Light Duty Basket Grip 1.50" - 1.99" | Max Rated Capacity: 1360 lb. | 1.50" - 1.99" |
| LBG-249 | 0-32886-69808-8 | 65018801 | Light Duty Basket Grip 2.00" - 2.49" | Max Rated Capacity: 1700 lb. | 2.00" - 2.49" |
| LBG-299 | 0-32886-69809-5 | 65018901 | Light Duty Basket Grip 2.50" - 2.99" | Max Rated Capacity: 2120 lb. | 2.50" - 2.99" |
| LBG-349 | 0-32886-69810-1 | 65019001 | Light Duty Basket Grip 3.00" - 3.49" | Max Rated Capacity: 2940 lb. | 3.00" - 3.49" |
| LBG-399 | 0-32886-69811-8 | 65019101 | Light Duty Basket Grip 3.5" - 3.99" | Max Rated Capacity: 2940 lb. | 3.5" - 3.99" |
| SHBG-061 | 0-32886-69812-5 | 65019301 | Short Basket Grip 0.50" - 0.61" | Max Rated Capacity: 900 lb. | 0.50" - 0.61" |
| SHBG-074 | 0-32886-69813-2 | 65019401 | Short Basket Grip 0.62" - 0.74" | Max Rated Capacity: 1120 lb. | 0.62" - 0.74" |
| SHBG-099 | 0-32886-69814-9 | 65019501 | Short Basket Grip 0.75" - 0.99" | Max Rated Capacity: 1360 lb. | 0.75" - 0.99" |
| SHBG-149 | 0-32886-69815-6 | 65019601 | Short Basket Grip 1.00" - 1.49" | Max Rated Capacity: 1920 lb. | 1.00" - 1.49" |
| SHBG-199 | 0-32886-69816-3 | 65019701 | Short Basket Grip 1.50" - 1.99" | Max Rated Capacity: 3280 lb. | 1.50" - 1.99" |
| SHBG-249 | 0-32886-69817-0 | 65019801 | Short Basket Grip 2.00" - 2.49" | Max Rated Capacity: 3700 lb. | 2.00" - 2.49" |
| SHBG-299 | 0-32886-69818-7 | 65019901 | Short Basket Grip 2.50" - 2.99" | Max Rated Capacity: 4900 lb. | 2.50" - 2.99" |
| SHBG-349 | 0-32886-69819-4 | 65020101 | Short Basket Grip 3.00" - 3.49" | Max Rated Capacity: 4900 lb. | 3.00" - 3.49" |
| SHBG-399 | 0-32886-69820-0 | 65020201 | Short Basket Grip 3.50" - 3.99" | Max Rated Capacity: 6200 lb. | 3.50" - 3.99" |
| STBG-099 | 0-32886-69821-7 | 65020301 | Standard Basket Grip 0.75" - 0.99" | Max Rated Capacity: 1360 lb. | 0.75" - 0.99" |
| STBG-149 | 0-32886-69822-4 | 65020401 | Standard Basket Grip 1.00" - 1.49" | Max Rated Capacity: 1920 lb. | 1.00" - 1.49" |
| STBG-199 | 0-32886-69823-1 | 65020501 | Standard Basket Grip 1.50" - 1.99" | Max Rated Capacity: 3280 lb. | 1.50" - 1.99" |
| STBG-249 | 0-32886-69824-8 | 65020601 | Standard Basket Grip 2.00" - 2.49" | Max Rated Capacity: 3700 lb. | 2.00" - 2.49" |
| STBG-299 | 0-32886-69825-5 | 65020701 | Standard Basket Grip 2.50" - 2.99" | Max Rated Capacity: 4900 lb. | 2.50" - 2.99" |
| STBG-349 | 0-32886-69826-2 | 65020801 | Standard Basket Grip 3.00" - 3.49" | Max Rated Capacity: 4900 lb. | 3.00" - 3.49" |

CABLE PULLING


BASKET GRIPS CONTINUED

| MODEL # | UPC | STOCK # | DESCRIPTION | WORKING LOAD LBS. | CABLE DIAMETER RANGER |
|----------|-----------------|----------|--|------------------------------|-----------------------|
| STBG-399 | 0-32886-69827-9 | 65020901 | Standard Basket Grip 3.50" - 3.99" | Max Rated Capacity: 6200 lb. | 3.50" - 3.99" |
| KBG-061 | 0-32886-69828-6 | 65021001 | K- Basket Grip 0.50" - 0.61" | Max Rated Capacity: 1120 lb. | 0.50" - 0.61" |
| KBG-074 | 0-32886-69829-3 | 65021101 | K- Basket Grip 0.62" - 0.74" | Max Rated Capacity: 1360 lb. | 0.62" - 0.74" |
| KBG-099 | 0-32886-69830-9 | 65021201 | K- Basket Grip 0.75" - 0.99" | Max Rated Capacity: 1920 lb. | 0.75" - 0.99" |
| KBG-149 | 0-32886-69831-6 | 65021301 | K- Basket Grip 1.00" - 1.49" | Max Rated Capacity: 3280 lb. | 1.00" - 1.49" |
| KBG-199 | 0-32886-69832-3 | 65021401 | K- Basket Grip 1.50" - 1.99" | Max Rated Capacity: 3280 lb. | 1.50" - 1.99" |
| KBG-249 | 0-32886-69833-0 | 65021501 | K- Basket Grip 2.00" - 2.49" | Max Rated Capacity: 5440 lb. | 2.00" - 2.49" |
| KBG-299 | 0-32886-69834-7 | 65021601 | K- Basket Grip 2.50" - 2.99" | Max Rated Capacity: 6600 lb. | 2.50" - 2.99" |
| KBG-349 | 0-32886-69835-4 | 65021701 | K- Basket Grip 3.00" - 3.49" | Max Rated Capacity: 8200 lb. | 3.00" - 3.49" |
| KBG-399 | 0-32886-69836-1 | 65021901 | K- Basket Grip 3.50" - 3.99" | Max Rated Capacity: 9600 lb. | 3.50" - 3.99" |
| KBG-449 | 0-32886-69837-8 | 65022001 | K- Basket Grip 4.00" - 4.49" | Max Rated Capacity: 9600 lb. | 4.00" - 4.49" |
| KBG-499 | 0-32886-69838-5 | 65022101 | K- Basket Grip 4.50" - 4.99" | Max Rated Capacity: 9600 lb. | 4.50" - 4.99" |
| KBG-599 | 0-32886-69839-2 | 65022201 | K- Basket Grip 5.00" - 5.99" | Max Rated Capacity: 9600 lb. | 5.00" - 5.99" |
| SMBG-061 | 0-32886-69851-4 | 65023601 | Split Mesh Basket Grip 0.50" - 0.61" | Max Rated Capacity: 300 lb. | 0.50" - 0.61" |
| SMBG-074 | 0-32886-69852-1 | 65023701 | Split Mesh Basket Grip 0.62" - 0.74" | Max Rated Capacity: 360 lb. | 0.62" - 0.74" |
| SMBG-099 | 0-32886-69853-8 | 65023801 | Split Mesh Basket Grip 0.75" - 0.99" | Max Rated Capacity: 440 lb. | 0.75" - 0.99" |
| SMBG-124 | 0-32886-69854-5 | 65023901 | Split Mesh Basket Grip 1.00" - 1.24" | Max Rated Capacity: 680 lb. | 1.00" - 1.24" |
| SMBG-149 | 0-32886-69855-2 | 65024001 | Split Mesh Basket Grip 1.25" - 1.49" | Max Rated Capacity: 900 lb. | 1.25" - 1.49" |
| SMBG-174 | 0-32886-69856-9 | 65024101 | Split Mesh Basket Grip 1.50" - 1.74" | Max Rated Capacity: 1160 lb. | 1.50" - 1.74" |
| SMBG-199 | 0-32886-69857-6 | 65024301 | Split Mesh Basket Grip 1.75" - 1.99" | Max Rated Capacity: 1520 lb. | 1.75" - 1.99" |
| SMBG-249 | 0-32886-69858-3 | 65024401 | Split Mesh Basket Grip 2.00" - 2.49" | Max Rated Capacity: 1800 lb. | 2.00" - 2.49" |
| SMBG-299 | 0-32886-69859-0 | 65024501 | Split Mesh Basket Grip 2.50" - 2.99" | Max Rated Capacity: 2200 lb. | 2.50" - 2.99" |
| SMBG-349 | 0-32886-69860-6 | 65024601 | Split Mesh Basket Grip 3.00" - 3.49" | Max Rated Capacity: 2400 lb. | 3.00" - 3.49" |
| SMBG-399 | 0-32886-69861-3 | 65024701 | Split Mesh Basket Grip 3.50" - 3.99" | Max Rated Capacity: 2400 lb. | 3.50" - 3.99" |
| MBG-049 | 0-32886-69840-8 | 65022301 | Multi-Strength Basket Grip 0.25" - 0.49" | Max Rated Capacity: 1360 lb. | 0.25" - 0.49" |
| MBG-074 | 0-32886-69841-5 | 65022401 | Multi-Strength Basket Grip 0.50" - 0.74" | Max Rated Capacity: 2000 lb. | 0.50" - 0.74" |
| MBG-099 | 0-32886-69842-2 | 65022501 | Multi-Strength Basket Grip 0.75" - 0.99" | Max Rated Capacity: 2880 lb. | 0.75" - 0.99" |
| MBG-124 | 0-32886-69843-9 | 65022701 | Multi-Strength Basket Grip 1.00" - 1.24" | Max Rated Capacity: 4920 lb. | 1.00" - 1.24" |
| MBG-149 | 0-32886-69844-6 | 65022801 | Multi-Strength Basket Grip 1.25" - 1.49" | Max Rated Capacity: 6120 lb. | 1.25" - 1.49" |
| MBG-174 | 0-32886-69845-3 | 65022901 | Multi-Strength Basket Grip 1.50" - 1.74" | Max Rated Capacity: 6120 lb. | 1.50" - 1.74" |
| MBG-199 | 0-32886-69846-0 | 65023001 | Multi-Strength Basket Grip 1.75" - 1.99" | Max Rated Capacity: 9600 lb. | 1.75" - 1.99" |
| MBG-249 | 0-32886-69847-7 | 65023101 | Multi-Strength Basket Grip 2.00" - 2.49" | Max Rated Capacity: 9600 lb. | 2.00" - 2.49" |
| MBG-299 | 0-32886-69848-4 | 65023201 | Multi-Strength Basket Grip 2.50" - 2.99" | Max Rated Capacity: 9600 lb. | 2.50" - 2.99" |
| MBG-349 | 0-32886-69849-1 | 65023301 | Multi-Strength Basket Grip 3.00" - 3.49" | Max Rated Capacity: 9600 lb. | 3.00" - 3.49" |
| MBG-399 | 0-32886-69850-7 | 65023501 | Multi-Strength Basket Grip 3.50" - 3.99" | Max Rated Capacity: 9600 lb. | 3.50" - 3.99" |

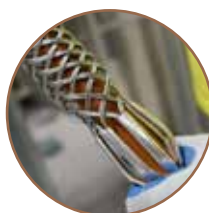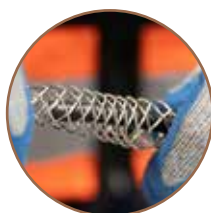

CABLE PULLING

PULLING GRIPS

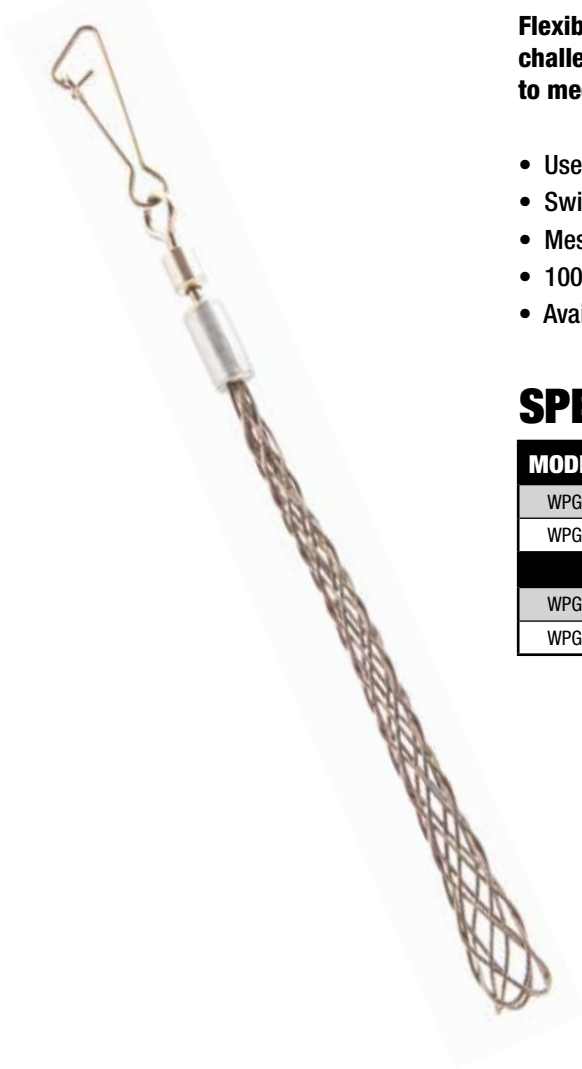

Flexible leader guides steel tapes through conduit and helps reduce the challenge of pulling wire and cable. Available in two separate grip sizes to meet your pulling requirements.

- Used to pull wire and cable through walls and conduit
- Swivel design minimizes cable twisting
- Mesh design holds wire or cable securely during pull
- 100 lb. pulling force capacity
- Available in 1/2" and 3/4" diameters

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | | |
|---------|----------|-------------------|-------|--------|----------|---------|
| WPG3/4 | 58280801 | 3/4" Pulling Grip | | | | |
| WPG1/2 | 58281001 | 1/2" Pulling Grip | | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | DIAMETER | LOAD |
| WPG3/4 | 14.25" | 0.5" | 0.5" | 2 oz. | 3/4" | 100 lb. |
| WPG1/2 | 14.25" | 0.5" | 0.5" | 2 oz. | 1/2" | 100 lb. |

CABLE PULLING

INDUSTRIAL GRIPit™ PULLING DEVICE



GRIPit™ Circuit management system can help make every branch circuit and home run pull safer, easier, and more productive.

- Reusable pulling head
- No need to strip the wire
- Low-profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Easily attach and remove wires without cutting
- Save time making pulling heads
- Usable on solid and stranded wires from sizes 14AWG to 10AWG
- Staggered lengths (6", 12", 18", 24", & 30" lengths available)

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | LANYARD LENGTH |
|---------|----------|---------------------------------------|---|
| IG-06 | 64801501 | Industrial GRIPit™ 6" Pulling Device | 6" length |
| IG-12 | 64801601 | Industrial GRIPit™ 12" Pulling Device | 12" length |
| IG-18 | 64801701 | Industrial GRIPit™ 18" Pulling Device | 18" length |
| IG-24 | 64801801 | Industrial GRIPit™ 24" Pulling Device | 24" length |
| IG-30 | 64801901 | Industrial GRIPit™ 30" Pulling Device | 30" length |
| IG-KIT | 64802001 | Industrial GRIPit™ Pulling Device Kit | Staggered lengths (6", 12", 18", 24", & 30" lengths included) |



CABLE PULLING

SIMpull™ GRIPit™ CIRCUIT SIZED PULLING HEAD

CSPH1HD



The SIMpull™ GRIPit™ circuit sized pulling head can help make every branch circuit and home run pull safer, easier, and more productive.

- Easily connects to fish tape, string, or rope
- 14 AWG - 10 AWG solid or stranded conductors
- 600 lb. pulling force
- Reusable pulling head for circuit wire
- Easily attach up to 7 wires of 10-14 AWG solid or stranded wires per pulling head
- No cutting, stripping, taping, or weaving wire to make pulling head

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | |
|---------|----------|---|---------|
| CSPH1HD | 58294505 | SIMpull™ GRIPit™ Circuit Sized Pulling Head | |
| | WIDTH | DEPTH | WEIGHT |
| CSPH1HD | 1.5" | 0.06" | 1.3 oz. |



CABLE PULLING

REEL ROLLERS

RR-SW30



WE'VE GOT IT
MADE IN AMERICA™

With its heavy-duty, all-welded construction, the Southwire RR-SW30 is built to support up to a 30,000 lb wire reel. With convenient fork tubes and lifting eyes, maneuvering the equipment around the jobsite is easy. You can now safely operate the reel roller by standing outside of the wire's path by remotely operating the unit with the hand controller with variable speed adjustment. When the job is finished and it is time to store the unit, the RR-SW30 will not take up as much room as traditional reel rollers with our new stackability feature. All that is needed for the RR-SW30 is 2" piece of rigid conduit cut to the desired length and installed in the feature. This RR-SW30 can be stacked 4 units high. For the RR-SW45 all that is needed is a 2.5" piece of rigid conduit cut to the desired length and installed in the feature. This unit can be stacked 3 units high.

- RR-SW30 handles up to 30,000 lb.
- Stackable up to 4 units for the RR-SW30
- Variable speed control
- Hand control for remote operation
- Heavy-duty 10-amp motor
- Convenient fork tubes on both sides
- Made in the USA
- Heavy-duty all welded construction

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-----------------|
| RR-SW30 | 65241740 | 30K Reel Roller |



CABLE PULLING

SIMpull™ Guidelt™ CIRCUIT ROUTER

WG01





A wire router for circuit panel and junction boxes.

- Universal adapter for hands free circuit wire feeding
- Routes circuit wire in enclosures up to 32"
- Helps to prevent any damage to wire during installation
- Reduces the need to route circuit wire into a raceway or conduit

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|----------------------------------|-------|--------|
| WG01 | 58387301 | SIMpull™ Guidelt™ Circuit Router | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| WG01 | 2.5" | 7.5" | 23" | 2 lb. |

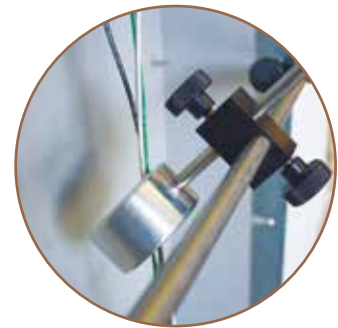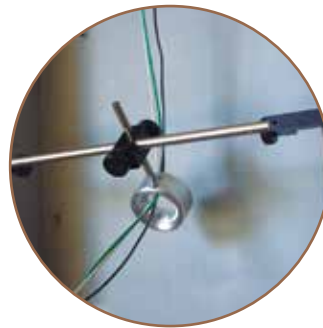

TERMINATION

The Southwire line of termination tools sets a new industry standard.

We've revolutionized these tools to make them faster, safer, and smarter than ever before. With Southwire cable stripping, cutting and crimping tools on your job site you can see an increase in safety, efficiency, and profitability.



TERMINATION

XT CABLE STRIPPER

XTS01
XTS01RB



 **WE'VE GOT IT
MADE IN AMERICA™**

The XTS-01 cable stripper is made for end and mid-span terminations of 600 volt 1/0 AWG to 1000 KCMIL or outside diameters from .33"-1.284". Works on THHN, XHHW, RHH, RHW, and USE jackets.

- Cutting depth is adjustable to precisely match insulation thickness for fast stripping while eliminating cable scoring
- Adjustable 4" depth gauge provides consistent repeatable strips
- Replaceable, precision razor sharp blade that is safely enclosed within the tool, eliminates stripping cables with a knife
- Capacity : wire 1/0 AWG (.33" in diameter) in size to 1000 KCMIL (approx. 1.284" diameter)

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---|-------|----------|
| XTS-01 | 64984901 | XT Cable Stripper | | |
| XTS01-RB | 59368901 | XTS-01 Cable Stripper Replacement Blade Kit | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| XTS-01 | 8.5" | 2.5" | 2.25" | 1.30 lb. |
| XTS01-RB | 1" | 3/8" | 3/8" | 3gm |



TERMINATION | CABLE STRIPPERS

TERMINATION

XT MINI STRIPPER

XTS02
XTS02RB



**WE'VE GOT IT
MADE IN AMERICA™**

XT Mini stripper for sizes #6 AWG through 1/0 AWG.

- For end termination on THHN/XHHW 600V insulation types
- Cutting depth is self setting to eliminate cable scoring
- Replaceable blade that is safely enclosed within the housing
- Capacity: Wire sizes #6 AWG through 1/0 AWG

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|--------|---------|
| XTS02 | 59894601 | XT Mini Stripper | | |
| XTS02RB | 59973501 | XT Mini Stripper Replacement Blade Kit | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| XTS02 | 1.2" | 1.38" | 5" | .38 lb. |
| XTS02RB | 1/2" | 1/4" | 5/16" | 2.34 gm |

XT CABLE STRIPPER COMBO KIT

XTC100



**WE'VE GOT IT
MADE IN AMERICA™**

XTC100 Combination stripper kit includes XTS01 and XTS02. Strips wire and cable from #6 AWG-1000 KCMIL.

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------------|--------|---------|
| XTC100 | 59894501 | XT Cable Stripper Combo Kit | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| XTC100 | 10" | 10" | 3" | 2.9 lb. |

CONDUIT BENDING

We don't just help you bend conduit, we change the way you do it. In addition to offering traditional conduit bending tools, Southwire has designed bending platforms that allow you to bend 1/2" to 2" EMT, IMC, and GRC conduit more efficiently, helping you do more work faster.



CONDUIT BENDING

BENDMAX™ POWER BENDER

PB2000



Power bender 3/4" - 2" EMT, IMC, GRC conduit.

- Easily adjustable to ergonomic working height
- Programmable spring back incorporated into digital readout
- Backlit digital display
- Includes free standing conduit roller support
- 3/4" - 2" EMT, IMC/GRC Conduit Bender
- 2 degree leveling adjustment
- Industrial grade DC drive, and electrical components
- Push cart mounted platform
- Total lock casters
- Large analog protractor for accurate bends
- Solid aluminum remote control pendant with quick change control cable

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|-------|--------|
| PB2000 | 59840601 | Powered Bender 3/4"- 2" EMT,IMC, GRC Conduit | | |
| | | DEPTH | WIDTH | HEIGHT |
| PB2000 | | 41" | 30" | 52" |
| | | WEIGHT | | |
| PB2000 | | 600 lb. | | |

BENDMAX™ COMPACT POWER BENDER

BML2000



Compact Power Bender for 3/4"- 2" EMT, IMC, GRC Conduit

- Bends 3/4" - 2" EMT, IMC/GRC Conduits
- Double sided shoe for EMT and IMC/GRC Conduit
- Large analog protractor for accurate bends
- Push cart mounted platform
- Industrial-grade DC drive and electrical components
- Adjustable squeeze setting for wrinkle-free bends on EMT/IMC conduit
- Durable locking casters
- Fits through finished 30" door frames
- Durable two-position hand pendant
- Solid aluminum remote control pendant with quick change control cable

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | CAPACITY | |
|---------|----------|-------------------------------|-------------------------------|---------|
| BML2000 | 64601201 | BENDMAX™ Compact Power Bender | 3/4"-2" EMT, IMC, GRC Conduit | |
| | | HEIGHT | WIDTH | DEPTH |
| BML2000 | | 42.94" | 27.125" | 29.625" |
| | | WEIGHT | | |
| BML2000 | | 500 lb. | | |

CONDUIT BENDING

BENDSTATION™ CONDUIT BENDING WORKSTATION

RB1000



**WE'VE GOT IT
MADE IN AMERICA™**



BENDSTATION™ Conduit Bending Workstation is faster, more efficient, more accurate, and much easier to use than a hand or Chicago-style bender. It's a mobile workstation that stores all the tools and conduit you need for a full day of bending.

- Measure, bend, clamp and cut at a comfortable 36" work table height for reduced labor fatigue
- More accurate measurements, bends, and cuts
- Store up to 900 feet of conduit or strut dependent on size
- Extra shelf for storage of tools and materials
- Heavy-duty casters for easy transportation and mobility
- Requires up to 40% less effort than other mechanical benders
- Built-in 60" ruler for quick and accurate measuring
- Eliminates the need to bend over to get a closer look at hand bends
- Unique speed vice designed specifically to hold conduit and unistrut, helps make cutting quicker and safer
- Speeds up the entire bending process up to 30%

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|--------|---------|
| BSCC01 | 59840701 | BENDSTATION™ GRC for 3/4" and 1" GRC and IMC | | |
| RB1000 | 59840701 | BENDSTATION™ for 3/4" and 1" GRC and IMC | | |
| MB1250 | 64795101 | BENDSTATION™ for 1" and 1.25" EMT | | |
| MB1000 | 64306901 | BENDSTATION™ for 3/4" and 1" EMT | | |
| MB750 | 58315201 | BENDSTATION™ for 1/2" and 3/4" EMT | | |
| LENGTH | | WIDTH | HEIGHT | WEIGHT |
| BSCC01 | 80" | 29" | 44" | 170 lb. |
| RB1000 | 80" | 29" | 44" | 180 lb. |
| MB1250 | 80" | 29" | 44" | 185 lb. |
| MB1000 | 80" | 29" | 44" | 150 lb. |
| MB750 | 80" | 29" | 44" | 132 lb. |

| MODEL # | STOCK # | DESCRIPTION | CAPACITY | |
|------------|----------|------------------------------------|-----------------------|--------|
| RBCCH-1000 | 64316601 | Head Kit for 3/4" - 1" GRC and IMC | 3/4" - 1" GRC and IMC | |
| MBCCH-750 | 64601001 | Head Kit for 1/2" - 3/4" EMT | 1/2" - 3/4" EMT | |
| MBCCH-1000 | 64316701 | Head Kit for 3/4" - 1" EMT | 3/4" - 1" EMT | |
| MBCCH-1250 | 64795301 | Head Kit for 1" - 1.25" EMT | 1" - 1.25" EMT | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| RBCCH-1000 | 9.20" | 17.45" | 20.80" | 80 lb. |
| MBCCH-750 | 7.60" | 16.13" | 14.87" | 32 lb. |
| MBCCH-1000 | 8.70" | 16.63" | 16.61" | 49 lb. |
| MBCCH-1250 | 10" | 12.75" | 15.23" | 86 lb. |

CONDUIT BENDING

BEND^{dolly}™ BENDING PLATFORM

BD1000R



WE'VE GOT IT
MADE IN AMERICA™



Mechanical bending platform.

- Lightweight bending platform
- Interchangeable shoe mounting plate
- Large dolly wheels for easy maneuverability
- Stable bending platform
- Interchangeable EMT shoes and IMC/GRC shoes
- Durable black powder coating for increased corrosion resistance
- Accepts four different Southwire bending shoes
- Upright storage position

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | CAPACITY | |
|---------|----------|--|--|---------|
| BD1000R | 64602501 | BEND <i>dolly</i> ™ 3/4" - 1" GRC IMC Bender | 3/4" - 1" IMC/GRC conduit | |
| BD-01 | 64601101 | BEND <i>dolly</i> ™ Bending Platform | EMT, IMC/GRC bending shoe sizes 1/2" - 1.25" | |
| BD750E | 64602301 | BEND <i>dolly</i> ™ 1/2" - 3/4" EMT Bender | 1/2" - 3/4" EMT conduit | |
| BD1000E | 64602401 | BEND <i>dolly</i> ™ 3/4" - 1" EMT Bender | 3/4" - 1" EMT conduit | |
| BD1250E | 64602401 | BEND <i>dolly</i> ™ 1" - 1.25" EMT Bender | 1" - 1.25" EMT conduit | |
| LENGTH | | WIDTH | HEIGHT | WEIGHT |
| BD1000R | 55" | 26" | 28.75" | 140 lb. |
| BD-01 | 55" | 26" | 28.75 | 60 lb. |
| BD750E | 55" | 26" | 28.75 | 92 lb. |
| BD1000E | 55" | 26" | 28.75 | 110 lb. |
| BD1250E | 55" | 26" | 28.75 | 145 lb. |

BENDING SHOE HEAD KITS

| MODEL # | STOCK # | DESCRIPTION | | CAPACITY |
|------------|----------|------------------------------|-------|-----------------|
| MBCCH-750 | 64601001 | Head Kit for 1/2"-3/4" EMT | | 1/2"-3/4" EMT |
| MBCCH-1000 | 64316701 | Head Kit for 3/4-1" EMT | | 3/4"-1" EMT |
| MBCCH-1250 | 64795301 | Head Kit for 1"-1.25" EMT | | 1"-1.25" EMT |
| RBCCH-1000 | 64316601 | Head Kit for 3/4"-1" GRC/IMC | | 3/4"-1" GRC/IMC |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| MBCCH-750 | 14.87" | 16.13" | 7.60" | 32 lb. |
| MBCCH-1000 | 16.61" | 16.63" | 8.70" | 49 lb. |
| MBCCH-1250 | 15.23" | 12.75" | 10" | 85 lb. |
| RBCCH-1000 | 20.80" | 17.45" | 9.20" | 80 lb. |

CONDUIT BENDING

1/2" TO 6" PVC MOTORIZED BENDER

PVCB-06M



6300 watts, 230 VAC, 28 Amp PVC bender.

- Motorized version that rotates PVC conduit at a constant speed for even heating and consistent results
- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome-plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---------------------------------|--------|--------|
| PVCB-06M | 64301301 | 1/2" to 6" PVC Motorized Bender | | |
| | DEPTH | WIDTH | HEIGHT | WEIGHT |
| PVCB-06M | 11.75" | 73" | 16.5" | 81 lb. |

1/2" TO 6" PVC BENDER

PVCB-06



6300 watts, 230 VAC, 28 Amp PVC bender.

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome-plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------|--------|--------|
| PVCB-06 | 64301201 | 1/2" to 6" PVC Bender | | |
| | DEPTH | WIDTH | HEIGHT | WEIGHT |
| PVCB-06 | 11.75" | 73" | 16.5" | 80 lb. |

CONDUIT BENDING

1/2" TO 4" PVC BENDER

PVCB-04



2400 watts, 120 VAC, 20 Amp PVC bender.

- Durable black powder coating for increased corrosion resistance
- Solid 6" wheels for easy maneuverability
- Chrome-plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright red indicator light to advise when unit is turned "ON"

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------|--------|--------|
| PVCB-04 | 64301101 | 1/2" to 4" PVC Bender | | |
| | DEPTH | WIDTH | HEIGHT | WEIGHT |
| PVCB-04 | 8.5" | 56" | 13" | 50 lb. |

1/2" TO 2" PVC BENDER

PVCB-02



1700 watts, 115 VAC, 15 Amp PVC bender.

- Durable black powder coating for increased corrosion resistance
- Chrome-plated reflectors for maximum reflection of infrared energy for a faster bend
- Label includes NEC bending tables
- Bright green indicator light to advise when unit is turned "ON"

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------|--------|--------|
| PVCB-02 | 64812201 | 1/2" to 2" PVC Bender | | |
| | DEPTH | WIDTH | HEIGHT | WEIGHT |
| PVCB-02 | 32" | 10" | 11" | 19 lb. |

CONDUIT BENDING

PVC HEATING BLANKET



PVCHB-13, PVCHB-30, PVCHB-38 heating blankets.

- Heats to 300° F
- Wrap blanket around PVC and easily secure with velcro strap
- Make bends, offsets or saddles in PVC
- Compact for easy storage and transport
- Power source: 120 VAC

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | WORKING LOAD |
|----------|----------|-------------------------|--------------|
| PVCHB-13 | 67589540 | PVC Heating Blanket 13" | 200 WATT |
| PVCHB-30 | 67589640 | PVC Heating Blanket 30" | 800 WATT |
| PVCHB-38 | 67589740 | PVC Heating Blanket 38" | 1300 WATT |

PVCHB13



PVCHB30



PVCHB38



CONDUIT BENDING

PLUG KITS

PVCP-01



Use with Southwire electric PVC benders and PVC heating blankets. Plugs are inserted into the ends of the PVC conduit to prevent the conduit from collapsing during heating.

- Prevents conduit from collapsing when heated
- Plug kits for all Southwire PVC conduit benders and PVC conduit heating blankets
- Rugged carrying case to store and transport plugs
- Durable long lasting neoprene gaskets
- Twist lock design for easy installation and removal
- Provides air tight seal

PVCP-02



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|---------|---------------------------|
| PVCP-01 | 643014 | 2" to 4" Bending Plug Kit |
| PVCP-02 | 643016 | 2" to 6" Bending Plug Kit |



**WE'VE GOT IT
MADE IN AMERICA™**

HOLE MAKING

Southwire has developed industry leading tools for electrical contractors, including a comprehensive line of hole making solutions. With tools ranging from cutting dies to the original drill-powered knockout punch, you can make quick, accurate holes every time with optimal efficiency.



HOLE MAKING

MAX PUNCH® XD

MPXD



Heavy-duty knockout punch driver for stainless and mild steel.

- No hydraulics, no ratcheting, no mess
- Thread-in/thread-out removable drawstuds (universal to fit most common KO dies)
- Rated to cut 10 gauge mild and stainless steel up to 4"
- Minimum drill recommendations: 18V cordless, equivalent of 550 in. lbs. torque rated

MPXD-SD

INCLUDES:

- MAX PUNCH® XD drive unit
- 1/2" – 2" MAX PUNCH® Pro cutting dies (rated for stainless steel)
- 2 drawstuds sizes 3/4" & 7/16"
- Marksman™ conduit layout tool
- Step drill bit (3/16" – 7/8", 2 nut drivers) (7/16")
- Heavy-duty carrying case

MPXD-SD



MP-03PRO

INCLUDES:

- 2 1/2" - 4" MAX PUNCH® Pro cutting dies
- 1 1/8" drawstud
- Heavy-duty carrying case

MP-03PRO



SPECIFICATIONS

| MODEL# | STOCK # | DETAILS | | |
|----------|----------|--|-------|----------|
| MPXD | 63159701 | MAX PUNCH® XD: drive unit only (no case) | | |
| MPXD-SD | 63159901 | MAX PUNCH® XD w/ stainless steel rated dies - 1/2" - 2" set (1 case) | | |
| MP-03PRO | 57177201 | MAX PUNCH® PRO STAINLESS STEEL 2 1/2" - 4" SET | | |
| MODEL# | LENGTH | WIDTH | DEPTH | WEIGHT |
| MPXD | 5.5" | 11.5" | 4.25" | 5.5 lb. |
| MPXD-SD | 16.5" | 8.5" | 13" | 14.5 lb. |
| MP-03PRO | 16.5" | 13" | 5" | 22.5 lb. |

HOLE MAKING

MAX PUNCH™ 360 HYDRAULIC KNOCKOUT TOOL

MP360HP



Heavy duty 12-ton hydraulic knockout with 360° articulation.

- Full 360° articulating head for tight spaces
- Lightweight aluminum head
- Compact pump with padded handle

SPECIFICATIONS

| MODEL# | STOCK # | DETAILS | | |
|------------|----------|--|-------|----------|
| MP360HP | 59159001 | MAX PUNCH™ 360 DRIVE UNIT ONLY | | |
| MP360SDPRO | 58973801 | MAX PUNCH™ 360 STAINLESS STEEL 1/2" - 2" SET | | |
| MP-03PRO | 57177201 | MAX PUNCH™ PRO STAINLESS STEEL SET 2 1/2" - 4" SET | | |
| MODEL# | LENGTH | WIDTH | DEPTH | WEIGHT |
| MP360HP | 4.5" | 5.25" | 3.75" | 5.5 lb. |
| MP360SDPRO | 21" | 12" | 4" | 15 lb. |
| MP-03PRO | 16.5" | 13" | 5" | 22.5 lb. |

MP360SDPRO



MP-03PRO



HOLE MAKING

MAX PUNCH™ HSP HYDRAULIC STUD PUNCH

MPHSP



4 tools in 1 and is adjustable for 3 5/8" and 6" studs, punches 7/8" or 1 11/32" holes.

- Punches holes in 16 gauge structural steel studs
- Compact design fits in tight spaces
- Padded handles provide gripping comfort and greater control
- Heavy-duty carrying case

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------------------|--------|--|
| MPHSP | 58946501 | MAX PUNCH™ Hydraulic Stud Punch | | |
| MODEL # | LENGTH | WIDTH | WEIGHT | |
| MPHSP | 17.5" | 10.5" | 11 lb. | |



HOLE MAKING

MAX PUNCH™ MANUAL STUD PUNCH

MSP01



2 tools in 1, punches 7/8" and 1 11/32" holes.

- Sizes include - 7/8" (22.5mm) & 1-11/32" (34.1mm)
- MAX PUNCH™ Manual Stud Punch is intended to punch round holes in 20 gauge steel studs
- Lock to keep handle in place when not in use
- Lightweight punch makes accurate location of holes easier
- Cushioned handle gives more leverage and makes it easier to punch in tight spaces, meaning less operator fatigue and more comfortable handling

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|------------------------------|--------|---------|
| MSP01 | 57576201 | MAX PUNCH™ MANUAL STUD PUNCH | | |
| MODEL # | HEIGHT | WIDTH | LENGTH | WEIGHT |
| MSP01 | 2.25" | 8.55" | 18.5" | 7.5 lb. |



HOLE MAKING | KNOCKOUTS

HOLE MAKING

MAX PUNCH™ RATCHET SET WITH 1/2" - 2" CUTTING DIES

MPR-01SD



Flex head ratchet wrench allows for easy maneuverability around obstacles.

- Cuts through 12 gauge mild steel as well as aluminum, fiberglass, and plastics
- Unique 3-point cup cutting surface provides a clean, quick, and easy cut for 1" through 2" dies
- Cup design creates crimping effect on slug for easy removal for 1" through 2" dies
- Ball bearing draw stud for reduced friction
- Includes Southwire Marksman® (Model # MM01) Conduit Layout Tool
- Includes 1/2", 3/4", 1", 1 1/4", 1 1/2", and 2" dies

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|--|--------|-----------|--|
| MPR-01SD | 58289240 | MAX PUNCH™ Ratchet Set with 1/2"-2" Dies | | | |
| | HEIGHT | WIDTH | LENGTH | WEIGHT | |
| MPR-01SD | 14.17" | 10.43" | 2.76" | 11.57 lb. | |

HOLE MAKING

MAX PUNCH® STAINLESS STEEL CUPS & CUTTERS

Stainless steel cups and cutters.



- Unique 3 point cutting surface provides a cleaner, quicker and easier cut for 1" through 4" dies
- Rated for 10 gauge stainless steel (3.5mm) as well as mild steel, aluminum, fiberglass and plastics
- Will not bow panel or leave jagged edges
- Crimping effect on slug for easy removal

| MODEL # | STOCK # | DESCRIPTION | CONDUIT & PIPE SIZE | ACTUAL HOLE SIZE (IN) | ACTUAL HOLE SIZE (MM) | CAPACITY S.S. GA |
|------------|----------|---|---------------------|-----------------------|-----------------------|------------------|
| MPK050PRO | 57174601 | MAX PUNCH® Cutter for Stainless Steel 1/2" | 1/2" | .89 | 23 | 10 |
| MPC50PRO | 57176101 | MAX PUNCH® Cup for Stainless Steel 1/2" | 1/2" | .89 | 23 | 10 |
| MPK075PRO | 57174701 | MAX PUNCH® Cutter for Stainless Steel 3/4" | 3/4" | 1.12 | 28 | 10 |
| MPC75PRO | 57176201 | MAX PUNCH® Cup for Stainless Steel 3/4" | 3/4" | .12 | 28 | 10 |
| MPK0100PRO | 57174801 | MAX PUNCH® Cutter for Stainless Steel 1" | 1" | 1.36 | 35 | 10 |
| MPC100PRO | 57176301 | MAX PUNCH® Cup for Stainless Steel 1" | 1" | 1.36 | 35 | 10 |
| MPK0125PRO | 57174901 | MAX PUNCH® Cutter for Stainless Steel 1 1/4" | 1 1/4" | 1.70 | 43 | 10 |
| MPC125PRO | 57176401 | MAX PUNCH® Cup for Stainless Steel 1 1/4" | 1 1/4" | 1.70 | 43 | 10 |
| MPK0150PRO | 57175001 | MAX PUNCH® Cutter for Stainless Steel 1 1/2" | 1 1/2" | 1.95 | 50 | 10 |
| MPC150PRO | 57176501 | MAX PUNCH® Cup for Stainless Steel 1 1/2" | 1 1/2" | 1.95 | 50 | 10 |
| MPK0200PRO | 57175101 | MAX PUNCH® Cutter for Stainless Steel 2" | 2" | 2.42 | 62 | 10 |
| MPC200PRO | 57176601 | MAX PUNCH® Cup for Stainless Steel 2" | 2" | 2.42 | 62 | 10 |
| MPK0250PRO | 57175301 | MAX PUNCH® Cutter for Stainless Steel 2 1/2" | 2 1/2" | 2.92 | 74 | 10 |
| MPC250PRO | 57176701 | MAX PUNCH® Cup for Stainless Steel 2 1/2" | 2 1/2" | 2.92 | 74 | 10 |
| MPK0300PRO | 57175401 | MAX PUNCH® Cutter for Stainless Steel 3" | 3" | 3.55 | 90 | 10 |
| MPC300PRO | 57176801 | MAX PUNCH® Cup for Stainless Steel 3" | 3" | 3.55 | 90 | 10 |
| MPK0350PRO | 57175501 | MAX PUNCH® Cutter for Stainless Steel 3 1/2" | 3 1/2" | 4.04 | 103 | 10 |
| MPC350PRO | 57176901 | MAX PUNCH® Cup for Stainless Steel 3 1/2" | 3 1/2" | 4.04 | 103 | 10 |
| MPK0400PRO | 57175601 | MAX PUNCH® Cutter for Stainless Steel 4" | 4" | 4.54 | 115 | 10 |
| MPC400PRO | 57177001 | MAX PUNCH® Cup for Stainless Steel 4" | 4" | 4.54 | 115 | 10 |
| MP02PRO* | 57177101 | Small Die Set 1/2"-2" in case (drive unit not included) | 1/2" – 2" | .89-2.42 | 23-62 | 10 |
| MP03PRO* | 57177201 | MAX PUNCH® PRO STAINLESS STEEL SET 2 1/2" - 4" | 2 1/2" – 4" | 2.92-4.54 | 74-115 | 10 |

HOLE MAKING | KNOCKOUTS

HOLE MAKING

MARKSMAN® CONDUIT LAYOUT TOOL

MM01



A conduit layout tool that will pinpoint a center knockout in seconds. The Marksman® Layout Tool also features a panel schedule showing the branch circuit number and its corresponding phase.

- Easy to use
- Does not require math
- For KO sizes 1/2" to 4"
- Underground and overhead
- The Southwire Marksman® conduit layout tool is constructed of tough durable anodized aluminum
- Markings are etched for maximum durability

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|------------------------------|-------|---------|----------------|
| MM01 | 58281940 | Marksman Conduit Layout Tool | | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT | KNOCKOUT SIZES |
| MM01 | 6.5" | 2" | 0.25" | 2.5 oz. | 1/2" - 4" |

HOLE MAKING

DRAW STUDS FOR MAX PUNCH® DRIVE UNITS

XDDS34
PRDS716
PRDS118
MPDS12



MAX PUNCH® PRO DRAW STUDS

- 3/4" - Main Draw Stud - Stock #64864001 Model #XDDS34
- 7/16" - Medium Draw Stud - Stock #57717901 Model #PRDS716
- 1 1/8" - Large Draw Stud (for 2 1/2" – 4" MAX PUNCH® and MAX PUNCH® PRO Dies) Stock #58306101 Model #PRDS118

MAX PUNCH® DRAW STUDS

- 3/4" - Main Draw Stud - Stock #56825901 Model #MPDS12

SPECIFICATIONS

| MODEL# | STOCK # | DESCRIPTION | LENGTH | WEIGHT | DIAMETER |
|---------|----------|--|--------|----------|--------------|
| XDDS34 | 64864001 | 3/4" MAIN DRAW STUD MAX PUNCH® PRO | 5" | 8.7 oz. | 3/4" |
| PRDS716 | 57717901 | 7/16" MEDIUM DRAW STUD - MAX PUNCH® PRO | 4.25" | 4.6 oz. | 7/16" - 3/4" |
| PRDS118 | 58306101 | LARGE DRAW STUD - 1 1/8" (FOR MILD STEEL OR STAINLESS STEEL LARGE DIES) | 4.4" | 15.6 oz. | 1 1/8" |
| MPDS12 | 56825901 | 1/2" MAIN DRAW STUD - MAX PUNCH® | 11.5" | 4.4 oz. | 15/16" |

MANUAL KNOCKOUTS

Manual knockout sets with unique 3-point cup cutting surface provide clean, quick, and easy cuts.

- Optimized design reduces wrench effort
- Unique 3-point cup cutting surface provides a clean, quick, and easy cut
- Cup design creates crimping effect on slug for easy removal



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|-----------|----------|--|
| KOKIT6 | 58297840 | Manual Knockout Kit |
| KODRAW1/2 | 58297940 | Knockout Set |
| KODRAW3/4 | 58298040 | Knockout Set |
| MODEL # | STOCK # | INCLUDES |
| KOKIT6 | 58297840 | (4) Maxis® MAX PUNCH® Cups & Cutters 1/2" to 1-1/4", (1) 7/16" Draw Stud, (1) 3/4" Draw Stud |
| KODRAW1/2 | 58297940 | (1) 1/2" Knockout Draw Stud |
| KODRAW3/4 | 58298040 | (1) 3/4" Knockout Draw Stud |

HOLE MAKING

BI-METAL HOLE SAWS

BMHSKIT9



These bi-metal hole saws are heavy duty and allow for fast cutting of steel, aluminum, brass, wood, plastic, and drywall.

- Increased plug ejection slots for easy removal of cutting materials
- Larger hole saw depth limits blocked ejection slots
- Custom steel body and M42 teeth for improved performance
- Lifetime tooth breakage warranty

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|-----------|----------|--|
| BMHSKIT9 | 58297640 | 9-Piece Bi-Metal Hole Saw Kit |
| BMHS4-3/8 | 64278140 | Bi-Metal Hole Saw 4-3/8" (111mm) (4" Recessed Lights) |
| BMHS5-3/8 | 64278240 | Bi-Metal Hole Saw 5-3/8" (137mm) (5" Recessed Lights) |
| BMHS6-3/8 | 58297540 | Bi-Metal Hole Saw 6-3/8" (162mm) (6" Recessed Lights) |
| ABS1/2 | 58295340 | Large Quick Connect Arbor |
| ABS3/8 | 64605440 | Small Arbor 3/4" to 1-1/8" |
| MODEL # | STOCK # | INCLUDES |
| BHMSKIT9 | 58297640 | (6) Bi-metal hole saws: 7/8", 1-1/8", 1-3/8", 1-3/4", 2", 2-1/2", (1) 3/8" hex shank mandrel, (1) 3/8" qck. chg. mandrel, (2) pilot bits |
| BMHS4-3/8 | 64278140 | (1) 4-3/8" Hole Saw |
| BMHS5-3/8 | 64278240 | (1) 5-3/8" Hole Saw |
| BMHS6-3/8 | 58297540 | (1) 6-3/8" Hole Saw |
| ABS1/2 | 58295340 | (1) 1/2" Arbor bit shank |
| ABS3/8 | 64605440 | (1) 3/8" Arbor bit shank |

ADJUSTABLE CAN LIGHT HOLE SAW

ACLHS



Adjustable hole saw featuring black oxide blades cleanly and efficiently cuts precise holes in drywall and ceiling tiles.

- 19 blade adjustment positions ranging from 2-1/2" to 7"
- 1/4" increments
- Black oxide blades cut cleanly through drywall and ceiling tiles
- Hex key adjustment allows for easy movement of blade
- Includes two dust shields

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-------------------------------|-------|----------|
| ACLHS | 59705440 | Adjustable Can Light Hole Saw | | |
| | | HEIGHT | WIDTH | WEIGHT |
| ACLHS | | 2.17" | 8.27" | 2.08 lb. |

HOLE MAKING

FLEX AUGER BITS

FAB9/16X54



FAB3/8X54



FAB1X54



FAB3/4X54



54" flex auger bits with screw point tips easily drill clean holes through wood inside walls.

- Pilot feed-screw draws bit into wood
- Spring steel shaft resists deformation
- Hole in tip for use with wire and cable pulling grips

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|-------------|----------|--|
| FABK9/16X54 | 58297740 | 9/16" Flex Bit Kit |
| FAB9/16X54 | 58296940 | 9/16" Flex Bit |
| FAB3/8X54 | 58296840 | 3/8" Flex Bit |
| FAB3/4X54 | 58296740 | 3/4" Flex Bit |
| FAB1x54 | 58297040 | 1" Flex Bit |
| MODEL # | STOCK # | INCLUDES |
| FABK9/16X54 | 58297740 | (1) 9/16" X 54" Flex Bit, (1) Cable Pulling Grip, (1) Folding Placement Tool |
| FAB3/8X54 | 58296840 | (1) 3/8" Flex Bit |
| FAB9/16X54 | 58296940 | (1) 9/16" Flex Bit |
| FAB3/4X54 | 58296740 | (1) 3/4" Flex Bit |
| FAB1x54 | 58297040 | (1) 1" Flex Bit |

FLEX AUGER BIT EXTENSION

FAE3/16X54



For use with bits to extend length to easily drill clean holes through wood inside walls.

- Extends auger bit lengths
- Spring steel shaft resists deformation
- 54" overall length
- Tapered back for easy bit retrieval

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|------------|----------|--------------------------|-------|---------|
| FAE3/16X54 | 59705340 | Flex Auger Bit Extension | | |
| | HEIGHT | WIDTH | DEPTH | WEIGHT |
| FAE3/16X54 | 54" | 0.91" | 0.91" | .11 lb. |

HOLE MAKING

FLEXIBLE QUICK CONNECT EXTENSION KIT

FQCKIT



Perfect for installing wire in existing walls and ceilings.

- Kit includes everything needed to drill and pull light to medium wire
- Multiple extensions can be joined for increased versatility
- Convenient 1/4" quick connect receivers
- Auger bit with self-feeding screw tip draws bit through wood
- Quick connect accepts bits up to 3/4" in diameter
- Includes:
 - (1) 1/2" O.D. pulling grip
 - (1) 18" Flexible Quick Connect Extension
 - (1) 36" Flexible Quick Connect Extension
 - (1) 3/4" x 4-1/2" auger bit

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | INCLUDES | |
|---------|-----------------|--------------------------------------|---|----------|
| FQCKIT | 59705040 | Flexible Quick Connect Extension Kit | (1) 1/2" O.D. pulling grip, (1) 18" Flexible Quick Connect Extension, (1) 36" Flexible Quick Connect Extension, and (1) 3/4" x 4-1/2" auger bit | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| FQCKIT | 59.5" Assembled | 3/4" (max bit width) | 1" | 0.66 lb. |

FLEXIBLE QUICK CONNECT EXTENSION

FQCE36



36" flexible quick change extension is perfect for installing wire in existing walls and ceilings.

- Flexible shaft allows easy access to difficult and confined areas
- Quick connect accepts bits up to 3/4" in diameter
- Multiple extensions can be joined for increased versatility
- Convenient 1/4" quick connect receivers

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|----------------------------------|-------|----------|
| FQCE36 | 59704940 | Flexible Quick Connect Extension | | |
| HEIGHT | | WIDTH | DEPTH | WEIGHT |
| FQCE36 | 36" | 1/4" (shank) | 0.86" | 0.33 lb. |

HOLE MAKING

SHIP AUGER BITS

SAB3/4X18



Heavy-duty ship auger bit, featuring a self-feeding screw tip, drills clean holes through nails, wood, vinyl, plastic, and heavy timber.

- Screw tip draws bit through wood
- Polished and coated flutes increase removal of cutting material
- 18" length allows deep drilling without an extension

SAB7/8X18



SAB1X18



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|-----------|----------|---------------------|
| SAB3/4x18 | 58295540 | 3/4" Ship Auger Bit |
| SAB7/8x18 | 58295640 | 7/8" Ship Auger Bit |
| SAB1x18 | 58295440 | 1" Ship Auger Bit |
| MODEL # | STOCK # | |
| SAB3/4x18 | 58295540 | --- |
| SAB7/8x18 | 58295640 | --- |
| SAB1x18 | 58295440 | --- |

WOOD BORING BITS

WAB3/4X4-1/2



Heavy-duty, self-feeding wood boring bits cut clean holes in wood.

- Screw tip draws bit through wood
- Polished and coated flutes increase removal of cutting material
- 4.5" length for drilling in tight spaces

WAB7/8X4-1/2



WAB1X4-1/2



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|--------------|----------|---------------------|
| WAB3/4X4-1/2 | 58296040 | 3/4" Wood Auger Bit |
| WAB7/8X4-1/2 | 58296140 | 7/8" Wood Auger Bit |
| WAB1X4-1/2 | 58295940 | 1" Wood Auger Bit |
| MODEL # | STOCK # | INCLUDES |
| WAB3/4X4-1/2 | 58296040 | (1) Wood Auger Bit |
| WAB7/8X4-1/2 | 58296140 | (1) Wood Auger Bit |
| WAB1X4-1/2 | 58295940 | (1) Wood Auger Bit |

HOLE MAKING

DRILL / TAP BITS



Our drill/tap bits feature a one-piece drill and tap design that saves time by drilling, tapping, countersinking, and deburring in one smooth operation.

- Made of high-speed steel for durability
- Tapered design prevents thread damage
- For use with steel, copper, brass, aluminum, and plastic

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---|
| CDTBKIT | 58296340 | Combination Drill and Tap Set |
| MODEL # | STOCK # | INCLUDES |
| CDTBKIT | 58296340 | (6) Drill/Tap Bits: 6-32 NC, 8-32 NC, 10-24 NC, 10-32 NC, 12-24 NC, 1/4-20 NC, (1) Quick Change Adapter |

STEP DRILL BITS

SB3/16-7/8



Step drill bits for clean hole drilling in metals.

- Laser-etched sizes for easy identification
- Tri-lobe shank reduced reduces slipping and provides a firm grip in the chuck
- Double flute design for a true, round hole every time

SB1/4-1-3/8



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|-------------|----------|-----------------------------|
| SB3/16-7/8 | 58297440 | 3/16"-7/8" Step Drill Bit |
| SB1/4-1-3/8 | 58297240 | 1/4"- 1-3/8" Step Drill Bit |
| MODEL # | STOCK # | INCLUDES |
| SB3/16-7/8 | 58297440 | (1) Step Drill Bit |
| SB1/4-1-3/8 | 58297240 | (1) Step Drill Bit |

HOLE MAKING

CARBIDE TIPPED HOLE CUTTERS



The carbide tipped hole cutters have a durable cutting design specifically for stainless steel and sheet metal.

- Precision ground teeth for fast cutting of clean, round holes
- Double helix grooves for faster starts
- Grooved edge design to prevent extended penetration

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|----------|----------|--|
| CHCKIT4 | 58295140 | Carbide Tipped Hole Cutter Kit |
| CHC7/8 | 58295040 | 7/8" Carbide Tipped Hole Cutter |
| CHC1-1/8 | 58294940 | 1-1/8" Carbide Tipped Hole Cutter |
| CHC1-3/8 | 64606940 | 1-3/8" Carbide Tipped Hole Cutter |
| MODEL # | STOCK # | INCLUDES |
| CHCKIT4 | 58295140 | (3) Carbide Tipped Hole Cutters: 7/8", 1-1/8", 1-3/8" ; (4) Pilot drill bits; (1) Allen wrench |
| CHC7/8 | 58295040 | (1) 7/8" Carbide tipped hole cutter: For use with 1/2" fittings |
| CHC1-1/8 | 58294940 | (1) 1-1/8" Carbide tipped hole cutter: For use with 3/4" fittings |
| CHC1-3/8 | 64606940 | (1) 1-3/8" Carbide tipped hole cutter: For use with 1" fittings |

MATERIAL HANDLING

As one of the most innovative tool lines in the industry, Southwire Tools and Equipment has provided material handling solutions that move material quickly, easily, and safely. With a product line that includes reel jacks, SIMpull™ CoilPAK™ carts, and Wire Wagon® carts, you can complete the job better than ever before while saving both time and energy.



MATERIAL HANDLING

SIMpull™ FLANGE

SF-01



The SIMpull™ Flange's patented shaftless design, safely allows one person to turn a wooden or plastic reel up to 34 in. and 2,000 lb. into a time saving, field-installable solution that removes the need to handle heavy jack stands. Each flange rotates independently, and allows free movement of loaded wooden or plastic reels. The SIMpull™ Flange is reusable in the field and can be installed on multiple reels throughout the jobsite.

U.S. PATENT #: US9617112

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-----------------|
| SF-01 | 64864901 | SIMpull™ FLANGE |



MATERIAL HANDLING | FLANGE

MATERIAL HANDLING

PROJAX™ REEL STANDS

MPJ01
MPJ02



A 10,000 lb. capacity portable reel stand.

- One person can easily transport through most jobsite environments
- PROJAX™ stands can lift up to 10,000 lb. as a pair (4545 kg)
- Easy adjustment for uneven surfaces on jobsite
- Axle rests on steel rollers for easy wire payoff
- Axle safety guard ensures that reel will not fall off of jack stands
- Uses an 18V cordless drill to lift wire reels
- Minimum drill recommendations: 18V cordless, equivalent of 1000 in. lb. torque rated, for reels up to 10,000 lb.
- Can be used with 1 1/4" - 3" axle
- Includes axle storage assembly



WE'VE GOT IT
MADE IN AMERICA™

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------------|----------|------------------------------|-------|--------|---------|
| MPJ01 | 58133201 | PROJAX™ Reel Stands (Single) | | | |
| MPJ02 | 58526401 | PROJAX™ Reel Stands (Pair) | | | |
| | | LENGTH | WIDTH | HEIGHT | WEIGHT |
| MPJ01 (single) | | 41" | 17" | 43" | 118 lb. |



MATERIAL HANDLING

QWIKJAX™ REEL STANDS

QJ-01



QWIKJAX™ 3,000 lb. collapsible reel stand (Single)

- 6,000 lb. capacity per pair (2727 kg)
- One person can easily transport through most jobsite environments
- Axle safety catch hook ensures that reel will not fall off of jack stands
- Axle rests on steel rollers for easy wire pay off
- Maximum reel height: up to 72" reel
- Quick folding feature for compact storage
- Sliding cradle for quick adjustments on large reels
- Easy-to-use, one person setup and operation
- Easy adjustment for uneven surfaces on jobsites

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|---------------------------------------|-----------|--------|
| QJ-01 | 64237801 | QWIKJAX™ Portable Reel Stand (Single) | | |
| | DEPTH | WIDTH | HEIGHT | WEIGHT |
| QJ-01 | 29" | 17" | 29" - 42" | 35 lb. |



MATERIAL HANDLING | REEL STANDS

MATERIAL HANDLING

MAXISJAX® REEL STANDS

MJ707



A unique reel stand that will quickly set up and lift wire reels safely and efficiently without the hassle of conventional stands.

- Easy to store and transport
- Breaks down into a compact storable tool
- Jaw clamps onto axle so that wire reels won't come off or fall over
- Multiple steel rollers make it easy for one person to roll off heavy wire
- Max lever allows one person to lift wire reels off the ground with minimal effort
- Uses either a 1-1/2" to 2" rigid pipe for an axle
- Each pair lifts wire reels up to 3,000 lb. and reels up to 48" tall

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--|--------|--------|
| MJ707 | 56824501 | MAXISJAX® - 3,000 lb. Reel Stands (Pair) | | |
| | HEIGHT | WIDTH | LENGTH | WEIGHT |
| MJ707 | 37" | 7" | 9.5" | 54 lb. |



MATERIAL HANDLING

REEL MAC™

CJ01
CJ02
CJ03



The Sumner Reel Mac™ jack stands are a heavy-duty version of the traditional reel stand with capacity up to 3,750 lbs.

- Designed for large loads up to 3,750 lbs. depending on reel stand
- Height range of 13" - 45" depending on reel stand
- Extra strength double locking pin for quick set up
- 1.5" ACME fine adjustment thread with large, convenient adjustment handle
- Designed to work with the Sumner Reel/Econo Mac Spindles

| MODEL # | STOCK # | DESCRIPTION | LOAD CAPACITY |
|--------------------------------|---------|--------------------------------|---------------|
| CJ02 | 780941 | Reel Mac™ No. 60 | 2500 lb. |
| CJ01 | 780942 | Reel Mac™ No. 70 | 2500 lb. |
| CJ03 | 780943 | Reel Mac™ No. 80 | 3750 lb. |
| OPTIONAL REEL MAC™ ACCESSORIES | | | |
| SA60 | 780229 | No. 61 Reel Mac™ Spindle (62") | 5000 lb. |
| SA70 | 780230 | No. 71 Reel Mac™ Spindle (76") | 5000 lb. |

MATERIAL HANDLING

PROJAX™ AXLES

PJA-01



PJA-02



**WE'VE GOT IT
MADE IN AMERICA™**

PROJAX™ AXLES

- Heavy duty 10,000 lb. capacity
- Low deflection high strength steel
- Available in 60" and 72" lengths

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|-----------------------------------|
| PJA-01 | 58948701 | 10,000 lb. capacity 72" reel axle |
| PJA-02 | 59161901 | 10,000 lb. capacity 60" reel axle |

PROJAX™ RISERS

PJS-01



PROJAX™ RISERS

- Enables PROJAX™ reel stands to be used with 104" reels

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|----------|---|
| PJS-01 | 58955301 | Riser attachment for PROJAX™ reel stands (Pair) |

MATERIAL HANDLING

PALLET JACKS



779765



779766

The Sumner low profile 20" or 27" pallet jack will handle heavy lifting for you with it's 2.5" low profile fork height allowing for easy engagement of most pallets.

- 6,600 lbs. weight capacity
- Three-function handle controls raising, lowering, and neutral
- Welded all-steel frame and tough powder coat finish provides maximum durability and protection
- Minimum fork height of 2.5"
- Maximum lift height of 6.25"
- 180° turning radius
- 2.5" inch low profile allows for easy engagement of pallets

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | LOAD CAPACITY |
|---------|---------|-----------------------|---------------|
| PJ27 | 779765 | 27" x 48" Pallet Jack | 6,600 lb. |
| PJ20 | 779766 | 20" x 48" Pallet Jack | 6,600 lb. |

MATERIAL HANDLING

SIMpull™ CoilPAK™ CART

CK01



**WE'VE GOT IT
MADE IN AMERICA™**

The best material handling solution for SIMpull™ CoilPAK™ Payoffs.

- Rugged transport system for (8) SIMpull™ CoilPAK™ Payoffs with an integrated pay off system
- Allows SIMpull™ CoilPAK™ Wire Payoffs to be added or changed easily without impacting other SIMpull™ CoilPAK™ Wire Payoffs
- Innovative staging springs allow you to secure and organize up to 8 wires
- Best for scenarios where conductors are frequently changing, adding or dropping
- Cart includes 8" total lock casters
- Easy to use in hallways and fits through standard doors
- Individual wire feeds similar to a wire cart

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|------------------------|--------|---------|
| CK01 | 58386901 | SIMpull™ CoilPAK™ CART | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CK01 | 52" | 24" | 90" | 178 lb. |

SIMpull™ CoilPAK™ UTILITY CART

UC100



**WE'VE GOT IT
MADE IN AMERICA™**

Multipurpose cart designed for SIMpull™ CoilPAK™ solutions.

- Can hold and transport a verity of materials, tools, supplies, and SIMpull™ CoilPAK™ Payoffs
- Ability to hold up to 8 SIMpull™ CoilPAK™ Payoffs
- Incorporated low payoff height for easy circuit wire pulling at any angle
- Compact cart design for easy storage and transport
- Cart includes 8" total lock casters

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--------------------------------|--------|---------|
| UC100 | 58617201 | SIMpull™ CoilPAK™ UTILITY CART | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| UC100 | 46" | 24" | 45" | 107 lb. |

MATERIAL HANDLING

SIMpull™ BARREL™ HAND TRUCK



The SIMpull™ BARREL™ Hand Truck makes it easy to handle and transport your SIMpull™ BARREL™ Drum.

- The SIMpull™ BARREL™ Hand Truck, when used with the SIMpull™ BARREL™ package, replaces the old wire cart and reels and the issues associated with them
- The hand truck includes a wire payoff feature, and is designed to transport the SIMpull™ BARREL™ package anywhere on the jobsite - through narrow electrical room doors, over cords on the floor or construction gravel
- Solid rubber tires for no-flat jobsite peace of mind
- Rugged steel frame with unique design

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------------------|--------|---------|
| SBT01 | 58133001 | SIMpull™ BARREL™ HAND TRUCK | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| SBT01 | 27" | 24.5" | 61" | 145 lb. |



WE'VE GOT IT
MADE IN AMERICA™

SIMpull™ BARREL™ TRIPOD



The SIMpull™ BARREL™ Tripod is a circuit wire payoff accessory used in connection with your SIMpull™ BARREL™ Drum.

- The SIMpull™ BARREL™ Tripod is a circuit wire guide that mounts easily on the rim of the SIMpull™ BARREL™
- This wire guide system provides unique means for guiding the paralleled conductors out of the barrel when it is not on the SIMpull™ BARREL™ Hand Truck

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|----------|-------------------------|--------|---------|----------------------|
| SBT02 | 58133101 | SIMpull™ BARREL™ TRIPOD | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | TAP OUTSIDE DIAMETER |
| SBT02 | 36.5" | 6.25" | 6.25" | 5.5 lb. | 4.98" |



WE'VE GOT IT
MADE IN AMERICA™

MATERIAL HANDLING

WIRE WAGON® 510

WW510



**WE'VE GOT IT
MADE IN AMERICA™**

Conduit and wire cart.

- Holds up to 14 - 2,500' spools or a combination of 2,500' and 1,000' spools
- Holds several hundred feet of conduit as well as all the additional materials and tools needed for your entire work day
- Designed with a full 24" x 60" metal top shelf for storage and assembly
- Cart includes 8" total lock casters
- 2,000 lb. capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|---------|
| WW510 | 56824801 | Wire Wagon® 510 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW510 | 60.5" | 29.5" | 46.25" | 191 lb. |

WIRE WAGON® 520

WW520



**WE'VE GOT IT
MADE IN AMERICA™**

MC cable and conduit cart.

- Holds 4 spools of 1,000' MC cable
- Allows for different sizes and colors on one rack
- Comes standard with two sets of axles for wider than normal spools
- Eliminate spool jacks and the unnecessary set up and tear down time between pulls
- Cart includes 8" total lock casters
- Holds up to 1,000 ft. of conduit or strut
- 2,000 lb. capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|---------|
| WW520 | 56825001 | Wire Wagon® 520 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW520 | 60" | 52" | 13" | 125 lb. |

MATERIAL HANDLING

WIRE WAGON® 530

WW530



Large spool cart.

- Holds 8 spools up to 16" in diameter
- Storage for extra tools, spools and materials
- Easy to load and unload
- Cart includes 8" total lock casters
- 1,000 lb. capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|---------|
| WW530 | 56825101 | Wire Wagon® 530 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW530 | 50" | 29.5" | 42" | 155 lb. |

WIRE WAGON® 535

WW535



Large capacity wire cart.

- Holds up to 20 – 500' spools of 12 AWG and 14 AWG or 6 -2500' spools of 12 AWG and 14 AWG
- Will hold up to 9 boxes of data cable or 6 - 1,000 ft. spools
- Extra storage shelf for tools, spools and materials
- Easy to load and unload, there are no axles or pins to remove
- Cart includes 8" total lock casters
- 1,000 lb. capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|---------|
| WW535 | 56825201 | Wire Wagon® 535 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW535 | 50" | 29.5" | 42" | 142 lb. |

MATERIAL HANDLING

WIRE WAGON® 538

WW538



Service cart.

- Holds up to 12 – 500' spools of 12 AWG and 14 AWG
- Constructed with 5/8" solid steel bar to support almost any combination of wire spools
- Easy movement around the jobsite
- Folds flat in seconds for minimal storage
- Great for service trucks or vans

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|----------|
| WW538 | 56825401 | Wire Wagon® 538 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW538 | 32.5" | 26.5" | 36.5" | 25.5 lb. |

WIRE WAGON® 550

WW550



Mobile print table and work station.

- No wasting time back and forth to a stationary print table
- Move your plans and materials right to the work area
- 1,000 lb. capacity
- Cart includes 8" total lock casters
- Multiple uses:
 - Mobile print table
 - Material shelf
 - Conduit rack
 - Portable work bench

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|-----------------|--------|---------|
| WW550 | 56825501 | Wire Wagon® 550 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WW550 | 54" | 32" | 42" | 180 lb. |

MATERIAL HANDLING

6 PACK MAC™ WIRE CART

PM06



 **WE'VE GOT IT
MADE IN AMERICA™**

The 6 Pack Mac™ is a compact mobile wire dispensing cart that provides convenient storage, easy maneuverability, and seamless payoff for overall convenient use.

- Stores in one-third of the space of conventional dispensers
- Reel spindles fold and lock for convenient storage
- Fits through a 30" doorway
- Two 10" wheels with one 8" locking swivel caster for easy maneuverability
- Welded wire guides for easy payoff
- Stores up to (6) 2,500' spools (18" diameter) of wire

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|---------|-----------------------|--------|--------|--|
| PM06 | 783350 | 6 PACK MAC™ Wire Cart | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| PM06 | 28.75" | 39.5" | 31.5" | 81 lb. | |

10 PACK MAC™ WIRE CART

PM10



 **WE'VE GOT IT
MADE IN AMERICA™**

The 10 Pack Mac™ is a mobile wire dispensing cart that provides convenient storage, easy maneuverability, and seamless payoff for overall convenient use.

- Handle/guide loop position controlled by plunger: 4-positions, no loose parts
- Spindles fold up & lock
- Mast swivels 360 degrees, but can be locked in fixed positions
- Mast may be removed for compact storage
- 4-heavy duty, locking 8" swivel casters
- Feed handle and guide loops are built into one part

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|---------|---------|------------------------|--------|---------|--|
| PM10 | 783366 | 10 PACK MAC™ Wire Cart | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| PM10 | 33" | 41" | 56.5" | 250 lb. | |

MATERIAL HANDLING

CADDY MAC™ #1 DOLLY

CM01



WE'VE GOT IT
MADE IN AMERICA™

Transports spools on spindles and works as a dolly. Wire is dispensed while laying flat.

- 1/2" solid spindles are attached to cart
- No loose pieces. Spindles lock into place, even during transport
- Spindles swing out to set position for convenient loading of wire spools
- Can be used with Handi Mac for extra storage

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------------|--------|--------|
| CM01 | 783398 | CADDY MAC™ #1 Dolly | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CM01 | 20" | 26" | 49" | 50 lb. |

CADDY MAC™ #2 DOLLY

CM02



WE'VE GOT IT
MADE IN AMERICA™

CADDY MAC™ #2 Dolly holds 16 spools of #10 AWG or 24 spools of #12 AWG.

- Spindles can be easily removed for the occasional use of larger spools
- Inner spindles store in special loops which can hold four pieces and will not fall out during transportation
- Hinge design allows easy access to all spools for wire dispensing and folds for compact storage

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------------|--------|--------|
| CM02 | 783395 | CADDY MAC™ #2 Dolly | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CM02 | 14" | 26" | 49.5" | 63 lb. |

MATERIAL HANDLING

CADDY MAC™ #3 DOLLY

CM03



CADDY MAC™ #3 Dolly is a versatile wire cart that doubles as a dolly.

- Uses five 5/8" diameter spindles
- Unique spindle locking system, no loose clips
- Storage loops retain up to 5 spindles
- Dual wire guides
- Large spool capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------------|--------|--------|
| CM03 | 783400 | CADDY MAC™ #3 Dolly | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CM03 | 21.5" | 26.5" | 47.25" | 78 lb. |



SPOOL MAC™ CART

SM-01



Wire payoff cart.

- All steel frame construction
- 10" wheels for easy transport over rough terrain
- Rollers on spool arm allow for smooth reel rotation and easy payoff
- No loose pieces to account for
- Folding design allows for compact storage
- Fits through 32" doorways
- 350 lb. (160 kg) load capacity

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|-----------------|--------|--------|
| SM-01 | 783444 | SPOOL MAC™ Cart | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| SM-01 | 16" | 31.5" | 63.5" | 80 lb. |



MATERIAL HANDLING

HANDI MAC™

HM-01



Wire dispenser.

- Provides extra spool storage for CADDY MAC™ #1 or as a free standing wire dispenser
- Holds up to 8 additional spools
- Spindles are made of sturdy 3/8" steel bar

SPECIFICATIONS


| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------------------|--------|---------|
| HM-01 | 783490 | HANDI MAC™ Wire Dispenser | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| HM-01 | 22.5" | 12.5" | 10" | 7.5 lb. |

WIRESMART™ HAND CADDY

MH8110



MH8120

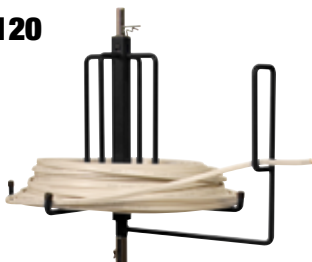

MH8010



MH8110 - Cable Dispenser

- Includes 2-brackets to mount to floor or stud
- Versatility of 3 items in 1
- Square-tube steel with a premium powder coat finish
- Convenient carry handle included
- Max weight: 50 lb. with arm, 100 lb. with reel

MH8120 - Cable Dispenser Add-On

- Mounts to cable dispenser MH8110 (sold separately)
- Stacks easily, no tools required
- Allows for double the capacity
- Inside capacity: 5.5" min. inside coil diameter
- Outside capacity: 17" min. outside coil diameter
- Max weight (separate unit): 50 lb.

MH8010 - Hand Caddy

- Convenient hand carrying design
- Square-tube steel with a premium powder coat finish
- Shipped knocked down, takes up less shelf space
- Convenient one hand portability

SPECIFICATIONS

| MODEL # | DESCRIPTION | INSIDE CAPACITY | OUTSIDE CAPACITY | MAX WEIGHT |
|---------|------------------------|-------------------------------------|--|--------------------------------------|
| MH8110 | Cable Dispenser | 5.5" Min. Inside Coil Diameter | 17" Min. Outside Coil Diameter | 50 lb. W/Arms, 100 lb. W/Reel |
| MH8120 | Cable Dispenser Add-On | 5.5" Min. Inside Coil Diameter | 17" Min. Outside Coil Diameter | 50 lb. Each Dispenser, 100 lb. Total |
| MH8010 | Hand Caddy | 8 Max. Spools 7" Diameter X 5" Wide | 4 Max. Spools 7" Diameter X 6-10" Wide | -- |

MATERIAL HANDLING

MAC RACK I™ & MAC RACK II™



MRACKI

Sumner Mac Rack™ carts are mobile jobsite and conduit and pipe storage carts.

- 1,000 lbs. weight capacity
- Double wall square tubing
- Eight storage sections
- Arms fold easily with plunger pins for compact storage
- Shipped assembled with 6" heavy-duty casters
- Durable powder coat finish
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Mac Rack II™ cart has a mesh deck for material storage

MRACKII



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | LOAD CAPACITY |
|---------|---------|-----------------------------|---------------|
| MRACKI | 783317 | Mac Rack I™ | 1,000 lb. |
| MRACKII | 783299 | Mac Rack II™ with Mesh Base | 1,000 lb. |



MATERIAL HANDLING

HANGER MAC™

HMACII



The Sumner Hanger Mac™ cart is a patented pipe hanger and transportation solution.

- Eliminates multiple handling and reduces fabrication transport costs
- Available with or without wire mesh base
- Hanger Mac™ cart holds (40) 6-8" and (120) 2-4" pipe hangers
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Folds for compact storage and transportation without tools

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION |
|---------|---------|-------------------------------|
| HMACI | 785650 | HANGER MAC™ without mesh base |
| HMACII | 785651 | HANGER MAC™ with mesh base |



MATERIAL HANDLING

PIPE MAC™

PMAC



The Sumner Pipe Mac™ cart is purposely built to transport large pipes and pipe bundles.

- Transports 2,000 lbs. of pipe individually or up to a height of 34"
- Six 6" heavy-duty casters
- Removable posts for compact storage
- Stacks when not in use
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Includes Vee Attachment to prevent pipe from rolling when in motion
- Vee Attachment easily slips over the four post holders – no tools required

PMACVEE



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | LOAD CAPACITY |
|--------------------|---------|-------------------------------|---------------|
| PMAC | 783230 | PIPE MAC™ w/Vee | 2,000 lb. |
| OPTIONAL ACCESSORY | | | |
| PMACVEE | 783240 | Pipe Mac™ Vee Attachment only | --- |

BUNDLE MAC™

BMAC



The Sumner Bundle Mac™ cart is designed to transport large quantities of conduit, strut, threaded rod, PVC pipe or copper tubing in one large cradle.

- Arms fold easily with plunger pins for compact storage
- 1,000 lbs. load capacity
- Patented stacking feature: Stack similar carts together or with other Stacking Mac carts
- Shipped assembled with 6" heavy-duty casters

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | LOAD CAPACITY |
|---------|---------|-------------|---------------|
| BMAC | 783320 | BUNDLE MAC™ | 1,000 lb. |

MATERIAL HANDLING

STOR MAC™ STORAGE CABINETS

SM30



Security storage cabinet.

- Steel wire mesh
- Four 6" heavy duty casters (standard)
- For high visibility storage
- Removable shelves for adjustable storage
- Lockable doors
- Load capacity 1,500 lb.

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|--------------|--------|---------|
| SM30 | 785920 | STOR MAC™ 30 | | |
| SM48 | 785921 | STOR MAC™ 48 | | |
| SM60 | 784920 | STOR MAC™ 60 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| SM30 | 33.75" | 31.5" | 58" | 210 lb. |
| SM48 | 33.75" | 51.5" | 58" | 310 lb. |
| SM60 | 33.75" | 63.5" | 58" | 345 lb. |

SM48



SM60



WE'VE GOT IT
MADE IN AMERICA™

MATERIAL HANDLING

KNOCK DOWN STOR MAC™ STORAGE CABINET

KDSM-60



A collapsible security storage cabinet for those who require high visibility of contents.

- Quickly collapses and assembles in under 5 minutes
- Four 6" heavy duty casters (standard)
- Reinforced frame and door
- Removable shelves for adjustable storage
- Load capacity 1,500 lb.
- Lockable doors work with puck or pad locks

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|----------------------|--------|---------|
| KDSM-60 | 786920 | Knock Down STOR MAC™ | | |
| | HEIGHT | WIDTH | LENGTH | WEIGHT |
| KDSM-60 | 58.5" | 62.5" | 32" | 425 lb. |



**WE'VE GOT IT
MADE IN AMERICA™**



MATERIAL HANDLING | KD STOR MAC™

MATERIAL HANDLING

TAINER MAC™ 60

TMAC60



A mobile, heavy-duty stacking container.

- Transports 1,500 lb. / 680 kg of material
- Large storage capacity
- Four 6" heavy-duty lockable casters
- Posts for stacking & steering
- Fits through 36" (91 cm) doorway
- Stacks with other Sumner Stacking Macs

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|----------------|--------|---------|
| TMAC60 | 784990 | TAINER MAC™ 60 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| TMAC60 | 56" | 32" | 40" | 200 lb. |



MATERIAL HANDLING

WELDBOX™ 3617

WB3617



The ideal storage chest for all welders & electricians.

- Two-point latching system requires only one lock
- Caster ready
- 16-gauge steel construction
- Powder coat finish for superior durability and corrosion resistance

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------|--------|----------|
| WB3617 | 779928 | WELDBOX™ 3617 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WB3617 | 22.5" | 36" | 17" | 97.9 lb. |

WELDBOX™ 2008

WB2008



Tool storage box.

- Powder coat finish for superior durability and corrosion resistance

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------|--------|----------|
| WB2008 | 779910 | WELDBOX™ 2008 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WB2008 | 9.5" | 20.125" | 8.5" | 12.1 lb. |

WELDBOX™ 3010

WB3010



Storage box.

- 16-gauge steel construction
- Powder-coat finish for superior durability and corrosion resistance

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|---------|---------------|--------|----------|
| WB3010 | 799910 | WELDBOX™ 3010 | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| WB3010 | 29.5" | 13.5" | 10" | 30.4 lb. |

MATERIAL HANDLING

BI-FOLD CABINET

CB603065



Photography may not represent actual product.



Bi-fold cabinet gives you unrestricted access to your tools with heavy-duty shelves and a single locking point.

- Recessed lock housing for protection against theft with one-time lock installation
- Powder coat finish for superior durability and corrosion resistance
- Heavy duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|-----------------|--------|---------|--|
| CB603065 | 59822701 | Bi-Fold Cabinet | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| CB603065 | 62.5" | 30" | 63.5" | 503 lb. | |

TWO DOOR CABINET

CB602460



Photography may not represent actual product.



Two door cabinet gives you two ways to store your tools. With heavy-duty shelves and a large vertical storage area, you can easily organize and secure your tools.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|------------------|--------|---------|--|
| CB602460 | 59822801 | Two Door Cabinet | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| CB602460 | 60.125" | 24.25" | 60.75" | 366 lb. | |

MATERIAL HANDLING

PIANO BOX

PB603049



Photography may not represent actual product.



Piano boxes offer, at a glance, storage for both small and large tools, making it possible to organize and secure your livelihood, save time, and reduce costs on the jobsite.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|-------------|--------|---------|--|
| PB603049 | 59822401 | Piano Box | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| PB603049 | 30" | 60" | 48.5" | 337 lb. | |

PIANO BOX

PB483048



Photography may not represent actual product.

Piano boxes offer, at a glance, storage for both small and large tools, making it possible to organize and secure your livelihood, save time, and reduce costs on the jobsite.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | | |
|----------|----------|-------------|--------|---------|--|
| PB483048 | 59822301 | Piano Box | | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT | |
| PB483048 | 30" | 48" | 48" | 287 lb. | |

MATERIAL HANDLING

PIANO BOX

PB603034



Photography may not represent actual product.



Piano boxes offer, at a glance, storage for both small and large tools, making it possible to organize and secure your livelihood, save time, and reduce costs on the jobsite.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|-------------|--------|---------|
| PB603034 | 59822201 | Piano Box | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| PB603034 | 30" | 60" | 34" | 282 lb. |

FIELD OFFICE

F0604482



Photography may not represent actual product.



Field office offers a large workstation with shelved storage and a single locking point, allowing you to control and secure any jobsite.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included
- Adjustable and removable split shelves let you organize your storage in the lower cabinets
- Dual gas springs for smooth, one-handed lift, one spring locks securely in place

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|--------------|--------|---------|
| F0604482 | 59822501 | Field Office | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| F0604482 | 63.5" | 42.5" | 80" | 772 lb. |

MATERIAL HANDLING

COMPACT CHEST

CC482423



Photography may not represent actual product.

Compact chest is a highly mobile storage vault. With the perfect profile for a truck bed and steel fork lift skids, this box will become your workhorse.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder-coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|----------|---------------|--------|---------|
| CC482423 | 59822601 | Compact Chest | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CC482423 | 48" | 24" | 27.75" | 170 lb. |

MINI COMPACT CHEST

CC191932



Photography may not represent actual product.

Mini compact chest is a highly mobile storage solution that stores easily in about any location.

- Recessed lock housing for protection against theft with one-time lock installation
- Four-way skids allow access from any side, making it easier and faster to transport
- Powder-coat finish for superior durability and corrosion resistance
- Caster-ready 7 gauge steel skids
- Heavy-duty 16 gauge box construction
- Welded shelves
- Heavy-duty hinges to resist break in
- Casters not included

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|----------|---------|--------------------|--------|--------|
| CC191932 | 6303601 | Mini Compact Chest | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| CC191932 | 31" | 18" | 17.5" | 82 lb. |

MATERIAL HANDLING

TWO SHELF UTILITY CARTS

UCTS-LG



Designed to help make transporting materials and items around the job site easier and more efficient.

- 550 lb. load capacity
- Handle includes built in storage for nuts, bolts, screws, and other small items

UCTS-SM



SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|---------|----------|--------------------|--------|--------|
| UCTS-LG | 65240240 | Large Utility Cart | | |
| UCTS-SM | 65240340 | Small Utility Cart | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| UCTS-LG | 46.75" | 25.5" | 33.5" | 45 lb. |
| UCTS-SM | 40.7" | 16.9" | 33.5" | 33 lb. |

MATERIAL HANDLING

CARTLOCKER™ KITS

UCLX-LG



Make your Southwire two shelf utility cart a mobile lockable storage solution with Southwire's CartLocker™ Kits. Specifically designed to fit and install to your Southwire utility cart easily and keep items safe, secure, and out of sight.

- Designed to fit Southwire's large and small two shelf utility carts
- Keep items safe, secure, and out of sight
- Heavy-duty powder coated steel panels and door
- Lockable door works with puck and pad locks
- No drilling required. Easily install CartLocker™ Kit using pre-existing holes in utility cart
- Xtreme™ option has accessories including 2 bolt on trays, 2 large hooks, and 2 small hooks

SPECIFICATIONS

| MODEL # | STOCK # | DESCRIPTION | | |
|-----------|----------|---|--------|---------|
| UCLX-LG | 66101840 | CartLocker™ Xtreme™ Large Kit | | |
| UCLX-SM | 66222140 | CartLocker™ Xtreme™ Small Kit | | |
| UC-LGCL | 66321440 | CartLocker™ Large Kit | | |
| UC-SMCL | 66351740 | CartLocker™ Small Kit | | |
| TSUCLX-LG | 66777440 | Large Utility Cart with CartLocker™ Xtreme™ Large Kit | | |
| TSUCLX-SM | 66149040 | Small Utility Cart with CartLocker™ Xtreme™ Small Kit | | |
| TSUCL-LG | 66149640 | Large Utility Cart with CartLocker™ Large Kit | | |
| TSUCL-SM | 66159540 | Small Utility Cart with CartLocker™ Small Kit | | |
| LHCL | 66165240 | Large Hooks for CartLocker™ (2 pack) | | |
| SMCL | 66179340 | Small Hooks for CartLocker™ (2 pack) | | |
| SCDTCL-LG | 66183540 | Spray Can and Drill Holder Tray for Large CartLocker™ | | |
| SCDTCL-SM | 66185040 | Spray Can and Drill Holder Tray for Small CartLocker™ | | |
| THTCL-LG | 66186840 | Tool Holder Tray for Large CartLocker™ | | |
| THTCL-SM | 66201540 | Tool Holder Tray for Small CartLocker™ | | |
| | LENGTH | WIDTH | HEIGHT | WEIGHT |
| UCLX-LG | 35" | 19" | 4.5" | 60 lb. |
| UCLX-SM | 28" | 19" | 4.5" | 51 lb. |
| UC-LGCL | 35" | 19" | 4.5" | 52 lb. |
| UC-SMCL | 28" | 19" | 4.5" | 42 lb. |
| TSUCLX-LG | 46.75" | 25.5" | 33.5" | 105 lb. |
| TSUCLX-SM | 40.7" | 16.9" | 33.5" | 84 lb. |
| TSUCL-LG | 46.75" | 25.5" | 33.5" | 97 lb. |
| TSUCL-SM | 40.7" | 16.9" | 33.5" | 75 lb. |
| LHCL | 1" | 5" | 10.5" | .4 lb. |
| SMCL | 1" | 3.5" | 6" | .2 lb. |
| SCDTCL-LG | 3.75" | 16" | 1" | 2.4 lb. |
| SCDTCL-SM | 3.5" | 9.5" | 1" | 1.5 lb. |
| THTCL-LG | 3.5" | 16" | 3" | .8 lb. |
| THTCL-SM | 3" | 9.5" | 3" | .5 lb. |

NOTES

NOTES

NOTES

NOTES



Southwire™

TOOLS & EQUIPMENT CATALOG

get social with us:



/SOUTHWIRETOOLS



/SOUTHWIRE-COMPANY



@SOUTHWIRETOOLS



@SOUTHWIRE



SCAN TO LEARN MORE

WWW.SOUTHWIRE.COM | 1-855-SWT00LS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/®- Trademark or Registered Trademark of Southwire Company.

SOFTWEAR-TOOLS & EQUIPMENT-GATALOG-SOUTH-E-GOIN-1-85-SWTOOLS

